



4" SQUARE OUTLET BOXES – 18.0 CUBIC INCH CAPACITY
1 1/4" DEEP – FOR CONDUIT

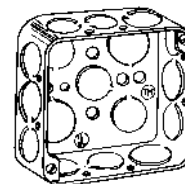


TP408

Product Number	Bracket	Description	KNOCKOUTS		Std. Unit Pkg.	Wt. Lbs. Per 100
			Sides	Bottom		
TP408	—	Drawn	12-1/2"	5-1/2"	50	61


4" SQUARE OUTLET BOXES – 22.0 CUBIC INCH CAPACITY (WELDED)† 1½" DEEP – FOR CONDUIT 21.0 CUBIC INCH CAPACITY (DRAWN)

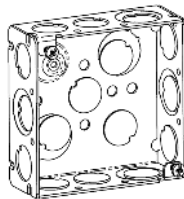


TP404/TP404PF

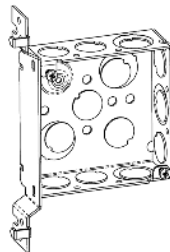


TP425

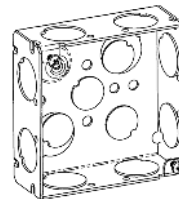


TP467

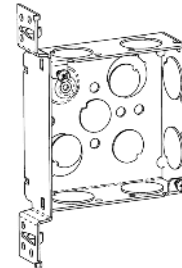


TP469

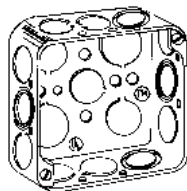


TP830*

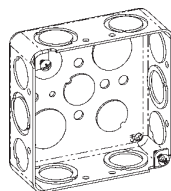


TP405

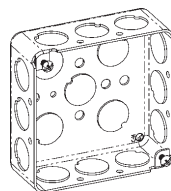


TP410

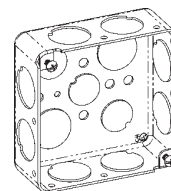


TP412
TP839*

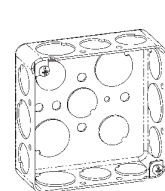

TP414

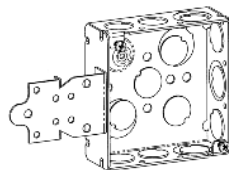

TP418

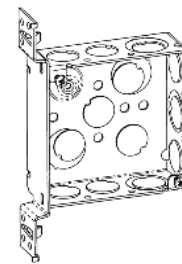

TP423

* For Air Plenum (No Mounting Holes)

Product Number	Metal Stud Sizes	Bracket	Description	KNOCKOUTS		Std. Unit Pkg.	Wt. Lbs. Per 100
				Sides	Bottom		
TP404	—	—	Welded	8-1/2", 4-1/2" + 3/4" E	2-1/2", 2-1/2" + 3/4" E	50	72
TP404PF*	—	—	Welded	8-1/2", 4-1/2" + 3/4" E	2-1/2", 2-1/2" + 3/4" E	50	72
TP425	—	"VP"	Welded	6-1/2", 3-1/2" + 3/4" E	2-1/2", 2-1/2" + 3/4" E	25	82
TP423	All	"VMS"	Welded	6-1/2", 3-1/2" + 3/4" E	2-1/2", 2-1/2" + 3/4" E	25	81
TP405	—	—	Drawn	4-1/2", 6-1/2" & 3/4"-C	3-1/2", 2-3/4"	50	67
TP410	—	—	Drawn	12-1/2"	5-1/2"	50	67
TP412	—	—	Drawn	8-3/4"	3-1/2", 2-3/4"	50	67
TP414	—	—	Drawn	8-1/2", 4-3/4"	3-1/2", 2-3/4"	50	67
TP418	—	"F", Set Flush	Welded	6-1/2", 3-1/2" + 3/4" E	2-1/2", 2-1/2" + 3/4" E	25	84
TP467	—	—	Welded	8-3/4"	2-1/2", 2-1/2" + 3/4" E	50	72
TP469	ALL	"VMS"	Welded	6-3/4"	2-1/2", 2-1/2" + 3/4" E	25	81
Air Plenum							
TP830*	—	—	Drawn	8-1/2", 4-3/4"	3-1/2", 2-3/4"	50	72
TP839*	—	—	Drawn	8-3/4"-C	3-1/2", 2-3/4"	50	72


† All welded 4" square outlet boxes have a raised dimple for ground screw

* TP404PF includes ground screw with pigtail lead


4" SQUARE OUTLET BOXES – 22.0 CUBIC INCH CAPACITY

1½" DEEP


FOR NONMETALLIC CABLE – CLAMPS IN EACH END

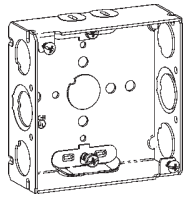


TP444

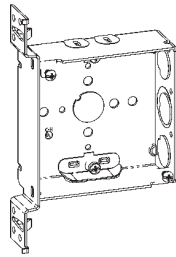

TP449

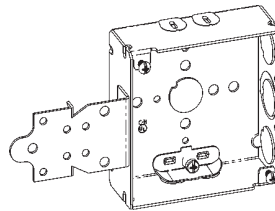

TP446

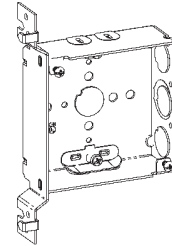


TP445

Product Number	Bracket	Description	KNOCKOUTS		Std. Unit Pkg.	Wt. Lbs. Per 100
			Sides	Bottom		
TP449	"VMS"	Welded	4-Cable, 2-½", 1-½" & ¾"-E	1-½"	25	85
TP444	—	Welded	4-Cable, 4-½", 2-½" & ¾"-E	1-½"	50	77
TP446	"F", Set Flush	Welded	4-Cable, 2-½", 1-½" & ¾"-E	1-½"	25	88
TP445	"VP"	Welded	4-Cable, 2-½", 1-½" & ¾"-E	1-½"	25	85


4" SQUARE OUTLET BOXES – 22.0 CUBIC INCH CAPACITY

1½" DEEP


FOR ARMORED & METAL CLAD (MCI) CABLE – CLAMPS IN EACH END

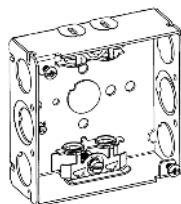


TP454

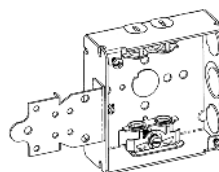

TP456

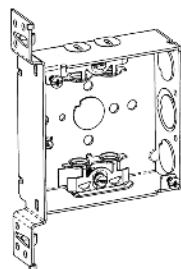


TP459

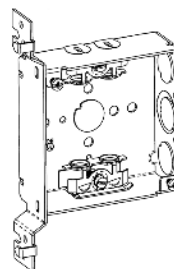


TP461

Product Number	Metal Stud Sizes	Bracket	Description	KNOCKOUTS		Std. Unit Pkg.	Wt. Lbs. Per 100
				Sides	Bottom		
TP459	All	"VMS"	Welded	4-Cable, 2-½", 1-½" & ¾"-E	1-½"	25	89
TP454	—	—	Welded	4-Cable, 4-½", 2-½" & ¾"-E	1-½"	50	81
TP456	—	"F", Set Flush	Welded	4-Cable, 2-½", 1-½" & ¾"-E	1-½"	25	92
TP461	—	"VP"	Welded	4-Cable, 2-½", 1-½" & ¾"-E	1-½"	25	89


4" SQUARE OUTLET BOXES – 30.3 CUBIC INCH CAPACITY 2 1/8" DEEP WITH CONDUIT KOs

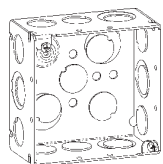


TP403/TP403PF

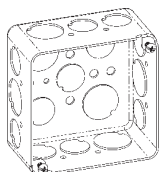


TP434

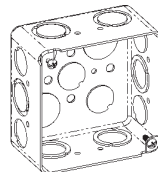


TP438
TP831*

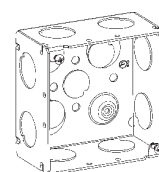

TP432
TP436
TP840*

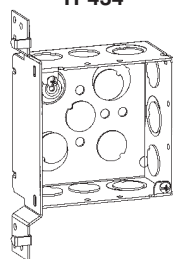

TP437

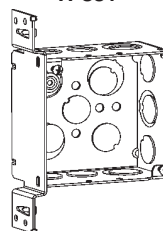


TP451

* For Air Plenum (No Mounting Holes)


Product Number	Bracket	Description	KNOCKOUTS		Std. Unit Pkg.	Wt. Lbs. Per 100
			Sides	Bottom		
TP403	—	Welded	8-1/2", 4-1/2" & 3/4"-E	2-1/2", 2-1/2" & 3/4"E	25	84
TP403PF†	—	Welded	8-1/2", 4-1/2" & 3/4"-E	2-1/2", 2-1/2" & 3/4"E	25	84
TP432	—	Welded	8-3/4"	2-1/2", 2-1/2" & 3/4"E	25	84
TP436	—	Welded	8-1"	2-1/2", 2-1/2" & 3/4"E	25	84
TP434	—	Drawn	8-1/2", 4-3/4"	3-1/2", 2-3/4"	25	84
TP438	—	Drawn	4-1/2", 6-1/2" & 3/4"-C	3-1/2", 2-3/4"	25	84
TP451	"VMS"	Welded	6-1/2", 3-1/2" & 3/4"-E	2-1/2", 2-1/2" & 3/4"E	25	96
TP437	"VP"	Welded	6-1/2", 3-1/2" & 3/4"-E	2-1/2", 2-1/2" & 3/4"E	25	98
Air Plenum						
TP831*	—	Drawn	8-1/2", 4-3/4"	3-1/2", 2-3/4"	25	90
TP840*	—	Drawn	8-3/4"	3-1/2", 2-3/4"	25	90

† TP403PF includes ground screw with pigtail lead

2 1/8" DEEP – 30.3 CUBIC INCH CAPACITY FOR NONMETALLIC CABLE CLAMPS

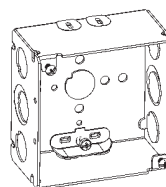

TP450

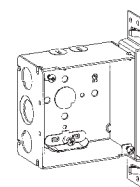


TP452

Product Number	Bracket	Description	KNOCKOUTS		Std. Unit Pkg.	Wt. Lbs. Per 100
			Sides	Bottom		
TP450	—	Welded	4-Cable, 4-1/2", 2-1/2" & 3/4"-E	1-1/2"	25	90
TP452	"VMS"	Welded	4-Cable, 2-1/2", 1-1/2" & 3/4"-E	1-1/2"	25	104


4" SQUARE OUTLET BOXES 30.3 CUBIC INCH CAPACITY

2 1/8" DEEP

FOR ARMORED & METAL CLAD (MCI) CABLE – CLAMPS IN EACH END

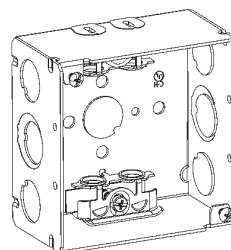

TP431

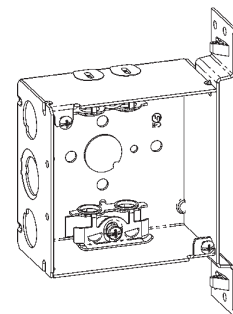


TP440

Product Number	Metal Stud Sizes	Bracket	Description	KNOCKOUTS		Std. Unit Pkg.	Wt. Lbs. Per 100
				Sides	Bottom		
TP431	—	—	Welded	4-Cable, 4-1/2", 2-1/2" & 3/4"-E	1-1/2"	25	91
TP440	All	"VMS"	Welded	4-Cable, 2-1/2", 1-1/2" & 3/4"-E	1-1/2"	25	103

4" SQUARE TWO-DEVICE BOXES – 30.3 CUBIC INCH CAPACITY

2 1/8" DEEP

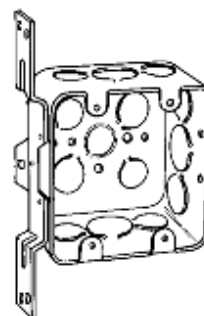

TP391




TP393, TP395

Product Number	Bracket	Description	KNOCKOUTS		Std. Unit Pkg.	Wt. Lbs. Per 100
			Sides	Bottom		
TP391	"VS"	Drawn	6-1/2", 3-3/4"	3-1/2", 2-3/4"	25	95
TP393	—	Drawn	12-1/2"	3-1/2", 2-3/4"	25	84
TP395	—	Drawn	8-1/2", 4-3/4"	3-1/2", 2-3/4"	25	84


CP Steel Square Boxes & Covers

CP Steel Boxes


4" SQUARE EXTENSION RINGS – 21.0 CUBIC INCH CAPACITY 1½" DEEP WITH CONDUIT KNOCKOUTS

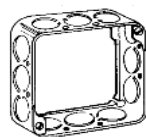


TP424

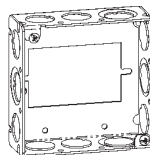

TP422

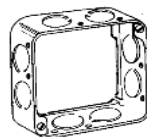

TP426

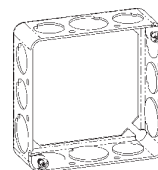

TP428,
TP833*, TP841*

* For Air Plenum (No Mounting Holes)

Product Number	KNOCKOUTS		Std. Unit Pkg.	Wt. Lbs. Per 100
	Sides	Bottom		
TP424	12-½"	—	50	46
TP422	8-½", 4-½" + ¾" E	—	50	50
TP426	8-¾"	—	50	46
TP428	8-½", 4-¾"	—	50	46

Air Plenum

TP833*	8-½", 4-¾"	—	50	48
--------	------------	---	----	----

2½" DEEP WITH CONDUIT KNOCKOUTS

Air Plenum


TP841*	8-½", 4-¾"	—	25	66
--------	------------	---	----	----

Note: TP833 and TP841 require the use of TP854, purchased separately.




4" SQUARE BRACKETED OUTLET BOXES

 
BRACKETED BOXES OFFER QUICK AND EASY INSTALLATION ONTO EITHER SIDE OF A STEEL STUD. FOR USE WITH CONDUIT, ARMORED/METAL CLAD CABLE OR NON-METALLIC SHEATHED CABLE.




TP404SSB

 


TP444SSB

 


TP454SSB

 


TP403SSB

 

TP450SSB

 

TP431SSB

 

TP563SSB

Catalog Number	Box Size	Box Depth	For Use With	Cubic Inch Capacity	Description	Bottom
TP404SSB	4"	1-½"	Conduit	22.0	8-½", 4-½" & ¾" E	2-½", 2-½" & ¾" E
TP444SSB	4"	1-½"	Non-metallic Sheathed Cable	22.0	4 Cable, 4-½", 2-½" & ¾" E	1-½"
TP454SSB	4"	1-½"	Armored/Metal Clad Cable	22.0	4 Cable, 4-½", 2-½" & ¾" E	1-½"
TP403SSB	4"	2-½"	Conduit	30.3	8-½", 4-½" & ¾" E	2-½", 2-½" & ¾" E
TP450SSB	4"	2-½"	Non-metallic Sheathed Cable	30.3	4 Cable, 4-½", 2-½" & ¾" E	1-½"
TP431SSB	4"	2-½"	Armored/Metal Clad Cable	30.3	4 Cable, 4-½", 2-½" & ¾" E	1-½"
TP563SSB	4-11/16"	2-½"	Conduit	42.0	6-½", 6-½" & ¾" -C	3-½", 2-¾"