

COVERS FOR 4" SQUARE BOXES – CUBIC INCH CAPACITY (SEE BELOW)

8-32 screw used on covers





TP472




TP474



 TP478

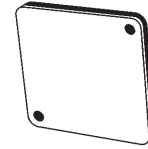TP473, TP475, TP476,
TP477, TP479, TP483

TP850*

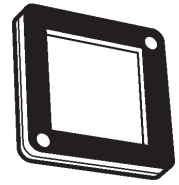

TP854*

*For Air Plenum


Product Number	Description	Std. Unit Pkg.	Wt. Lbs. Per 100	Capacity Cu. In.
TP472†	Flat Blank	50	31	—
TP474	Flat Blank, Open With Ears 2¾"	50	21	—
TP478†	Flat with ½", ko	50	31	—
TP473	Raised ¼", Open With Ears 2¾"	50	23	1.3
TP476†	Raised ½", Open With Ears 2¾"	50	26	4.0
TP477	Raised ⅝", Open With Ears 2¾"	50	27	5.0
TP475	Raised ¾", Open With Ears 2¾"	25	31	6.0
TP479	Raised 1", Open With Ears 2¾"	25	34	7.0
TP483	Raised 1¼", Open With Ears 2¾"	25	37	8.5

Air Plenum


TP850*	Flat Blank Gasketed With Captive Screws	25	31	—
TP854*	Flat Ring Double Gasketed	25	12	—

† CSA Certified

ONE DEVICE

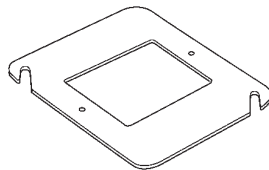

TP480

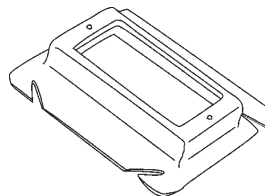
TP482, TP484, TP486,
TP488, TP489, TP490

Product Number	Description	Std. Unit Pkg.	Wt. Lbs. Per 100	Capacity Cu. In.
TP480	Flat	50	20	—
TP482	¼" Raised	50	21	1.8
TP484	½" Raised	50	23	3.5
TP489	⅝" Raised	50	26	4.3
TP486	¾" Raised	50	30	5.5
TP488	1" Raised	50	34	6.8
TP490	1¼" Raised	25	39	8.8

TWO DEVICE



 TP494

TP496, TP488, TP499,
TP500, TP501, TP502

Product Number	Description	Std. Unit Pkg.	Wt. Lbs. Per 100	Capacity Cu. In.
TP494	Flat	50	12	—
TP496‡	¼" Raised	50	13	3.0
TP498‡	½" Raised	50	18	6.0
TP499‡	⅝" Raised	50	22	8.0
TP500‡	¾" Raised	50	24	9.0
TP501	1¼" Raised	25	31	14.0
TP502	1" Raised	25	30	11.7

‡ Slotted design for use with 4" square box partitions


SURFACE COVERS FOR 4" SQUARE BOXES – 5.5 CUBIC INCH CAPACITY RAISED 1/2"



TP503




TP504

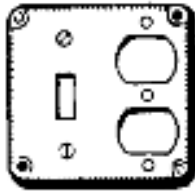


TP506




TP508

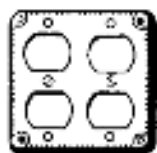


TP510

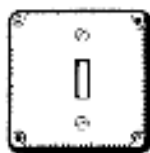


TP512

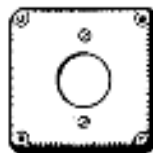

TP507
TP514
TP519

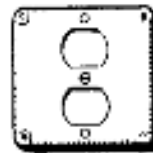


TP516

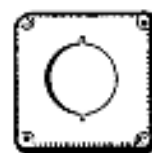


TP509
TP518




TP513

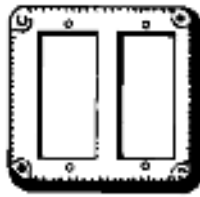

TP511

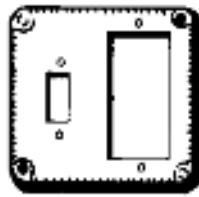

TP515

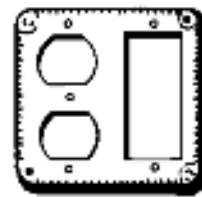


TP517


Product Number	Description	Std. Unit Pkg.	Wt. Lbs. Per 100
TP503†	Raised Blank	50	35
TP504†	For One Toggle Switch, One Single Receptacle 1 ¹³ / ₃₂ " Dia.	50	31
TP506†	For One Toggle Switch, One Duplex Receptacle	50	31
TP508	For Two Toggle Switches	50	35
TP510	For Two Duplex Receptacles	50	26
TP512	For One Toggle Switch	50	35
TP507	For One 20 Amp. Single Receptacle 1 ¹⁹ / ₃₂ " Dia.	50	37
TP514	For One Single Receptacle 1 ¹³ / ₃₂ " Dia.	50	34
TP519†	For One 30 Amp. Twist-Lock Single Receptacle 1 ²³ / ₃₂ " Dia.	50	37
TP516	For One Duplex Receptacle	50	31
TP509	For One 30–60 Amp. Receptacle (4-wire) 2 ⁷ / ₁₆ " Dia.	50	23
TP518	For One 30–50 Amp. Receptacle 2 ⁹ / ₆₄ " Dia.	50	34
TP513	For One GFCI Receptacle	50	31
TP511	For Two GFCI Receptacles	50	26
TP515	For One Toggle Switch, One GFCI Receptacle	50	31
TP517	For One Duplex Receptacle, One GFCI Receptacle	50	26

† CSA certified

**TILE WALL COVERS FOR 4" SQUARE BOXES –
CUBIC INCH CAPACITY (SEE BELOW)
APPLICATIONS: TYPICALLY USED WITH TILE
OR BRICK**

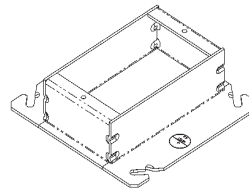

TP524

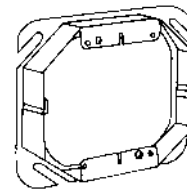


TP534

Product Number	Description	Std. Unit Pkg.	Wt. Lbs. Per 100	Capacity Cu. In.
ONE DEVICE				
TP520	1/2" Raised	50	30	3.7
TP522	3/4" Raised	50	36	5.5
TP524	1" Raised	50	40	7.4
TP526	1 1/4" Raised	25	46	9.2
TP528	1 1/2" Raised	25	50	11.0
TP530	2" Raised	25	62	14.7
TWO DEVICE				
TP532	1/2" Raised	10	24	5.0
TP534	3/4" Raised	10	30	7.8
TP536	1" Raised	10	36	10.3
TP538	1 1/4" Raised	10	44	13.0
TP540	1 1/2" Raised	10	50	15.5
TP542	2" Raised	10	66	20.8


4" SQUARE BOX PARTITIONS




TP860

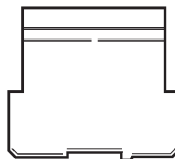

TP861

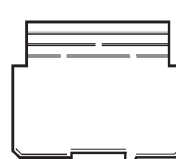


TP862

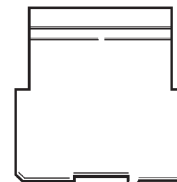


TP863

Product Number	Description	Std. Unit Pkg.	Wt. Lbs. Per 100
FOR 1 1/2" DEEP BOX WITH SQUARE CUT TILE WALL TWO-GANG COVERS			
TP860	For 1/2", 3/4", 1" Raised Covers	25	13
TP861	For 1 1/4", 1 1/2", 2" Raised Covers	25	18
FOR 2 1/8" DEEP BOX WITH SQUARE CUT TILE WALL TWO-GANG COVERS			
TP862	For 1/2", 3/4", 1" Raised Covers	25	16
TP863	For 1 1/4", 1 1/2", 2" Raised Covers	25	21

**4 11/16" SQUARE OUTLET BOXES –
29.5 CUBIC INCH CAPACITY
1 1/2" DEEP WITH CONDUIT KOs**

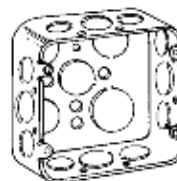

TP548

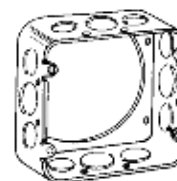

TP550

KNOCKOUTS				
Product Number	Sides	Bottom	Std. Unit Pkg.	Wt. Lbs. Per 100
TP548	8-1 1/2", 4-3/4"	3-1 1/2", 2-3/4"	25	84
4 11/16" SQUARE EXTENSION RING				
TP550	8-1 1/2", 4-3/4"	—	25	66