

Straight Blade Plugs & Connectors Rubber & Watertight Plugs & Connectors

Pass & Seymour




IP67
Suitability


2 Pole, 3 Wire Grounding 15 & 20A, 125 & 250V

Features


- Rubber body construction stands up to impacts, oil, chemicals, heat and weather.
- Floating blades allow self-alignment with contacts and reduce stress on blades and contacts.
- Neoprene grommet keeps out contaminants at cord entrance.
- Terminal screws come backed-out – ready-to-wire.
- Nickel-plated blades and connectors provide an extra measure of corrosion resistance.
- Closure cap on watertight model forms a seal to keep out contaminants when connector is not in use.
- Multiple seals between plug and connector on watertight version protects electrical connection from contaminants.

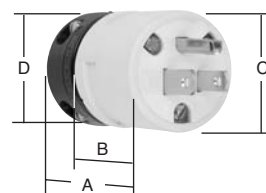

1447

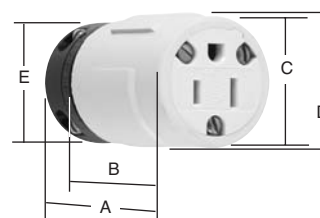


1547

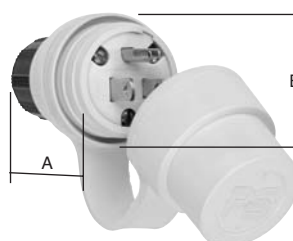

14W47

Shown with 14WPS (cap).
Sold separately.

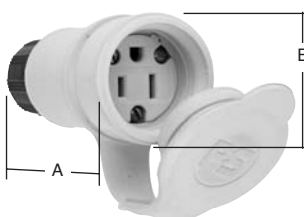

15W47

Catalog Number	Rating A. V.	Description	NEMA Config. No.	3rd Party Compliance	
				 UL498	 C22.2 No. 42
Straight Blade					
1447	15 125	Rubber Straight Blade Plug	5-15P	•	•
1547	15 125	Rubber Straight Blade Connector	5-15R	•	•
1433P	20 125	Rubber Straight Blade Plug	5-20P	•	•
1533	20 125	Rubber Straight Blade Connector	5-20R	•	•
1449	15 250	Rubber Straight Blade Plug	6-15P	•	•
1549	15 250	Rubber Straight Blade Connector	6-15R	•	•
1448	20 250	Rubber Straight Blade Plug	6-20P	•	•
1548	20 250	Rubber Straight Blade Connector	6-20R	•	•

NEMA 4X – Watertight Devices

14W47	15 125	NEMA 4X Straight Blade Plug	5-15P	•	•
15W47	15 125	NEMA 4X Straight Blade Connector	5-15R	•	•
14W33	20 125	NEMA 4X Straight Blade Plug	5-20P	•	•
15W33	20 125	NEMA 4X Straight Blade Connector	5-20R	•	•
14W49	15 250	NEMA 4X Straight Blade Plug	6-15P	•	•
15W49	15 250	NEMA 4X Straight Blade Connector	6-15R	•	•
14W48	20 250	NEMA 4X Straight Blade Plug	6-20P	•	•
15W48	20 250	NEMA 4X Straight Blade Connector	6-20R	•	•

Catalog Number	Rating A. V.	Description	NEMA Config. No.	3rd Party Compliance	
				 UL498	 C22.2 42M
Caps – Watertight Only					
14WPS		Male Cap	All	•	•
50W50PS		Female Replacement Cap	All	•	•



NEMA 5-15R



NEMA 5-15P



NEMA 5-20R



NEMA 5-20P



NEMA 6-15R



NEMA 6-15P



NEMA 6-20R



NEMA 6-20P

(Inch)	A	B	C	D	E
Rubber Straight Blade Plug					
15A	2.27"	1.44"	1.53"	1.53"	
20A	2.59"	1.76"	1.93"	1.60"	
Rubber Straight Blade Connector					
15A	2.99"	2.16"	1.53"	1.66"	1.53"
20A	3.74"	2.19"	1.93"	2.07"	1.60"
Cord Grip Range: .335"-.640"					

(Inch)	A	B
Watertight Plug		
15A	2.62"	1.85"
20A	2.62"	1.85"
Watertight Connector		
15A	4.03"	1.85"
20A	4.03"	1.85"
Cord Grip Range: .062"-.625"		

All devices listed on this page conform to NEMA WD-1 and WD-6.