

# Straight Blade Devices Specification Grade Single Receptacles

15 & 20A, 125 & 250V

Pass & Seymour




Straight Blade Devices


Specification Grade Single Receptacles

| Catalog Number                                 | Rating<br>A. V. | Color        | NEMA<br>Config. No. | 3rd Party Compliance                                                                       |                                                                                                     |
|------------------------------------------------|-----------------|--------------|---------------------|--------------------------------------------------------------------------------------------|-----------------------------------------------------------------------------------------------------|
|                                                |                 |              |                     | <br>UL498 | <br>C22.2 No. 42 |
| Single Receptacles Side Wire                   |                 |              |                     |                                                                                            |                                                                                                     |
| 5251-I                                         | 15 125          | Ivory        | 5-15R               | •                                                                                          | •                                                                                                   |
| 5251-W                                         | 15 125          | White        | 5-15R               | •                                                                                          | •                                                                                                   |
| 5251                                           | 15 125          | Brown        | 5-15R               | •                                                                                          | •                                                                                                   |
| 5251-LA                                        | 15 125          | Light Almond | 5-15R               | •                                                                                          | •                                                                                                   |
| 5351-I                                         | 20 125          | Ivory        | 5-20R               | •                                                                                          | •                                                                                                   |
| 5351-W                                         | 20 125          | White        | 5-20R               | •                                                                                          | •                                                                                                   |
| 5351                                           | 20 125          | Brown        | 5-20R               | •                                                                                          | •                                                                                                   |
| 5351-LA                                        | 20 125          | Light Almond | 5-20R               | •                                                                                          | •                                                                                                   |
| 5651-I                                         | 15 250          | Ivory        | 6-15R               | •                                                                                          | •                                                                                                   |
| 5651-W                                         | 15 250          | White        | 6-15R               | •                                                                                          | •                                                                                                   |
| 5651                                           | 15 250          | Brown        | 6-15R               | •                                                                                          | •                                                                                                   |
| 5651-LA                                        | 15 250          | Light Almond | 6-15R               | •                                                                                          | •                                                                                                   |
| 5851-I                                         | 20 250          | Ivory        | 6-20R               | •                                                                                          | •                                                                                                   |
| 5851-W                                         | 20 250          | White        | 6-20R               | •                                                                                          | •                                                                                                   |
| 5851                                           | 20 250          | Brown        | 6-20R               | •                                                                                          | •                                                                                                   |
| 5851-LA                                        | 20 250          | Light Almond | 6-20R               | •                                                                                          | •                                                                                                   |
| Single Receptacles Side Wire Right Angle Slots |                 |              |                     |                                                                                            |                                                                                                     |
| 5371-I                                         | 20 125          | Ivory        | Non-NEMA            | •                                                                                          | •                                                                                                   |
| 5371-W                                         | 20 125          | White        | Non-NEMA            | •                                                                                          | •                                                                                                   |
| 5371                                           | 20 125          | Brown        | Non-NEMA            | •                                                                                          | •                                                                                                   |


|                                                            |        |       |       |   |   |
|------------------------------------------------------------|--------|-------|-------|---|---|
| <b>Short Strap Single Receptacles Screw Spacing 1.750"</b> |        |       |       |   |   |
| 5258-I                                                     | 15 125 | Ivory | 5-15R | • | • |
| 5258-W                                                     | 15 125 | White | 5-15R | • | • |
| 5258                                                       | 15 125 | Brown | 5-15R | • | • |
| 5358-I                                                     | 20 125 | Ivory | 5-20R | • | • |
| 5358-W                                                     | 20 125 | White | 5-20R | • | • |
| 5358                                                       | 20 125 | Brown | 5-20R | • | • |
| 5358-BK                                                    | 20 125 | Black | 5-20R | • | • |
| 5658-I                                                     | 15 250 | Ivory | 6-15R | • | • |
| 5658                                                       | 15 250 | Brown | 6-15R | • | • |
| 5858-I                                                     | 20 250 | Ivory | 6-20R | • | • |
| 5858-W                                                     | 20 250 | White | 6-20R | • | • |
| 5858                                                       | 20 250 | Brown | 6-20R | • | • |
| Supplied with mounting screws.                             |        |       |       |   |   |

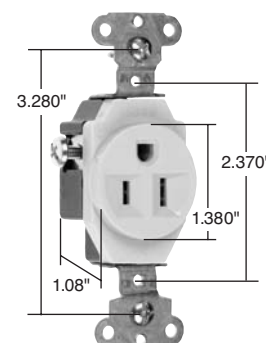

5251-I

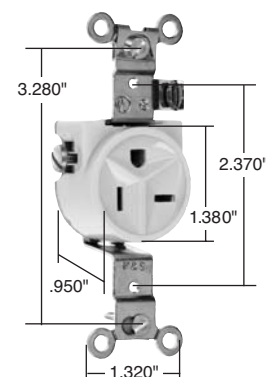

5371-I

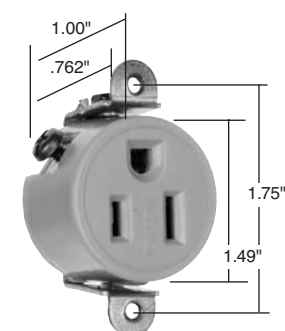

5258-I

2 Pole, 3 Wire



NEMA  
5-15R



NEMA  
5-20R



NEMA  
6-15R



NEMA  
6-20R