

Straight Blade Devices

TradeMaster® Decorator Receptacles


15A, 125V

Pass & Seymour




Straight Blade Devices

Features	
<ul style="list-style-type: none"> ■ High impact-resistant thermoplastic construction. ■ Extra-long strap. ■ Quickloop wire looping aid. ■ Long-term blade retention. ■ Tri-drive screws. ■ Extra-large circuit break-off tabs. 	<ul style="list-style-type: none"> ■ Side-access push wire release. ■ Ultrasonic welding of face to back body. ■ Side wire accepts #12 – #14 AWG solid. ■ Push wire accepts #14 AWG solid only. ■ “S” model provides self-grounding clip.

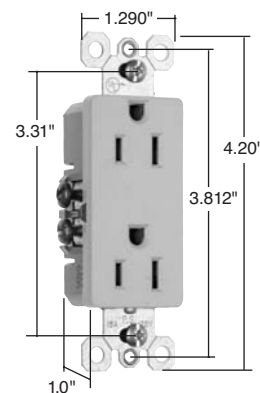

885-I

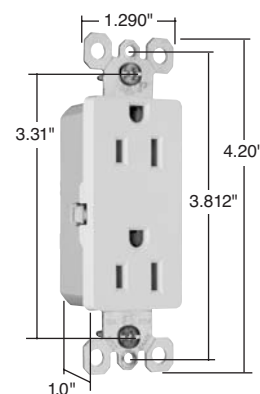

880-DECOLA

2 Pole, 3 Wire



NEMA
5-15R

Catalog Number	Rating A. V.	Color	NEMA Config. No.	3rd Party Compliance	
				UL498	C22.2 42
Decorator Duplex Receptacles					
885-I	15 125	Ivory	5-15R	•	•
885-W	15 125	White	5-15R	•	•
885	15 125	Brown	5-15R	•	•
885-BK	15 125	Black	5-15R	•	•
885-LA	15 125	Light Almond	5-15R	•	•
Self-Grounding Decorator Duplex Receptacles					
885-SI	15 125	Ivory	5-15R	•	•
885-SW	15 125	White	5-15R	•	•
885-SLA	15 125	Light Almond	5-15R	•	•

For Configurable Solutions, see Page U-1.

Features	
<ul style="list-style-type: none"> ■ High-impact resistant thermoplastic construction. ■ Extra-long strap. ■ Quickloop wire looping aid. ■ Long-term blade retention. ■ Longer tri-drive screws for easier 12 AWG looping. 	<ul style="list-style-type: none"> ■ Extra-large circuit break-off tabs. ■ Side-access push wire release. ■ Ultrasonic welding of face to back body. ■ Side wire accepts #12 – #14 AWG solid wire. ■ Push wire accepts #14 AWG solid only.

Catalog Number	Rating A. V.	Color	NEMA Config. No.	3rd Party Compliance	
				UL498	C22.2 42
Decorator 8 Hole Push Wire Without Terminal Screws					
880-DECOI	15 125	Ivory	5-15R	•	•
880-DECOW	15 125	White	5-15R	•	•
880-DECOBK	15 125	Black	5-15R	•	•
880-DECOLA	15 125	Light Almond	5-15R	•	•

All devices listed on this page conform to NEMA WD-1 and WD-6.

TradeMaster® Decorator Receptacles