

Catalog Number
Notes
Type

FEATURES & SPECIFICATIONS

INTENDED USE — The OLF 2RH provides years of maintenance-free general illumination for residential and commercial outdoor applications such as yards, driveways, patios, loading areas and warehouses.

CONSTRUCTION — Rugged cast-aluminum, corrosion-resistant rear housing and lamp heads thermally isolate the LEDs and driver promoting long life.

120V driver operates at 60 Hz.

25W, .25A.

Operating temperature -40°C to 40°C.

OPTICS — High-performance LEDs produce over 2,000 lumens and maintain 70% of light output at 50,000 hours of service. (LED lifespan based on IESNA LM-80-08 results and calculated per IESNA TM-21-11 methodology.)

Removable aluminum visors allow for maximum brightness or “neighbor-friendly” shading. 4000K CCT.

See Lighting Facts labels for specific fixture performance.

INSTALLATION — Designed for wall- or eave-mounting to existing junction box (provided by others). Mount 6-10 feet high for optimum range and detection.

LISTINGS — UL Certified to US and Canadian safety standards for wet-location mounting higher than 4 feet off the ground.

Tested in accordance with IESNA LM-79 and LM-80 standards.

WARRANTY — 5-year limited warranty. Complete warranty terms located at www.acuitybrands.com/CustomerResources/Terms_and_conditions.aspx

Note: Actual performance may differ as a result of end-user environment and application.

All values are design or typical values, measured under laboratory conditions at 25 °C.

Specifications subject to change without notice.




Outdoor General Purpose

OLF 2RH



LED SECURITY FLOODLIGHT

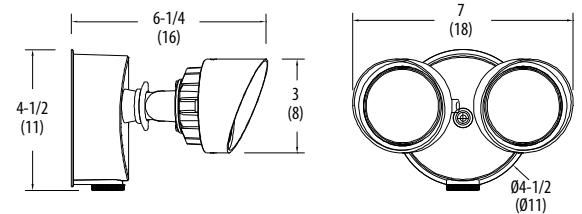

All dimensions are inches (centimeters) unless otherwise indicated.

ORDERING INFORMATION

For shortest lead times, configure product using standard options (shown in bold).

Example: OLF 2RH 40K 120V BZ

Series	Light Heads	Color Temperature ¹	Voltage	Options	Finish
OLF	2RH 2 heads, round	40K 4000K	120 120V	PE Photoelectric cell, button	BZ Bronze WH White

Notes



¹ Nominal correlated color temperature (CCT) per ANSI C78.377-2008.

OLF 2RH Outdoor LED Security Floodlight

PHOTOMETRICS

To see complete photometric reports or download .ies files for this product, visit www.lithonia.com

OLF 2RH

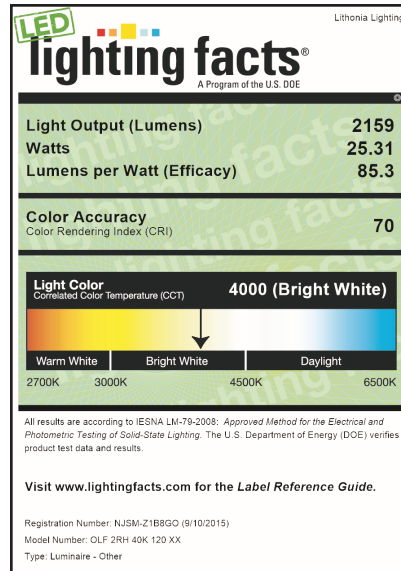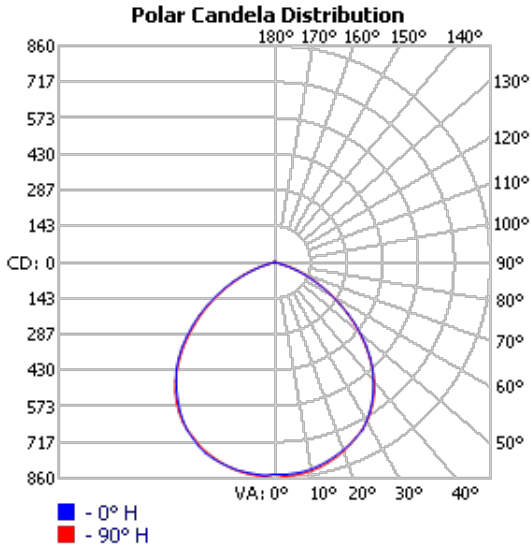

Catalog Number
Notes
Type

FEATURES & SPECIFICATIONS

INTENDED USE — The OLF 2RH provides years of maintenance-free general illumination for residential and commercial outdoor applications such as yards, driveways, patios, loading areas and warehouses.

CONSTRUCTION — Rugged cast-aluminum, corrosion-resistant rear housing and lamp heads thermally isolate the LEDs and driver promoting long life.

120V driver operates at 60 Hz.

25W, .25A.

Operating temperature -40°C to 40°C.

OPTICS — High-performance LEDs produce over 2,000 lumens and maintain 70% of light output at 50,000 hours of service. (LED lifespan based on IESNA LM-80-08 results and calculated per IESNA TM-21-11 methodology.)

Removable aluminum visors allow for maximum brightness or “neighbor-friendly” shading.
4000K CCT.

See Lighting Facts labels for specific fixture performance.

INSTALLATION — Designed for wall- or eave-mounting to existing junction box (provided by others). Mount 6-10 feet high for optimum range and detection.

LISTINGS — UL Certified to US and Canadian safety standards for wet-location mounting higher than 4 feet off the ground.

Tested in accordance with IESNA LM-79 and LM-80 standards.

WARRANTY — 5-year limited warranty. Complete warranty terms located at www.acuitybrands.com/CustomerResources/Terms_and_conditions.aspx

Note: Actual performance may differ as a result of end-user environment and application.

All values are design or typical values, measured under laboratory conditions at 25 °C.

Specifications subject to change without notice.




Outdoor General Purpose

OLF 2RH



LED SECURITY FLOODLIGHT

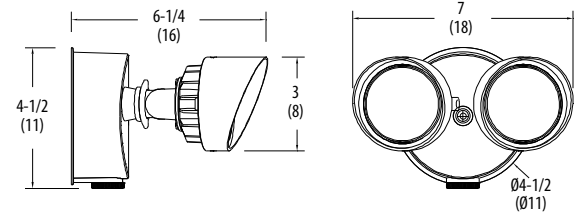

All dimensions are inches (centimeters) unless otherwise indicated.

ORDERING INFORMATION

For shortest lead times, configure product using standard options (shown in bold).

Example: OLF 2RH 40K 120V BZ

Series	Light Heads	Color Temperature ¹	Voltage	Options	Finish
OLF	2RH 2 heads, round	40K 4000K	120 120V	PE Photoelectric cell, button	BZ Bronze WH White

Notes


¹ Nominal correlated color temperature (CCT) per ANSI C78.377-2008.

OLF 2RH Outdoor LED Security Floodlight

PHOTOMETRICS

To see complete photometric reports or download .ies files for this product, visit www.lithonia.com

OLF 2RH

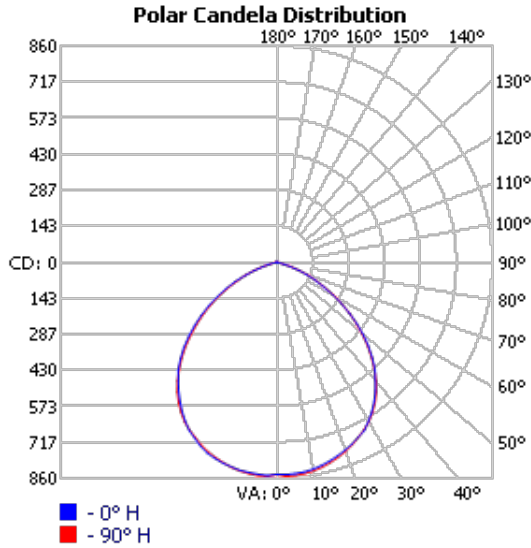

Lithonia Lighting

LED lighting facts®
A Program of the U.S. DOE

Light Output (Lumens)	2159
Watts	25.31
Lumens per Watt (Efficacy)	85.3

Color Accuracy Color Rendering Index (CRI)	70
---	----

Light Color
Correlated Color Temperature (CCT) **4000 (Bright White)**

Warm White | Bright White | Daylight
2700K | 3000K | 4500K | 6500K

All results are according to IESNA LM-79-2008: *Approved Method for the Electrical and Photometric Testing of Solid-State Lighting*. The U.S. Department of Energy (DOE) verifies product test data and results.

Visit www.lightingfacts.com for the **Label Reference Guide**.

Registration Number: NJSM-Z1B8G0 (8/10/2015)
Model Number: OLF 2RH 40K 120 XX
Type: Luminaire - Other