

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301410038](#)
Status: **Active**
Overview: [Heavy-Duty Industrial Wiring Devices](#)
Description: Super-Safeway Connector, 2 Pole/3 Wire, NEMA 6-15, 250V

Documents:

[RoHS Certificate of Compliance \(PDF\)](#) [Product Literature \(PDF\)](#)

Agency Certification

CSA LR6837
 UL E10176

General

Product Family Wiring Devices
 Series [130141](#)
 IP Rating N/A
 NEMA Configuration NEMA 6-15
 Overview [Heavy-Duty Industrial Wiring Devices](#)
 Product Literature Order No 987650-8068
 Product Name Super-Safeway
 Receptacle Type Single
 Specialty N/A
 Type Connector
 UPC 78678870303
 Woodhead Yes

Physical


Flange No
 Flip Lid No
 Gender Female
 Length N/A
 Locking Blade No
 Poles 2-pole/3-wire

Electrical

Cord Type N/A
 Current - Maximum per Contact 15.0A
 GFCI No
 Lighted Connector No
 Voltage - Maximum 250V

Material Info

Engineering Number 1549

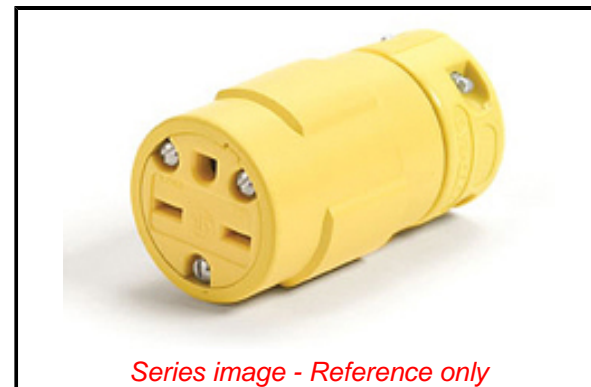

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

China RoHS

Search Parts in this Series

[130141 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1301410038](#)
Status: **Active**
Overview: [Heavy-Duty Industrial Wiring Devices](#)
Description: Super-Safeway Connector, 2 Pole/3 Wire, NEMA 6-15, 250V

Documents:

[RoHS Certificate of Compliance \(PDF\)](#) [Product Literature \(PDF\)](#)

Agency Certification

CSA LR6837
UL E10176

General

Product Family Wiring Devices
Series [130141](#)
IP Rating N/A
NEMA Configuration NEMA 6-15
Overview [Heavy-Duty Industrial Wiring Devices](#)
Product Literature Order No 987650-8068
Product Name Super-Safeway
Receptacle Type Single
Specialty N/A
Type Connector
UPC 78678870303
Woodhead Yes

Physical


Flange No
Flip Lid No
Gender Female
Length N/A
Locking Blade No
Poles 2-pole/3-wire

Electrical

Cord Type N/A
Current - Maximum per Contact 15.0A
GFCI No
Lighted Connector No
Voltage - Maximum 250V

Material Info

Engineering Number 1549

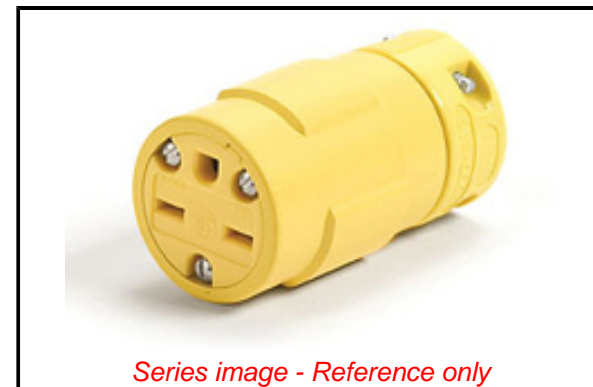

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

China RoHS

Search Parts in this Series

[130141 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION