



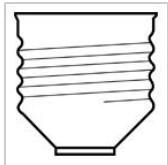

GE
Lighting

12658 - 15A15

GE A15

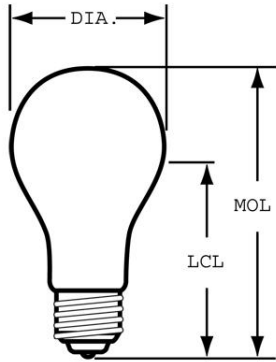

GENERAL CHARACTERISTICS

| | |
|---------------------|-----------------------|
| Lamp Type | Incandescent - A-line |
| Bulb | A15 |
| Base | Medium Screw (E26) |
| Filament | C-9 |
| Bulb Finish | Inside frost |
| Rated Life | 2500.0 hrs |
| Bulb Material | Soft glass |
| Primary Application | Ceiling Fan |

PHOTOMETRIC CHARACTERISTICS

| | |
|---------------------------------|-------|
| Initial Lumens | 115.0 |
| Nominal Initial Lumens per Watt | 7 |

ELECTRICAL CHARACTERISTICS

| | |
|---------|-------|
| Wattage | 15.0 |
| Voltage | 130.0 |

DIMENSIONS

| | |
|------------------------------|--------------------|
| Maximum Overall Length (MOL) | 3.5000 in(88.9 mm) |
| Bulb Diameter (DIA) | 1.875 in(47.6 mm) |
| Light Center Length (LCL) | 2.370 in(60.2 mm) |

PRODUCT INFORMATION



| | |
|----------------------------------|----------------|
| Product Code | 12658 |
| Description | 15A15 |
| Standard Package | Case |
| Standard Package GTIN | 00043168126588 |
| Standard Package Quantity | 120 |
| Sales Unit | Unit |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard Package | 120 |
| UPC | 043168909839 |



GE
Lighting

12658 - 15A15

GE A15

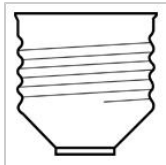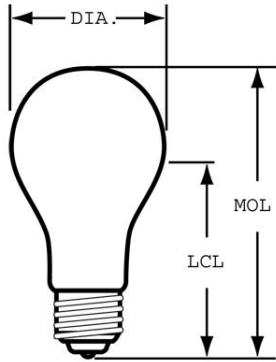

GENERAL CHARACTERISTICS

| | |
|---------------------|-----------------------|
| Lamp Type | Incandescent - A-line |
| Bulb | A15 |
| Base | Medium Screw (E26) |
| Filament | C-9 |
| Bulb Finish | Inside frost |
| Rated Life | 2500.0 hrs |
| Bulb Material | Soft glass |
| Primary Application | Ceiling Fan |

PHOTOMETRIC CHARACTERISTICS

| | |
|---------------------------------|-------|
| Initial Lumens | 115.0 |
| Nominal Initial Lumens per Watt | 7 |

ELECTRICAL CHARACTERISTICS

| | |
|---------|-------|
| Wattage | 15.0 |
| Voltage | 130.0 |

DIMENSIONS

| | |
|------------------------------|--------------------|
| Maximum Overall Length (MOL) | 3.5000 in(88.9 mm) |
| Bulb Diameter (DIA) | 1.875 in(47.6 mm) |
| Light Center Length (LCL) | 2.370 in(60.2 mm) |

PRODUCT INFORMATION

| | |
|----------------------------------|----------------|
| Product Code | 12658 |
| Description | 15A15 |
| Standard Package | Case |
| Standard Package GTIN | 00043168126588 |
| Standard Package Quantity | 120 |
| Sales Unit | Unit |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard Package | 120 |
| UPC | 043168909839 |