




GE
Lighting

27868 - 1866

GE T3.25 (T3 1/4) - Low Voltage

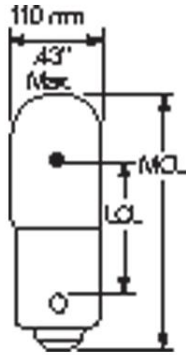

GENERAL CHARACTERISTICS

Lamp Type	Miniature - T & TL Shape
Bulb	T3.25 (T3 1/4)
Base	Miniature Bayonet (Ba9s)
Filament	C-2R
Rated Life	5000.0 hrs
Atmosphere	Vacuum
Primary Application	Low Voltage

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	8.0
Nominal Initial Lumens per Watt	4
Mean Spherical Candlepower (MSCP)	0.65

ELECTRICAL CHARACTERISTICS

Wattage	2.0
Voltage	6.3

DIMENSIONS

Maximum Overall Length (MOL)	1.1900 in(30.2 mm)
Bulb Diameter (DIA)	0.406 in(10.3 mm)
Light Center Length (LCL)	0.780 in(19.8 mm)

PRODUCT INFORMATION


Product Code	27868
Description	1866
ANSI Code	1866
Standard Package	Case
Standard Package GTIN	20043168278687
Standard Package Quantity	50
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	50
UPC	043168278683



GE
Lighting

27868 - 1866

GE T3.25 (T3 1/4) - Low Voltage

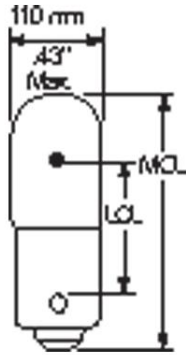

GENERAL CHARACTERISTICS

Lamp Type	Miniature - T & TL Shape
Bulb	T3.25 (T3 1/4)
Base	Miniature Bayonet (Ba9s)
Filament	C-2R
Rated Life	5000.0 hrs
Atmosphere	Vacuum
Primary Application	Low Voltage

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	8.0
Nominal Initial Lumens per Watt	4
Mean Spherical Candlepower (MSCP)	0.65

ELECTRICAL CHARACTERISTICS

Wattage	2.0
Voltage	6.3

DIMENSIONS

Maximum Overall Length (MOL)	1.1900 in(30.2 mm)
Bulb Diameter (DIA)	0.406 in(10.3 mm)
Light Center Length (LCL)	0.780 in(19.8 mm)

PRODUCT INFORMATION

Product Code	27868
Description	1866
ANSI Code	1866
Standard Package	Case
Standard Package GTIN	20043168278687
Standard Package Quantity	50
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	50
UPC	043168278683