




GE  
Lighting

**27868 - 1866**

GE T3.25 (T3 1/4) - Low Voltage

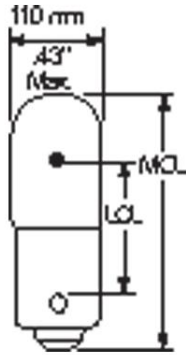

**GENERAL CHARACTERISTICS**

Lamp Type	Miniature - T & TL Shape
Bulb	T3.25 (T3 1/4)
Base	Miniature Bayonet (Ba9s)
Filament	C-2R
Rated Life	5000.0 hrs
Atmosphere	Vacuum
Primary Application	Low Voltage

**PHOTOMETRIC CHARACTERISTICS**

Initial Lumens	8.0
Nominal Initial Lumens per Watt	4
Mean Spherical Candlepower (MSCP)	0.65

**ELECTRICAL CHARACTERISTICS**

Wattage	2.0
Voltage	6.3

**DIMENSIONS**

Maximum Overall Length (MOL)	1.1900 in(30.2 mm)
Bulb Diameter (DIA)	0.406 in(10.3 mm)
Light Center Length (LCL)	0.780 in(19.8 mm)

**PRODUCT INFORMATION**


Product Code	27868
Description	1866
ANSI Code	1866
Standard Package	Case
Standard Package GTIN	20043168278687
Standard Package Quantity	50
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	50
UPC	043168278683



GE  
Lighting

**27868 - 1866**

GE T3.25 (T3 1/4) - Low Voltage

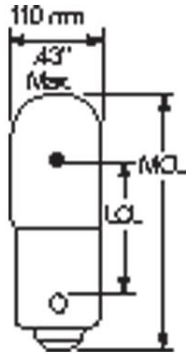

**GENERAL CHARACTERISTICS**

Lamp Type	Miniature - T & TL Shape
Bulb	T3.25 (T3 1/4)
Base	Miniature Bayonet (Ba9s)
Filament	C-2R
Rated Life	5000.0 hrs
Atmosphere	Vacuum
Primary Application	Low Voltage

**PHOTOMETRIC CHARACTERISTICS**

Initial Lumens	8.0
Nominal Initial Lumens per Watt	4
Mean Spherical Candlepower (MSCP)	0.65

**ELECTRICAL CHARACTERISTICS**

Wattage	2.0
Voltage	6.3

**DIMENSIONS**

Maximum Overall Length (MOL)	1.1900 in(30.2 mm)
Bulb Diameter (DIA)	0.406 in(10.3 mm)
Light Center Length (LCL)	0.780 in(19.8 mm)

**PRODUCT INFORMATION**

Product Code	27868
Description	1866
ANSI Code	1866
Standard Package	Case
Standard Package GTIN	20043168278687
Standard Package Quantity	50
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	50
UPC	043168278683