



## C-CLAMP, STEEL, EG, 3/8" ROD, 3/4" MAX FLANGE

### CATALOG NUMBER

**2000037EG**



### FEATURES

Pressed steel beam clamp

Conforms with Federal Specification WW-H-171 (Type 23), Manufacturers Standardization Society ANSI®/MSS-SP-58 (Type 23)

### PRODUCT ATTRIBUTES

Material: Steel

Finish: Electrogalvanized

Static Load Safety Factor: 3.5:1

Rod Size (RS): 3/8"

Flange Thickness (FT): 3/4" Max

A: 1 1/8"

Screw Diameter (Sc): 0.375

Screw Length (L): 1 1/4"

Pipe Size: 4" Max

Torque (TQ): 5 ft·lbf


Static Load (F): 250lb

### ADDITIONAL PRODUCT DETAILS

Setscrew must be tightened and torqued onto the sloped side of the I-beam.

## DIAGRAMS

---

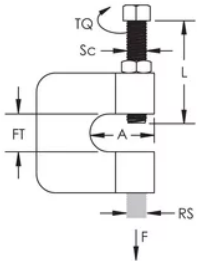

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



[nVent.com](http://nVent.com)

Our powerful portfolio of brands:  
**CADDY ERICO HOFFMAN RAYCHEM SCHROFF**

**TRACER**



## C-CLAMP, STEEL, EG, 3/8" ROD, 3/4" MAX FLANGE

### CATALOG NUMBER

**2000037EG**



### FEATURES

Pressed steel beam clamp

Conforms with Federal Specification WW-H-171 (Type 23), Manufacturers Standardization Society ANSI®/MSS-SP-58 (Type 23)

### PRODUCT ATTRIBUTES

Material: Steel

Finish: Electrogalvanized

Static Load Safety Factor: 3.5:1

Rod Size (RS): 3/8"

Flange Thickness (FT): 3/4" Max

A: 1 1/8"

Screw Diameter (Sc): 0.375

Screw Length (L): 1 1/4"

Pipe Size: 4" Max

Torque (TQ): 5 ft·lbf


Static Load (F): 250lb

### ADDITIONAL PRODUCT DETAILS

Setscrew must be tightened and torqued onto the sloped side of the I-beam.

## DIAGRAMS

---

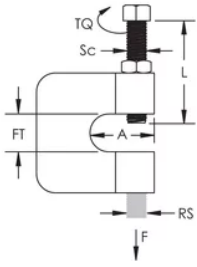

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



nVent.com

Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN RAYCHEM SCHROFF**

**TRACER**