


## Connectors - Steel - Raintight

### Images

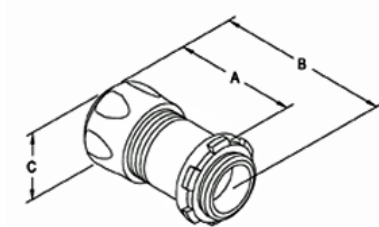

### Application

Used to join EMT to box or enclosure. Concrete tight/Raintight. Insulated Throat - 105°C. Patented

### Product Information

Material: Steel  
Finish: Zinc electro-plate

### Certifications & Codes:

Federal Specification Number:	A-A-50553
NEMA Standard:	FB-1
UL File Number:	E24001
UL Standard:	UL-514B
UNSPSC:	39121434

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-13/32  
Dimension B in Inches: 1-27/32  
Dimension C in Inches: 1-5/16

**Catalog ID:** 251-SRTI

**UPC Number:** 781747122513

**Description:** Connector, Compression, Steel, Insulated Throat - 105°C, Size 3/4 Inch

**Application:** Used to join EMT to box or enclosure. Concrete tight/Raintight. Insulated Throat - 105°C. Patented

**Trade Size:** 3/4"

**Std Pkg Qty:** 250

**Unit Qty:** 25