


Connectors - Zinc - Raintight

Images

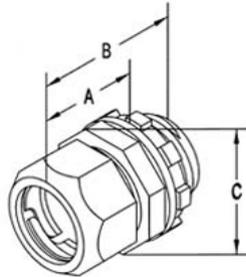

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 9/16
Dimension B in Inches: 15/16
Dimension C in Inches: 1-11/16

Application

Compression style connector with internal sealing ring and knockout gasket to create a raintight seal when connecting EMT to box or enclosure. Insulated Throat - 90° C. Patented

Product Information

Material: Zinc Die Cast
Finish: Ball burnished, mirror smooth

Certifications & Codes:

Federal Specification Number: A-A-50553
NEMA Standard: FB-1
UL File Number: E24001
UL Standard: UL-514B
UNSPSC: 39121434

Catalog ID: 252-RTI2

UPC Number: 781747192523

Description: 1" Raintight Compression Connector, Insulated

Application: Compression style connector with internal sealing ring and knockout gasket to create a raintight seal when connecting EMT to box or enclosure. Insulated Throat - 90° C. Patented

Trade Size: 1"

Country of Manufacture: USA of USA and Imported Parts

Std Pkg Qty: 150

Unit Qty: 15