


## Connectors - Zinc - Raintight

### Images

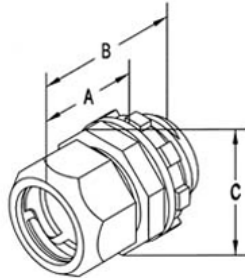

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 5/8

Dimension B in Inches: 1-5/16

Dimension C in Inches: 2-7/16

### Application

Compression style connector with internal sealing ring and knockout gasket to create a raintight seal when connecting EMT to box or enclosure. Insulated Throat - 90° C. Patented

### Product Information

Material: Zinc Die Cast

Finish: Ball burnished, mirror smooth

### Certifications & Codes:

Federal Specification Number: A-A-50553

NEMA Standard: FB-1

UL File Number: E24001

UL Standard: UL-514B

UNSPSC: 39121434

**Catalog ID:** 254-RTI2

**UPC Number:** 781747192547

**Description:** 1-1/2" Raintight Compression Connector, Insulated

**Application:** Compression style connector with internal sealing ring and knockout gasket to create a raintight seal when connecting EMT to box or enclosure. Insulated Throat - 90° C. Patented

**Trade Size:** 1-1/2"

**Country of Manufacture:** USA of USA and Imported Parts

**Std Pkg Qty:** 40

**Unit Qty:** 10