


## Connectors - Zinc

### Images

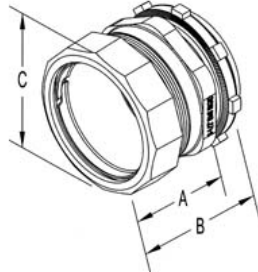

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 2.50

Dimension B in Inches: 3.50

Dimension C in Inches: 4.80

### Application

Used to join steel EMT to box or enclosure. Concrete-tight. 2 1/2" thru 4" suitable for use with Steel EMT. 2-1/2" through 4" also listed for use with Steel and Aluminum Rigid Conduit. CSA Listed Raintight/For Use in Wet Locations in Canada Only

### Product Information

Material: Zinc Die Cast

Finish: Ball burnished, mirror smooth

### Certifications & Codes:

CSA File Number: LR39354

Federal Specification Number: A-A-50553

NEMA Standard: FB-1

UL File Number: E24001

UL Standard: UL-514B

UNSPSC: 39121434

**Catalog ID:** 258-DC2

**UPC Number:** 781747152589

**Description:** Connector, Compression, Zinc Die Cast, Size 3 1/2 Inch

**Application:** Used to join steel EMT to box or enclosure. Concrete-tight. 2 1/2" thru 4" suitable for use with Steel EMT. 2-1/2" through 4" also listed for use with Steel and Aluminum Rigid Conduit. CSA Listed Raintight/For Use in Wet Locations in Canada Only

**Trade Size:** 3-1/2"

**Country of Manufacture:** USA

**Std Pkg Qty:** 6

**Unit Qty:** Bulk