






GE  
Lighting

## 12983 - 25G25 6PK

### GE crystal clear 25 watt G25 1-pack

- Add a decorative touch by using GE Crystal Clear bulbs in chandeliers, sconces or anywhere the bulb is visible.
- Add sparkle to your decorative fixtures with GE crystal clear bulbs. The clear glass and elegant filament design provide a decorative touch in fixtures where the bulb is visible. And, GE crystal clear globes' decorative round shape is perfect for illuminating pendant and vanity fixtures
- G25 globe with medium base for use in vanity strips
- Lasts 1.4 years based on 3 hours per day usage
- 190 lumens providing subtle, reassuring™ light
- 2500K soft white light appearance
- Estimated yearly energy costs \$3.01 based on 3 hours per day \$0.11 per kWh

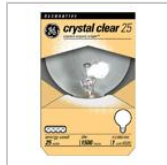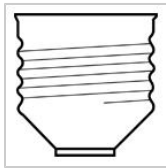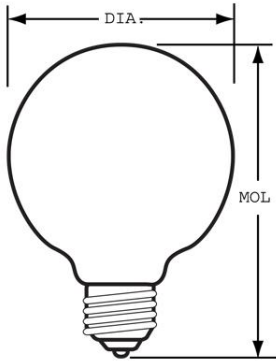

### GENERAL CHARACTERISTICS

Lamp Type	Incandescent - Decorative
Bulb	G25
Base	Medium Screw (E26)
Filament	CC-6
Bulb Finish	Clear
Rated Life (Vert)	1500.0 h
Rated Life	1500.0 hrs
Bulb Material	Soft glass
Primary Application	Globe

### PHOTOMETRIC CHARACTERISTICS

Initial Lumens	190.0
Color Temperature	2500.0 K

### ELECTRICAL CHARACTERISTICS

Wattage	25.0
Voltage	120.0

### DIMENSIONS

Maximum Overall Length (MOL)	4.5000 in(114.3 mm)
Bulb Diameter (DIA)	3.125 in(79.4 mm)

### PRODUCT INFORMATION

Product Code	12983
Description	25G25 6PK
Standard Package	Case
Standard Package GTIN	00043168129831
Standard Package Quantity	6
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	6
UPC	043168908825





GE  
Lighting

## 12983 - 25G25 6PK

### GE crystal clear 25 watt G25 1-pack

- Add a decorative touch by using GE Crystal Clear bulbs in chandeliers, sconces or anywhere the bulb is visible.
- Add sparkle to your decorative fixtures with GE crystal clear bulbs. The clear glass and elegant filament design provide a decorative touch in fixtures where the bulb is visible. And, GE crystal clear globes' decorative round shape is perfect for illuminating pendant and vanity fixtures
- G25 globe with medium base for use in vanity strips
- Lasts 1.4 years based on 3 hours per day usage
- 190 lumens providing subtle, reassuring™ light
- 2500K soft white light appearance
- Estimated yearly energy costs \$3.01 based on 3 hours per day \$0.11 per kWh

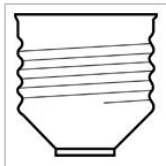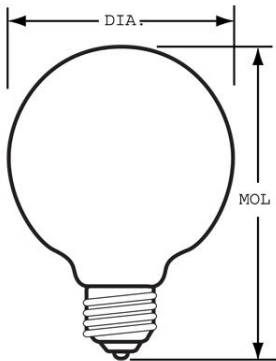

### GENERAL CHARACTERISTICS

Lamp Type	Incandescent - Decorative
Bulb	G25
Base	Medium Screw (E26)
Filament	CC-6
Bulb Finish	Clear
Rated Life (Vert)	1500.0 h
Rated Life	1500.0 hrs
Bulb Material	Soft glass
Primary Application	Globe

### PHOTOMETRIC CHARACTERISTICS

Initial Lumens	190.0
Color Temperature	2500.0 K

### ELECTRICAL CHARACTERISTICS

Wattage	25.0
Voltage	120.0

### DIMENSIONS

Maximum Overall Length (MOL)	4.5000 in(114.3 mm)
Bulb Diameter (DIA)	3.125 in(79.4 mm)

### PRODUCT INFORMATION

Product Code	12983
Description	25G25 6PK
Standard Package	Case
Standard Package GTIN	00043168129831
Standard Package Quantity	6
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	6
UPC	043168908825