




HEATED GEAR



2023

ADVANCED HEAT TECHNOLOGY SYSTEM

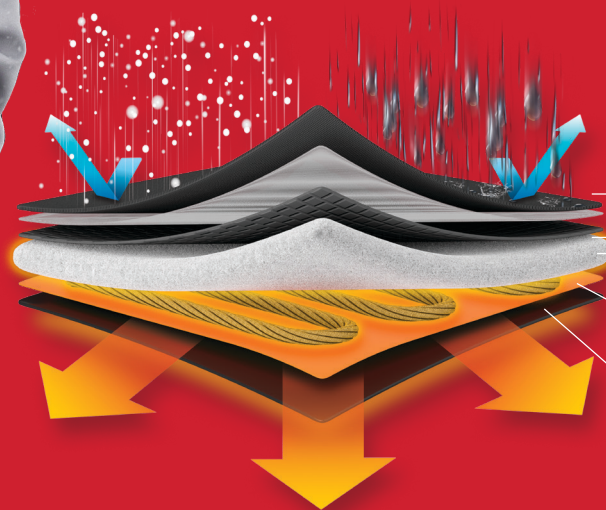

TOUGHSHELL™
Stretch Polyester

Insulation
Traps Heat

Carbon Fiber Coils
Generate Heat

Optimized Liner
Transfers Heat

Born out of necessity on sub-zero commercial jobsites and developed by teams of advanced engineers, MILWAUKEE® M12™ Heated Gear combines patented Carbon Fiber Heating Technology with the power and durability of M12™ REDLITHIUM™ Batteries to battle extreme temperatures.

QUICK HEAT FUNCTION: 3X Faster Heat

ALL-DAY RUN-TIME*

*With M12™ REDLITHIUM™ CP3.0 Battery



HIGH
3
HOURS

MED
6
HOURS

LOW
11
HOURS

Multiple Heat Settings



2023 HEATED GEAR LINEUP

M12

HEATED TOUGHShell™ JACKETS AND VESTS



M12

HEATED AXIS™ JACKETS AND VESTS



M12

HEATED HOODIES



M12

WOMEN'S HEATED GEAR



 
M12
HEATED TOUGHShell™ VEST

TOUGHShell™
HEAT BUILT TO OUTLAST



**FREEFLEX™
MOBILITY**

**REINFORCED
HIGH WEAR ZONES**



**HIDDEN FRONT OR BACK
POCKET BATTERY PLACEMENT**



TOUGHShell™
STRETCH
POLYESTER



**5X
LONGER
LIFE**



**80%
MORE
STRETCH**

**CHEST AND BACK
HEAT ZONES**

**WASHER AND
DRYER SAFE**



**100% POLYESTER
INSULATION**

M12 **HEAT ON
DEMAND**



Gray

M12™ Heated TOUGHShell™ Vest-Only

304G-20S	304G-20XL
304G-20M	304G-202X
304G-20L	304G-203X

Vest-Only Includes:
Heated Vest and Battery Holder.
Battery and Charger Not Included.



M12
HEATED TOUGHShell™ JACKET

**WIND AND WATER
RESISTANT**



**DROP TAIL
EXTENDED BACK**



**HIDDEN FRONT OR BACK
POCKET BATTERY PLACEMENT**

TOUGHShell™

HEAT BUILT TO OUTLAST



**TOUGHShell™
STRETCH
POLYESTER**



**5X
LONGER
LIFE**



**80%
MORE
STRETCH**

**CHEST, BACK AND
FRONT POCKET
HEAT ZONES**

**WASHER AND
DRYER SAFE**



**ADJUSTABLE
CUFFS AND WAIST**

**M12™ COMPACT CHARGER
AND POWER SOURCE**

CHARGES

**M12™
BATTERIES**



**IN WALL OUTLET
OR USB**



**MOBILE
DEVICES**



M12 **HEAT ON
DEMAND**



Black (B)



Gray (G)



Red (R)



Blue (BL)

M12™ Heated TOUGHShell™ Jacket Kit

204(B/G/R/BL)-21S	204(B/G/R/BL)-21XL
204(B/G/R/BL)-21M	204(B/G/R/BL)-212X
204(B/G/R/BL)-21L	204(B/G/R/BL)-213X

M12™ Heated TOUGHShell™ Jacket-Only

204(B/G)-20S	204(B/G)-20XL
204(B/G)-20M	204(B/G)-202X
204(B/G)-20L	204(B/G)-203X



Realtree EDGE®
© 2016 of Jordan
Outdoor Enterprises, Ltd.
all rights reserved.

**M12™ Heated QUIETSHELL
Jacket Kit – Realtree Edge® Camouflage**

224C-21S	224C-21XL
224C-21M	224C-212X
224C-21L	224C-213X

Kit Includes:

Heated Jacket, (1) M12™ REDLITHIUM™ CP3.0 Battery Pack, Micro-USB 3 ft Cable and M12™ Compact Charger and Power Source.

Jacket-Only Includes:

Heated Jacket, M12™ Compact Charger and Power Source. Battery and Charging Cable Not Included.

See Page 9 for Sizing Chart




M12
HEATED AXIS™ VEST

AXIS™
HEAT BUILT FOR
LIGHTWEIGHT DURABILITY

REDLITHIUM™
CP2.0

**WIND AND WATER
RESISTANT**

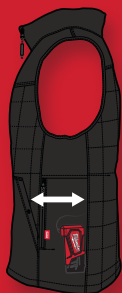

**HIDDEN FRONT OR BACK
POCKET BATTERY PLACEMENT**



AXIS™
RIP STOP
POLYESTER
PREVENTS TEARS FROM SPREADING

**CHEST AND BACK
HEAT ZONES**

**WASHER AND
DRYER SAFE**



**REINFORCED
HIGH WEAR ZONES**

M12 **HEAT ON
DEMAND**



Black (B) Blue (BL)

M12™ Heated AXIS™ Vest Kit

305B-21S	305B-21XL
305B-21M	305B-212X
305B-21L	305B-213X

M12™ Heated AXIS™ Vest-Only

305(B/BL)-20S	305(B/BL)-20XL
305(B/BL)-20M	305(B/BL)-202X
305(B/BL)-20L	305(B/BL)-203X



Black

M12™ Women's Heated AXIS™ Vest Kit

334B-21S	334B-21XL
334B-21M	334B-212X
334B-21L	

M12™ Women's Heated AXIS™ Vest-Only

334B-20S	334B-20XL
334B-20M	334B-202X
334B-20L	

Kit Includes:

Heated Vest, (1) M12™ REDLITHIUM™ CP2.0 Battery Pack, M12™ Charger and Battery Holder.

Vest-Only Includes:

Heated Vest and Battery Holder.
Battery and Charger Not Included.



M12**HEATED AXIS™ HOODED JACKET****WIND AND WATER
RESISTANT****SHOULDER
HEAT ZONES****HIDDEN FRONT OR BACK
POCKET BATTERY PLACEMENT**

AXIS™

**HEAT BUILT FOR
LIGHTWEIGHT DURABILITY**

AXIS™
RIP STOP
POLYESTER

PREVENTS TEARS FROM SPREADING

**CHEST AND BACK
HEAT ZONES****WASHER AND
DRYER SAFE****REINFORCED
HIGH WEAR ZONES****M12™ COMPACT CHARGER
AND POWER SOURCE****CHARGES****M12™
BATTERIES****IN WALL OUTLET
OR USB****MOBILE
DEVICES****M12****HEAT ON
DEMAND**

Black (B)



Gray (G)

M12™ Heated AXIS™ Jacket Kit

205(B/G)-21S	205(B/G)-21XL
205(B/G)-21M	205(B/G)-212X
205(B/G)-21L	205(B/G)-213X



Black (B)



Gray (G)

**M12™ Women's Heated AXIS™
Jacket Kit**

234(B/G)-21S	234(B/G)-21XL
234(B/G)-21M	234(B/G)-212X
234(B/G)-21L	

Kit Includes:

Heated Jacket, (1) M12™ REDLITHIUM™ CP3.0 Battery Pack, Micro-USB 3 ft Cable and M12™ Compact Charger and Power Source.

REDLITHIUM™
CP3.0

See Page 9 for Sizing Chart



M12 HEATED HOODIE

RAGLAN SLEEVE CONSTRUCTION

Designed to Move and Layer.



HIDDEN FRONT OR BACK POCKET BATTERY PLACEMENT

RIB KNIT CUFFS AND WAIST

HEAT BUILT FOR COMPLETE COMFORT

FITTED HOOD Full Range of Vision

CHEST AND BACK HEAT ZONES

DURABLE UTILITY POCKETS Reinforced Edges

WASHER AND DRYER SAFE



REDLITHIUM™
CP2.0

M12™ HEAT ON DEMAND



Black (B) Gray (G)

M12™ Heated Hoodie Kit

306(B/G)-21S	306(B/G)-21XL
306(B/G)-21M	306(B/G)-212X
306(B/G)-21L	306(B/G)-213X

M12™ Heated Hoodie-Only

306(B/G/R/HV/GN)-20S	306(B/G/R/HV/GN)-20XL
306(B/G/R/HV/GN)-20M	306(B/G/R/HV/GN)-202X
306(B/G/R/HV/GN)-20L	306(B/G/R/HV/GN)-203X



Red (R) Hi-Vis (HV) Green (GN)



Black (B) Gray (G)

M12™ Women's Heated Hoodie Kit

336(B/G/R/BL)-21S	336(B/G/R/BL)-21XL
336(B/G/R/BL)-21M	336(B/G/R/BL)-212X
336(B/G/R/BL)-21L	



Red (R) Blue (BL)

Kit Includes:

Heated Hoodie, (1) M12™ REDLITHIUM™ CP2.0 Battery Pack, M12™ Charger and Battery Holder.


Hoodie-Only Includes:

Heated Hoodie and Battery Holder.
Battery and Charger Sold Separately.



MILWAUKEE® SIZING CHART


For best fit, measure body at specified points and match measurement to appropriate size range.

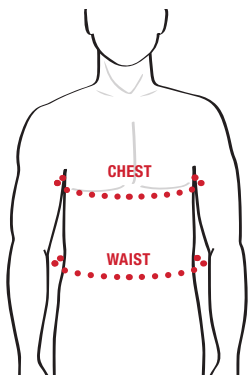

MEN'S REGULAR FIT

Comfortable with room to move

SIZE	S	M	L	XL	2X	3X
CHEST (in)	34" – 36"	38" – 40"	42" – 44"	46" – 48"	50" – 52"	54" – 56"
WAIST (in)	28½" – 30½"	32½" – 34½"	36½" – 38½"	41" – 43½"	46" – 48½"	51" – 53½"

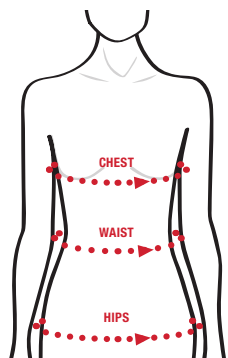

WOMEN'S REGULAR FIT

Fits true to size

SIZE	S	M	L	XL	2X
CHEST (in)	34½" – 35½"	36½" – 37½"	38½" – 41"	42" – 44"	45" – 48"
WAIST (in)	27½" – 28½"	29½" – 30½"	31½" – 34"	35" – 37"	38" – 40"
HIPS (in)	36½" – 37½"	38½" – 39½"	41" – 43"	44" – 46"	47" – 49"



Milwaukee®

A construction worker wearing a grey knit beanie, safety glasses, and a dark jacket is measuring a wooden beam on a roof. The worker is holding a long, yellow measuring tape against the beam. The background shows a residential neighborhood with houses and bare trees. The entire image has a red color overlay. The Milwaukee logo, featuring the brand name in a stylized font with a lightning bolt, is prominently displayed across the center of the image.