


Squeeze Type - Zinc

Images

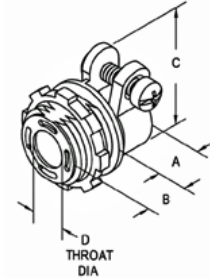

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-1/8
Dimension B in Inches: 1/2
Dimension C in Inches: 1-3/4
Dimension D in Inches: .743

Application

Used to connect steel flexible metal conduit or XRW FMC to box or enclosure. Insulator rated 105 degree C.

Product Information

Material: Zinc Die Cast
Finish: Ball burnished, mirror smooth

Certifications & Codes:

Federal Specification Number:	A-A-50552
NEMA Standard:	FB-1
UL File Number:	E9391
UL Standard:	UL-514B
UNSPSC:	39121419

Catalog ID: 408-DC12

UPC Number: 781747164087

Description: Connector, Squeeze, Zinc Die Cast, Insulated Throat, Trade Size 3/4 Inch

Application: Used to connect steel flexible metal conduit or XRW FMC to box or enclosure. Insulator rated 105 degree C.

Trade Size: 3/4"

Country of Manufacture: USA

Std Pkg Qty: 100

Unit Qty: 25