






GE
Lighting

27495 - 40A15/F/CD

GE appliance 40 watt A15 1-pack

- GE's specialty bulbs offer innovative solutions for a variety of lighting needs.
- GE's Appliance Lights can be used in many household appliances such as microwaves, refrigerators and ovens.
- 120 volts
- A15 shape with medium base for use in appliances
- Lasts 1500 hours
- Whether you're cooking it or keeping it fresh GE appliance lights lets you see it. They're specially designed to withstand high or low temperatures and feature a rugged filament that resists vibration, perfect for microwaves, refrigerators and ovens

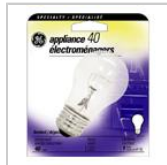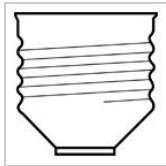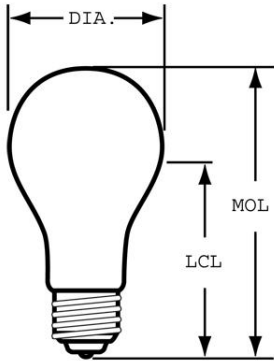

GENERAL CHARACTERISTICS

| | |
|---------------------|-----------------------|
| Lamp Type | Incandescent - A-line |
| Bulb | A15 |
| Base | Medium Screw (E26) |
| Filament | C-9 |
| Bulb Finish | Frost |
| Rated Life (NOM) | 1500.0 h |
| Bulb Material | Soft glass |
| Primary Application | Standard;Ceiling Fan |

PHOTOMETRIC CHARACTERISTICS

| | |
|---------------------------------------|----------|
| Initial Lumens (NOM) | 355.0 |
| Color Temperature (NOM) | 2600.0 K |
| Nominal Initial Lumens per Watt (NOM) | 8.875 |

ELECTRICAL CHARACTERISTICS

| | |
|---------------|----------------------------|
| Wattage (NOM) | 40.0 |
| Voltage (NOM) | 120.0 |
| Burn Position | Universal burning position |

DIMENSIONS

| | |
|------------------------------------|-------------------|
| Maximum Overall Length (MOL) (NOM) | 3.500 in(88.9 mm) |
| Bulb Diameter (DIA) (NOM) | 1.875 in(47.6 mm) |
| Light Center Length (LCL) (NOM) | 2.370 in(60.2 mm) |

PRODUCT INFORMATION

| | |
|----------------------------------|----------------|
| Product Code | 27495 |
| Description | 40A15/F/CD |
| Standard Package | BUNDLE |
| Standard Package GTIN | 30043168274952 |
| Standard Package Quantity | 60 |
| Sales Unit | Unit |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard Package | 60 |
| UPC | 043168274951 |






GE
Lighting

27495 - 40A15/F/CD

GE appliance 40 watt A15 1-pack

- GE's specialty bulbs offer innovative solutions for a variety of lighting needs.
- GE's Appliance Lights can be used in many household appliances such as microwaves, refrigerators and ovens.
- 120 volts
- A15 shape with medium base for use in appliances
- Lasts 1500 hours
- Whether you're cooking it or keeping it fresh GE appliance lights lets you see it. They're specially designed to withstand high or low temperatures and feature a rugged filament that resists vibration, perfect for microwaves, refrigerators and ovens

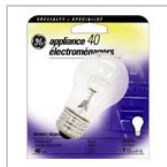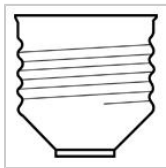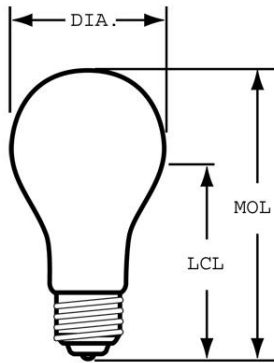

GENERAL CHARACTERISTICS

| | |
|---------------------|-----------------------|
| Lamp Type | Incandescent - A-line |
| Bulb | A15 |
| Base | Medium Screw (E26) |
| Filament | C-9 |
| Bulb Finish | Frost |
| Rated Life (NOM) | 1500.0 h |
| Bulb Material | Soft glass |
| Primary Application | Standard;Ceiling Fan |

PHOTOMETRIC CHARACTERISTICS

| | |
|---------------------------------------|----------|
| Initial Lumens (NOM) | 355.0 |
| Color Temperature (NOM) | 2600.0 K |
| Nominal Initial Lumens per Watt (NOM) | 8.875 |

ELECTRICAL CHARACTERISTICS

| | |
|---------------|----------------------------|
| Wattage (NOM) | 40.0 |
| Voltage (NOM) | 120.0 |
| Burn Position | Universal burning position |

DIMENSIONS

| | |
|------------------------------------|-------------------|
| Maximum Overall Length (MOL) (NOM) | 3.500 in(88.9 mm) |
| Bulb Diameter (DIA) (NOM) | 1.875 in(47.6 mm) |
| Light Center Length (LCL) (NOM) | 2.370 in(60.2 mm) |

PRODUCT INFORMATION

| | |
|----------------------------------|----------------|
| Product Code | 27495 |
| Description | 40A15/F/CD |
| Standard Package | BUNDLE |
| Standard Package GTIN | 30043168274952 |
| Standard Package Quantity | 60 |
| Sales Unit | Unit |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard Package | 60 |
| UPC | 043168274951 |