



Catalog Number: 4412-GSC3R-NK
Item Description: N3R SCREW CVR GUTTER NK
UPC Code: 784572106307





Brand Name: Milbank
Type: Wiring Trough
Special Features: Key Locking Cylinder Latch Provision,
Sealing Eye Lance
Application: Wireway
Standard: UL Listed, Type 3R
Cover Type: Screw Cover
Enclosure: Outdoor Enclosure
Nominal Cross Section: 4x4
Straight Section Length: 12
Material: Steel with Powder Coat Finish
Finish: ANSI 61 Gray
Knockouts: False




 
Utility requirements may vary. Always consult the serving utility for their requirements prior to ordering or installing this equipment. This product must always be installed by a licensed electrician. Installation of this equipment may require local electrical inspector approval.

| CAT. NO. | U/L LABEL |
|---------------|-----------|
| 4412-GSC3R | 1002943 |
| RC-4412-GSC3R | 1125051 |
| SPRSCG-4412 | 1132575 |

| ITEM | QTY. | PART NUMBER | DESCRIPTION |
|------|------|-------------|-------------------------|
| 1 | 1 | 1152999 | BACK WELDMENT |
| 2 | 1 | 1011015 | FRONT |
| 3 | 2 | 1001290 | SCREW, 10-32 X 5/16 |
| 4 | 1 | 1002898 | LABEL, RATING 4x4 GSC3R |
| 5 | 1 | (SEE CHART) | UL LABEL, WIREWAY |

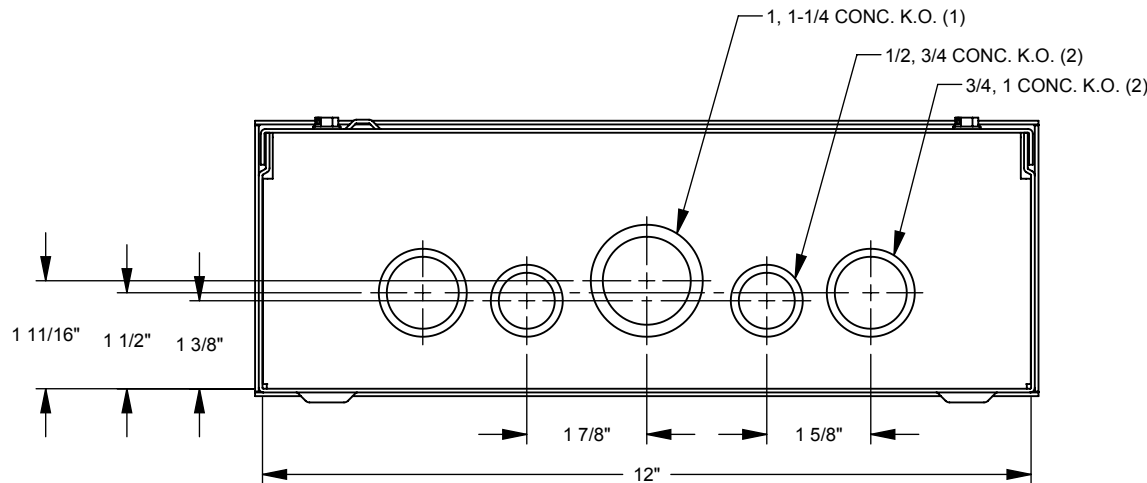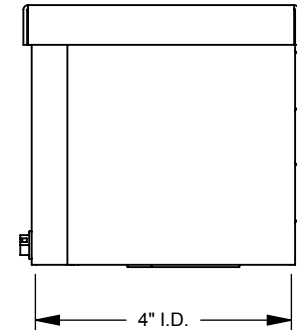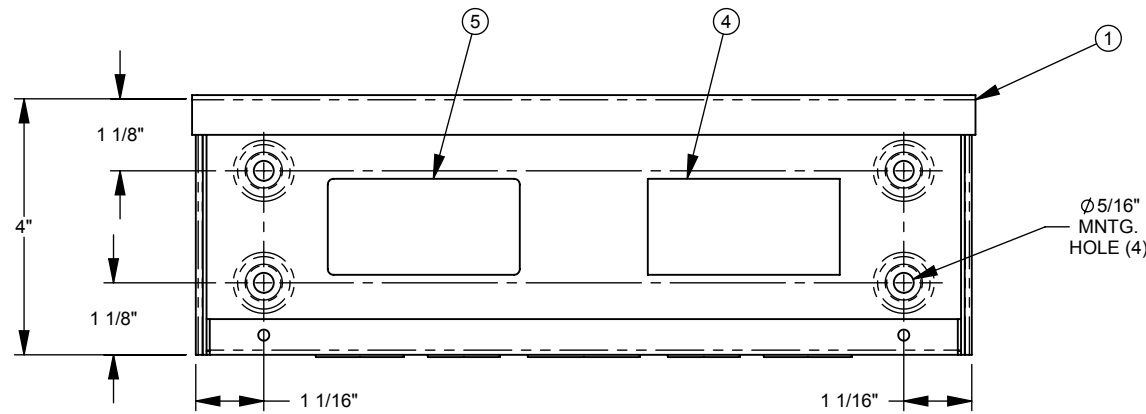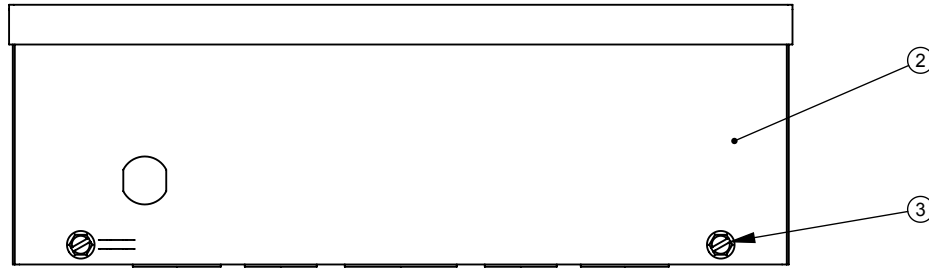

OLD DRAWING NO.: 267

| | | |
|--|--------------------|---|
| Material: | 16 GA. GALV. STEEL |  <p>General Offices: Kansas City, MO</p> |
| Shear/ Die#: | | |
| Finish: | MILBANK LIGHT GRAY | Title: SCREW COVER WIREWAY NEMA TYPE 3R |
| Part Wt.: | | Catalog No.: (SEE CHART) |
| Tolerances: Unless Specified Otherwise X.X ±.1 X.XX ±.03 X.XXX ±.015 X* ±2* | | Customer: |
| Third Angle  | | Drawing No.: 1001722 |
| Scale: | NTS | Date: 5/5/11 |
| Checked By: | | Sheet 1 of 1 |
| Approved By: | D.F. | |

| REV. | DATE | DESCRIPTION | BY |
|------|---------|--|------|
| A3 | 5/5/11 | REDRAW INTO SOLIDWORKS; UPDATE K.O. PATTERN (ECO #20576) | D.F. |
| A4 | 6/28/11 | DRAWING NUMBER WAS 267 (ECO #20896) | D.F. |



Catalog Number: 4412-GSC3R-NK
Item Description: N3R SCREW CVR GUTTER NK
UPC Code: 784572106307





Brand Name: Milbank
Type: Wiring Trough
Special Features: Key Locking Cylinder Latch Provision,
Sealing Eye Lance
Application: Wireway
Standard: UL Listed, Type 3R
Cover Type: Screw Cover
Enclosure: Outdoor Enclosure
Nominal Cross Section: 4x4
Straight Section Length: 12
Material: Steel with Powder Coat Finish
Finish: ANSI 61 Gray
Knockouts: False




Utility requirements may vary. Always consult the serving utility for their requirements prior to ordering or installing this equipment. This product must always be installed by a licensed electrician. Installation of this equipment may require local electrical inspector approval.

| CAT. NO. | U/L LABEL |
|---------------|-----------|
| 4412-GSC3R | 1002943 |
| RC-4412-GSC3R | 1125051 |
| SPRSCG-4412 | 1132575 |

| ITEM | QTY. | PART NUMBER | DESCRIPTION |
|------|------|-------------|-------------------------|
| 1 | 1 | 1152999 | BACK WELDMENT |
| 2 | 1 | 1011015 | FRONT |
| 3 | 2 | 1001290 | SCREW, 10-32 X 5/16 |
| 4 | 1 | 1002898 | LABEL, RATING 4x4 GSC3R |
| 5 | 1 | (SEE CHART) | UL LABEL, WIREWAY |

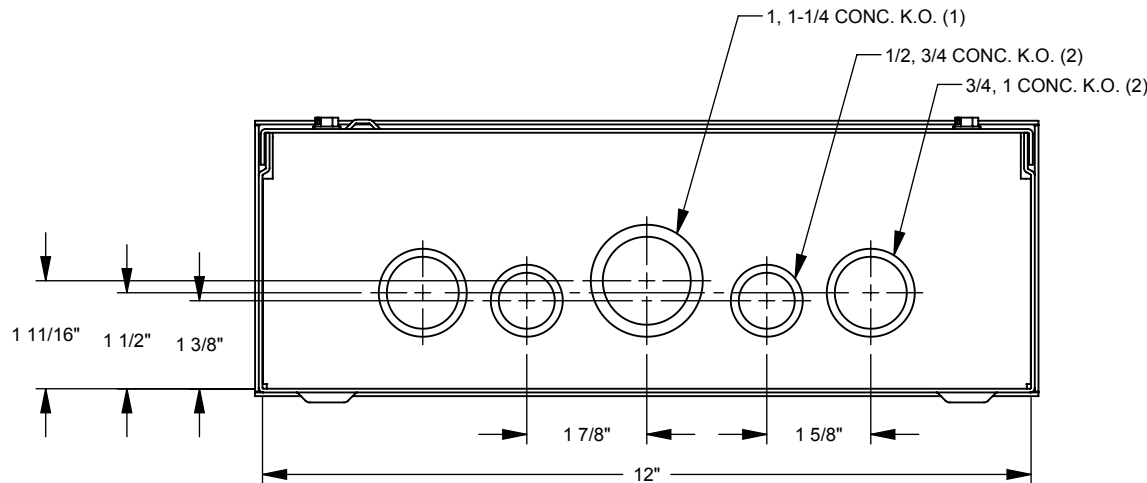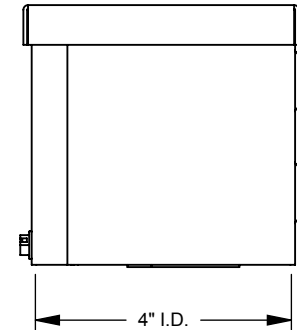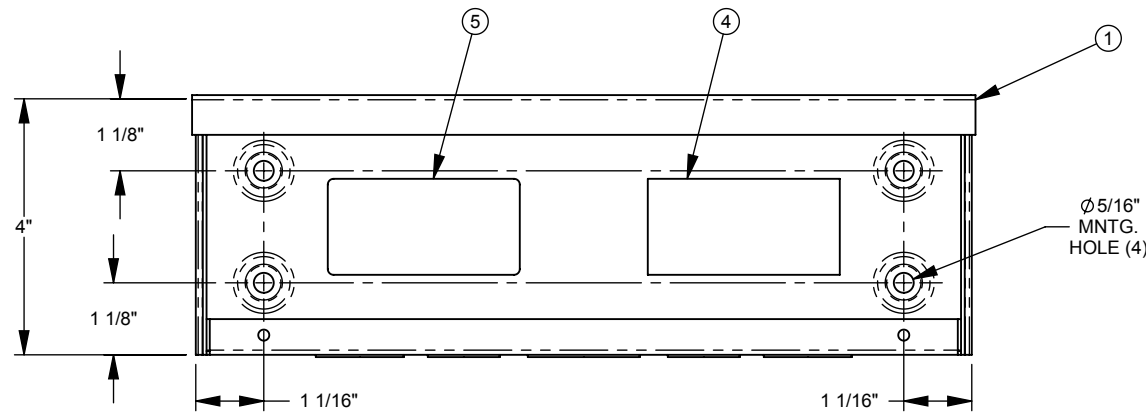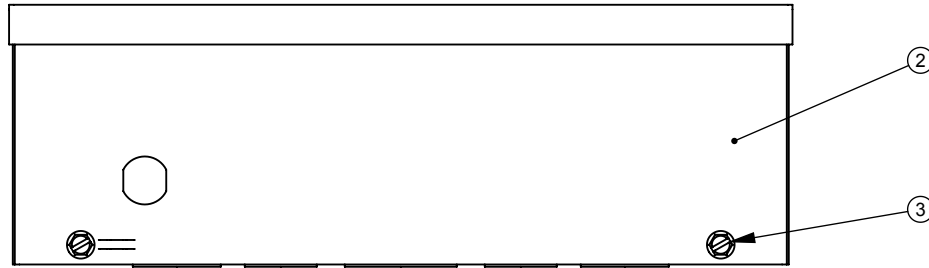

OLD DRAWING NO.: 267

| | | | |
|--|--------------------|---|--------------------------------------|
| Material: | 16 GA. GALV. STEEL |  <p>General Offices: Kansas City, MO</p> | |
| Shear/ Die#: | | | |
| Finish: | MILBANK LIGHT GRAY | Title: | SCREW COVER WIREWAY NEMA TYPE 3R |
| Part Wt.: | | Catalog No.: | (SEE CHART) |
| Tolerances: Unless Specified Otherwise X.X ±.1 X.XX ±.03 X.XXX ±.015 X* ±2* | | Customer: | |
| Scale: NTS Drawn By: D.F. | | Checked By: Approved By: | Drawing No.: 1001722 Date: 5/5/11 |
| | | Sheet | 1 of 1 |

| REV. | DATE | DESCRIPTION | BY |
|------|---------|--|------|
| A3 | 5/5/11 | REDRAW INTO SOLIDWORKS; UPDATE K.O. PATTERN (ECO #20576) | D.F. |
| A4 | 6/28/11 | DRAWING NUMBER WAS 267 (ECO #20896) | D.F. |