


## Zinc

### Images

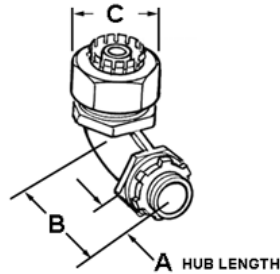

### Application

90 Degree connector for use with metallic and nonmetallic "Type B" liquid tight conduit.

### Product Information

Material: Zinc Cast

Finish: Zinc electro-plate

### Certifications & Codes:

CSA File Number:	LR39354
Federal Specification Number:	A-A-50552
NEMA Standard:	FB-1
UL File Number:	E9391
UL Standard:	UL-514B
UNSPSC:	39121420

[Download Photo Image](#)   [Download Dimensional Image](#)  
Dimension A in Inches: 9/16  
Dimension B in Inches: 1-3/4  
Dimension C in Inches: 1-3/4

**Catalog ID:** 471-LT2

**UPC Number:** 781747154712

**Description:** Connector, Liquid Tight, Cast Zinc, Size 3/4 Inch

**Application:** 90 Degree connector for use with metallic and nonmetallic "Type B" liquid tight conduit.

**Trade Size:** 3/4"

**Std Pkg Qty:** 50

**Unit Qty:** 10