

# SNAP<sup>2</sup>IT<sup>®</sup> MC Cable Connectors

with Locknut • Easy Snap-in Cable Insertion • NO TOOLS!



1/2" KO  
3838A  
installed in  
light fixture  
with locknut


Easy, snap  
onto cable  
installation

Snap on  
side

Threaded  
side

4040A  
1/2" KO

Snap  
onto cable  
**SAVES 12  
SECONDS  
per connector**

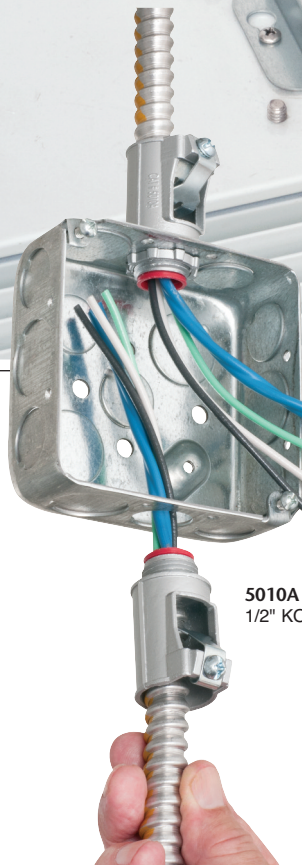

Ideal  
for MC-PCS  
conduit

5010A  
1/2" KO

38A

40A

3838A

4040A

505010A

Locknut  
attachment  
in box

Arlington's SNAP<sup>2</sup>IT<sup>®</sup> fittings with locknuts deliver a fast, safe installation.

Fitting-on-cable installation is easy, and requires NO TOOLS! Just snap the fitting onto cable and twist clockwise. Tangs inside the fitting hold the cable secure.




With this series the assembly installs into the knockout with a LOCKNUT.

The red tinting in the 40A, 4010A and 4040A indicates our 'OPEN TANG' design, meaning more room inside the fitting for easy insertion of wires.

- **Widest total cable ranges**  
14/2 to 6/3
- **Widest variety of cables**  
For AC, MCI-A, HCF steel and aluminum, steel and aluminum flexible metal conduit, MCI cable, continuous corrugated aluminum, AC90 and ACG90
- **Secure installation** No pullout
- Meets UL ground fault requirements
- **Fully assembled – Ready to use – Reusable connector**  
For 1/2" KO, in single and duplex styles, all with insulated throat

Patented

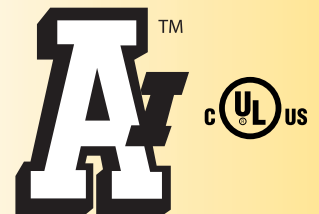


**Arlington<sup>®</sup>**

1 Stauffer Industrial Park  
Scranton, PA 18517  
800/233.4717 • Fax 570/562.0646  
www.aifittings.com

CATALOG NUMBER	UPC/DCI/NAED MFG. #018997	DESCRIPTION SNAP ON FITTINGS	CABLE TRADE SIZE	KO SIZE	CABLE (OD) OUTSIDE DIA.	CABLE SIZE	UNIT PKG	STD PKG
38A	00038	Single gang, SILVER inside	3/8"	1/2"	.405 to .610	14/2 & 12/2 w and w/o ground, 14/3, 14/4,	50	500
3838A	36200	Duplex, SILVER inside	3/8"	1/2"	(2) .405 to .610	12/3, 12/4, 10/2, 10/3	25	100
40A	48015	Single gang, RED TINT Open Tang	3/8"	1/2"	.485 to .610	14/3, 12/2 & 12/3 w and w/o ground, 14/4,	50	500
4010A	11420	Single gang, RED TINT Open Tang	3/8"	1/2"	.405 to .610	12/4, 10/2, 10/3	50	500
4040A	40350	Duplex, RED TINT Open Tang	3/8"	1/2"	(2) .485 to .610		25	100
5010A	01299	Single gang, SILVER inside	1/2"	1/2"	.580 to .780		25	250
505010A	76214	Duplex, SILVER inside	1/2"	3/4"	(2) .590 to .820	10/3 to 6/3	25	25

# SNAP<sup>2</sup>IT<sup>®</sup> MC Cable Connectors

with Locknut • Easy Snap-in Cable Insertion • NO TOOLS!

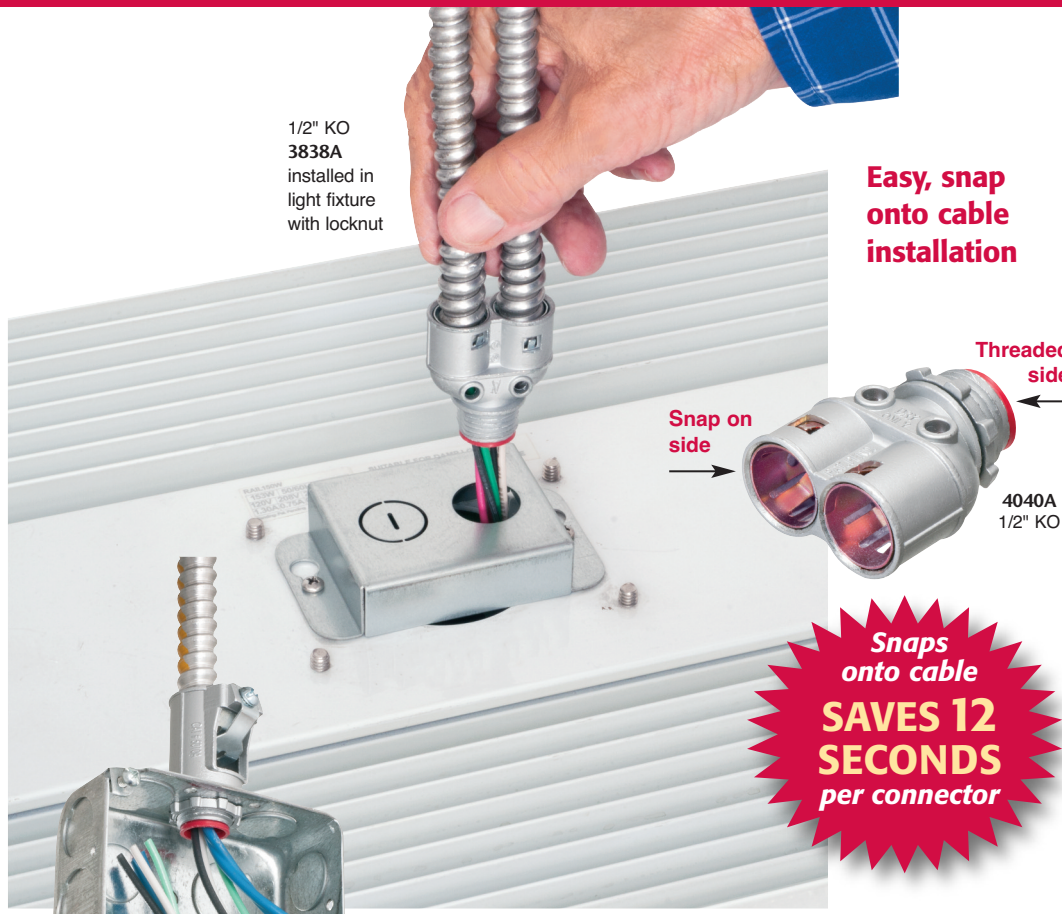

1/2" KO  
3838A  
installed in  
light fixture  
with locknut


Easy, snap  
onto cable  
installation

Snap on  
side

Threaded  
side

4040A  
1/2" KO

Snap  
onto cable  
**SAVES 12  
SECONDS  
per connector**

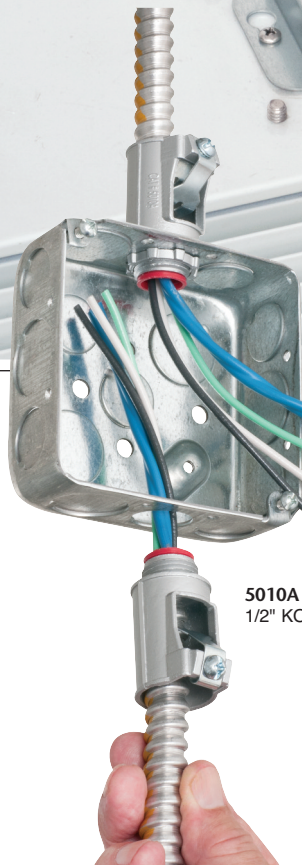

Ideal  
for MC-PCS  
conduit

5010A  
1/2" KO

38A

40A

3838A

4040A

505010A

Locknut  
attachment  
in box

Arlington's SNAP<sup>2</sup>IT<sup>®</sup> fittings with locknuts deliver a fast, safe installation.

Fitting-on-cable installation is easy, and requires NO TOOLS! Just snap the fitting onto cable and twist clockwise. Tangs inside the fitting hold the cable secure.




With this series the assembly installs into the knockout with a LOCKNUT.

The red tinting in the 40A, 4010A and 4040A indicates our 'OPEN TANG' design, meaning more room inside the fitting for easy insertion of wires.

- **Widest total cable ranges**  
14/2 to 6/3
- **Widest variety of cables**  
For AC, MCI-A, HCF steel and aluminum, steel and aluminum flexible metal conduit, MCI cable, continuous corrugated aluminum, AC90 and ACG90
- **Secure installation** No pullout
- Meets UL ground fault requirements
- **Fully assembled – Ready to use – Reusable connector**  
For 1/2" KO, in single and duplex styles, all with insulated throat

Patented

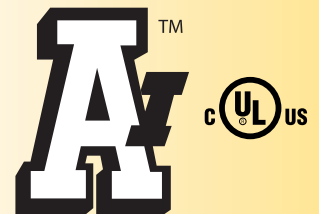

**Arlington<sup>®</sup>**

1 Stauffer Industrial Park  
Scranton, PA 18517  
800/233.4717 • Fax 570/562.0646  
www.aifittings.com

CATALOG NUMBER	UPC/DCI/NAED MFG. #018997	DESCRIPTION SNAP ON FITTINGS	CABLE TRADE SIZE	KO SIZE	CABLE (OD) OUTSIDE DIA.	CABLE SIZE	UNIT PKG	STD PKG
38A	00038	Single gang, SILVER inside	3/8"	1/2"	.405 to .610	14/2 & 12/2 w and w/o ground, 14/3, 14/4,	50	500
3838A	36200	Duplex, SILVER inside	3/8"	1/2"	(2) .405 to .610	12/3, 12/4, 10/2, 10/3	25	100
40A	48015	Single gang, RED TINT Open Tang	3/8"	1/2"	.485 to .610	14/3, 12/2 & 12/3 w and w/o ground, 14/4,	50	500
4010A	11420	Single gang, RED TINT Open Tang	3/8"	1/2"	.405 to .610	12/4, 10/2, 10/3	50	500
4040A	40350	Duplex, RED TINT Open Tang	3/8"	1/2"	(2) .485 to .610		25	100
5010A	01299	Single gang, SILVER inside	1/2"	1/2"	.580 to .780		25	250
505010A	76214	Duplex, SILVER inside	1/2"	3/4"	(2) .590 to .820	10/3 to 6/3	25	25