


## AC/MC/NM - Two Screw - Strap Type

### Images

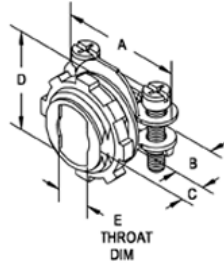

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-5/16

Dimension B in Inches: 7/16

Dimension C in Inches: 3/8

Dimension D in Inches: 15/16

Dimension E in Inches: .370

### Application

Recommended cable types to connect AC/MC/MCI-A/NM-B cable to box or enclosure. 12/2 (.44" 0 min) to 10/3 (.53" 0 max) For use with HCF/HCFMCI-A

### Product Information

Material: Zinc Die Cast

Finish: Ball burnished, mirror smooth

### Certifications & Codes:

Federal Specification Number: A-A-50552

NEMA Standard: FB-1

UL File Number: E20534

UL Standard: UL-514B

UNSPSC: 39121419

**Catalog ID:** 566-DC2

**UPC Number:** 781747155665

**Description:** Connector, Strap, Two Screw, Zinc Die Cast, Size K.O. 1/2 Inch, Rectangular throat

**Application:** Recommended cable types to connect AC/MC/MCI-A/NM-B cable to box or enclosure. 12/2 (.44" 0 min) to 10/3 (.53" 0 max) For use with HCF/HCFMCI-A

**Trade Size:** 1/2"

**Std Pkg Qty:** 1000

**Unit Qty:** 100