


"U" Strap Type - Zinc

Images

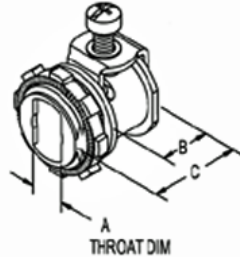

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 3/8

Dimension B in Inches: 5/8

Dimension C in Inches: 1

Application

Recommended cable types to connect MC & AC or 3/8 Inch flexible metal conduit to box or enclosure. 14/2 (.38" 0 min) to 10/3 (.61" 0 max) AC/MC/MCI-A/HCF/HCFMCIA

Product Information

Material: Zinc Die Cast

Certifications & Codes:

Federal Specification Number: A-A-50552

UL File Number: E20534

UL Standard: UL-514B

UNSPSC: 39121419

Catalog ID: 570-DC2

UPC Number: 781747155702

Description: Strap Connector, Single Screw, Zinc Die Cast, Trade Size 3/8 Inch

Application: Recommended cable types to connect MC & AC or 3/8 Inch flexible metal conduit to box or enclosure. 14/2 (.38" 0 min) to 10/3 (.61" 0 max) AC/MC/MCI-A/HCF/HCFMCIA

Trade Size: 3/8"

Country of Manufacture: USA

Std Pkg Qty: 500

Unit Qty: 50