


## "U" Strap Type - Zinc

### Images

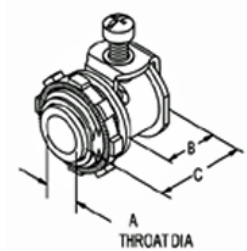

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 13/32

Dimension B in Inches: 5/8

Dimension C in Inches: 1

### Application

Recommended cable types to connect MC & AC cable or 3/8 Inch flexible metal conduit to box or enclosure. 14/2 (.38" 0 min) to 10/3 (.61" 0 max) MCI-A/HCF/HCFMCIA

### Product Information

Material: Zinc Die Cast

Finish: Ball burnished, mirror smooth. Strap:  
Zinc electro-plate

### Certifications & Codes:

Federal Specification Number: A-A-50552

UL File Number: E20534

UL Standard: UL-514B

UNSPSC: 39121419

**Catalog ID:** 570-DC12

**UPC Number:** 781747165701

**Description:** Low Profile "U" Shaped Strap Connectors, Zinc Die Cast/Insulated Throat

**Application:** Recommended cable types to connect MC & AC cable or 3/8 Inch flexible metal conduit to box or enclosure. 14/2 (.38" 0 min) to 10/3 (.61" 0 max) MCI-A/HCF/HCFMCIA

**Trade Size:** 3/8"

**Country of Manufacture:** USA

**Std Pkg Qty:** 500

**Unit Qty:** 50