


## Medium base ceiling lampholders

### Product description

Medium base  
660W, 125V/AC  
660W, 250V/AC

### Features

- Mounts on 4" (101.6mm) outlet boxes with breakout for 3.25" (82.5mm) box mounting
- Leads are 6" (152.4mm) 221°F (105°C) insulated stranded #16, stripped 0.75" (19.0mm)
- Pull chain devices include ball chain, 3' (0.9m) of cord, connector and end bell
- Top wire versions have terminal screws backed out – ready for wiring – without removing interior
- Push wire terminals are top wired with two push-in terminals and two screw terminals for continuous wiring
- Plastic models made with high-temperature thermoset plastic to reduce breakage
- Porcelain models made with high-strength insulator porcelain; pull chain versions feature removable interiors

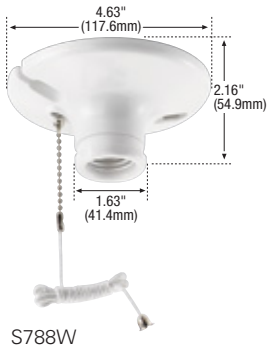

S788W



S1174W



669



604

### Plastic ceiling lampholders



Rating		Description	Color	Catalog no.	USA	RoHS
W	V/AC					
660	250	Two piece, push wire/top wire, pull chain switch	W	<input type="checkbox"/> S759W-CD	•	•
		Two piece, 6" (152.4mm) leads, pull chain switch	W	<input type="checkbox"/> S788W	•	•
		Two-piece, with 15A 125V/AC NEMA 1-15P 2P, 2W outlet push wire/top wire, pull chain switch	W	<input type="checkbox"/> S860W	•	•
		Two-piece, with 15A 125V/AC NEMA 1-15P 2P, 2W outlet push wire/top wire, pull chain switch	W	<input type="checkbox"/> S865W	•	•
		One piece, 4 top wire screws, keyless switch	W	<input type="checkbox"/> S1174W	•	•
		One piece, 6" (152.4mm) leads, keyless switch	W	<input type="checkbox"/> S1174-6W*	•	•
		Two piece, push wire/top wire, keyless switch	W	<input type="checkbox"/> S768W	•	•
		Two piece, 6" (152.4mm) leads, keyless switch	W	<input type="checkbox"/> S768-6W*	•	•

\* Not cULus Listed & NOM certified

### Porcelain ceiling lampholders



Rating		Description	Color	Catalog no.	USA	RoHS
W	V/AC					
660	125	Two piece, w/ 15A 125V/AC 2P 2W outlet, 2 screw terminals, top wire, pull chain switch	W	<input type="checkbox"/> 669	•	•
		Two piece, w/ 15A 125V/AC 2P 3W outlet, 2 screw terminals, top wire, pull chain switch	W	<input type="checkbox"/> 667	•	•
660	250	One piece, w/ feed-through, 4 screw terminals, top wire, keyless switch	W	<input type="checkbox"/> 604	•	•
		Two piece, w/ feed-through, 4 screw terminals, top wire, pull chain switch	W	<input type="checkbox"/> 659	•	•

### Color information:

W (White)



(White)

Compliances, specifications and availability are subject to change without notice.

Indicates NAFTA compliant - Page Q-32

RoHS compliant - Page Q-32


## Medium base ceiling lampholders

### Product description

Medium base  
660W, 125V/AC  
660W, 250V/AC

### Features

- Mounts on 4" (101.6mm) outlet boxes with breakout for 3.25" (82.5mm) box mounting
- Leads are 6" (152.4mm) 221°F (105°C) insulated stranded #16, stripped 0.75" (19.0mm)
- Pull chain devices include ball chain, 3' (0.9m) of cord, connector and end bell
- Top wire versions have terminal screws backed out – ready for wiring – without removing interior
- Push wire terminals are top wired with two push-in terminals and two screw terminals for continuous wiring
- Plastic models made with high-temperature thermoset plastic to reduce breakage
- Porcelain models made with high-strength insulator porcelain; pull chain versions feature removable interiors

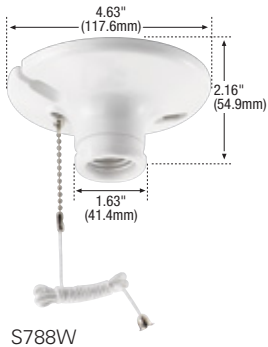

S788W



S1174W



669



604

### Plastic ceiling lampholders



Rating		Description	Color	Catalog no.	
W	V/AC				
660	250	Two piece, push wire/top wire, pull chain switch	W	<input type="checkbox"/> S759W-CD	•
		Two piece, 6" (152.4mm) leads, pull chain switch	W	<input type="checkbox"/> S788W	•
		Two-piece, with 15A 125V/AC NEMA 1-15P 2P, 2W outlet push wire/top wire, pull chain switch	W	<input type="checkbox"/> S860W	•
		Two-piece, with 15A 125V/AC NEMA 1-15P 2P, 2W outlet push wire/top wire, pull chain switch	W	<input type="checkbox"/> S865W	•
		One piece, 4 top wire screws, keyless switch	W	<input type="checkbox"/> S1174W	• •
		One piece, 6" (152.4mm) leads, keyless switch	W	<input type="checkbox"/> S1174-6W*	• •
		Two piece, push wire/top wire, keyless switch	W	<input type="checkbox"/> S768W	•
		Two piece, 6" (152.4mm) leads, keyless switch	W	<input type="checkbox"/> S768-6W*	•

\* Not cULus Listed & NOM certified

### Porcelain ceiling lampholders



Rating		Description	Color	Catalog no.	
W	V/AC				
660	125	Two piece, w/ 15A 125V/AC 2P 2W outlet, 2 screw terminals, top wire, pull chain switch	W	<input type="checkbox"/> 669	•
		Two piece, w/ 15A 125V/AC 2P 3W outlet, 2 screw terminals, top wire, pull chain switch	W	<input type="checkbox"/> 667	•
660	250	One piece, w/ feed-through, 4 screw terminals, top wire, keyless switch	W	<input type="checkbox"/> 604	•
		Two piece, w/ feed-through, 4 screw terminals, top wire, pull chain switch	W	<input type="checkbox"/> 659	•

### Color information:

W (White)



(White)

Compliances, specifications and availability are subject to change without notice.

Indicates NAFTA compliant - Page Q-32

RoHS compliant - Page Q-32