



Catalog Number: 6624-GSC3R-NK  
Item Description: N3R SCREW CVR GUTTER NK  
UPC Code: 784572107892



Brand Name: Milbank  
Type: Wiring Trough  
Special Features: Key Locking Cylinder Latch Provision,  
Sealing Eye Lance  
Application: Wireway  
Standard: UL Listed, Type 3R  
Cover Type: Screw Cover  
Enclosure: Outdoor Enclosure  
Nominal Cross Section: 6x6  
Straight Section Length: 24  
Material: Steel with Powder Coat Finish  
Finish: ANSI 61 Gray  
Knockouts: False


 


*Utility requirements may vary. Always consult the serving utility for their requirements prior to ordering or installing this equipment. This product must always be installed by a licensed electrician. Installation of this equipment may require local electrical inspector approval.*

CAT. NO.	U/L LABEL	SUFFIX	MATERIAL	FINISH	BACK WELDMENT	FRONT	K.O.s INSTALLED
6624-GSC3R-()	1002943	NONE	16 GA. GALV. STEEL	MILBANK LIGHT GRAY	1153010	1004419	YES
RC-6624-GSC3R-()	1125051	-NK	16 GA. GALV. STEEL	MILBANK LIGHT GRAY	1153011	1004419	NO
SPRSCG-6624-()	1132575	XS-NK	16 GA. 304 STAINLESS STEEL	GRAINED	1153012	1150622	NO

ITEM	QTY.	PART NUMBER	DESCRIPTION
1	1	(SEE CHART)	BACK WELDMENT
2	1	(SEE CHART)	FRONT
3	2	1001290	SCREW, 10-32 X 5/16
4	1	1002897	LABEL, RATING 6x6 GSC3R
5	1	(SEE CHART)	UL LABEL, WIREWAY

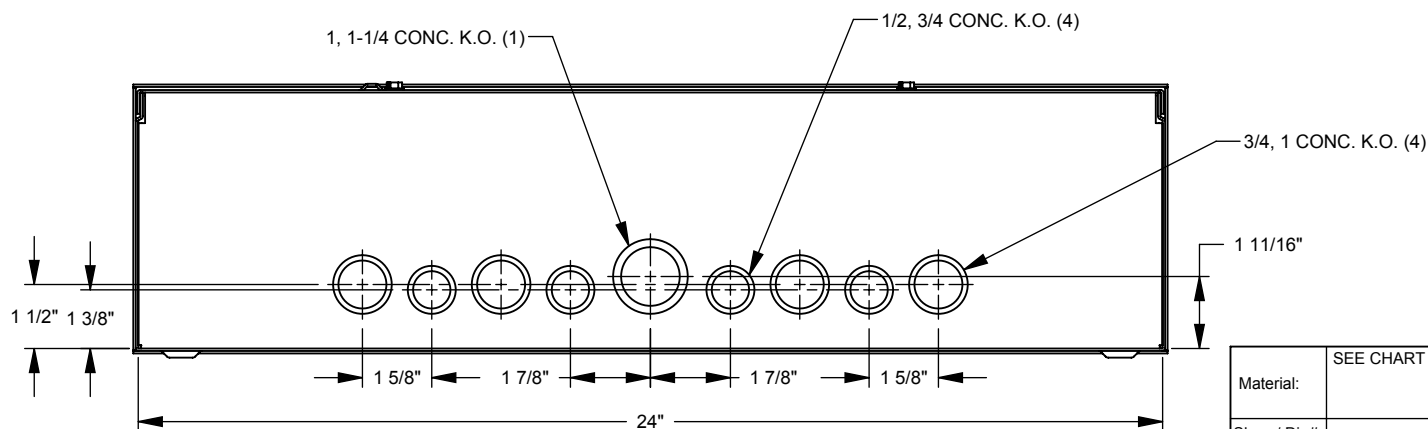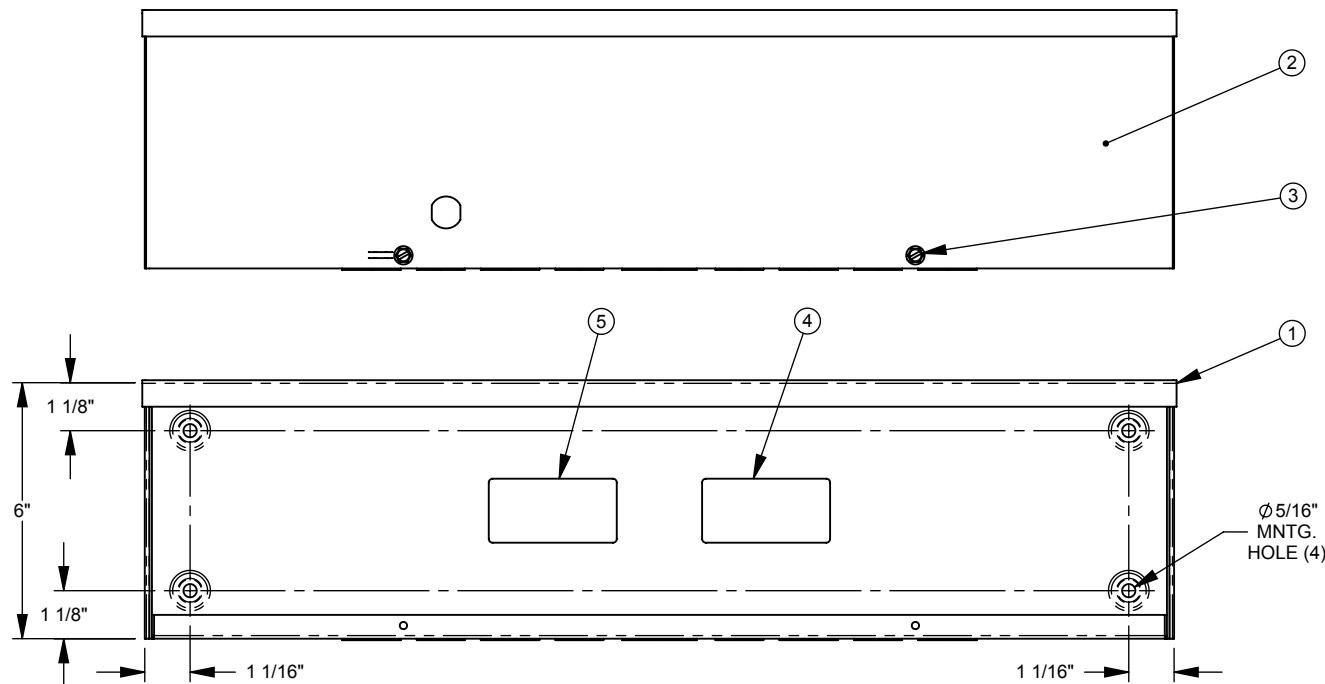

Material:	SEE CHART	 <p>General Offices: Kansas City, MO</p>
Shear/ Die#:		
Finish:	SEE CHART	
Part Wt.:		
Tolerances: Unless Specified Otherwise X.X ±.1 X.XX ±.03 X.XXX ±.015 X" ±2"		Title: SCREW COVER WIREWAY NEMA TYPE 3R
Third Angle 		Catalog No.: SEE CHART
Scale:	NTS	Customer:
Drawn By:	D.F.	Drawing No.: 280
Checked By:		Date: 5/12/11
Approved By:		Sheet 1 of 1

REV.	DATE	DESCRIPTION	BY
A4	5/12/11	REDRAW INTO SOLIDWORKS; UPDATE K.O. PATTERN (ECO #20576)	D.F.



Catalog Number: 6624-GSC3R-NK  
Item Description: N3R SCREW CVR GUTTER NK  
UPC Code: 784572107892

Brand Name: Milbank  
Type: Wiring Trough  
Special Features: Key Locking Cylinder Latch Provision,  
Sealing Eye Lance  
Application: Wireway  
Standard: UL Listed, Type 3R  
Cover Type: Screw Cover  
Enclosure: Outdoor Enclosure  
Nominal Cross Section: 6x6  
Straight Section Length: 24  
Material: Steel with Powder Coat Finish  
Finish: ANSI 61 Gray  
Knockouts: False






*Utility requirements may vary. Always consult the serving utility for their requirements prior to ordering or installing this equipment. This product must always be installed by a licensed electrician. Installation of this equipment may require local electrical inspector approval.*


 
CAT. NO.	U/L LABEL
6624-GSC3R-()	1002943
RC-6624-GSC3R-()	1125051
SPRSCG-6624-()	1132575

SUFFIX	MATERIAL	FINISH	BACK WELDMENT	FRONT	K.O.s INSTALLED
NONE	16 GA. GALV. STEEL	MILBANK LIGHT GRAY	1153010	1004419	YES
-NK	16 GA. GALV. STEEL	MILBANK LIGHT GRAY	1153011	1004419	NO
XS-NK	16 GA. 304 STAINLESS STEEL	GRAINED	1153012	1150622	NO

ITEM	QTY.	PART NUMBER	DESCRIPTION
1	1	(SEE CHART)	BACK WELDMENT
2	1	(SEE CHART)	FRONT
3	2	1001290	SCREW, 10-32 X 5/16
4	1	1002897	LABEL, RATING 6x6 GSC3R
5	1	(SEE CHART)	UL LABEL, WIREWAY

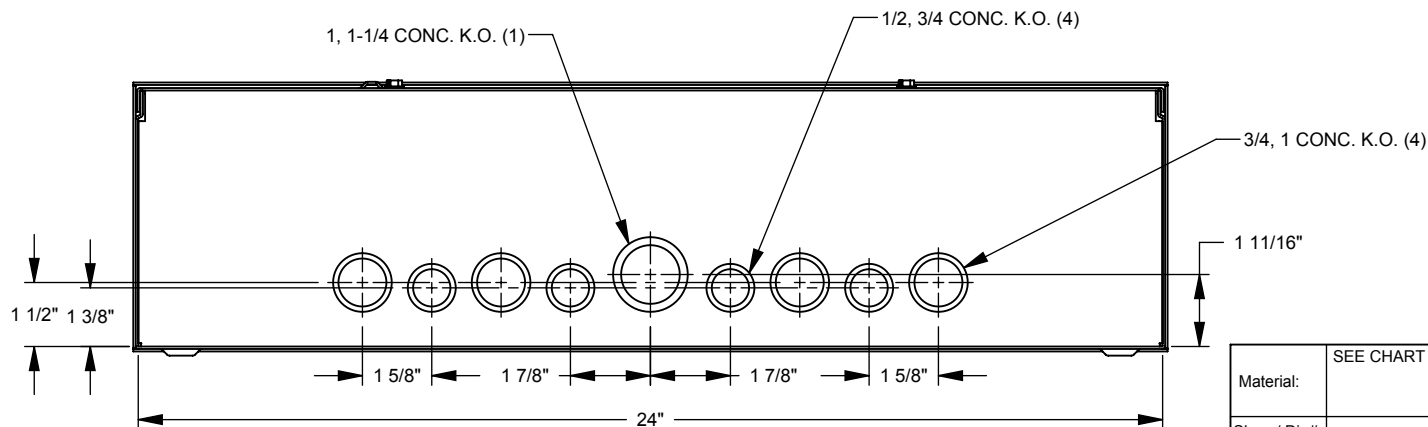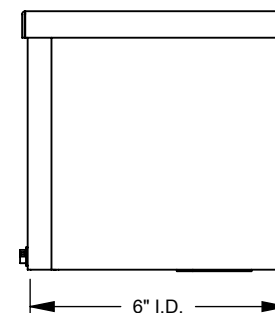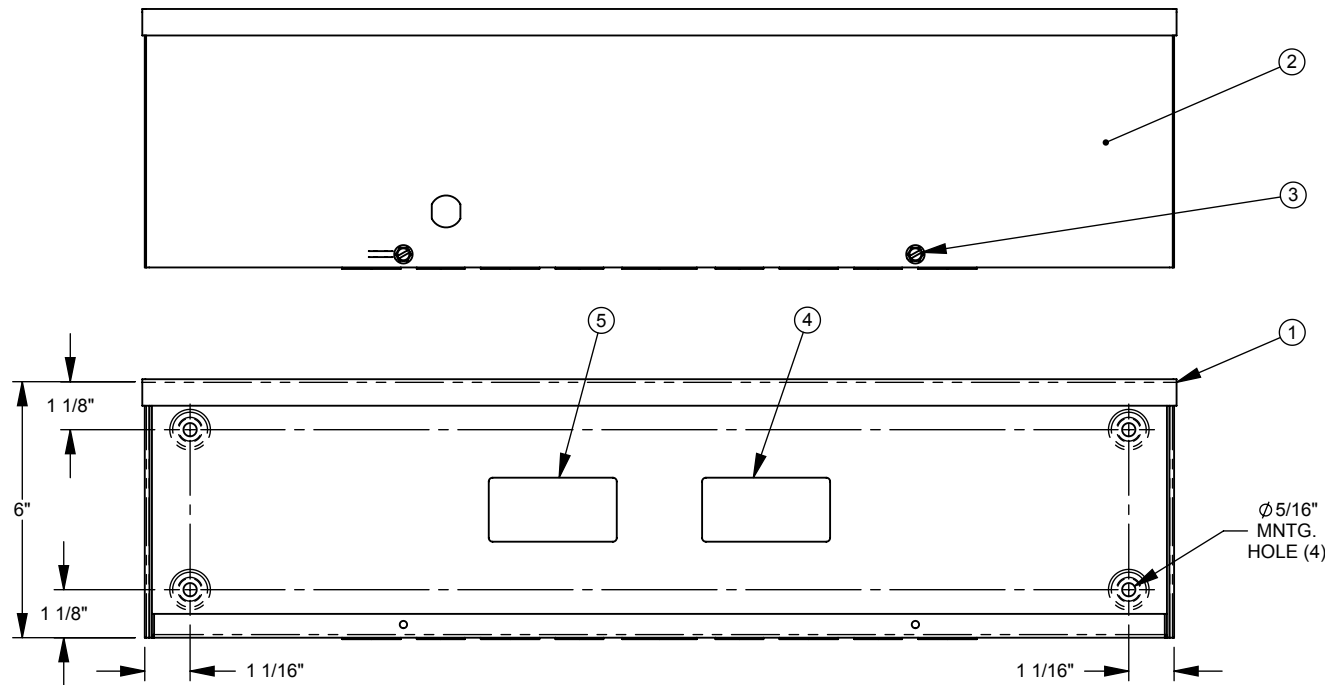

REV.	DATE	DESCRIPTION	BY
A4	5/12/11	REDRAW INTO SOLIDWORKS; UPDATE K.O. PATTERN (ECO #20576)	D.F.

Material:	SEE CHART	 <p>General Offices: Kansas City, MO</p>										
Shear/ Die#:												
Finish:	SEE CHART											
Part Wt.:												
<p>Tolerances:</p> <table border="0"> <tr><td>Unless Specified Otherwise</td><td></td></tr> <tr><td>X.X</td><td>±.1</td></tr> <tr><td>X.XX</td><td>±.03</td></tr> <tr><td>X.XXX</td><td>±.015</td></tr> <tr><td>X"</td><td>±2"</td></tr> </table>		Unless Specified Otherwise		X.X	±.1	X.XX	±.03	X.XXX	±.015	X"	±2"	<p>Third Angle</p> 
Unless Specified Otherwise												
X.X	±.1											
X.XX	±.03											
X.XXX	±.015											
X"	±2"											
Scale:	NTS	Checked By:										
Drawn By:	D.F.	Approved By:										
Title:	SCREW COVER WIREWAY NEMA TYPE 3R	Catalog No.:	SEE CHART									
Customer:		Drawing No.:	280									
Date:	5/12/11	Sheet	1 of 1									