



EM-M CONDUIT/PIPE TO FLANGE CLIP, SPRING ST. 14-2 TO 12-3 MC/AC,  
1/8"–1/4" FL.

## CATALOG NUMBER

---

**6M24**



## FEATURES

---

Supports conduit/pipe or cable from beam flanges

Snap close clip pivots a full 360°

Requires only a hammer to install

## PRODUCT ATTRIBUTES

---

Material: Spring Steel

Finish: nVent CADDY Armour

Rigid Conduit/Pipe Size: 3/8"

MC/AC Cable Size: 14-2 to 12-3

Outer Diameter (OD): 0.550" - 0.71"


Flange Thickness (FT): 1/8"

Flexible Conduit Size: 3/8"

Static Load (F): 75lb

## DIAGRAMS

---

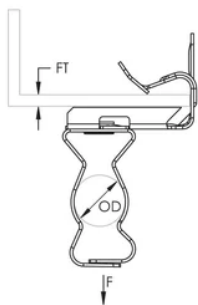

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**



EM-M CONDUIT/PIPE TO FLANGE CLIP, SPRING ST. 14-2 TO 12-3 MC/AC,  
1/8"–1/4" FL.

## CATALOG NUMBER

---

**6M24**



## FEATURES

---

Supports conduit/pipe or cable from beam flanges

Snap close clip pivots a full 360°

Requires only a hammer to install

## PRODUCT ATTRIBUTES

---

Material: Spring Steel

Finish: nVent CADDY Armour

Rigid Conduit/Pipe Size: 3/8"

MC/AC Cable Size: 14-2 to 12-3

Outer Diameter (OD): 0.550" - 0.71"


Flange Thickness (FT): 1/8"

Flexible Conduit Size: 3/8"

Static Load (F): 75lb

## DIAGRAMS

---

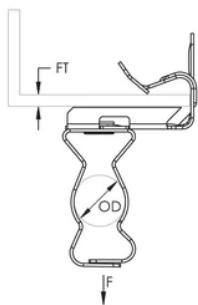

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**