



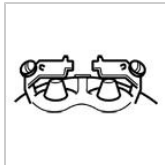

GE
Lighting

41865 - 7613

GE PAR36 - Emergency Building Light; Emergency Building

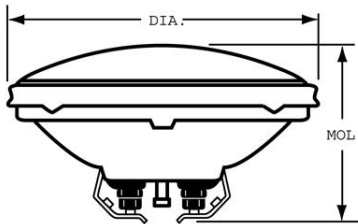

GENERAL CHARACTERISTICS

| | |
|---------------------|--|
| Lamp Type | Sealed Beam - PAR |
| Bulb | PAR36 |
| Base | Screw Terminals |
| Filament | C-6 |
| Rated Life | 50.0 hrs |
| Primary Application | Emergency Building Light; Emergency Building |

PHOTOMETRIC CHARACTERISTICS

| | |
|------------------------------------|---------------|
| Beam Spread - Horizontal | 30.0 - 10.0 ° |
| Beam Spread - Vertical | 20.0 - 10.0 ° |
| Max. Beam Candlepower (MBCP) (MAX) | 400.0 |

ELECTRICAL CHARACTERISTICS

| | |
|---------|-----|
| Wattage | 8.0 |
| Voltage | 6.0 |

DIMENSIONS

| | |
|------------------------------|--------------------|
| Maximum Overall Length (MOL) | 2.7500 in(69.8 mm) |
| Bulb Diameter (DIA) | 4.500 in(114.3 mm) |

PRODUCT INFORMATION



| | |
|----------------------------------|----------------|
| Product Code | 41865 |
| Description | 7613 |
| ANSI Code | 7613 |
| Standard Package | Case |
| Standard Package GTIN | 00043168418652 |
| Standard Package Quantity | 12 |
| Sales Unit | Unit |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard Package | 12 |
| UPC | 043168962278 |



GE
Lighting

41865 - 7613

GE PAR36 - Emergency Building Light; Emergency Building

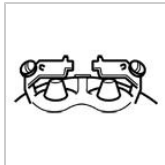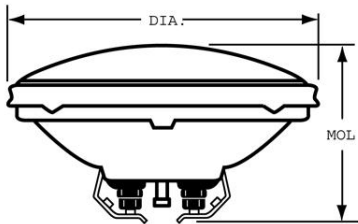

GENERAL CHARACTERISTICS

| | |
|---------------------|--|
| Lamp Type | Sealed Beam - PAR |
| Bulb | PAR36 |
| Base | Screw Terminals |
| Filament | C-6 |
| Rated Life | 50.0 hrs |
| Primary Application | Emergency Building Light; Emergency Building |

PHOTOMETRIC CHARACTERISTICS

| | |
|------------------------------------|---------------|
| Beam Spread - Horizontal | 30.0 - 10.0 ° |
| Beam Spread - Vertical | 20.0 - 10.0 ° |
| Max. Beam Candlepower (MBCP) (MAX) | 400.0 |

ELECTRICAL CHARACTERISTICS

| | |
|---------|-----|
| Wattage | 8.0 |
| Voltage | 6.0 |

DIMENSIONS

| | |
|------------------------------|--------------------|
| Maximum Overall Length (MOL) | 2.7500 in(69.8 mm) |
| Bulb Diameter (DIA) | 4.500 in(114.3 mm) |

PRODUCT INFORMATION

| | |
|----------------------------------|----------------|
| Product Code | 41865 |
| Description | 7613 |
| ANSI Code | 7613 |
| Standard Package | Case |
| Standard Package GTIN | 00043168418652 |
| Standard Package Quantity | 12 |
| Sales Unit | Unit |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard Package | 12 |
| UPC | 043168962278 |