


## 90° - Large Size- Malleable

### Images

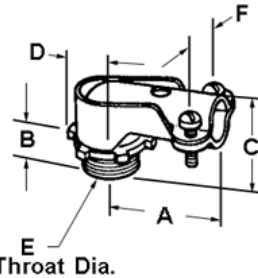

Throat Dia.

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-5/8  
Dimension B in Inches: 3/8  
Dimension C in Inches: 1-3/8  
Dimension D in Inches: 1/2  
Dimension E in Inches: .563  
Dimension F in Inches: 15/16

### Application

90 Degrees fitting with cover for connecting flexible metal conduit to box or enclosure.

### Product Information

Material: Malleable Iron  
Finish: Zinc electro-plate

### Certifications & Codes:

CSA File Number:	LR39354
Federal Specification Number:	A-A-50552
NEMA Standard:	FB-1
UL File Number:	E9391
UL Standard:	UL-514B
UNSPSC:	39121419

**Catalog ID:** 804

**UPC Number:** 781747008046

**Description:** Connector, 90 Degrees, Malleable Iron, Flex Size 1/2 Inch

**Application:** 90 Degrees fitting with cover for connecting flexible metal conduit to box or enclosure.

**Trade Size:** 1/2"

**Std Pkg Qty:** 100

**Unit Qty:** 25