


90° Zinc

Images

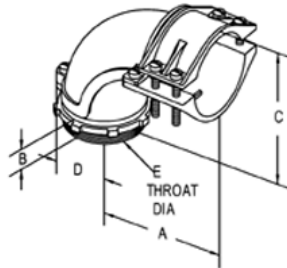

Application

90 Degrees connector suitable for used to connect flexible metal conduit to box or enclosure.

Product Information

Material: Zinc Die Cast

Finish: Ball burnished, mirror smooth

Certifications & Codes:

CSA File Number: LR39354

Federal Specification Number: A-A-50552

NEMA Standard: FB-1

UL File Number: E9391

UL Standard: UL-514B

UNSPSC: 39121419

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 5

Dimension B in Inches: 7/8

Dimension C in Inches: 6

Dimension D in Inches: 2

Dimension E in Inches: 2-1/2

Dimension F in Inches: 4-1/2

Catalog ID: 811-DC2

UPC Number: 781747158116

Description: Connector, 90 Degrees, Zinc Die Cast, Flex Size 2-1/2 Inch

Application: 90 Degrees connector suitable for used to connect flexible metal conduit to box or enclosure.

Trade Size: 2-1/2"

Std Pkg Qty: 5

Unit Qty: Bulk