



# Designer Switches & Outlets Catalog

#LegrandImprovingLives



# Elevate your space with exceptional style & innovative functionality.

Designer switches and outlets deliver advanced features to enhance everyday life while perfectly complementing any décor. Available in two distinct collections — adorne® and radiant® — and continuing a legacy of superb performance, these switches and outlets combine unmatched style with inventive technologies to offer comfort, safety and convenience.

From switches you wave on and self-calibrating universal dimmers, to next gen USB chargers and convenient smart lighting, this is where form and function converge.

For an accessible luxury that transforms how any room both looks and feels, explore designer switches and outlets.



## TURN ON PEACE OF MIND.

Select devices and wall plates from the adorne® and radiant® Collections now feature Microban® antimicrobial\* protection, helping to guard against odor, stains and deterioration for **99.9% cleaner** and more durable devices.

- Helps prevent the growth of microorganisms and damaging bacteria at the cellular level
- Offers continuous protection for the entire lifetime of the product
- Preserves the elevated style of adorne® devices with invisible protection that's smooth to the touch

**LEARN MORE AT [LEGRAND.US/MICROBAN](https://www.legrand.us/microban)**

*\*No antimicrobial efficacy claims are being made or are valid with respect to products sold in Canada.*




## TABLE OF CONTENTS

<b>04</b>	<b>Designer Switches &amp; Outlets</b> 04 • Overview & Inspiration
<b>07</b>	<b>The adorne® Collection</b> 08 • Featured Categories 16 • adorne Dimmers & Switches 20 • adorne Outlets & USB Charging Solutions 26 • adorne Smart Lighting 28 • adorne Connectivity Accessories 32 • adorne Wall Plates
<b>45</b>	<b>The radiant® Collection</b> 46 • Featured Categories 56 • radiant Dimmers & Switches 61 • radiant Outlets & USB Charging Solutions 68 • radiant Smart Lighting 72 • radiant Wall Plates
<b>74</b>	<b>Product Index</b> 74 • adorne Dimensions 75 • Index by Part Number

# Two Collections. Infinite Possibilities.

The adorne and radiant Collections offer solutions to fit any need, in colors and finishes to match every taste — whether it means blending seamlessly into a room that’s traditional and timeless, or adding an attention-grabbing accent to a more contemporary space.

*Find your perfect finishing touch with designer switches and outlets.*

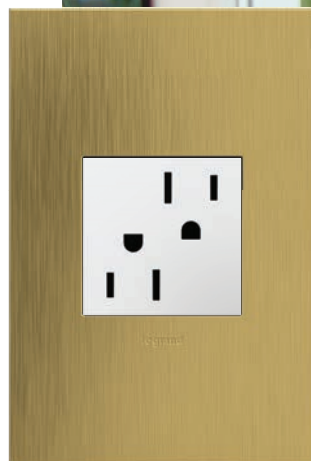

**The adorne Collection.** Bold and beautiful, in the signature square. Select from adorne switches, dimmers and outlets in graphite, magnesium and white finishes, then pair them with dazzling screwless wall plates available in on-trend colors, finishes and materials.




**The radiant Collection.** Clean lines and classic colors, for a sophisticated touch. Give your space a “little something extra” with this elegant upgrade to a standard rectangular device. Switches, dimmers, outlets and wall plates available in nine finishes to easily coordinate with popular paint and hardware trends.



*the*  
**adorne**<sup>®</sup>  
*collection*


# Dimmers & Switches

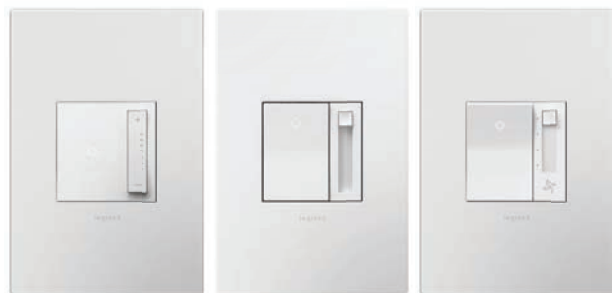

**SOFTAP® TRU-UNIVERSAL DIMMER** | ADTP703TUW4  
This dimmer self-calibrates to work with virtually any 120V dimmable bulb or fixture (excludes 0-10V). Turn lights on/off with a light push action.

**PADDLE LED ADVANCED DIMMER** | ADPD153LW2  
Upgrade from a standard switch or dimmer to turn lights on/off with an easy up-or-down action, or use the slider to adjust light level.

**PADDLE FAN SPEED CONTROL** | AAFN4S16AW4  
Adjust fan speed with modern style.

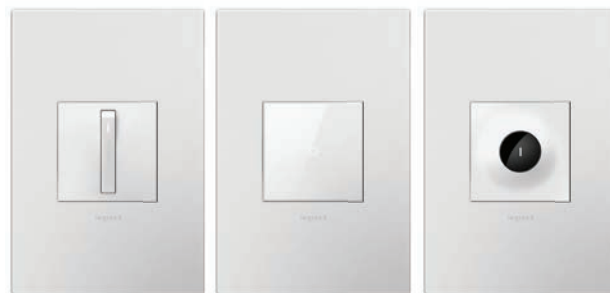


**WHISPER® SWITCH** | ASWR1532W4  
Turn lights on/off with a fluid, gentle action.

**TOUCH SWITCH** | ASTH1532W2  
Turn lights on/off with just a simple touch.

**WAVE® SWITCH** | ASWV1532W2  
Go germ-free. Turn lights on/off with a wave.

# Outlets & Night Lights

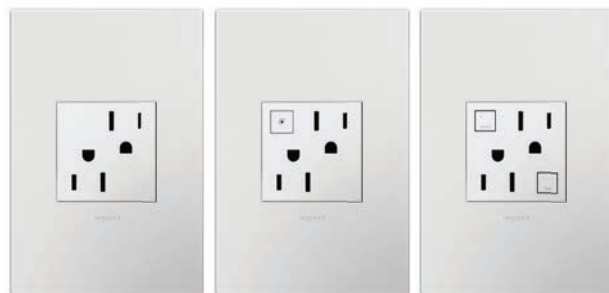

**TAMPER-RESISTANT OUTLET | ARTR152W4**

Upgrade from a standard outlet with discreet tamper-resistance.


**ENERGY-SAVING ON/OFF OUTLET | ARPS152W4**

Add style, while reducing energy waste. Outlet can be shut off when not in use to avoid pulling power in standby mode.

**TAMPER-RESISTANT SELF-TEST**

**GFCI OUTLET | AGFTR2152W4**

Get superior safety and superior style. Protects against electrical shock caused by ground-faults.

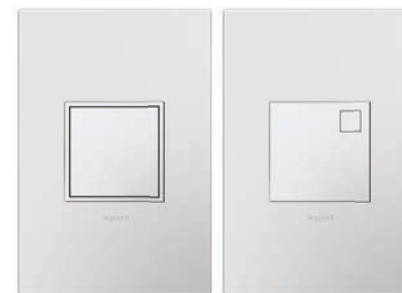

**POP-OUT OUTLET | ARPTR151GW2**

Pop it out to fit up-to-3 plugs simultaneously, then gently push back into the wall when not in use.

**NIGHT LIGHT | AANLM24**

Add built-in illumination for easier nighttime navigation.


**PORTABLE NIGHT LIGHT/FLASHLIGHT | AARNL2**

An in-wall night light that can be popped out for use as a flashlight.






# USB Charging Solutions

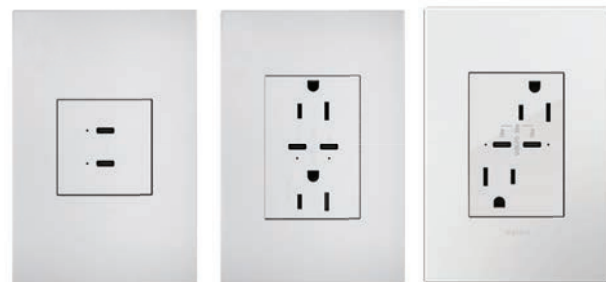

**65W USB OUTLET MODULE, TYPE-C | ARUSB65PDW4**  
Featuring dual Type-C ports with industry-leading 65W of power each. Includes advanced Power Delivery\* technology. Ideal for charging phones, tablets and laptops.

**65W USB OUTLET, PLUS-SIZE, TYPE-C, 15A, TAMPER-RESISTANT | ARTRUSB15PD65W4**  
Features dual Type-C charging ports with 65W each. Includes two 15-amp AC receptacles. Advanced Power Delivery optimizes charging speeds while safeguarding against overheating.

**30W USB OUTLET, PLUS-SIZE, TYPE-C, 15A, TAMPER-RESISTANT | ARTRUSB15PD30W4**  
Includes two USB Type-C charging ports of 30W each, coupled with two 15-amp AC receptacles. Advanced Power Delivery optimizes charging speeds while safeguarding against overheating.

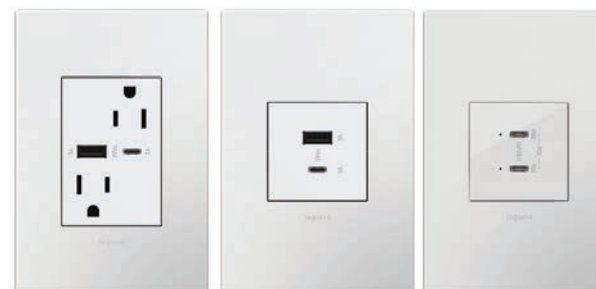

**15W USB OUTLET, PLUS-SIZE, TYPE-A/C, 15A, TAMPER-RESISTANT | ARTRUSB156ACW4**  
One Type-A and one Type-C charging port of 15W each, coupled with two 15-amp AC receptacles.

**15W USB OUTLET MODULE, TYPE-A/C | ARUSB2AC6W4**  
One Type-A and one Type-C USB charging ports. No need for bulky adapters.

**30W USB MODULE, TYPE-C | ARUSB30PDW4**  
Two USB Type-C charging ports. Advanced Power Delivery optimizes charging speeds while safeguarding against overheating.

# Smart Lighting



works with alexa

works with Google Home

Works with Apple HomeKit

Manage lights and power, from anywhere, with the Legrand Home + Control app.

adorne<sup>®</sup> WITH Netatmo



**SMART GATEWAY WITH NETATMO | WNAH1W1**  
Start here to create a robust, dedicated network for advanced smart control throughout an entire home. Required for all "with Netatmo" smart lighting solutions. Surface-mount version also available.

**SMART SWITCH WITH NETATMO | WNAL10W1**  
Get advanced control of your lights from any smart device, from anywhere. Plug-in version also available.

**SMART TRU-UNIVERSAL DIMMER WITH NETATMO | WNAL50W1**  
This dimmer self-calibrates to work with virtually any 120V dimmable bulb or fixture (excludes 0-10V). Plug-in version also available.



**SMART OUTLET, PLUS-SIZE WITH NETATMO | WNAR153W1**  
Get advanced control of power from any smart device, from anywhere. One outlet is app-controlled, the other is always on. 15A and 20A versions available.

**WIRELESS SMART DIMMER WITH NETATMO | WNAL63W1**  
Add to any wall or surface for easy 3-way dimming control. Battery-operated; no wiring required. Switch also available.















**WIRELESS SMART SCENE CONTROLLER WITH NETATMO | WNACB40W1**  
Add to any wall or surface for one-tap control of four lighting scenes. Battery-operated; no wiring required.



## Paddle

The Paddle design features a simple up-or-down action, allowing you to turn lights on and off with ease. Dimmers include a slider for dimming or brightening lights. Pair with a Locator Status Light to add illumination to your Paddle switch or dimmer. See page 25.

Now with lasting Microban<sup>®</sup> antimicrobial\* protection for cleaner, more durable devices.

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPATIBLE LOADS	COMPLIANCE
	ASPD1532W4 ASPD1532M4 ASPD1532G4	Single-pole/3-way.	White Magnesium Graphite	15A, 120V	All Loads	 , RoHS
	ASPD2032W4 ASPD2032M4 ASPD2032G4		White Magnesium Graphite	20A, 120V	All Loads	 , RoHS
	ASPD1532W277 ASPD1532M277 ASPD1532G277		White Magnesium Graphite	15A, 277V	All Loads	 , RoHS
	ASPD2042W4 ASPD2042M4 ASPD2042G4	4-way switches work with two adorne switches OR with one adorne switch and one adorne dimmer.	White Magnesium Graphite	20A, 120V	All Loads	 , RoHS
	ASPD1542W277 ASPD1542M277 ASPD1542G277		White Magnesium Graphite	15A, 277V	All Loads	 , RoHS
	ADPD153LW2 ADPD153LM2 ADPD153LG2	LED Advanced Dimmer, Single-pole/3-way, No Neutral Required	White Magnesium Graphite	120V, 150W LED; 150W CFL/INC	LED**, CFL/INC	 , RoHS
	ADPD4FBL3P2W4 ADPD4FBL3P2M4 ADPD4FBL3P2G4	Single-pole/3-way.	White Magnesium Graphite	120/277V (0-10V dimming only) 120V 10A / 277V 5A LED/FL	0-10V Light Fixtures	 , RoHS
	ASPD1531W4 ASPD1531M4 ASPD1531G4	Single-pole/3-way.	White Magnesium Graphite	15A, 120V	All Loads	 , RoHS
	ASPD1531W277 ASPD1531M277 ASPD1531G277		White Magnesium Graphite	15A, 277V	All Loads	 , RoHS
	AAFN4S16AW4 AAFN4S16AM4 AAFN4S16AG4	Features four speeds. Includes de-hummer.	White Magnesium Graphite	1.6A, 120V	Paddle-Type Ceiling Fan	 , RoHS

Note: Due to manufacturer variations and modifications, we are unable to ensure indefinite dimming compatibility with any bulb or fixture.





\*No antimicrobial efficacy claims are being made or are valid with respect to products sold in Canada.

\*\*Not intended for ELV, MLV, or 0-10V loads

## Whisper<sup>®</sup>

The Whisper design features classic, elegant lines and a gentle action. Whisper dimmers include a slide for dimming or brightening lights. Pair with a Locator Status Light to add illumination to your Whisper switch or dimmer. See page 25.

Now with lasting Microban<sup>®</sup> antimicrobial\* protection for cleaner, more durable devices.





NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPATIBLE LOADS	COMPLIANCE
	ASWR1532W4 ASWR1532M4 ASWR1532G4	Single-pole/3-way.	White Magnesium Graphite	15A, 120V	All Loads	 , RoHS
	ADWR703TUW4 ADWR703TUM4 ADWR703TUG4	Self-calibrates to work with virtually any dimmable bulb or fixture (excludes 0-10V).	White Magnesium Graphite	120V 450W LED/ CFL; 700W INC/HAL; 500VA MLV; 700W MLV; 5.5A EFL	Incandescent, Halogen & ELV; 700W, MLV; 500VA, LED/CFL; 450W (not compatible with 0-10V LED drivers), EFL: 5.5A	 , RoHS

## Wave<sup>®</sup>

The Wave switch features innovative technology combined with sleek, contemporary design. Simply wave your hand in front of the switch to turn lights on and off.

With its touch-free motion, the Wave is ideal for countertop areas in kitchens and bathrooms. It has a preset sensor distance of approximately 4". However, this can be easily adjusted to sense movement from 1" to 6" in front of switch.

Now with lasting Microban<sup>®</sup> antimicrobial\* protection for cleaner, more durable devices.

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPATIBLE LOADS	COMPLIANCE
	ASWV1532W2 ASWV1532M2 ASWV1532G2	Single-pole/3-way.	White Magnesium Graphite	15A, 120V, 1/2 Hp	All Loads	 , RoHS
	ASWV2032W2 ASWV2032M2 ASWV2032G2	Single-pole/3-way.	White Magnesium Graphite	20A, 120V, 3/4 Hp	All Loads	 , RoHS

Note: Due to manufacturer variations and modifications, we are unable to ensure indefinite dimming compatibility with any bulb or fixture.

\*No antimicrobial efficacy claims are being made or are valid with respect to products sold in Canada.

## sofTap<sup>®</sup>

The sofTap design features an innovative micro-movement sensor that turns lights on or off with a lighter push action. Dimmers include a unique paddle to adjust light levels.

Now with lasting Microban<sup>®</sup> antimicrobial\* protection for cleaner, more durable devices.

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPATIBLE LOADS	COMPLIANCE
sofTap Switch	ASTP1532W4 ASTP1532M4 ASTP1532G4	Single-pole/3-way.	White Magnesium Graphite	15A, 120 V, 1/2 Hp	All Loads	, RoHS
sofTap Dimmer	ADTP703TUW4 ADTP703TUM4 ADTP703TUG4	Self-calibrates to work with virtually any dimmable bulb or fixture (excludes 0-10V).	White Magnesium Graphite	120V 450W LED/CFL; 700W INC/HAL; 500VA MLV; 700W ELV; 5.5A EFL	Incandescent, Halogen & ELV: 700W, MLV: 500VA, LED/CFL: 450W (not compatible with 0-10V LED drivers), EFL: 5.5A	, RoHS
	ADTP4FBL3PW4 ADTP4FBL3PM4 ADTP4FBL3PG4	Single-pole/3-way.	White Magnesium Graphite	120/277V (0-10V dimming only) 120V 10A / 277V 5A LED/FL	0-10V Light Fixtures	, RoHS

## Touch<sup>®</sup>

The Touch design features a stunning translucent face and operates just like a smartphone - simply touch your finger to the circle to turn lights on or off. Dimmer version uses arrows on the right to adjust light levels.

The white Touch interface is created using a unique translucent material. In multi-gang installations, we recommend pairing white Touch switches and dimmers for optimal consistency.

Now with lasting Microban<sup>®</sup> antimicrobial\* protection for cleaner, more durable devices.

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPATIBLE LOADS	COMPLIANCE
Touch Switch	ASTH1532W2 ASTH1532M2 ASTH1532G2	Single-pole/3-way.	White Magnesium Graphite	15A, 120 V, 1/2 Hp	All Loads	, RoHS
Touch Dimmer	ADTH703TUW4 ADTH703TUM4 ADTH703TUG4	Self-calibrates to work with virtually any dimmable bulb or fixture (excludes 0-10V).	White Magnesium Graphite	120V 450W LED/CFL; 700W INC/HAL; 500VA MLV; 700W ELV; 5.5A EFL	Incandescent, Halogen & ELV: 700W, MLV: 500VA, LED/CFL: 450W (not compatible with 0-10V LED drivers), EFL: 5.5A	, RoHS
	ADTH4FBL3PW4 ADTH4FBL3PM4 ADTH4FBL3PG4	Single-pole/3-way.	White Magnesium Graphite	120/277V (0-10V dimming only) 120V 10A / 277V 5A LED/FL	0-10V Light Fixtures	, RoHS
Dimmer Bypass Module	DIMBPASSv	This device is an adapter that can be installed at the dimmer or at the load that fixes most LED light anomalies such as flicker and ghosting.	Black	120V 60Hz 0.1 Amps		

Note: Due to manufacturer variations and modifications, we are unable to ensure indefinite dimming compatibility with any bulb or fixture.  
\*No antimicrobial efficacy claims are being made or are valid with respect to products sold in Canada.


## SensaSwitch<sup>®</sup> + SensaDimmer

SensaSwitches include passive infrared (PIR) sensor technology, automatically turning lights on or off when you enter or leave a room. The design features an innovative micro-movement sensor that allows you to also manually turn on lights with a soft touch of the finger. SensaSwitches are available in three models:

- Auto-ON/Auto-OFF: Automatically turns lights on when you enter a room and off when you leave. (Occupancy Sensor)
- Manual-ON/Auto-OFF: Allows you to turn lights on when you enter a room and automatically turns them off when you leave. (Vacancy Sensor)
- Manual-ON/Timed-OFF: Allows you to turn lights on when you enter a room and select a time for lights to turn off (options include 10, 20, 30, and 60 minutes). (Timer)

The SensaDimmer turns lights on when you enter a room and off when you leave, but can be adjusted to become Manual-ON/Auto-OFF if desired.

Now with lasting Microban<sup>®</sup> antimicrobial\* protection for cleaner, more durable devices.

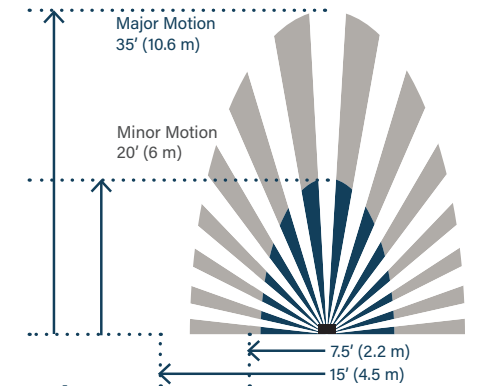





























### Coverage Area

The Occupancy Sensor, Vacancy Sensor, and SensaDimmer each have a maximum coverage range of 180 degrees and a coverage area of 600 sq. ft. The sensor must have a clear and unobstructed view of the coverage area. Objects blocking the sensor's lens may prevent detection thereby causing the light to turn off even though someone is in the area. Windows, glass doors, and other transparent barriers will obstruct the sensor's view and prevent detection.






















NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPATIBLE LOADS	COMPLIANCE
SensaSwitch, Auto-ON/Auto-OFF	ASOS32W4 ASOS32M4 ASOS32G4	Single-pole/3-way.  Time delay of 5-30 min.  Occupancy Sensor (Must be paired with another SensaSwitch or SensaDimmer in 3-way applications)	White Magnesium Graphite	120V, 600W, 60 Hz, 1/6 Hp	All Loads	, RoHS
SensaSwitch, Manual-ON/Auto-OFF	ASVS12W4 ASVS12M4 ASVS12G4	Single-pole/3-way.  Time delay of 5-30 min.  Vacancy Sensor (Must be paired with another SensaSwitch or SensaDimmer in 3-way applications)	White Magnesium Graphite	120V, 600W, 60 Hz, 1/6 Hp	All Loads	, RoHS CA Title 24
SensaSwitch, Manual-ON/Timed-OFF	ASTM2W2 ASTM2M2 ASTM2G2	Single-pole/3-way.  Time delay options include 10, 20, 30 or 60 min.  (Must be paired with another SensaSwitch or SensaDimmer in 3-way applications)	White Magnesium Graphite	120V, 600W, 60 Hz, 1/6 Hp	All Loads	, RoHS
SensaDimmer, Auto-ON/Auto-OFF	ADSM703HW2 ADSM703HM2 ADSM703HG2	Single-pole/3-way.  Time delay of 5-30 min.  Dimming Occupancy Sensor (Must be paired with another SensaSwitch or SensaDimmer in 3-way applications)	White Magnesium Graphite	120V 700W	Incandescent, Halogen	, RoHS

\*No antimicrobial efficacy claims are being made or are valid with respect to products sold in Canada.

**Outlets** Outlets from the adorne Collection feature a tamper-resistant design, complete with a patented black invisi-shutter system. All 15A outlets also have a 20A feed or pass-through for installation flexibility.

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPATIBLE LOADS	COMPLIANCE
15A Single Outlet 	ARTR151W10 ARTR151M10 ARTR151G10	A dedicated tamper-resistant outlet for use with appliances or devices with larger plugs.  Pair with a Half-Size Night Light or Paddle Switch for greater functionality in a 1-Gang+ Wall Plate. 15A provides 20A pass-through.	White Magnesium Graphite	15A, 125V   20A, 125V 	5-15R	 , RoHS
Tamper-Resistant Outlet 	ARTR152W4 ARTR152M4 ARTR152G4  ARTR202W4 ARTR202M4 ARTR202G4	Pair with a Half-Size Night Light or Paddle Switch for greater functionality in a 1-Gang+ Wall Plate. 15A provides 20A pass-through.	White Magnesium Graphite  White Magnesium Graphite	15A, 125V   20A, 125V 	5-15R  5-20R	 , RoHS
Tamper-Resistant Outlet, Plus-Size 	ARTR153W4 ARTR153M4 ARTR153G4	Compatible with 1-Gang+ Wall Plates only. Cannot be used in multi-gang installations. Provides 20A pass-through.	White Magnesium Graphite	15A, 125V 	5-15R	 , RoHS
Tamper-Resistant Self-Test GFCI Outlet 	AGFTR2152W4 AGFTR2152M4 AGFTR2152G4  AGFTR2202W4 AGFTR2202M4 AGFTR2202G4	GFCIs protect against serious injury due to electric shock. They are required by National Electrical Code in kitchens and bathrooms. All adorne GFCIs are self testing to meet the latest NEC requirement. 15A provides 20A pass-through.	White Magnesium Graphite  White Magnesium Graphite	15A, 125V   20A, 125V 	5-15R  5-20R	 , RoHS
Tamper-Resistant Self-Test GFCI Outlet, Plus-Size 	AGFTR2153W4 AGFTR2153M4 AGFTR2153G4	GFCIs protect against serious injury due to electric shock. They are required in kitchens and bathrooms. All adorne GFCIs are self testing to meet the latest NEC requirement. Provides 20A pass-through.  Compatible with 1-Gang+ Wall Plates only. Cannot be used in multi-gang installations.	White Magnesium Graphite	15A, 125V 	5-15R	 , RoHS
Energy-Saving ON/OFF Outlet 	ARPS152W4 ARPS152M4 ARPS152G4	On/off switch allows you to save energy and stop the flow of power without unplugging your device. Perfect for kitchens, bathrooms, and computer rooms. Provides 20A pass-through.	White Magnesium Graphite	15A, 125V 	5-15R	 , RoHS
Tamper-Resistant Dual Controlled Outlet 	ARCD152W10 ARCD152M10 ARCD152G10  ARCD202W10 ARCD202M10	This Plug Load outlet controls both receptacles, which will turn off for energy efficiency and cost savings. They are code-required, meet standards, and include permanent power markings. 15A provides 20A pass-through.	White Magnesium Graphite  White Magnesium	15A, 125V   20A, 125V 	5-15R  5-20R	 , RoHS
Tamper-Resistant Half Controlled Outlet 	ARCH152W10 ARCH152M10 ARCH152G10	This Plug Load outlet controls half the receptacle, featuring a factory-broken split-circuit tab, allowing half of the receptacle to turn off for energy efficiency and cost savings. They are code-required, meet standards, and include permanent power markings. Provides 20A pass-through.	White Magnesium Graphite	15A, 125V 	5-15R	 , RoHS

## USB Charging


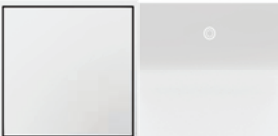
NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPATIBLE LOADS	COMPLIANCE
65W USB Outlet Module, Type-C 	ARUSB65PDW4 ARUSB65PDM4 ARUSB65PDG4	The fastest USB outlet available. Featuring dual Type-C ports with industry-leading 65W of power each. Includes advanced Power Delivery* technology. Ideal for charging phones, tablets and laptops.	White Magnesium Graphite	5V, 9V, 15V & 20V		 , RoHS
65W USB Outlet, Plus-Size, Type-C, Tamper Resistant 	ARTRUSB15PD65W4 ARTRUSB15PD65M4 ARTRUSB15PD65G4  ARTRUSB20PD65W4 ARTRUSB20PD65M4 ARTRUSB20PD65G4	Features industry-leading 65W of power, dual Type-C ports and Power Delivery for optimal charging capacity. Ideal for charging devices such as smartphones, tablets and laptops.	White Magnesium Graphite  White Magnesium Graphite	5V, 9V, 15V & 20V 15A, 125V   5V, 9V, 15V & 20V 20A, 125V 	5-15R for NEMA  5-20R for NEMA	 , RoHS   , RoHS
30W Dual USB Outlet, Type-C 	ARUSB30PDW4 ARUSB30PDM4 ARUSB30PDG4	Charge up to 2X faster with this module featuring advanced Power Delivery* technology in two future-proof USB Type-C ports.  30W power negotiation for the most optimal charge for devices.	White Magnesium Graphite	5V, 9V & 15V		 , RoHS
30W USB Outlet, Type-C/C, 15A, Tamper-Resistant 	ARTRUSB15PD30W4 ARTRUSB15PD30M4 ARTRUSB15PD30G4  ARTRUSB20PD30W4 ARTRUSB20PD30M4 ARTRUSB20PD30G4	Charges devices up to 2X faster by combining our ultra-fast speed with advanced Power Delivery* technology. Includes two future-proof USB Type-C ports.  30W power negotiation for the most optimal charge for devices.  Compatible with 1-Gang+ Wall Plates only. Cannot be used in multi-gang installations.	White Magnesium Graphite  White Magnesium Graphite	5V, 9V & 15V 15A, 125V   5V, 9V & 15V 20A, 125V 	5-15R for NEMA  5-20R for NEMA	 , RoHS   , RoHS
15W USB Outlet, Type-A/C 	ARUSB2AC6W4 ARUSB2AC6M4 ARUSB2AC6G4	Charges phones, tablets and more, faster, with 6 amps of power via USB Types-A and C ports.	White Magnesium Graphite	6A, 5V		 , RoHS
15W USB Outlet, Type-A/C, 15A, Tamper-Resistant 	ARTRUSB156ACW4 ARTRUSB156ACM4 ARTRUSB156ACG4  ARTRUSB206ACW4 ARTRUSB206ACM4 ARTRUSB206ACG4	Charges phones, tablets and more, faster, with 6 amps of power via USB Types-A and C connections. Compatible with 1-Gang+ Wall Plates only. Cannot be used in multi-gang installations.	White Magnesium Graphite  White Magnesium Graphite	6A, 5V 15A, 125V   6A, 5V 20A, 125V 	5-15R for NEMA  5-20R for NEMA	 , RoHS   , RoHS

\*Power Delivery enables connected devices to receive the precise amount of power needed for safely maximized charging speeds.



## Pop-Out™ Outlet

Pop-Out Outlets require a special frame (included in package) and are not compatible with those used with adorne wall plates. **They require a deep box, such as Pass & Seymour SI22R, for installation or in a location that has a thick material like a kitchen backsplash, in a standard box.** Each 15A outlet includes capacity for three plugs.




NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPATIBLE LOADS	COMPLIANCE
Pop-Out Outlet, 1-Gang 	ARPTR151GW2 ARPTR151GM2 ARPTR151GG2	Includes 1-gang frame for installation. Cannot be paired with other switches, dimmers, outlets, or accessories. 15A version provides 3 receptacles. 20A version provides 2 receptacles. Cannot be used in multi-gang installations.	White Magnesium Graphite	15A 	5-15R	, RoHS
	ARPTR201GW2 ARPTR201GM2 ARPTR201GG2		White Magnesium Graphite	20A 	5-20R	
Pop-Out Outlet, 2-Gang 	ARPTR152GW2 ARPTR152GM2 ARPTR152GG2	Includes one Pop-Out Outlet and 2-gang frame for installation. Select this option to pair your Pop-Out Outlet with another adorne switch, dimmer, outlet, or accessory.	White Magnesium Graphite	15A 	5-15R	, RoHS




## deQuorum™ Flip-Up Table Boxes

deQuorum Flip-Up Table Boxes provide flexibility in decor, communication connectivity options, and installation to meet specific functional and aesthetic needs. Flip-Up Table Boxes bring the modules above the work surface when in use for easy access. Available in a black powder coat or brushed stainless steel finish.




\*For additional configurations, contact your local rep.

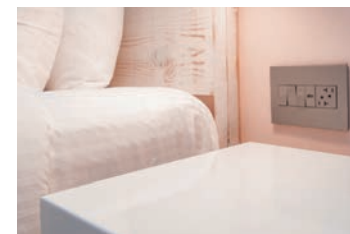
NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPATIBLE LOADS	COMPLIANCE
Field Wired Dequorum™ Single Flip Up Unit with USB 	DQFF15UBK DQFF15UST	Unit includes one (1) 15A tamper resistant duplex receptacle with two (2) USB ports that provide 3.1A.	Black Stainless	15A, 125V	5-15R	, RoHS
Cord Ended Dequorum™ Single Flip Up Unit with USB 	DQFP15UBK DQFP15UST	Unit includes one (1) 15A black tamper-resistant duplex receptacle with two (2) USB ports that provide 3.1A. Unit comes with a 6' (1.83m) cord. Comes with a black powder coat finish.	Black Stainless	15A, 125V	5-15R	, RoHS
Cord Ended Dequorum™ Single Flip Up Unit 	DQFP15BK DQFP15ST	Unit includes one (1) 15A black tamper-resistant duplex receptacle. Unit comes with a 6' (1.83m) cord. Comes with a black powder coat finish.	Black Stainless	15A, 125V	5-15R	, RoHS



## Furniture Power Centers




Furniture Power Centers offer endless design possibilities by allowing power and charging to be built directly into furniture. Available options can blend in seamlessly or add a beautiful accent to your furniture or space. Add power, charging and more directly into headboards, night stands or seating.

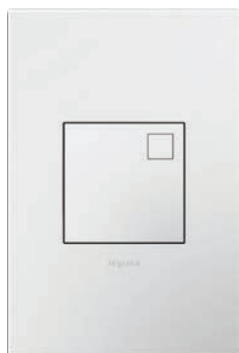NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPATIBLE LOADS	COMPLIANCE
Furniture Power, Outlet and USB Port 	AD1-RU-W AD1-RU-M	Easily add power and charging to furniture. 1 tamper-resistant outlet and 1 USB charging port in a magnesium finish. Wall plate sold separately. Comes standard with 8 foot cord with right angle plug.	White Magnesium	Receptacles: 15A 120V  USB charging ports: 2.4A, 5Vdc each	5-15R	, RoHS
Furniture Power, Outlet and 2 USB Ports 	AD2-2UR-W AD2-2UR-M	Easily add power and charging to furniture. 1 tamper-resistant outlet and 2 USB charging ports in a magnesium finish. Wall plate sold separately. Comes standard with 8 foot cord with right angle plug.	White Magnesium	Receptacles: 15A 120V  USB charging ports: 2.4A, 5Vdc each	5-15R	, RoHS
Furniture Power, 2 Outlets and 2 USB Ports 	AD3-R2UR-W AD3-R2UR-M	Easily add power and charging to furniture. 2 tamper-resistant outlets and 2 USB charging ports in a magnesium finish. Wall plate sold separately. Comes standard with 8 foot cord with right angle plug.	White Magnesium	Receptacles: 15A 120V  USB charging ports: 2.4A, 5Vdc each	5-15R	, RoHS



## Illumination Accessories

You've never seen a night light that hides itself so cleverly, yet responds so elegantly to a simple touch. Or one that can be lifted from its home on your wall to double as a carry-around flashlight. When it comes to brilliant solutions, adorne really shines. All night lights include ambient light level sensors. Each features a range of settings, including: Always Off, Low, Medium and High. If set to Low, Medium or High, the night light's LED will only be visible when the ambient room is dark. To change the selected setting, simply push on the square in the upper right-hand corner of the night light.

NAME	PART NUMBER	DESCRIPTION	COMPLIANCE
Night Light, Half-Size 	AANLM14	Features a soft, glowing LED light.  Pair with a switch or outlet in a 1-Gang+ Wall Plate for greater functionality.  <b>Light levels include:</b> Always Off Low Medium High	cUL <sup>®</sup> LISTED, RoHS
Night Light 	AANLM24	Features a soft, glowing LED light.  <b>Light levels include:</b> Always Off Low Medium High	cUL <sup>®</sup> LISTED, RoHS
Portable Night Light/Flashlight 	AARNL2	Simply push on this innovative night light to remove it from the wall and use it as a flashlight. Device recharges while mounted in wall and operates for up to 10 hours during a power failure.  Includes light level options listed above, as well as Flashlight Mode, which is activated only when device is removed from the wall.	cUL <sup>®</sup> LISTED, RoHS



In-wall Night Light function




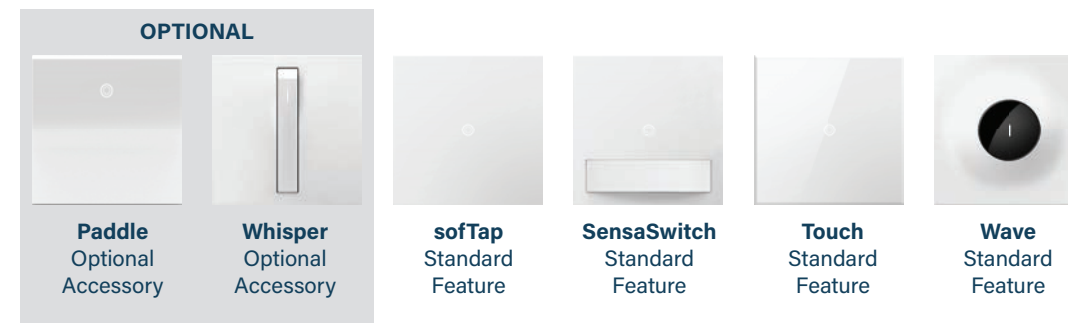
Press on Night Light to remove from wall



Portable flashlight function

## Locator Status Light: Find Us in the Dark

NAME	PART NUMBER	DESCRIPTION	COMPLIANCE
Locator Status Light 	AALS6 AALS277 (277 VAC)	Add a stylish, small locator light to your Paddle, or Whisper switch or dimmer and you'll never again have to slide your hand across the wall trying to find that switch.  The locator light is a standard feature of all other switches and dimmers. It can be disabled if desired.  Locator light is on when the load is off and off when the load is on.	cUL <sup>®</sup> LISTED, RoHS



## SMART LIGHTING





 











### Color Change Kits - adorne

NAME	PART NUMBER	INSTALLATION / WORKS WITH	DESCRIPTION	COLOR
Smart Switch with Netatmo Color Change Kit	WNAL10CKIT*	WNAL10*	Interchangeable faceplates for us with Smart Lighting with Netatmo devices	White (W1) Magnesium (M1) Graphite (G1)
Remote Smart Switch with Netatmo Color Change Kit	WNAL23CKIT*	WNAL23* WNAL24*	Interchangeable faceplates for us with Smart Lighting with Netatmo devices	White (W1) Magnesium (M1) Graphite (G1)
Smart Dimmer with Netatmo Color Change Kit	WNAL50CKIT*	WNAL50*	Interchangeable faceplates for us with Smart Lighting with Netatmo devices	White (W1) Magnesium (M1) Graphite (G1)
Remote Smart Dimmer with Netatmo Color Change Kit	WNAL63CKIT*	WNAL63* WNAL64*	Interchangeable faceplates for us with Smart Lighting with Netatmo devices	White (W1) Magnesium (M1) Graphite (G1)
Smart Home/Away Switch with Netatmo Color Change Kit	WNAL33CKIT*	WNAL33* WNAL34*	Interchangeable faceplates for us with Smart Lighting with Netatmo devices	White (W1) Magnesium (M1) Graphite (G1)
Smart Wake/Sleep Switch with Netatmo Color Change Kit	WNAL43CKIT*	WNAL43* WNAL44*	Interchangeable faceplates for us with Smart Lighting with Netatmo devices	White (W1) Magnesium (M1) Graphite (G1)
Smart Scene Controller with Netatmo Color Change Kit	WNACB40CKIT*	WNACB40* WNACB46*	Interchangeable faceplates for us with Smart Lighting with Netatmo devices	White (W1) Magnesium (M1) Graphite (G1)

## adorne with Netatmo

Control lights and power, from anywhere, with the ultra-reliable smart lighting solution optimized for whole-home use. Build a system in three easy steps: 1) select a Gateway; 2) select primary devices; and 3) select add-on devices. Works with Amazon Alexa, Google Home and Apple HomeKit. Compatible with radiant with Netatmo.

 





 







### STEP 1: Select a Gateway

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPATIBLE LOADS	COMPLIANCE
Smart Gateway with Netatmo 	WNAH1W1 WNAH1M1 WNAH1G1	Creates a robust and dedicated network as the foundation of an adorne with Netatmo smart lighting solution.	White Magnesium Graphite	120V		 , RoHS
Smart Surface-Mount Gateway with Netatmo 	WNAH2W1 WNAH2M1 WNAH2G1	Creates a robust and dedicated network as the foundation of an adorne with Netatmo smart lighting solution. Installs beside an outlet or switch in a single-gang electrical box.  Ideal for remodels.	White Magnesium Graphite	120V		 , RoHS
Smart Switch with Netatmo 	WNAL10W1 WNAL10M1 WNAL10G1	Controls lights from anywhere. Gateway required.	White Magnesium Graphite	15A, 120V		 , RoHS
Smart Tru-Universal Dimmer with Netatmo 	WNAL50W1 WNAL50M1 WNAL50G1	Controls lights from anywhere. Gateway required.  Trim and phase adjustments are made in the Home+Control app. Works with virtually any dimmable bulb or fixture (excludes 0-10V).	White Magnesium Graphite	120V 450W LED/ CFL; 700W INC/HAL; 500VA MLV; 700W ELV; 5.5A EFL	Incandescent, Halogen & ELV: 700W, MLV: 500VA, LED/CFL: 450W FWD/250W REV (not compatible with 0-10V LED drivers), EFL: 5.5A	 , RoHS
Smart Outlet with Netatmo, Plus-Size 	WNAR153W1 WNAR153M1 WNAR153G1  WNAR203W1 WNAR203M1 WNAR203G1	Control power from anywhere. Two methods of install: 1. Wire for one outlet always on, one controlled; 2. Wire for downstream control of all outlets. Pair with a Wireless Smart Switch for on-wall control. Gateway required.	White Magnesium Graphite  White Magnesium Graphite	15A, 125V,   20A, 125V, 	5-15R  5-20R	 , RoHS
Smart Plug-In Switch with Netatmo 	WNP10	Plugs into an existing outlet to provide smart control of lamps or small appliances. Gateway required.	White			 , RoHS
Smart Plug-In Tru-Universal Dimmer with Netatmo 	WNP20	Plugs into an existing outlet to provide smart dimming control. Gateway required.  Trim and phase adjustments are made in the Home+Control app. Works with virtually any dimmable bulb or fixture (excludes 0-10V).	White	120V 450W LED/ CFL; 700W INC/HAL; 500VA MLV; 700W ELV; 5.5A EFL	Incandescent, Halogen & ELV: 700W, MLV: 500VA, LED/CFL: 450W FWD/250W REV (not compatible with 0-10V LED drivers), EFL: 5.5A	 , RoHS

### STEP 2: Select Primary Devices
 
### STEP 3: Select Add-on Devices

### KITS

NAME	PART NUMBER	INSTALLATION	DESCRIPTION	COLOR/FINISH	COMPLIANCE
Remote Smart Switch with Netatmo 	WNAL23W1 WNAL23M1 WNAL23G1  WNAL24W1	Wireless (Battery-Operated)  Wired	For easy 3-way control. Must be paired with a primary Smart Switch or Outlet with Netatmo. Can also be used as a master switch to control multiple wired Smart Switches with Netatmo.	White Magnesium Graphite  White	 , RoHS
Remote Smart Dimmer with Netatmo 	WNAL63W1 WNAL63M1 WNAL63G1  WNAL64W1	Wireless (Battery-Operated)  Wired	For easy 3-way control. Must be paired with a primary wired (or plug-in) Smart Tru-Universal Dimmer with Netatmo. Can also be used as a master dimmer to control multiple primary Smart Tru-Universal Dimmers with Netatmo.	White Magnesium Graphite  White	 , RoHS
Smart Scene Controller with Netatmo 	WNACB40W1 WNACB40M1 WNACB40G1  WNACB46W1	Wireless (Battery-Operated)  Wired	"Controls 4 customizable lighting scenes with a single touch. Gateway required. For use in conjunction with Smart Switches, Dimmers and/or Outlets with Netatmo. Note: Maximum of 8 scenes per system, including Home/Away and Wake/Sleep."	White Magnesium Graphite  White	 , RoHS
Smart Home/Away Switch with Netatmo 	WNAL33W1 WNAL33M1 WNAL33G1  WNAL34W1	Wireless (Battery-Operated)  Wired	Controls 2 scenes of multiple lights. Turn the lights on (or off), simultaneously, with just a single tap. Gateway required. For use in conjunction with Smart Switches, Dimmers and/or Outlets with Netatmo. Note: Maximum of 8 scenes per system, including Home/Away and Wake/Sleep.	White Magnesium Graphite  White	 , RoHS
Smart Wake/Sleep Switch with Netatmo 	WNAL43W1 WNAL43M1 WNAL43G1  WNAL44W1	Wireless (Battery-Operated)  Wired	Controls 2 scenes of multiple lights. Turn the lights on (or off), simultaneously, with just a single tap. Gateway required. For use in conjunction with Smart Switches, Dimmers and/or Outlets with Netatmo. Note: Maximum of 8 scenes per system, including Home/Away and Wake/Sleep.	White Magnesium Graphite  White	 , RoHS
4-Scene Pocket Remote Control with Netatmo 	067695	Wireless (Battery-Operated)	Control up to four full lighting scenes with a touch with this portable smart remote and key fob. Gateway required. For use in conjunction with Smart Switches, Dimmers and/or Outlets with Netatmo. Note: Maximum of 8 scenes per system, including Home/Away and Wake/Sleep.	Black	
Wireless Motion Sensor with Netatmo 	064875	Wireless (Battery-Operated)	Automatically turns lights on/off when motion is detected/absent for added safety and efficiency. Battery-operated.  Gateway required. For use in conjunction with Smart Switches, Dimmers and/or Outlets with Netatmo.	White	
Smart Switch Starter Kit with Netatmo 	WNAH10KITW1 WNAH10KITM1 WNAH10KITG1		Kit includes (1) Smart Switch with Netatmo, (1) Smart Surface-Mount Gateway with Netatmo, (1) Home/Away Wireless Smart Switch with Netatmo  Rating: 15A, 125V	White Magnesium Graphite	 , RoHS

Note: Due to manufacturer variations and modifications, we are unable to ensure indefinite dimming compatibility with any bulb or fixture. See new adorne Color Change Kits on page 25


## Blank Module

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH
Half-Size Blank	AABK1W4 AABK1M4 AABK1G4	Use this blank insert to give your project a complete, finished look. Pair it with other half-size devices, like the Night Light, Paddle Switch or USB, in a 1-gang wall plate.	White Magnesium Graphite

## Keystone Frames

For a consistent look throughout the project, select an adorne keystone frame to enable audio, video and data connectivity in an adorne wall plate. Simply pair a 1-port, 2-port or 4-port frame with any keystone inserts shown on the next page and then mount in an adorne wall plate for a complete installation.

NAME	PART NUMBER	COLOR/FINISH
1-Port Frame	AC1PFW1 AC1PFM1 AC1PFG1	White Magnesium Graphite
2-Port Frame	AC2PFW1 AC2PFM1 AC2PFG1	White Magnesium Graphite
4-Port Frame	AC4PFW1 AC4PFM1	White Magnesium
In-Wall Cable Access Port	ACBRSTPW1 ACBRSTPM1	White Magnesium

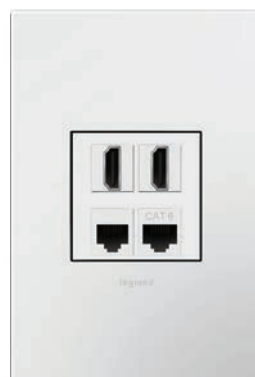

1-Port Frame



2-Port Frame



4-Port Frame




In-Wall Cable Access Port

## Keystone Inserts

NAME	PART NUMBER	COLOR/FINISH	NAME	PART NUMBER	COLOR/FINISH
Cat 5e RJ45 Data/Phone Insert	AC5ERJ45W1 AC5ERJ45M1	White Magnesium	HDMI Keystone Coupler	ACHDMIW1 ACHDMIM1	White Magnesium
Cat 5e RJ45 Data Coupler Insert	AC5ERJ45CW1 AC5ERJ45CM1	White Magnesium	Single Keystone Speaker Connector	ACSSIW1 ACSSIM1	White Magnesium
Cat 6 RJ45 Data Insert	AC6RJ45W1 AC6RJ45M1 AC6RJ45G1	White Magnesium Graphite	Speaker Binding Posts	ACABPW1 ACABPM1	White Magnesium
RJ25 Phone Jack	ACRJ25W1 ACRJ25M1	White Magnesium	Subwoofer RCA to F-Connector	ACPRCAFW1 ACPRCAFM1	White Magnesium
Component Video RCA to F Kit	ACRGBRCAFW1 ACRGBRCAFM1	White Magnesium	Video F-Connector	ACNRFCW1 ACNRFCM1 ACNRFCG1	White Magnesium Graphite
Composite Video RCA to F-Connector	ACYRCAFW1 ACYRCAFM1	White Magnesium	Blank Keystone Insert (4-Pack)	ACBLKW4 ACBLKM4	White Magnesium

## Modular Unit Dimensions

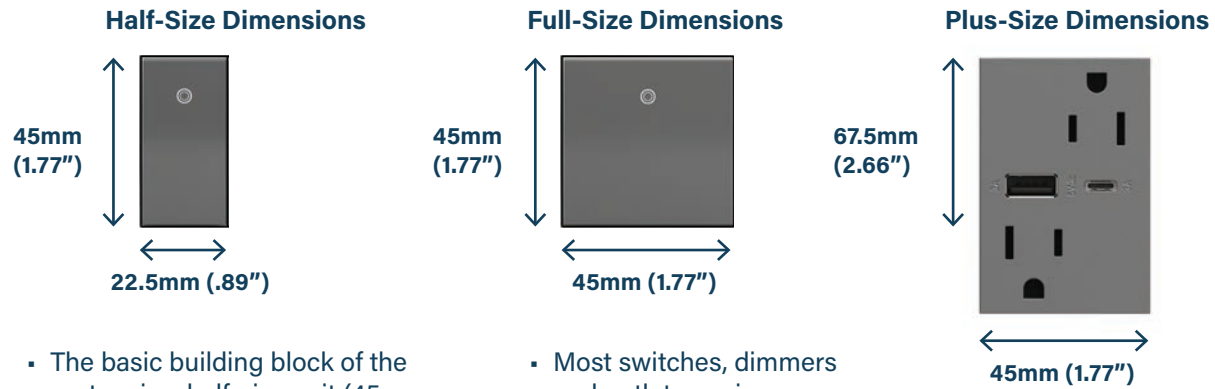

- The basic building block of the system is a half-size unit (45mm x 22.5mm).
- All devices have either half-size or full-size front faces.
- Devices can also have half-size, full-size or plus-size back bodies.
- Most switches, dimmers and outlets are in the full-size format (45mm x 45 mm). This is the standard adorne proprietary "45" opening.
- Select outlets are available with a plus-size front face (67.5mm x 45mm) for easier access to power and/or USB ports.
- Plus-size devices must be paired with 1-Gang+ wall plates.

## Front Face and Back Body Modular Sizes

### SWITCHES

NAME	FRONT FACE SIZE	BACK BODY SIZE
Paddle Switch, 2-Module	Full-Size	Full-Size
Paddle Switch, 1-Module	Half-Size	Half-Size
Whisper Switch	Full-Size	Full-Size
sofTap Switch	Full-Size	Plus-Size
SensaSwitch	Full-Size	Plus-Size
Touch	Full-Size	Plus-Size
Wave	Full-Size	Plus-Size

### DIMMERS

NAME	FRONT FACE SIZE	BACK BODY SIZE
Paddle	Full-Size	Plus-Size
Whisper	Full-Size	Plus-Size
sofTap	Full-Size	Plus-Size
SensaDimmer	Full-Size	Plus-Size
Touch	Full-Size	Plus-Size
Paddle Fan Speed Control	Full-Size	Plus-Size

### OUTLETS

NAME	FRONT FACE SIZE	BACK BODY SIZE
Tamper-Resistant Outlet, Full-Size	Full-Size	Full-Size
Tamper-Resistant Outlet, Plus-Size	Plus-Size	Plus-Size
GFCI Outlet, Full-Size	Full-Size	Plus-Size
GFCI Outlet, Plus-Size	Plus-Size	Plus-Size
Energy-Saving ON/OFF Outlet	Full-Size	Full-Size
Pop-Out Outlet	Full-Size	Plus-Size
Ultra-Fast USB Outlet, Plus-Size	Plus-Size	Plus-Size
Ultra-Fast Plus Power Delivery USB Outlet, Plus-Size	Plus-Size	Plus-Size

### ILLUMINATION

NAME	FRONT FACE SIZE	BACK BODY SIZE
Night Light, Half-Size	Half-Size	Half-Size
Night Light, Full-Size	Full-Size	Full-Size
Portable Night Light/Flashlight	Full-Size	Plus-Size

## Ways to Configure Various Device Sizes

### 1-GANG



### 1-GANG+



### 2-GANG



### 3-GANG



### 4-GANG





R REAL MATERIALS

CM CAST METALS

P PLASTIC




1 Black Stainless



1 Brushed Stainless



1 Custom with Magnesium Trim

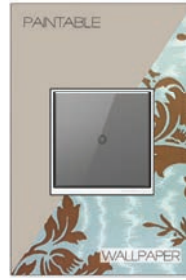

1 Custom with White Trim



1 Macassar



1 Mirror



1 Mirror Black



1 Mirror White



1 Mirror White, White-on-White



1 Slate Linen



1 Spiraled Stainless



1 Rustic Grey



1 True Linen



1 Copper



CM Brushed Stainless Steel



CM Satin Nickel



CM Oil-Rubbed Bronze



CM Brushed Satin Brass



1 Gloss White




1 Gloss White, White-on-White



1 Matte White



1 Bronze

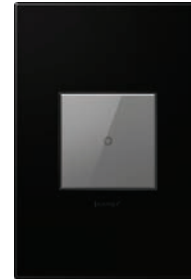

1 Black Ink



1 Oatmeal



1 Greige



1 Titanium



1 Magnesium



1 Graphite



1 Pale Blue



1 Rosa



1 Peachy



1 Mystic



1 Evergreen

REAL MATERIALS



## Real Materials













These adorne Wall Plates add unique beauty to any space with contemporary options like stainless and mirror, as well as natural materials like linen and wood.

NAME	GANGS	PART NUMBER	NAME	GANGS	PART NUMBER
Black Stainless 	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWM1G2BLS4 AWM1G3BLS4 AWM2GBLS4 AWM3GBLS4 AWM4GBLS4	Mirror White 	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWM1G2MW4 AWM1G3MW4 AWM2GMW4 AWM3GMW4 AWM4GMW4
Brushed Stainless 	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWM1G2MS4 AWM1G3MS4 AWM2GMS4 AWM3GMS4 AWM4GMS4	Mirror White, White-on-White 	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWM1G2MWW4 AWM1G3MWW4 AWM2GMWW4 AWM3GMWW4 AWM4GMWW4
Custom with Magnesium Trim 	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWM1G2M4 AWM1G3M4 AWM2GM4 AWM3GM4 AWM4GM4	Rustic Grey 	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWM1G2RG4 AWM1G3RG4 AWM2GRG4 AWM3GRG4 AWM4GRG4
Custom with White Trim 	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWM1G2W4 AWM1G3W4 AWM2GW4 AWM3GW4 AWM4GW4	Slate Linen 	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWM1G2SL4 AWM1G3SL4 AWM2GSL4 AWM3GSL4 AWM4GSL4
Macassar 	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWM1G2MA4 AWM1G3MA4 AWM2GMA4 AWM3GMA4 AWM4GMA4	Spiraled Stainless 	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWM1G2SP4 AWM1G3SP4 AWM2GSP4 AWM3GSP4 AWM4GSP4
Mirror 	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWM1G2MR1 AWM1G3MR1 AWM2GMR1 AWM3GMR1 AWM4GMR1	True Linen 	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWM1G2TL4 AWM1G3TL4 AWM2GTL4 AWM3GTL4 AWM4GTL4
Mirror Black 	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWM1G2MB4 AWM1G3MB4 AWM2GMB4 AWM3GMB4 AWM4GMB4	Copper 	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWM1G2CU4 AWM1G3CU4 AWM2GCU4 AWM3GCU4 AWM4GCU4



## Cast Metals














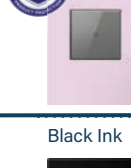
 
Cast metal Wall Plates from the adorne Collection are hand-crafted by artisans, making them unique and distinctive. These slight variations in finish and color add to the rich beauty of the adorne cast metal offering.

NAME	GANGS	PART NUMBER	NAME	GANGS	PART NUMBER
Brushed Satin Brass   	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWC1G2BSB4 AWC1G3BSB4 AWC2GBSB4 AWC3GBSB4 AWC4GBSB4	Oil-Rubbed Bronze   	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWC1G2OB4 AWC1G3OB4 AWC2GOB4 AWC3GOB4 AWC4GOB4
Brushed Stainless Steel   	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWC1G2BS4 AWC1G3BS4 AWC2GBS4 AWC3GBS4 AWC4GBS4	Satin Nickel   	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang	AWC1G2SN4 AWC1G3SN4 AWC2GSN4 AWC3GSN4 AWC4GSN4



## Plastics

Available in a variety of classic and contemporary colors, adorne plastic Wall Plates provide the perfect finishing touch to any installation.

NAME	GANGS	PART NUMBER	NAME	GANGS	PART NUMBER
 Gloss White	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	AWP1G2WH6 AWP1G3WH4 AWP2GWH4 AWP3GWH4 AWP4GWH4 AWP5GWH1 AWP6GWH1	 Titanium	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	AWP1G2TM6 AWP1G3TM4 AWP2GTM4 AWP3GTM4 AWP4GTM4 AWP5GTM1 AWP6GTM1
 Gloss White, White-on-White	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	AWP1G2WHW10 AWP1G3WHW4 AWP2GWHW10 AWP3GWHW4 AWP4GWHW4 AWP5GWHW1 AWP6GWHW1	 Bronze	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	AWP1G2BR6 AWP1G3BR4 AWP2GBR4 AWP3GBR4 AWP4GBR4 AWP5GBR1 AWP6GBR1
 Matte White	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	AWP1G2PW4 AWP1G3PW4 AWP2GPW4 AWP3GPW4 AWP4GPW4 AWP5GPW1 AWP6GPW1	 Greige	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	AWP1G2GG4 AWP1G3GG4 AWP2GGG4 AWP3GGG4 AWP4GGG4 AWP5GGG1 AWP6GGG1
 Magnesium	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	AWP1G2MG6 AWP1G3MG4 AWP2GMG4 AWP3GMG4 AWP4GMG4 AWP5GMG1 AWP6GMG1	 Pale Blue	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	AWP1G2BL6 AWP1G3BL4 AWP2GBL4 AWP3GBL4 AWP4GBL4 AWP5GBL1 AWP6GBL1
 Graphite	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	AWP1G2GR6 AWP1G3GR4 AWP2GGR4 AWP3GGR4 AWP4GGR4 AWP5GGR1 AWP6GGR1	 Oatmeal	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	AWP1G2OM AWP1G3OM AWP2GOM AWP3GOM AWP4GOM AWP5GOM AWP6GOM
 Evergreen	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	AWP1G2EG AWP1G3EG AWP2GEG AWP3GEG AWP4GEG AWP5GEG AWP6GEG	 Peachy	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	AWP1G2PY AWP1G3PY AWP2GPY AWP3GPY AWP4GPY AWP5GPY AWP6GPY
 Mystic	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	AWP1G2MY AWP1G3MY AWP2GMY AWP3GMY AWP4GMY AWP5GMY AWP6GMY	 Rosa	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	AWP1G2RA AWP1G3RA AWP2GRA AWP3GRA AWP4GRA AWP5GRA AWP6GRA
			 Black Ink	1-Gang 1-Gang+ 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	AWP1G2NK4 AWP1G3NK4 AWP2GNK4 AWP3GNK4 AWP4GNK4 AWP5GNK1 AWP6GNK1

PROTECTED WITH MICROBAN<sup>®</sup>

### FINISHES

-  Matte
-  Satin
-  Gloss



## The adorne Frame System

The frame is the foundation upon which the adorne modular system is built. It is manufactured with high-strength galvanized metal and includes a ground wire.

Frames include plastic spacers. The spacers remain in place for devices with full size back bodies. They must be removed for devices with plus size back bodies, such as dimmers and GFCI outlets.

The frame completes the enclosure, providing a safe installation during the construction phase and allowing the wall plate to be installed at the end of the project.

Each frame includes a leaded ground that supports the full adorne system. Most switches, outlets and wall plates (including cast metals) are automatically grounded to the frame, saving time and ensuring a safe and reliable ground path.

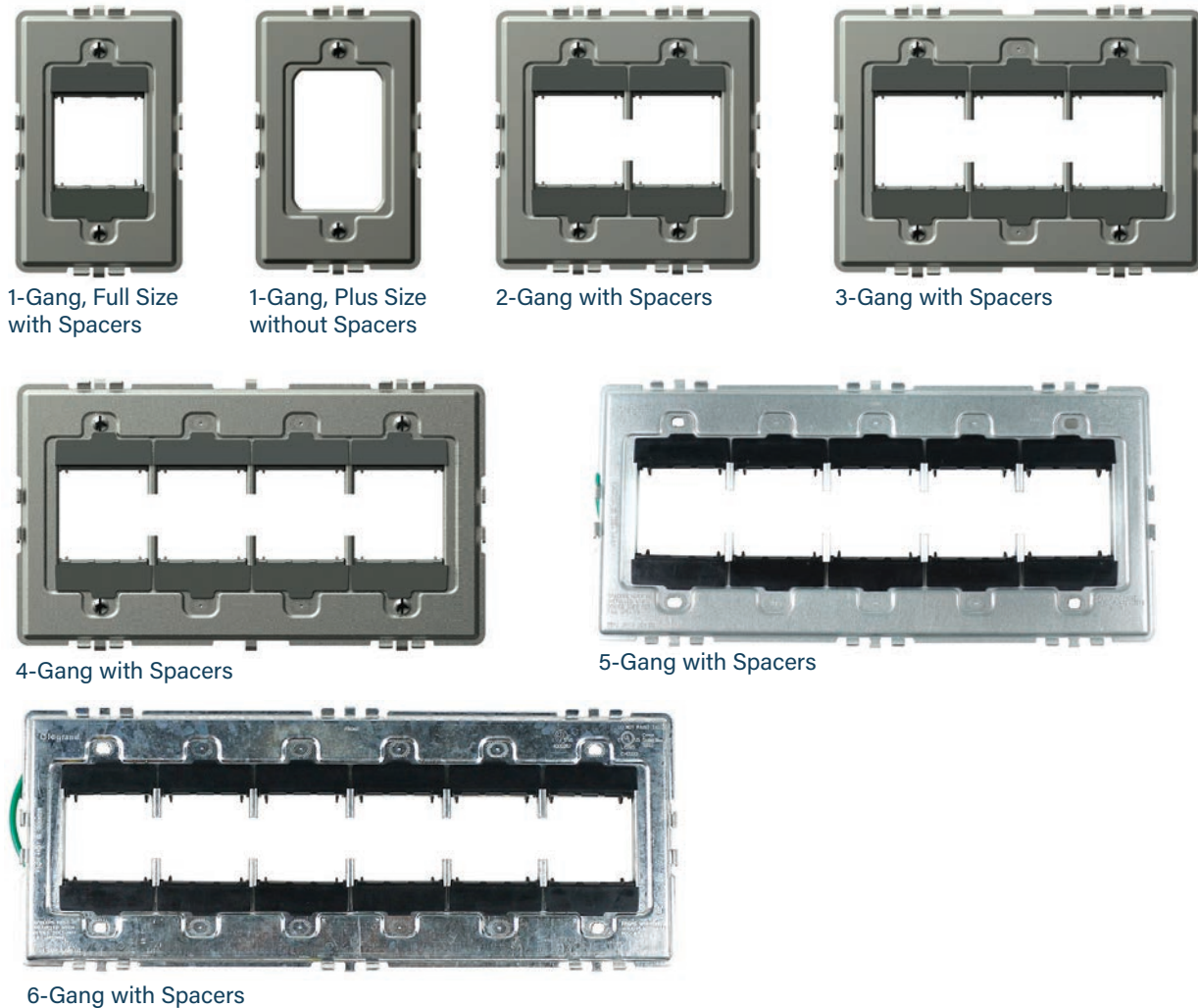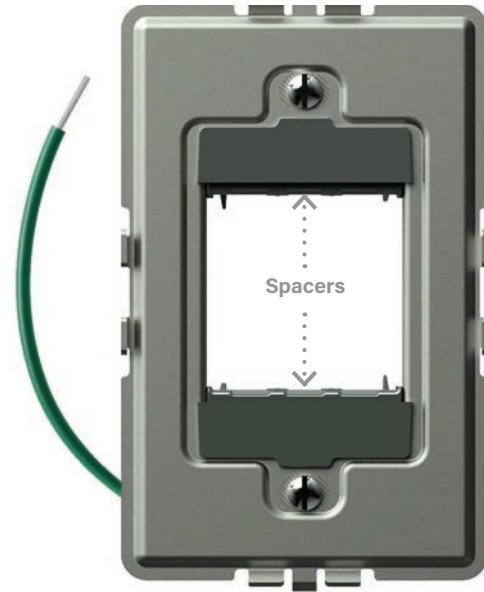

## Mounting Frames

NAME	PART NUMBER
1-Gang Mounting Frame	AF1G
2-Gang Mounting Frame	AF2G
3-Gang Mounting Frame	AF3G
4-Gang Mounting Frame	AF4G
5-Gang Mounting Frame	AF5G
6-Gang Mounting Frame	AF6G

## The adorne Modular System

Complete versatility and unmatched flexibility

adorne fits in all existing NEMA-approved wallboxes.\*

The frame is grounded.

Device snaps into the frame and is automatically grounded\*\*. It self-aligns without any screws.

Standard Wallbox

Ground Wire

Frame

Device


Wall Plate




Wall plate snaps onto frame; no screws required.

Modular system solves device alignment problems, improving fit and finish in multi-gang installations.

\* Does not apply to Pop-Out Outlet.  
\*\* Does not apply to Pop-Out Outlet, 20A Outlet, or 20A GFCI Outlet.

Devices simply snap into the frame from the front. During installation, screw the frame to the box, then pull the wires through the frame and wire the device. Then, simply snap the device into the frame.


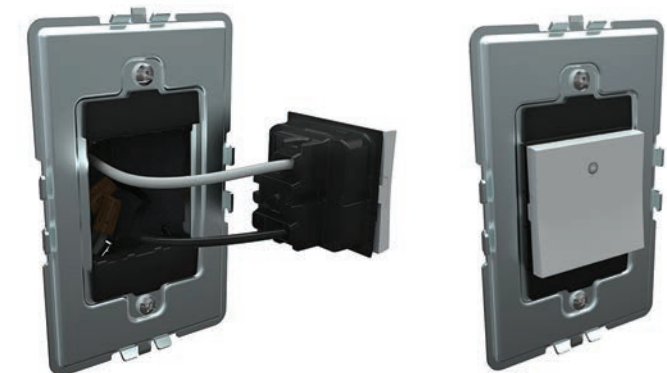


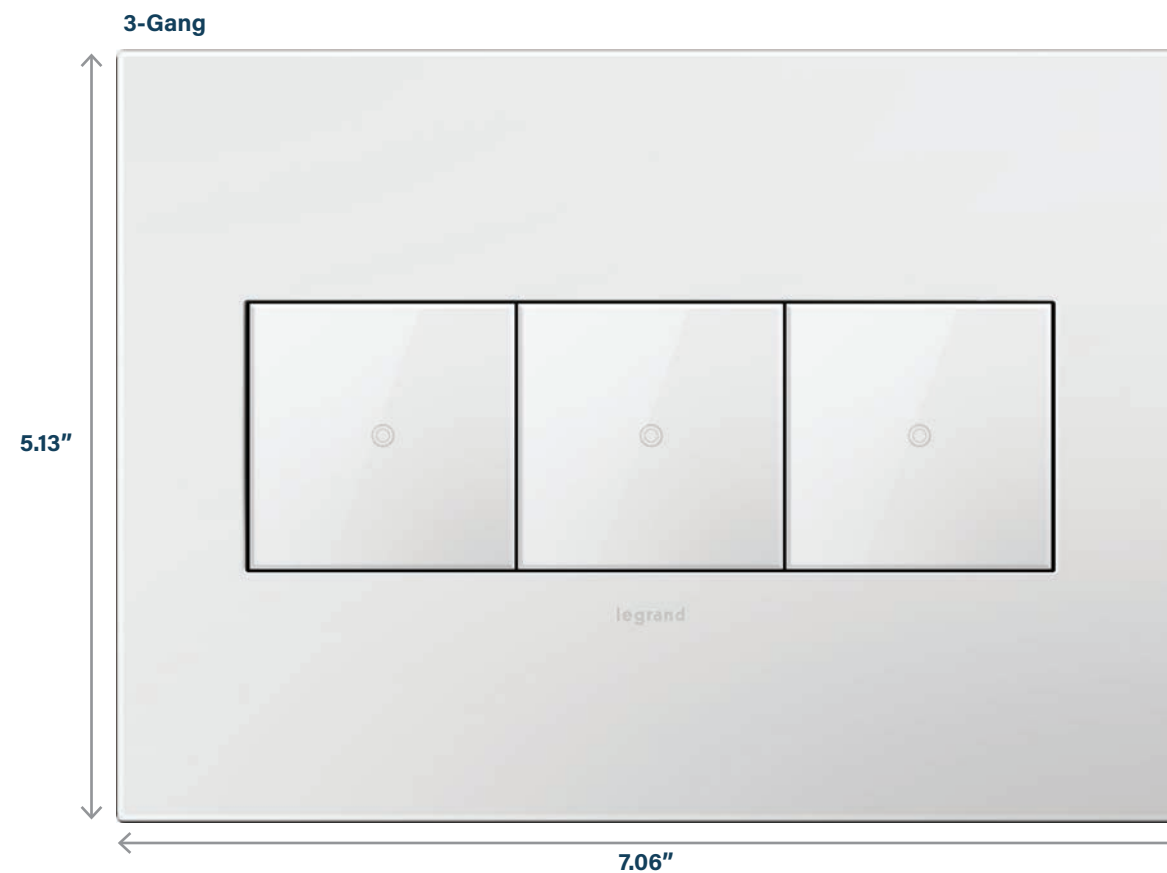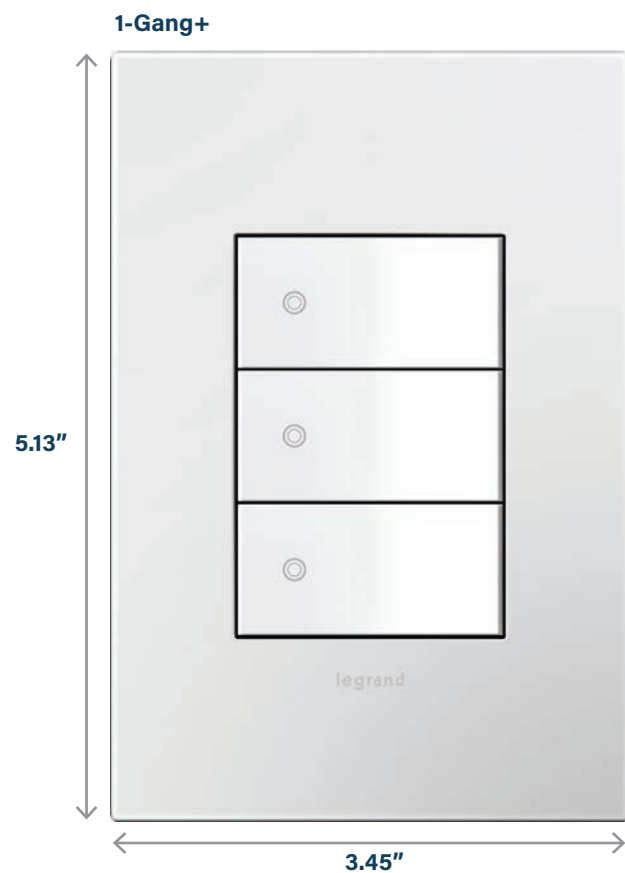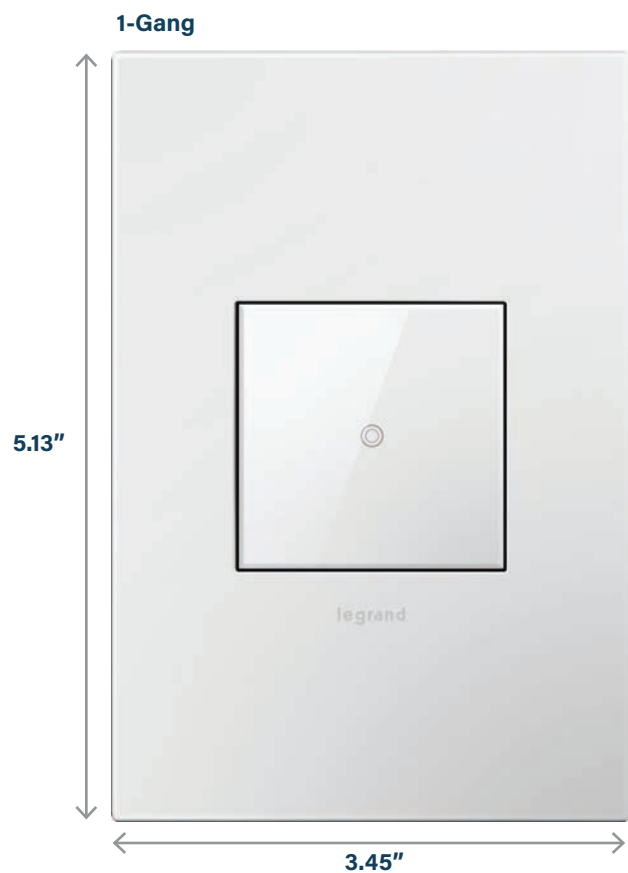

## Wall Plates

Available in six gang sizes, adorne wall plates provide the perfect complement to adorne switches, dimmers, outlets and accessories. The collection includes a variety of finishes, from cast metals like Satin Nickel and Oil-Rubbed Bronze to real materials such as linen and wood. In addition, the collection includes a full offering of plastic plates in contemporary and classic colors, as well as three innovative Soft Touch finishes. Each wall plate is packaged with a mounting frame to enable easy installation when paired with a device. All plates are screwless and simply snap onto the included metal frame. See page 40 for more information on the adorne frame system.

All adorne wall plates are UL and ETL-approved. 5- and 6-Gang wall plates are not available in all colors.

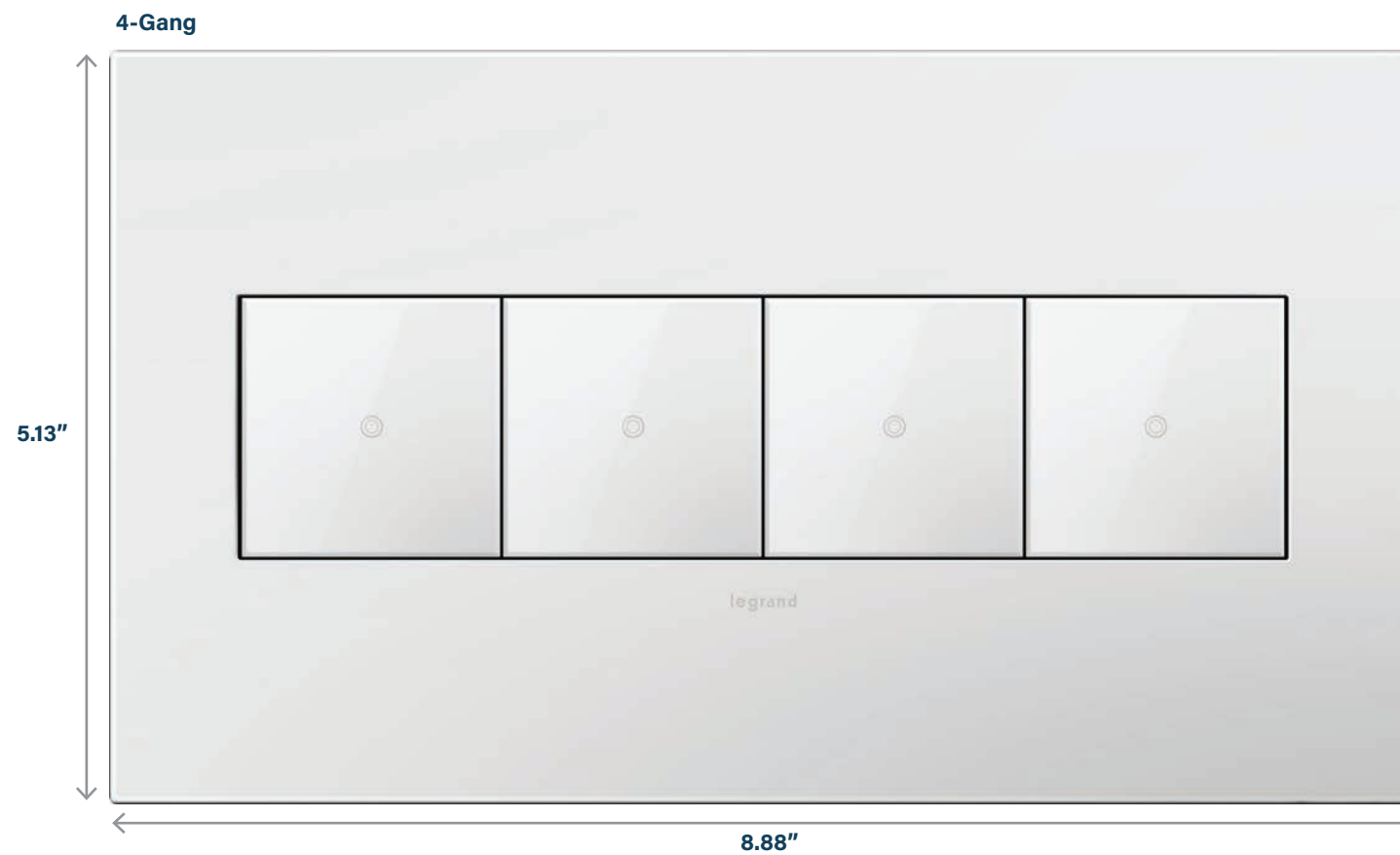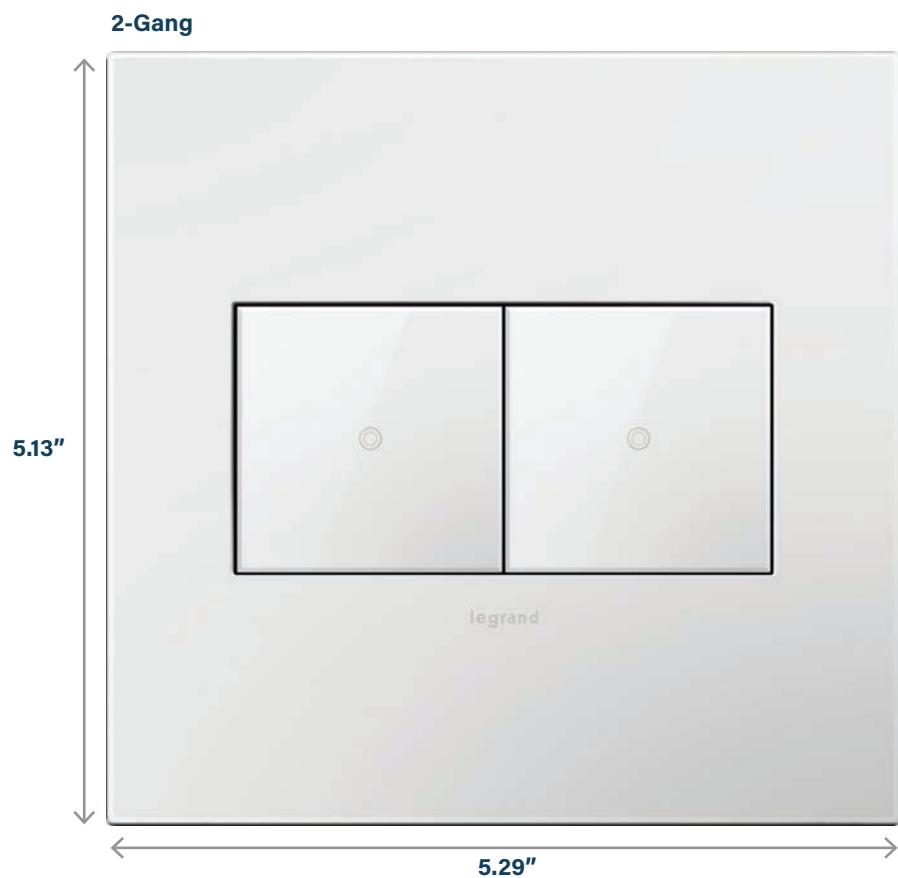

**5-Gang**  
5.13" x 10.7"



**6-Gang**  
5.13" x 12.5"



*the*  
**radiant**<sup>®</sup>  
*collection*

# Dimmers & Switches



**TRU-UNIVERSAL DIMMER | RH703PTUW**  
This dimmer self-calibrates to work with virtually any 120V dimmable bulb or fixture (excludes 0-10V). **Also available with Microban® product protection: RH703PTUWAMCC4**

**LED ADVANCED DIMMER | RHL153PW**  
Designed with advanced dimming technology and optimized to work right out of the box, this LED dimmer offers a wide range of adjustability and compatibility with LED bulbs and fixtures.

**0-10V LED/FLUORESCENT DIMMER | RH4FBL3PW**  
Control dimmable low-voltage fluorescent or LED bulbs or fixtures with efficiency and ease.



**SINGLE POLE/3-WAY OCCUPANCY SENSOR | RRW600UTC**  
Automatically turns lights on when someone enters the room and shuts lights off when it's empty.

**SINGLE-POLE SWITCH WITH LOCATOR LIGHT | TM870WSL**  
Conveniently locate your switch in the dark with the small, subtle locator light that illuminates when switched off.

**WAVE® SWITCH | RSWV203**  
Go germ-free. Turn lights on/off with a wave.



# Outlets



**TAMPER-RESISTANT OUTLET | 885TRW**  
Discreetly prevents insertion of foreign objects with patented "invisi-shutters."

**TAMPER-RESISTANT SELF-TEST GFCI OUTLET | 1597TRW**  
Self-tests at the industry-leading rate of every 3 seconds to offer superior ground-fault protection.

**TAMPER-RESISTANT SELF-TEST GFCI USB TYPE-A/C OUTLET | 1597TRUSBACW**  
Combines superior ground-fault protection and convenient built-in charging in a single outlet.



**SINGLE POLE/3-WAY SWITCH/TAMPER-RESISTANT OUTLET COMBINATION | RCD38TRW**  
Fit two devices neatly into the footprint of one with this combination single-pole/3-way switch and tamper-resistant outlet.

**WEATHER-RESISTANT OUTLET | 885TREXWRW**  
Perfect for a home's outdoor spaces, this outlet is made to work, rain or shine.

# USB Charging Solutions



**65W USB OUTLET, TYPE C, 15A, TAMPER-RESISTANT | R26USBPD65W**  
 Features dual Type-C charging ports with 65W each, advanced Power Delivery, integrated GaN and industry-exclusive power indicator lights.

**30W USB OUTLET, TYPE C, 15A, TAMPER-RESISTANT | R26USBPDW**  
 Features dual Type-C charging ports with 30W each, advanced Power Delivery and industry-exclusive power indicator lights.



**15W USB OUTLET, TYPE A/C, 15A, TAMPER-RESISTANT | R26USBAC6W**  
 With 6 amps of power, this USB outlet provides a quicker charge for phones, tablets and other devices, meaning no more low battery anxiety.

**QUAD USB CHARGER | TM8USB4WCC6**  
 With 4.2 amps of charging capacity, the quad USB gives users the power to charge up to four devices simultaneously without the need for bulky adapters.

# Night Lights



 
**FULL LED NIGHT LIGHT | NTLFULLW**  
Energy-efficient soft-glow LED features five adjustable brightness levels and optional louver for greater control. Shown with included optional louver.




**NIGHT LIGHT WITH TAMPER-RESISTANT OUTLET | NTL885TRW**  
This seamlessly integrated night light features five adjustable brightness levels, an optional louver for greater light control and a hidden sensor that turns light on in the dark, off in daylight.

**COMBINATION TAMPER-RESISTANT SELF-TEST NIGHT LIGHT/GFCI | 1597NTLTRW**  
For superior safety, this outlet offers all the protection of tamper-resistance and GFCI functionality, with an included night light for added convenience.

# Smart Lighting



Manage lights and power, from anywhere, with the Legrand Home + Control app.

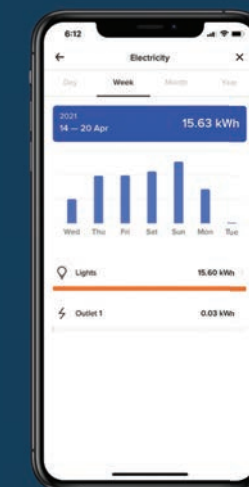


## radiant<sup>®</sup> WITH Netatmo



**SMART GATEWAY WITH NETATMO | WNRH1WH**  
Start here to create a robust, dedicated network for advanced smart control throughout an entire home. Required for all “with Netatmo” smart lighting solutions.

**SMART SWITCH WITH NETATMO | WNRL10WH**  
Get advanced control of your lights from any smart device, from anywhere. Optimized for whole home use. Requires Smart Gateway. Plug-in version also available.

**SMART TRU-UNIVERSAL DIMMER WITH NETATMO | WNRL50WH**  
This dimmer self-calibrates to work with virtually any 120V dimmable bulb or fixture (excludes 0-10V). Plug-in version also available.

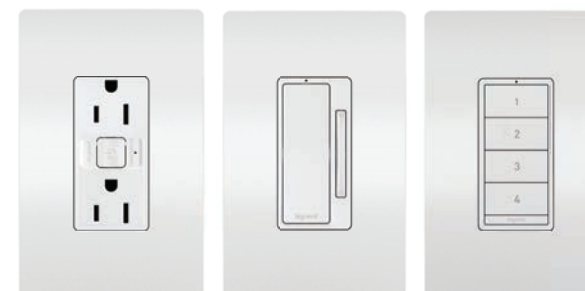















**SMART OUTLET WITH NETATMO | WNRR15WH**  
Get advanced control of power from any smart device, from anywhere. One outlet is app-controlled, the other is always on. Requires Smart Gateway. 15A and 20A versions available.

**SMART WIRELESS DIMMER WITH NETATMO | WNRL63WH**  
Add to any wall or surface for easy 3-way dimming control. Battery-operated; no wiring required. Switch also available.




**SMART WIRELESS SCENE CONTROLLER WITH NETATMO | WNRCB40WH**  
Add to any wall or surface for one-tap control of four lighting scenes. Battery-operated; no wiring required.

## Dimmers

Conveniently conserve energy and create the perfect mood by adjusting dimmer light levels with a single slide.









NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	NEUTRAL NEEDED	COMPLIANCE
 LED Advanced Dimmer	RHL153PW RHL153PLA RHL153PI RHL153PBK RHL153PGRY RHL153P RHL153PRED RHL153PNI RHL153PDB RHL153PG RHL153PW10PK	Single-pole/3-way.  Advanced circuitry provides flicker-free control of dimmable LED bulbs and fixtures (except for 0-10V and ELV drivers) with adjustable high- and low-end dimming range.	White Light Almond Ivory Black Gray Brown Red Nickel Dark Bronze Graphite White	120V, 150W LED; 150W CFL/INC	No	 , RoHS
 Tru-Universal Single-Pole/3-Way Dimmer	RH703PTUTC RH703PTUW	Self-calibrates to work with virtually any dimmable bulb or fixture (excludes 0-10V). Single-pole/3-way.  Features interchangeable faceplates.	Tri-Color* White	120V 450W LED/CFL; 700W INC/HAL; 500VA MLV; 700W ELV; 5.5A EFL	Yes	 , RoHS
 Tru-Universal Single-Pole/3-Way Dimmer with Microban <sup>®</sup>	RH703PTUWAMCC4	A self-calibrating dimmer to work with virtually any dimmable bulb or fixture (excludes 0-10V) also featuring built-in, lasting Microban <sup>®</sup> antimicrobial* protection for a cleaner, more durable device.	White			
 0-10V LED/Fluorescent Dimmer	RH4FBL3PTC RH4FBL3PW	Single-pole/3-way.  Features interchangeable faceplates.	Tri-Color* White	120/277V (0-10V dimming only) 120V 10A / 277V 5A LED/FL	No	 , RoHS
 LED/CFL Dimmer, SSL 7A-Compliant	RHL373PTC RHL373PW  RHL743PTC RHL743PW	2-Wire. Single-Pole/3-Way.  Single-Pole/3-Way.	Tri-Color* White  Tri-Color* White	50W LED CFL  450W LED CFL	Yes	 , RoHS
 LED/CFL Dimmer (Not intended for electronic low voltage loads)	RHCL453PDBCCV4 RHCL453PGCCV4 RHCL453PNICCV4 RHCL453PTC RHCL453PW	Single-pole/3-way.  Features interchangeable faceplates.	Dark Bronze Graphite Nickel Tri-Color* White	120V 450W LED/CFL; 700W INC/HAL	No	 , RoHS
 LED/CFL Dimmer with Microban <sup>®</sup>	RHCL453PWAMCC4	A single-pole/3-way dimmer (not intended for use with electronic low voltage loads) featuring built-in, lasting Microban <sup>®</sup> antimicrobial* protection for a cleaner, more durable device.	White			
 Magnetic Low-Voltage Single-Pole/3-Way Dimmer	RHLV703PTC RHLV703PW	Single-pole/3-way.  Features interchangeable faceplates.	Tri-Color* White	120V 700VA MLV	No	 , RoHS

Note: Wall plates sold separately. Tri-color includes: White, Light Almond and Ivory. Bi-Color includes: Nickel & Dark Bronze  
Due to manufacturer variations and modifications, we are unable to ensure indefinite dimming compatibility with any bulb or fixture.  
\*No antimicrobial efficacy claims are being made or are valid with respect to products sold in Canada.

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPLIANCE
 Interchangeable Face Cover	RHKIT RHKITBK RHKITDB RHKITGPCCV6 RHKITGRY RHKITI RHKITLA RHKITNI RHKITW	Features interchangeable faceplates.  Usable with all dimmers on pages 64 and 65 except RHL153P.	Brown Black Dark Bronze Graphite Gray Ivory Light Almond Nickel White		 , RoHS
 Dimmer Bypass Module	DIMBPASS	This device is an adapter that can be installed at the dimmer or at the load that fixes most LED light anomalies such as flicker and ghosting.	Black	120V, 60Hz 0.1 Amps	

## Multi-Location Dimmers






Conveniently conserve energy and create the perfect mood by adjusting dimmer light levels with a single slide.

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPLIANCE
 Multi-Location Master Dimmer	HCL453PMMTC HCL453PMMW	Features interchangeable faceplates.	Tri-Color* White	120V, 450W LED/ CFL; 700W INC/HAL; 700VA MLV	 , RoHS
 Interchangeable Face Cover for Multi-Location Master Dimmer	HMKIT HMKITBK HMKITDB HMKITGRY HMKITI HMKITLA HMKITNI HMKITW	Features interchangeable faceplates.	Brown Black Dark Bronze Gray Ivory Light Almond Nickel White		 , RoHS
 Multi-Location Remote Dimmer	HMRTC HMRW	Features interchangeable faceplates.	Tri-Color* White	120V, 60Hz	 , RoHS
 Interchangeable Face Cover for Multi-Location Remote Dimmer	HMRKIT HMRKITBK HMRKITDB HMRKITGRY HMRKITI HMRKITLA HMRKITNI HMRKITW	Features interchangeable faceplates.	Brown Black Dark Bronze Gray Ivory Light Almond Nickel White		 , RoHS

## Switches

Modern low-profile paddle switches with no screws in sight.





Note: The single-pole, 3-way and 4-way switch faces are identical.

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPLIANCE
15A Single-Pole Switch 	TM870 TM870BK TM870DBCC10 TM870GCC10 TM870GRY TM870I TM870ISL* TM870LA TM870LASL* TM870NICC10 TM870W TM870WSL*	15A Switch. Part numbers with an asterisk indicate a model with included locator light.	Brown Black Dark Bronze Graphite Gray Ivory Ivory Light Almond Light Almond Nickel White White	15A, 120V	, RoHS
 15A Single-Pole Switch with Microban <sup>®</sup>	TM870WAMCC4	Single-Pole Switch with lasting Microban <sup>®</sup> antimicrobial* protection for a cleaner, more durable device.	White	15A, 120V	, RoHS
15A 3-Way Switch 	TM873 TM873BK TM873DBCC10 TM873GCC10 TM873GRY TM873I TM873ISL* TM873LA TM873LASL* TM873NICC10 TM873W TM873WSL*	15A Switch. Part numbers with an asterisk indicate a model with included locator light.	Brown Black Dark Bronze Graphite Gray Ivory Ivory Light Almond Light Almond Nickel White White	15A, 120V	, RoHS
 15A 3-Way Switch with Microban <sup>®</sup>	TM873WAMCC4	3-Way Switch with lasting Microban <sup>®</sup> antimicrobial* protection for a cleaner, more durable device.	White	15A, 120V	, RoHS
15A 4-Way Switch 	TM874 TM874BK TM874DBCC6 TM874GCC6 TM874I TM874ISL* TM874LA TM874LASL* TM874NICC6 TM874W TM874WSL*	15A Switch. Part numbers with an asterisk indicate a model with included locator light.  4-way switch works with two radiant 3-way switches OR one radiant Dimmer and a radiant 3-way switch.	Brown Black Dark Bronze Graphite Ivory Ivory Light Almond Light Almond Nickel White White	15A, 120V	, RoHS



## Combination Switches

Modern low-profile paddle switches with no screws in sight.

Note: The single-pole and single-pole/3-way combination switch faces are identical.

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPLIANCE
 Two Single-Pole Switches & Single-Pole/3-Way Switch	RCD113 RCD113BK RCD113GRY RCD113I RCD113LA RCD113W	Single-pole/3-way.  Features a locator light.	Brown Black Gray Ivory Light Almond White	15A, 120/125V	, RoHS
 Two Single-Pole Switches	RCD11 RCD11BKCC6 RCD11GRY RCD11I RCD11LA RCD11W	Single-pole/3-way.  Features a locator light.	Brown Black Gray Ivory Light Almond White	15A, 120/125V	, RoHS
 Two Single-Pole/3-Way Switches	RCD33BK RCD33GRY RCD33I RCD33LA RCD33W	Single-pole/3-way.  Features a locator light.	Black Gray Ivory Light Almond White	15A, 120/125V	, RoHS
 Single-Pole/3-Way Switch & Tamper-Resistant Single Outlet	RCD38TRBK RCD38GRY RCD38TRI RCD38TRLA RCD38TRW	Single-pole/3-way.  Features a locator light.	Black Gray Ivory Light Almond White	15A, 120/125V	, RoHS



## Fan Controls

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPLIANCE
Fan Speed Control De-Hummer, Single-Pole/3-Way 	RHDH163PTC RHDH163PBCCCV4  RHDH163PW	Single-pole/3-way.	Tri-Color* Bi-Color*  White	1.6A, 120V	, RoHS
Fan Speed Control De-Hummer, Single-Pole/3-Way 	HDH163PMMW  HDH163PMMTC	Single-pole/3-way. Multilocation fan speed controls.	White  Tri-Color*	1.6A, 120V	, RoHS





Note: Wall plates sold separately.

## Wave<sup>®</sup> Switches





Featuring innovative touchless technology, this switch controls lights with a simple wave. Internal sensor is preset to register motion at approximately 4" from switch, but can be easily adjusted for any distance from 1" to 6."

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPLIANCE
Wave Switch 	RSWV153 RSWV203	Single-pole/3-way.  Features a sleek, full-face sensor in black. Pair with any radiant Wall Plate to fit your taste and décor.	Black	15A, 120/125V, 1/2 Hp 20A, 120/125V, 3/4 Hp	 , RoHS

## Sensors

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPLIANCE
120V Single-Pole/3-Way Occupancy Sensor 	RRW600UW RRW600UBK RRW600UTC RRW600UBCCCV4	Single-pole/3-way.  Features interchangeable faceplates.	White Black Tri-Color* Bi-Color*	120V, 600W, 1/6 HP	 , RoHS
120V Single-Pole Vacancy Sensor 	RRW600VW RRW600VBK RRW600VTC	Features interchangeable faceplates.	White Black Tri-Color*	120V, 600W, 1/6 HP	 , RoHS

## Timers









NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPLIANCE
4-Button Countdown Timer Switch, 60-Min 	RT2BK RT2DBCCV4 RT2I RT2LA RT2NICCV4 RT2W	Preset time delay options include 10, 20, 30 or 60 min. Includes LED indicator light.  Single-pole/3-way.  Must be paired with another Timer Switch in 3-way applications.	Black Dark Bronze Ivory Light Almond Nickel White	120V, 600W, 1/6 HP	 , RoHS
4-Button Countdown Timer Switch, 30 Min 	RT230BK RT230I RT230LA RT230W	Preset time delay options include 5, 10, 20 or 30min. Includes LED indicator light.  Single-pole/3-way.  Must be paired with another Timer Switch in 3-way applications.	Black Ivory Light Almond White	120V, 600W, 1/4 HP	 , RoHS

Note: Wall plates sold separately.
















\*Tri-color includes: White, Light Almond and Ivory.

\*Bi-Color includes: Nickel & Dark Bronze

## Outlets









NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	NEMA CONFIG. NUMBER	COMPLIANCE
Tamper-Resistant Outlet 	885TR 885TRBK 885TRDBCC12 885TRGCC12 885TRGRY 885TRI 885TRLA 885TRNICC12 885TRW	Tamper-resistant outlet featuring patented invis-shutters for discreet protection.	Brown Black Dark Bronze Graphite Gray Ivory Light Almond Nickel White	15A, 120/125V	5-15R	 , RoHS
	TR26352R TR26352RBK TR26352RDBCC6 TR26352RGCC6 TR26352RGRY TR26352RI TR26352RLA TR26352RNICC6 TR26352RW		Brown Black Dark Bronze Graphite Gray Ivory Light Almond Nickel White	20A, 125V	5-20R	 , RoHS
Weather-Resistant Outlet 	885TREWXR 885TREWWRBK 885TREWGRY 885TREWRI 885TREWRLA 885TREWWRW	NEC compliant for both tamper- and weather-resistance.  Accepts #14-#10AWG solid & stranded wires.	Brown Black Gray Ivory Light Almond White	15A, 125V	5-15R	 , RoHS
radiant In-Wall Outlet Relocation Kit 	IWPE-WH IWPEUSBAC-WH	Extends power from any hard-to-reach outlet to a more convenient location. Available versions include a Tamper-Resistant Outlet or a Tamper-Resistant USB Type-A/C Outlet.	White	15A	5-15R	 , RoHS

## GFCI

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	NEMA CONFIG. NUMBER	COMPLIANCE
 <p>Tamper-Resistant Self-Test GFCI Outlet with Night Light</p>	1597NLTTRBKCCD4 1597NLTTRDBCC4 1597NLTTRI 1597NLTTRLA 1597NLTTRNICC4 1597NLTTRW	Provides superior, point-of-use ground-fault protection. Self-tests every three seconds to ensure it is ready to protect. Features built-in night light.	Black Dark Bronze Ivory Light Almond Nickel White	15A, 125V	5-15R	 , RoHS
	2097NLTTRBK 2097NLTTRGRY 2097NLTTRI 2097NLTTRLA 2097NLTTRW		Black Gray Ivory Light Almond White	20A, 125V	5-20R	 , RoHS
 <p>Single-Pole Switch with Tamper-Resistant Self-Test GFCI Outlet</p>	1597SWTTRBKCCD4 1597SWTTRGRY 1597SWTTRICCD4 1597SWTTRLACCD4 1597SWTTRWCCD4	Combination switch and GFCI outlet. Provides superior, point-of-use ground-fault protection. Self-tests every three seconds to ensure it is ready to protect.	Black Gray Ivory Light Almond White	15A, 125V	5-15R	 , RoHS
 <p>Tamper-Resistant Self-Test GFCI Outlet</p>	1597TR 1597TRBK 1597TRDBCC4 1597TRGCC4 1597TRGRY 1597TRI 1597TRLA 1597TRNICC4 1597TRW	Provides superior, point-of-use ground-fault protection. Self-tests every three seconds to ensure it is ready to protect.	Brown Black Dark Bronze Graphite Gray Ivory Light Almond Nickel White	15A, 125V	5-15R	 , RoHS
	2097TR 2097TRBK 2097TRDB 2097TRGCC4 2097TRGRY 2097TRI 2097TRLA 2097TRNI 2097TRW		Brown Black Dark Bronze Graphite Gray Ivory Light Almond Nickel White	20A, 125V	5-20R	 , RoHS
 <p>Tamper-Resistant Self-Test GFCI Outlet with Audible Alarm</p>	1597TRA 1597TRAI 1597TRALA 1597TRAW	Provides superior, point-of-use ground-fault protection. Self-tests every three seconds to ensure it is ready to protect. Features an audible alarm to alert users to trips or failures, perfect for sub-pumps and deep freezers.	Brown Ivory Light Almond White	15A, 125V	5-15R	 , RoHS
 <p>Spec-Grade Weather-Resistant Self-Test GFCI Outlet</p>	1597TRWR 1597TRWRBK 1597TRWRGRY 1597TRWRRI 1597TRWRRLA 1597TRWRW	Provides superior, point-of-use ground-fault protection for outdoor use. NEC compliant for weather-resistance. Self-tests every three seconds to ensure it is ready to protect.	Brown Black Gray Ivory Light Almond White	15A, 125V	5-15R	 , RoHS
 <p>Tamper-Resistant Self-Test Sensitive Appliance GFCI Outlet</p>	1597TRAPLW  2097TRAPLW	For use with large and/or stationary appliances like refrigerators, dishwashers and washing machines, this outlet provides dedicated power and superior ground-fault protection while also limiting the nuisance tripping often caused by variable-speed drives.	White  White	15A, 125V  20A, 125V	5-15R  5-20R	 , RoHS   , RoHS















NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	NEMA CONFIG. NUMBER	COMPLIANCE
 <p>Tamper-Resistant Self-Test Simplex GFCI Outlet</p>	1597TRSGL 1597TRSGLBK 1597TRSGLGRY 1597TRSGLI 1597TRSGLLA 1597TRSGLW	Provides superior, point-of-use ground-fault protection. Self-tests every three seconds to ensure it is ready to protect. Features built-in night light.	Brown Black Gray Ivory Light Almond White	15A, 125V	5-15R	 , RoHS
	2097TRSGL 2097TRSGLBK 2097TRSGLGRY 2097TRSGLI 2097TRSGLLA 2097TRSGLW			Brown Black Gray Ivory Light Almond White	20A, 125V	5-15R

## Dual-Function AFCI/GFCI & AFCI










NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	NEMA CONFIG. NUMBER	COMPLIANCE
 <p>Tamper-Resistant Dual-Function AFCI/GFCI Outlet</p>	AFGF152TR AFGF152TRBK AFGF152TRGRY AFGF152TRI AFGF152TRLA AFGF152TRW	Provides protection against arc- and ground-fault occurrences. Includes individual indicator lights for each fault type.	Brown Black Gray Ivory Light Almond White	15A, 125V	5-15R	 , RoHS
	AFGF202TR AFGF202TRBK AFGF202TRGRY AFGF202TRI AFGF202TRLA AFGF202TRW			Brown Black Gray Ivory Light Almond White	20A, 125V	5-20R
 <p>Tamper-Resistant Branch Circuit AFCI Outlet</p>	AF152TR AF152TRBK AF152TRGRY AF152TRI AF152TRLA AF152TRW	Provides point-of-use arc-fault protection.	Brown Black Gray Ivory Light Almond White	15A, 125V	5-15R	 , RoHS
	AF202TR AF202TRBK AF202TRGRY AF202TRI AF202TRLA AF202TRW			Brown Black Gray Ivory Light Almond White	20A, 125V	5-20R
 <p>Dead Front Dual-Function AFCI/GFCI Outlet</p>	AFGF202DFI AFGF202DFLA AFGF202DFW	Provides protection against arc-fault and ground-fault occurrences.	Ivory Light Almond White	20A, 125V		 , RoHS
 <p>Dead Front Branch Circuit AFCI Outlet</p>	AF202DFI AF202DFLA AF202DFW	Point-of-Use Arc Fault Detection	Ivory Light Almond White	20A, 125V		 , RoHS



## USB Charging Solutions

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	NEMA CONFIG. NUMBER	COMPLIANCE
 <p>65W USB Outlet, Type-C, 15A, Tamper-Resistant</p>	R26USBPD65BK R26USBPD65 R26USBPD65DBCC6 R26USBPD65GCC6 R26USBPD65GRY R26USBPD65I R26USBPD65LA R26USBPD65NICC6 R26USBPD65W	Features industry-leading 65W of power, dual Type-C ports and Power Delivery for optimal charging capacity. Ideal for charging devices such as smartphones, tablets and small laptops.	Black Brown Dark Bronze Graphite Gray Ivory Light Almond Nickel White	5V, 9V, 15V & 20V 15A, 125V 	5-15R	 , RoHS
	TR20USBPD65BK TR20USBPD65 TR20USBPD65DB TR20USBPD65G TR20USBPD65GRY TR20USBPD65I TR20USBPD65LA TR20USBPD65NI TR20USBPD65W TR20USBPD65RED		Black Brown Dark Bronze Graphite Gray Ivory Light Almond Nickel White Red	5V, 9V, 15V & 20V 20A, 125V 	5-20R	
 <p>30W USB Outlet, Type-C, 15A, Tamper-Resistant</p>	R26USBPDBK R26USBPD R26USBPDDBCC6 R26USBPDGCC6 R26USBPDGRY R26USBPDI R26USBPDLA R26USBPDNICC6 R26USBPDW	Charges devices up to 2X faster with advanced Power Delivery* technology. Includes two USB Type-C ports. 30W power negotiation for the optimal charge for devices.	Black Brown Dark Bronze Graphite Gray Ivory Light Almond Nickel White	5V, 9V, & 15V, 15A, 125V, 	5-15R	 , RoHS
	TR20USBPDBK TR20USBPD TR20USBPDDB TR20USBPDG TR20USBPDGRY TR20USBPDI TR20USBPDLA TR20USBPDNI TR20USBPDRED TR20USBPDW		Black Brown Dark Bronze Graphite Gray Ivory Light Almond Nickel Red White	5V, 9V, & 15V, 20A, 125V, 	5-20R	
 <p>15W USB Outlet, Type-C, 15A, Tamper-Resistant</p>	R26USBC6BK R26USBC6DBCCV4 R26USBC6G R26USBC6I R26USBC6LA R26USBC6NICCV4 R26USBC6W	USB Outlet to charge devices up to 40% faster. Features two built-in USB Type-C ports for charging of the smartphones and tablets.	Black Dark Bronze Graphite Ivory Light Almond Nickel White	6A, 5V, 125V 	5-15R	 , RoHS
 <p>15W USB Outlet, Type-A/C, 15A, Tamper-Resistant</p>	R26USBAC6BK R26USBAC6DBCCV4 R26USBAC6G R26USBAC6I R26USBAC6LA R26USBAC6NICCV4 R26USBAC6W	USB Outlet with industry-leading speed to charge devices up to 40% faster. Includes ports for USB Type-A and Type-C to fit any device, no adapter needed.	Black Dark Bronze Graphite Ivory Light Almond Nickel White	6A, 5V, 125V 	5-15R	 , RoHS
















Note: Wall plates sold separately.

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	NEMA CONFIG. NUMBER	COMPLIANCE
 <p>15W Weather-Resistant USB Outlet, Type A/C, 15A, Tamper-Resistant</p>	WRR26USBAC6BK  WRR26USBAC6I  WRR26USBAC6LA WRR26USBAC6W	Bring USB charging outdoors to decks, patios and porches. The outlet is UL listed to UL498 for weather resistance and must be installed in a weatherproof enclosure per NEC requirements.	Black Ivory Light Almond White	6A, 5V, 125V 	5-15R	 , RoHS
	 <p>3.1A USB Outlet, Type-A/C, 15A, Tamper-Resistant</p>		R26USBACBK R26USBACDBCCV4 R26USBACG R26USBACI R26USBACLA R26USBACNICC6 R26USBACW	Outlet features built-in ports for both USB Type-A and USB Type-C to fit any device, no adapter needed. Features discreet tamper-resistance through patented invis-shutters.	Black Dark Bronze Graphite Ivory Light Almond Nickel White	
 <p>3.1A USB Outlet, Type-A/A, 15A, Tamper-Resistant</p>	TM826USBBK TM826USBDBCCV4 TM826USBGCCV4 TM826USBI TM826USBLA TM826USBNICCV4 TM826USBW	Outlet with two built-in USB Type-A ports. Features discreet tamper-resistance through patented invis-shutters.	Black Dark Bronze Graphite Ivory Light Almond Nickel White	3.1A, 15A, 125V 	5-15R	 , RoHS
 <p>Quad USB Charger</p>	TM8USB4BKCC6 TM8USB4ICC6 TM8USB4LACC6 TM8USB4NICC6 TM8USB4WCC6	Charge more devices simultaneously with four USB Type-A ports in a single device. Features 4.2A of total charging capacity.	Black Ivory Light Almond Nickel White	4.2A, 15A, 125V		 , RoHS









Note: Wall plates sold separately.

\*Power Delivery enables connected devices to receive the precise amount of power needed for safely maximized charging speeds.

GFCI USB

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	NEMA CONFIG. NUMBER	COMPLIANCE
 <p>Tamper-Resistant Self-Test GFCI USB Type-A/A Outlet</p>	1597TRUSBAABK 1597TRUSBAADBC4 1597TRUSBAAGC4 1597TRUSBAAGRY 1597TRUSBAAI 1597TRUSBAALA 1597TRUSBAANIC4 1597TRUSBAAW	The first-ever GFCI Outlet with built-in USB charging, offering superior ground-fault protection and modern convenience in a single solution. Includes two USB Type-A ports.	Black Dark Bronze Graphite Gray Ivory Light Almond Nickel White	15A, 125V	5-15R	  
	2097TRUSBAABK 2097TRUSBAA 2097TRUSBAAGRY 2097TRUSBAAI 2097TRUSBAALA 2097TRUSBAAW		Black Brown Gray Ivory Light Almond White	20A, 125V	5-20R	
 <p>Tamper-Resistant Self-Test GFCI USB Type-A/C Outlet</p>	1597TRUSBACBK 1597TRUSBAC 1597TRUSBACDBC4 1597TRUSBACGC4 1597TRUSBACGRY 1597TRUSBACI 1597TRUSBACLA 1597TRUSBACNIC4 1597TRUSBACW	The first-ever GFCI Outlet with built-in USB charging, offering superior ground-fault protection and modern convenience in a single solution. Includes USB Type-A and USB Type-C ports to charge any and all your devices, no adapter necessary.	Black Brown Dark Bronze Graphite Gray Ivory Light Almond Nickel White	15A, 125V	5-15R	  
	2097TRUSBACBK 2097TRUSBAC 2097TRUSBACDBC4 2097TRUSBACGC4 2097TRUSBACGRY 2097TRUSBACI 2097TRUSBACLA 2097TRUSBACNIC4 2097TRUSBACW		Black Brown Dark Bronze Graphite Gray Ivory Light Almond Nickel White	20A, 125V	5-20R	
 <p>Outdoor Self-Test GFCI USB Type-A/C Outlet</p>	1597TRWRUSBACBK 1597TRWRUSBACGRY 1597TRWRUSBACI 1597TRWRUSBACLA 1597TRWRUSBACW	Engineered for outdoor use, this version of our first-of-its-kind GFCI USB Outlet also features weather-resistance to bring superior ground-fault protection and modern convenience to patios, pool areas and more -- all in a single solution. Includes USB Type-A and USB Type-C ports to charge any and all your devices, no adapter necessary.	Black Gray Ivory Light Almond White	15A, 125V	5-15R	  
	2097TRWRUSBACBK 2097TRWRUSBACGRY 2097TRWRUSBACI 2097TRWRUSBACLA 2097TRWRUSBACW		Black Gray Ivory Light Almond White	20A, 125V	5-20R	
 <p>Tamper-Resistant Self-Test GFCI USB Type-C/C Outlet</p>	1597TRUSBCCI 1597TRUSBCCLA 1597TRUSBCCW	The first-ever GFCI Outlet with built-in USB charging, offering superior ground-fault protection and modern convenience in a single solution. Includes two future-proof USB Type-C ports to accommodate the latest and upcoming devices.	Ivory Light Almond White	15A, 125V	5-15R	  
	2097TRUSBCCW		White	20A, 125V	5-20R	
 <p>Outdoor Self-Test GFCI USB Type-C/C Outlet</p>	1597TRWRUSBCCBK 1597TRWRUSBCCW	Engineered for outdoor use, this version of our first-of-its-kind GFCI USB Outlet also features weather-resistance to bring superior ground-fault protection and modern convenience to patios, pool areas and more -- all in a single solution. Includes two future-proof USB Type-C ports to accommodate the latest and upcoming devices.	Black White	15A, 125V	5-15R	  
	2097TRWRUSBCCBK 2097TRWRUSBCCW		Black White	20A, 125V	5-20R	

Night Lights

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	NEMA CONFIG. NUMBER	COMPLIANCE
 <p>Night Light with Two 15A Tamper-Resistant Outlets</p>	NTL885TRBKCC6 NTL885TRICC6 NTL885TRLACC6 NTL885TRNICC6 NTL885TRW	Five Adjustable Light Settings	Black Ivory Light Almond Nickel White	15A, 120/125V	5-15R	  
	NTL873BKCC6 NTL873ICC6 NTL873LACC6 NTL873NICC6 NTL873WCC6		Black Ivory Light Almond Nickel White	15A, 120/125V	5-20R	
 <p>Full Night Light with Adjustable Light Levels</p>	NTLFULLTC NTLFULLW	Five Adjustable Light Settings  An optional louver is included for added light-level control	Tri-Color* White	120/125V		  
	NTLHORZTCCC6 NTLHORZWCC6		Tri-Color* White	120/125V		
 <p>Horizontal Step Light</p>	NTLHORZTCCC6 NTLHORZWCC6	Five Adjustable Light Settings	Tri-Color* White	120/125V		

## radiant with Netatmo

Control lights and power, from anywhere, with the ultra-reliable smart lighting solution optimized for whole-home use. Build a system in three easy steps: 1) select a Gateway; 2) select primary devices; and 3) select add-on devices. Works with Amazon Alexa, Google Home and Apple HomeKit. Compatible with adorne with Netatmo.

### STEP 1: Select a Gateway

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPATIBLE LOADS	COMPLIANCE
Smart Gateway with Netatmo 	WNRH1WH WNRH1LA WNRH1NI	Creates a robust and dedicated network as the foundation of the Netatmo smart lighting solution.	White Light Almond Nickel			 , RoHS
Smart Surface-Mount Gateway with Netatmo 	WNRH2WH WNRH2LA WNRH2NI	Creates a robust and dedicated network as the foundation of the Netatmo smart lighting solution. Installs beside an outlet or switch in a single-gang electrical box.  Ideal for remodels.	White Light Almond Nickel			 , RoHS
Smart Switch with Netatmo 	WNRL10WH WNRL10LA WNRL10NI	Controls lights from anywhere. Gateway required.	White Light Almond Nickel	15A, 120V		 , RoHS
Smart Tru-Universal Dimmer with Netatmo 	WNRL50WH WNRL50LA WNRL50NI	Controls lights from anywhere. Gateway required.  Trim and phase adjustments are made in the Home+Control app. Works with virtually any dimmable bulb or fixture (excludes 0-10V).	White Light Almond Nickel	15A, 120V	Incandescent, Halogen & ELV: 700W, MLV: 500VA, LED/CFL: 450W FWD/250W REV (not compatible with 0-10V LED drivers), EFL: 5.5A	 , RoHS
Smart Outlet with Netatmo 	WNRR15WH WNRR15LA WNRR15NI  WNRR20WH WNRR20LA WNRR20NI	Control power from anywhere. Two methods of install: 1. Wire for one outlet always on, one controlled; 2. Wire for downstream control of all outlets. Pair with a Wireless Smart Switch for on-wall control. Gateway required.	White Light Almond Nickel  White Light Almond Nickel	15A, 125V, TR  20A, 125V, TR	5-15R  5-20R	 , RoHS
Smart Plug-In Switch with Netatmo 	WNP10	Plugs into an existing outlet to provide smart control of lamps or small appliances. Gateway required.	White			 , RoHS
Smart Plug-In Tru-Universal Dimmer with Netatmo 	WNP20	Plugs into an existing outlet to provide smart dimming control. Gateway required.  Trim and phase adjustments are made in the Home+Control app. Works with virtually any dimmable bulb or fixture (excludes 0-10V).	White		Incandescent, Halogen & ELV: 700W, MLV: 500VA, LED/CFL: 450W FWD/250W REV (not compatible with 0-10V LED drivers), EFL: 5.5A	 , RoHS

### STEP 2: Select Primary Devices











### STEP 3: Select Add-on Devices

NAME	PART NUMBER	INSTALLATION	DESCRIPTION	COLOR/FINISH	COMPLIANCE
Remote Smart Switch with Netatmo 	WNRL23WH WNRL23LA WNRL23NI  WNRL24WH	Wireless (Battery-Operated)  Wired	<b>For easy 3-way control.</b> Must be paired with a primary Smart Switch or Outlet with Netatmo. Can also be used as a master switch to control multiple wired Smart Switches with Netatmo.	White Light Almond Nickel  White	 , RoHS
Remote Smart Dimmer with Netatmo 	WNRL63WH WNRL63LA WNRL63NI  WNRL64WH	Wireless (Battery-Operated)  Wired	<b>For easy 3-way control.</b> Must be paired with a primary wired (or plug-in) Smart Tru-Universal Dimmer with Netatmo. Can also be used as a master dimmer to control multiple primary Smart Tru-Universal Dimmers with Netatmo.	White Light Almond Nickel  White	 , RoHS
Smart Scene Controller with Netatmo 	WNRCB40WH WNRCB40LA WNRCB40NI  WNRCB46WH	Wireless (Battery-Operated)  Wired	Controls 4 customizable lighting scenes with a single touch. Gateway required. For use in conjunction with Smart Switches, Dimmers and/or Outlets with Netatmo.  Note: Maximum of 8 scenes per system, including Home/Away and Wake/Sleep.	White Light Almond Nickel  White	 , RoHS
Smart Home/Away Switch with Netatmo 	WNRL33WH WNRL33LA WNRL33NI  WNRL34WH	Wireless (Battery-Operated)  Wired	Controls 2 scenes of multiple lights. Turn the lights on (or off), simultaneously, with just a single tap. Gateway required. For use in conjunction with Smart Switches, Dimmers and/or Outlets with Netatmo.  Note: Maximum of 8 scenes per system, including Home/Away and Wake/Sleep.	White Light Almond Nickel  White	 , RoHS
Smart Wake/Sleep Switch with Netatmo 	WNRL43WH WNRL43LA WNRL43NI  WNRL44WH	Wireless (Battery-Operated)  Wired	Controls 2 scenes of multiple lights. Turn the lights on (or off), simultaneously, with just a single tap. Gateway required. For use in conjunction with Smart Switches, Dimmers and/or Outlets with Netatmo.  Note: Maximum of 8 scenes per system, including Home/Away and Wake/Sleep.	White Light Almond Nickel  White	 , RoHS
4-Scene Pocket Remote Control with Netatmo 	067695	Wireless (Battery-Operated)	Control up to four full lighting scenes with a touch with this portable smart remote and key fob. Gateway required. For use in conjunction with Smart Switches, Dimmers and/or Outlets with Netatmo  Note: Maximum of 8 scenes per system, including Home/Away and Wake/Sleep.	Black	
Wireless Motion Sensor with Netatmo 	064875	Wireless (Battery-Operated)	Automatically turns lights on/off when motion is detected/absent for added safety and efficiency. Battery-operated.  Gateway required. For use in conjunction with Smart Switches, Dimmers and/or Outlets with Netatmo.	White	

Note: Wall plates included with all radiant with Netatmo products.

## radiant with Netatmo – Smart Kits

Control lights and power, from anywhere, with the ultra-reliable smart lighting solution optimized for whole-home use. Get started building a system with one of these ready kits, then select additional select wired, plug-in and/or wireless add-on devices as desired. Works with Amazon Alexa, Google Home and Apple HomeKit. Compatible with adorne with Netatmo.

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPLIANCE
 Smart Switch Starter Kit with Netatmo	WNRH10KITWH WNRH10KITLA WNRH10KITNI	Kit includes (1) Smart Switch with Netatmo, (1) Smart Surface-Mount Gateway with Netatmo, (1) Home/Away Wireless Smart Switch with Netatmo	White Light Almond Nickel	15A, 120V	 , RoHS
 Smart Outlet Starter Kit with Netatmo	WNRH15KITWH WNRH15KITLA WNRH15KITNI	Kit includes (1) Smart 15A Outlet with Netatmo, (1) Smart Surface-Mount Gateway with Netatmo, (1) Home/Away Wireless Smart Switch with Netatmo	White Light Almond Nickel	15A, 120V	 , RoHS
 Smart Switch Gateway Kit with Netatmo	WNRKH10WH	Kit includes (1) Smart Switch with Netatmo and (1) Smart Surface-Mount Gateway with Netatmo	White	15A, 120V	 , RoHS
 Smart 3-Way Dimmer Gateway Kit with Netatmo	WNRKH53WH	Kit includes (1) Smart Tru-Universal Dimmer with Netatmo, (1) Smart Surface-Mount Gateway with Netatmo, (1) Wireless Smart Dimmer with Netatmo	White	15A, 120V	 , RoHS
 Smart 3-Way Dimmer Gateway Kit with Netatmo, 2-Pack	WNRKH532WH	Kit includes (1) Smart Surface-Mount Gateway with Netatmo, (2) Smart Tru-Universal Dimmers with Netatmo, (2) Wireless Smart Dimmers with Netatmo	White	15A, 120V	 , RoHS







## Color Change Kits - radiant

Interchangeable faceplates for us with Smart Lighting with Netatmo devices.

NAME	PART NUMBER	WORKS WITH	COLOR
Smart Switch with Netatmo Color Change Kit	WNRL10CKIT*	WNRL10*	Brown, Black (BK), Dark Bronze (DB), Graphite (G), Gray (GY), Ivory (IV), Light Almond (LA), Nickel (NI), White (WH)
Remote Smart Switch with Netatmo Color Change Kit	WNRL23CKIT*	WNRL23* WNRL24*	Brown, Black (BK), Dark Bronze (DB), Graphite (G), Gray (GY), Ivory (IV), Light Almond (LA), Nickel (NI), White (WH)
Smart Dimmer with Netatmo Color Change Kit	WNRL50CKIT*	WNRL50*	Brown, Black (BK), Dark Bronze (DB), Graphite (G), Gray (GY), Ivory (IV), Light Almond (LA), Nickel (NI), White (WH)
Remote Smart Dimmer with Netatmo Color Change Kit	WNRL63CKIT*	WNRL63* WNRL64*	Brown, Black (BK), Dark Bronze (DB), Graphite (G), Gray (GY), Ivory (IV), Light Almond (LA), Nickel (NI), White (WH)
Smart Home/Away Switch with Netatmo Color Change Kit	WNRL33CKIT*	WNRL33* WNRL34*	Brown, Black (BK), Dark Bronze (DB), Graphite (G), Gray (GY), Ivory (IV), Light Almond (LA), Nickel (NI), White (WH)
Smart Wake/Sleep Switch with Netatmo Color Change Kit	WNRL43CKIT*	WNRL43* WNRL44*	Brown, Black (BK), Dark Bronze (DB), Graphite (G), Gray (GY), Ivory (IV), Light Almond (LA), Nickel (NI), White (WH)
Smart Scene Controller with Netatmo Color Change Kit	WNRCB40CKIT*	WNRCB40* WNRCB46*	Brown, Black (BK), Dark Bronze (DB), Graphite (G), Gray (GY), Ivory (IV), Light Almond (LA), Nickel (NI), White (WH)

## radiant with Netatmo – Easy Kits

Using the Wireless Switch or Dimmer with Netatmo, these kits allow users to easily add control of a light from a second location, or add on-wall control of an outlet, without cutting or wiring. Perfect for rooms or areas not currently wired for 3-way control or in rooms without overhead lighting.

NAME	PART NUMBER	DESCRIPTION	COLOR/FINISH	RATING	COMPATIBLE LOADS / NEMA	COMPLIANCE
 Easy 3-Way Switch Kit	WNREZK10WH	This kit uses a wireless switch to easily add control of a light or fixture from a second location, even in rooms or locations currently without 3-way wiring. Kit includes a Switch (wired) and a battery operated Wireless Switch that mounts with adhesive to any wall or surface (battery and adhesive included).	White	15A, 120V		 , RoHS
 Easy 3-Way Dimmer Kit	WNREZK50WH	This kit uses a wireless dimmer to easily add light level control of a light or fixture from a second location, even in rooms or locations currently without 3-way wiring. Kit includes a Tru-Universal Dimmer (wired) and a battery operated Wireless Dimmer that mounts with adhesive to any wall or surface (battery and adhesive included).	White	120V, 450W LED/CFL; 700W INC/HAL; 500VA MLV; 700W ELV; 5.5A EFL	Incandescent, Halogen & ELV: 700W MLV: 500VA LED/CFL: 450W EFL: 5.5A	 , RoHS
 Easy Switched Outlet Kit	WNREZK15WH	This kit uses a wireless switch to easily add on-wall control of an outlet, then simply flip the switch to control a plugged-in lamp or small appliance. Kit includes a 15A Outlet (wired) and a battery operated Wireless Switch that mounts with adhesive to any wall or surface (battery and adhesive included).	White	15A	5-15R	 , RoHS



### WANT APP CONTROL?

Thanks to the “with Netatmo” platform, these devices are equipped for enhanced functionality.

Simply add a Smart Gateway with Netatmo and use the Legrand Home + Away app to control your lights from anywhere (and much more).


## Screwless Wall Plates

How to build a better wall plate? Try clean lines and a satin finish, all without a screw in sight.

NAME	GANGS	PART NUMBER	NAME	GANGS	PART NUMBER
Black	1-Gang 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	RWP26BK RWP262BK RWP263BK RWP264BK RWP265BK RWP266BK	Ivory	1-Gang 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	RWP26I RWP262I RWP263I RWP264I RWP265I RWP266I
Brown	1-Gang 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	RWP26B RWP262B RWP263B RWP264B RWP265B RWP266B	Light Almond	1-Gang 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	RWP26LA RWP262LA RWP263LA RWP264LA RWP265LA RWP266LA
Gray	1-Gang 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	RWP26GRY RWP262GRY RWP263GRY RWP264GRY RWP265GRY RWP266GRY	White	1-Gang 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	RWP26W RWP262W RWP263W RWP264W RWP265W RWP266W

## Metallic Screwless Wall Plates

NAME	GANGS	PART NUMBER	NAME	GANGS	PART NUMBER
Dark Bronze	1-Gang 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	RWP26DBCC6 RWP262DBCC6 RWP263DBCC6 RWP264DB RWP265DB RWP266DB	Nickel	1-Gang 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	RWP26NICC6 RWP262NICC6 RWP263NICC6 RWP264NI RWP265NI RWP266NI
Graphite	1-Gang 2-Gang 3-Gang 4-Gang 5-Gang 6-Gang	RWP26GCC6 RWP262GCC6 RWP263GCC6 RWP264CC6 RWP265G RWP266G			

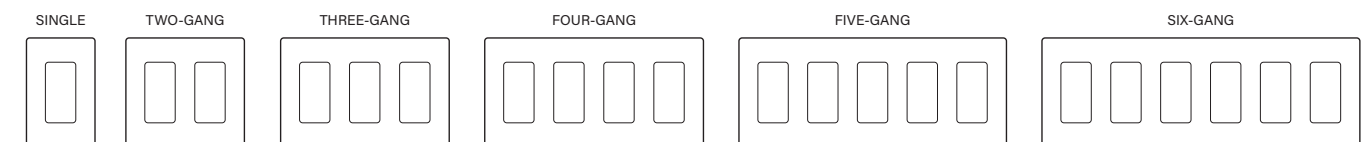

## Screwless Wall Plates with Microban<sup>®</sup>

Classic radiant style made cleaner and more durable through lasting Microban<sup>®</sup> antimicrobial\* protection.

NAME	GANGS	PART NUMBER
White with Microban	1-Gang 2-Gang 3-Gang 4-Gang	RWP26WAMCC6 RWP262WAMCC6 RWP263WAMCC6 RWP264WAMCC6

## adorne Dimensions

NAME	PART NUMBER	DIMENSIONS (H x W x D)	NAME	PART NUMBER	DIMENSIONS (H x W x D)
Paddle Switch	ASPD1531W4	1.77" x 1.77" x 1.5"	SensaSwitch, Auto-ON/ Auto-OFF	ASOS32W4	2.66" x 1.77" x 1.85"
	ASPD1532M4	1.77" x 1.77" x 1.59"		ASOS32M4	
	ASPD1532G4		SensaSwitch, Manu- al-ON/Auto-OFF	ASVS12W4	2.66" x 1.77" x 1.85"
	ASPD2032W4	ASVS12M4			
Paddle Dimmer	ADPD703HW4	4.20" x 1.77" x 1.62"	SensaSwitch, Manu- al-ON/Timed-OFF	ASTM2W2	2.66" x 1.77" x 1.85"
	ADPD703HM4	4.20" x 2.51" x 1.62"		ASTM2M2	
	ADPD703HG4		4.20" x 1.77" x 1.62"	SensaDimmer, Auto-ON/ Auto-OFF	ADSM703HW2
	ADPD1103HW4	ADSM703HM2			
Paddle Switch, Half-Size	ASPD1531W4	1.77" x 0.89" x 1.5"	Wave Switch	ASWV1532W2	2.66" x 1.77" x 1.71"
	ASPD1531M4	1.77" x 0.89" x 1.5"		ASWV1532M2	
	ASPD1531G4		Touch Switch	ASTH1532W2	2.66" x 1.77" x 1.63"
		ASTH1532M2			
Paddle Fan Speed Control	AAFN4S16AW4	2.66" x 1.77" x 1.85"	Touch Wi-Fi Ready Switch	ASTH1532G2	2.66" x 1.77" x 1.63"
	AAFN4S16AM4	1.77" X 1.77" x 1.63"		ASTH155RMW1	
	AAFN4S16AG4			ASTH155RMM1	
Whisper Switch	ASWR1532W4	1.77" X 1.77" x 1.63"	Touch Wi-Fi Ready Dimmer	ASTH155RMG1	2.66" x 1.77" x 1.63"
	ASWR1532M4			ASTHRRW1	
	ASWR1532G4			ASTHRRM1	
Whisper Dimmer	ADWR703HW4	4.20" x 1.77" x 1.77"	Blank, Half-Size	AABK1W4	1.77" X 0.89" x 0.96"
	ADWR703HM4	4.20" x 2.51" x 1.77"		AABK1M4	
	ADWR1103HW4			AABK1G4	
sofTap Switch	ASTP1532W4	2.66" x 1.77" x 1.63"	Tamper-Resistant Outlet	ARTR152W4	2.12" x 1.77" x 1.73"
	ASTP1532M4	4.20" x 1.77" x 1.79"		ARTR152M4	
	ASTP1532G4			ARTR152M4	
sofTap Dimmer	ADTP703HW2	4.20" x 1.77" x 1.79"	Tamper Resistant Outlet, Plus-Size	ARTR202W4	2.12" x 1.77" x 1.73"
	ADTP703HM2	4.20" x 2.51" x 1.79"		ARTR202M4	
	ADTP1103HW4		4.20" x 1.77" x 1.79"	Tamper-Resistant GFCI	AGFTR152W4
	ADTP1103HM4	AGFTR152M4			
sofTap Smart Switch with Netatmo	WNAL10W1	2.66" x 1.77" x 1.63"	Tamper-Resistant GFCI, Plus-Size	AGFTR202W4	3.00" x 1.76" x 1.82"
	WNAL10M1	2.66" x 1.77" x 1.63"		AGFTR153W4	
	WNAL10G1			AGFTR153M4	
sofTap Smart Tru- Universal Dimmer with Netatmo	WNAL50W1	4.20" x 1.77" x 1.79"	Energy-Saving ON/OFF Outlet	AGFTR153G4	2.66" x 1.77" x 1.73"
	WNAL50M1	4.20" x 1.77" x 1.79"		ARPS152W4	
	WNAL50G1			ARPS152M4	
				ARPS152G4	

## NUMERICAL

064875.....	27, 69
067695.....	27, 69
8851 .....	61
885TR .....	61
885TRBK.....	61
885TRDBCC12.....	61
885TRGCC12.....	61
885TRGRY.....	61
885TRI.....	61
885TRLA.....	61
885TRNICC12.....	61
885TRWR.....	48, 61
885TREXRW.....	61
885TREXRWBK.....	61
885TREXRWRGRY.....	61
885TREWRI.....	61
885TREWRLA.....	61
885TREWRLW.....	49, 61
1597NTLTRABCC4.....	62
1597NTLTRBKCCD4.....	62
1597NTLTRDBCC4.....	62
1597NTLTRI.....	62
1597NTLTRICC4.....	62
1597NTLTRLA.....	62
1597NTLTRLACC4.....	62
1597NTLTRNICC4.....	62
1597NTLTRW.....	53, 62
1597NTLTRWCCD4.....	62
1597SWTTRBKCCD4.....	62
1597SWTTRGRY.....	62
1597SWTTRICC4.....	62
1597SWTTRLACC4.....	62
1597SWTTRWCCD4.....	62
1597TR.....	62
1597TRA.....	62
1597TRABK.....	62
1597TRAI.....	62
1597TRALA.....	62
1597TRAPLW.....	62
1597TRAW.....	62
1597TRBK.....	62
1597TRDBCC4.....	62
1597TRGCC4.....	62
1597TRGRY.....	62
1597TRI.....	62
1597TRLA.....	62
1597TRNICC4.....	62
1597TRSGL.....	63
1597TRSGLBK.....	63
1597TRSGLGRY.....	63
1597TRSGLI.....	63
1597TRSGLLA.....	63
1597TRSGLW.....	63
1597TRW.....	48, 62
1597TRWR.....	62
1597TRWRBK.....	62

1597TRWRGRY.....	62
1597TRWRI.....	62
1597TRWRLA.....	62
1597TRWRW.....	62
1597TRUSBAA.....	66
1597TRUSBAABK.....	66
1597TRUSBAADB.....	66
1597TRUSBAAG.....	66
1597TRUSBAAGRY.....	66
1597TRUSBAAI.....	66
1597TRUSBAALA.....	66
1597TRUSBAANI.....	66
1597TRUSBAAW.....	66
1597TRUSBAC.....	66
1597TRUSBACBK.....	66
1597TRUSBACDB.....	66
1597TRUSBACG.....	66
1597TRUSBACG4.....	66
1597TRUSBACGRY.....	66
1597TRUSBACI.....	66
1597TRUSBACLA.....	66
1597TRUSBACNIC4.....	66
1597TRUSBACW.....	66
1597TRWRUSBACBK.....	66
1597TRWRUSBACG4.....	66
1597TRWRUSBACGRY.....	66
1597TRWRUSBACI.....	66
1597TRWRUSBACLA.....	66
1597TRWRUSBACW.....	66
1597TRUSBACI.....	66
1597TRUSBACLA.....	66
1597TRUSBACNI.....	66
1597TRUSBACW.....	48, 66
1597TRUSBCC.....	66
1597TRUSBCCBK.....	66
1597TRUSBCCDB.....	66
1597TRUSBCCG.....	66
1597TRUSBCCGRY.....	66
1597TRUSBCCI.....	66
1597TRUSBCCLA.....	66
1597TRUSBCCNI.....	66
1597TRUSBCCW.....	66
1597TRWRUSBACBK.....	66
1597TRWRUSBACG4.....	66
1597TRWRUSBACGRY.....	66
1597TRWRUSBACI.....	66
1597TRWRUSBACLA.....	66
1597TRWRUSBACW.....	66
1597TRWRUSBACBK.....	66
1597TRWRUSBACG4.....	66
1597TRWRUSBACGRY.....	66
1597TRWRUSBACI.....	66
1597TRWRUSBACLA.....	66
1597TRWRUSBACW.....	66
2097NTLTRBK.....	62
2097NTLTRGRY.....	62
2097NTLTRI.....	62
2097NTLTRLA.....	62
2097NTLTRW.....	62
2097TR.....	62
2097TRAPLW.....	62
2097TRBK.....	62
2097TRDB.....	62
2097TRGCC4.....	62
2097TRGRY.....	62
2097TRI.....	62
2097TRLA.....	62
2097TRNI.....	62
2097TRW.....	62
2097TRWR.....	62
2097TRUSBAABK.....	66
2097TRUSBAA.....	66
2097TRUSBAAGRY.....	66
2097TRUSBAAI.....	66
2097TRUSBAALA.....	66
2097TRUSBAAW.....	66
2097TRUSBACBK.....	66
2097TRUSBAC.....	66
2097TRUSBACDBC4.....	66
2097TRUSBACGC4.....	66
2097TRUSBACGRY.....	66
2097TRUSBACI.....	66
2097TRUSBACLA.....	66
2097TRUSBACNIC4.....	66
2097TRUSBACW.....	66
2097TRWRUSBACBK.....	66
2097TRWRUSBACGRY.....	66
2097TRWRUSBACI.....	66
2097TRWRUSBACLA.....	66
2097TRWRUSBACW.....	66
2097TRUSBCCW.....	66
2097TRWRUSBCCBK.....	66
2097TRWRUSBCCW.....	66

## A

AABK1G4.....	28
AABK1M4.....	28
AABK1W4.....	28
AAFN4S16AG4.....	16
AAFN4S16AM4.....	16
AAFN4S16AW4.....	8, 16
AALSL6.....	25
AALSL277.....	25
AANLM14.....	24
AANLM24.....	11, 24
AARNL2.....	11, 24
AC1PFM1.....	28
AC1PFW1.....	28
AC2PFM1.....	28
AC2PFW1.....	28
AC4PFM1.....	28
AC4PFW1.....	28
AC5ERJ45CM1.....	29
AC5ERJ45CW1.....	29
AC5ERJ45M1.....	29
AC5ERJ45W1.....	29
AC6RJ45M1.....	29
AC6RJ45W1.....	29
ACABPM1.....	29
ACABPW1.....	29
ACBLKM4.....	29
ACBLKW4.....	29
ACBRSTPM1.....	28
ACBRSTPW1.....	28
ACHDMIM1.....	29
ACHDMIW1.....	29
ACNRFCM1.....	29
ACNRFCW1.....	29
ACPRCAF1.....	29
ACPRCAF1.....	29

ACRGRBCAFM1 .....	29	AF152TRI .....	63	ARTR151W10 .....	20	ASPD2042G4 .....	16	AWM1G3BLS4 .....	35	AWM4GMWW4 .....	35
ACRGRBCAFW1 .....	29	AF152TRLA .....	63	ARTR152G4 .....	20	ASPD2042M4 .....	16	AWM1G3CU4 .....	35	AWM4GRG4 .....	35
ACRJ25M1 .....	29	AF152TRW .....	63	ARTR152M4 .....	20	ASPD2042W4 .....	16	AWM1G3HFBR1 .....	37	AWM4GSL4 .....	35
ACRJ25W1 .....	29	AF202DFI .....	63	ARTR152W4 .....	10, 20	ASTH1532G2 .....	18	AWM1G3HFFE1 .....	37	AWM4GSP4 .....	35
ACSSIM1 .....	29	AF202DFLA .....	63	ARTR153G4 .....	20	ASTH1532M2 .....	18	AWM1G3M4 .....	35	AWM4GTL4 .....	35
ACSSIW1 .....	29	AF202DFW .....	63	ARTR153M4 .....	20	ASTH1532W2 .....	9, 18	AWM1G3MA4 .....	35	AWM4GW4 .....	35
ACYRCAFM1 .....	29	AF202TR .....	63	ARTR153W4 .....	20	ASTM2G2 .....	19	AWM1G3MB4 .....	35	AWP1G2BL6 .....	39
ACYRCAFW1 .....	29	AF202TRBK .....	63	ARTR202G4 .....	22	ASTM2M2 .....	19	AWM1G3MR1 .....	35	AWP1G2BN4 .....	39
AD1-RU-M .....	23	AF202TRGRY .....	63	ARTR202M4 .....	20	ASTM2W2 .....	19	AWM1G3MS4 .....	35	AWP1G2BR6 .....	39
AD1-RU-W .....	23	AF202TRI .....	63	ARTR202W4 .....	20	ASTP1532G4 .....	18	AWM1G3MW4 .....	35	AWP1G2CA4 .....	39
AD2-2UR-M .....	23	AF202TRLA .....	63	ARTRUSB156ACM4 .....	21	ASTP1532M4 .....	18	AWM1G3MWW4 .....	35	AWP1G2GG4 .....	39
AD2-2UR-W .....	23	AF202TRW .....	63	ARTRUSB156ACW4 .....	12, 21	ASTP1532W4 .....	18	AWM1G3RG4 .....	35	AWP1G2GR6 .....	39
AD2-Z-M .....	23	AFGF152TR .....	63	ARTRUSB156ACG4 .....	21	ASVS12G4 .....	19	AWM1G3SL4 .....	35	AWP1G2GS4 .....	39
AD2-Z-W .....	23	AFGF152TRBK .....	63	ARTRUSB15PD30G4 .....	21	ASVS12M4 .....	19	AWM1G3SP4 .....	35	AWP1G2HB4 .....	39
AD3-R2UR-M .....	23	AFGF152TRGRY .....	63	ARTRUSB15PD30M4 .....	21	ASVS12W4 .....	19	AWM1G3TL4 .....	35	AWP1G2LA6 .....	39
AD3-R2UR-W .....	23	AFGF152TRI .....	63	ARTRUSB15PD30W4 .....	12, 21	ASWR1532G4 .....	17	AWM1G3W4 .....	35	AWP1G2MG6 .....	39
AD3-ZR-W .....	23	AFGF152TRLA .....	63	ARTRUSB206ACM4 .....	21	ASWR1532M4 .....	17	AWM2GBLS4 .....	35	AWP1G2NK4 .....	39
ADPD153LW2 .....	8, 16, 75	AFGF152TRW .....	63	ARTRUSB206ACW4 .....	21	ASWR1532W4 .....	9, 17	AWM2GCU4 .....	35	AWP1G2PW4 .....	39
ADPD153LM2 .....	16, 75	AFGF202DFI .....	63	ARTRUSB206ACG4 .....	21	ASWV1532G2 .....	17	AWM2GHFBFR1 .....	37	AWP1G2TM6 .....	39
ADPD153LG2 .....	16, 75	AFGF202DFLA .....	63	ARTRUSB20PD30G4 .....	21	ASWV1532M2 .....	17	AWM2GHFFE1 .....	37	AWP1G2WH6 .....	39
ADPD4FBL3P2G4 .....	16	AFGF202DFW .....	63	ARTRUSB20PD30M4 .....	21	ASWV1532W2 .....	9, 17	AWM2GM4 .....	35	AWP1G2WHW10 .....	39
ADPD4FBL3P2G4 (0-10V) .....	16	AFGF202TR .....	63	ARTRUSB20PD30W4 .....	21	AWC1G2BS4 .....	37	AWM2GMA4 .....	35	AWP1G3BL4 .....	39
ADPD4FBL3P2M4 .....	16	AFGF202TRBK .....	63	ARUSB65PDW4 .....	21	AWC1G2BSB4 .....	37	AWM2GMB4 .....	35	AWP1G3BN4 .....	39
ADPD4FBL3P2M4 (0-10V) .....	16	AFGF202TRGRY .....	63	ARUSB65PDM4 .....	21	AWC1G2OB4 .....	37	AWM2GMR1 .....	35	AWP1G3BR4 .....	39
ADPD4FBL3P2W4 .....	16	AFGF202TRI .....	63	ARUSB65PDG4 .....	21	AWC1G2SN4 .....	37	AWM2GMS4 .....	35	AWP1G3CA4 .....	39
ADPD4FBL3P2W4 (0-10V) .....	16	AFGF202TRLA .....	63	ARTRUSB20PD65W4 .....	21	AWC1G3BS4 .....	37	AWM2GMW4 .....	35	AWP1G3GG4 .....	39
ADSM703HG2 .....	19	AFGF202TRW .....	63	ARTRUSB20PD65M4 .....	21	AWC1G3BSB4 .....	37	AWM2GMWW4 .....	35	AWP1G3GR4 .....	39
ADSM703HM2 .....	19	AGFTR2152G4 .....	20	ARTRUSB20PD65G4 .....	21	AWC1G3OB4 .....	37	AWM2GRG4 .....	35	AWP1G3GS4 .....	39
ADSM703HW2 .....	19	AGFTR2152M4 .....	10, 20	ARTRUSB15PD65W4 .....	21	AWC1G3SN4 .....	37	AWM2GSL4 .....	35	AWP1G3HB4 .....	39
ADTH4FBL3PG4 .....	18	AGFTR2153G4 .....	20	ARTRUSB15PD65M4 .....	21	AWC2GBS4 .....	37	AWM2GSP4 .....	35	AWP1G3LA4 .....	39
ADTH4FBL3PG4 (0-10V) .....	18	AGFTR2153M4 .....	20	ARTRUSB15PD65G4 .....	21	AWC2GBSB4 .....	37	AWM2GTL4 .....	35	AWP1G3MG4 .....	39
ADTH4FBL3PM4 .....	18	AGFTR2153W4 .....	20	ARUSB2AC6M4 .....	21	AWC2GOB4 .....	37	AWM2GW4 .....	35	AWP1G3NK4 .....	39
ADTH4FBL3PW4 .....	18	AGFTR2202G4 .....	20	ARUSB2AC6W4 .....	12, 21	AWC2GSN4 .....	37	AWM3GBLS4 .....	35	AWP1G3PW4 .....	39
ADTH703TUG4 .....	18	AGFTR2202M4 .....	20	ARUSB2AC6G4 .....	21	AWC3GBS4 .....	37	AWM3GCU4 .....	35	AWP1G3TM4 .....	39
ADTH703TUM4 .....	18	AGFTR2202M4 .....	20	ARUSB30PDG4 .....	21	AWC3GBSB4 .....	37	AWM3GHFBFR1 .....	37	AWP1G3WH4 .....	39
ADTH703TUW4 .....	18	AGFTR2202W4 .....	20	ARUSB30PDM4 .....	21	AWC3GOB4 .....	37	AWM3GHFFE1 .....	37	AWP1G3WHW4 .....	39
ADTP4FBL3PG4 .....	18	ARCD152G4 .....	20	ARUSB30PDW4 .....	13, 21	AWC3GSN4 .....	37	AWM3GM4 .....	35	AWP2GBL4 .....	39
ADTP4FBL3PM4 .....	18	ARCD152M10 .....	20	ASOS32G4 .....	19	AWC4GBS4 .....	37	AWM3GMA4 .....	35	AWP2GBN4 .....	39
ADTP4FBL3PW4 .....	18	ARCD152W10 .....	20	ASOS32M4 .....	19	AWC4GBSB4 .....	37	AWM3GMB4 .....	35	AWP2GBR4 .....	39
ADTP703HM2 .....	18	ARCD202M10 .....	20	ASOS32W4 .....	19	AWC4GOB4 .....	37	AWM3GMR1 .....	37	AWP2GCA4 .....	39
ADTP703HW2 .....	18	ARCD202W10 .....	20	ASPD1531G4 .....	16	AWC4GSN4 .....	37	AWM3GMS4 .....	35	AWP2GGG4 .....	39
ADTP703TUG4 .....	18	ARCH152G10 .....	20	ASPD1531G277 .....	16	AWM1G2BLS4 .....	35	AWM3GMW4 .....	35	AWP2GGR4 .....	39
ADTP703TUM4 .....	18	ARCH152M10 .....	20	ASPD1531M4 .....	16	AWM1G2CU4 .....	35	AWM3GMWW4 .....	35	AWP2GGS4 .....	39
ADTP703TUW4 .....	8, 18	ARCH152W10 .....	20	ASPD1531M277 .....	16	AWM1G2HFBR4 .....	37	AWM3GGR4 .....	35	AWP2GHB4 .....	39
ADTP103HM4 .....	18	ARPS152G4 .....	20	ASPD1531W4 .....	16	AWM1G2HFBS4 .....	37	AWM3GSL4 .....	35	AWP2GLA4 .....	39
ADTP1103HW4 .....	18	ARPS152M4 .....	10, 20	ASPD1531W277 .....	16	AWM1G2HFFE4 .....	37	AWM3GSP4 .....	35	AWP2GMG4 .....	39
ADWR703TUW4 .....	17	ARPS152W4 .....	22	ASPD1532G4 .....	16	AWM1G2M4 .....	35	AWM3GTL4 .....	35	AWP2GNK4 .....	39
ADWR703TUM4 .....	17	ARPTR151GG2 .....	22	ASPD1532G277 .....	16	AWM1G2MA4 .....	35	AWM3GW4 .....	35	AWP2GPW4 .....	39
ADWR703TUG4 .....	17	ARPTR151GM2 .....	22	ASPD1532M4 .....	16	AWM1G2MB4 .....	35	AWM4GBLS4 .....	35	AWP2GTM4 .....	39
AF1G .....	41	ARPTR151GW2 .....	11, 22	ASPD1532M277 .....	16	AWM1G2MR1 .....	35	AWM4GCU4 .....	35	AWP2GWH4 .....	39
AF2G .....	41	ARPTR152GG2 .....	22	ASPD1532W4 .....	8, 16	AWM1G2MS4 .....	35	AWM4GHFBFR1 .....	37	AWP2GWHW10 .....	39
AF3G .....	41	ARPTR152GM2 .....	22	ASPD1532M277 .....	16	AWM1G2MW4 .....	35	AWM4GHFFE1 .....	37	AWP3GBL4 .....	39
AF4G .....	41	ARPTR152GW2 .....	22	ASPD1542G277 .....	16	AWM1G2MWW4 .....	35	AWM4GM4 .....	35	AWP3GBN4 .....	39
AF5G .....	41	ARPTR201GG2 .....	22	ASPD1542M277 .....	16	AWM1G2RG4 .....	35	AWM4GMA4 .....	35	AWP3GBR4 .....	39
AF6G .....	41	ARPTR201GM2 .....	22	ASPD1542W277 .....	16	AWM1G2SL4 .....	35	AWM4GMB4 .....	35	AWP3GCA4 .....	39
AF152TR .....	63	ARPTR201GW2 .....	22	ASPD2032G4 .....	16	AWM1G2SP4 .....	35	AWM4GMR1 .....	35	AWP3GGG4 .....	39
AF152TRBK .....	63	ARTR151G10 .....	20	ASPD2032M4 .....	16	AWM1G2TL4 .....	35	AWM4GMS4 .....	35	AWP3GGR4 .....	39
AF152TRGRY .....	63	ARTR151M10 .....	20	ASPD2032W4 .....	16	AWM1G2W4 .....	35	AWM4GMW4 .....	35	AWP3GGS4 .....	39

AWP3GHB4.....	39
AWP3GLA4.....	39
AWP3GMG4.....	39
AWP3GNK4.....	39
AWP3GPW4.....	39
AWP3GTM4.....	39
AWP3GWH4.....	39
AWP3GWHW4.....	39
AWP4GBL4.....	39
AWP4GBN4.....	39
AWP4GBR4.....	39
AWP4GCA4.....	39
AWP4GGG4.....	39
AWP4GGR4.....	39
AWP4GGS4.....	39
AWP4GHB4.....	39
AWP4GLA4.....	39
AWP4GMG4.....	39
AWP4GNK4.....	39
AWP4GPW4.....	39
AWP4GTM4.....	39
AWP4GWH4.....	39
AWP4GWHW4.....	39
AWP5GBL1.....	39
AWP5GBN1.....	39
AWP5GBR1.....	39
AWP5GCA1.....	39
AWP5GGG1.....	39
AWP5GGR1.....	39
AWP5GGS1.....	39
AWP5GHB1.....	39
AWP5GMG1.....	39
AWP5GNK1.....	39
AWP5GPW1.....	39
AWP5GTM1.....	39
AWP5GWH1.....	39
AWP5GWHW1.....	39
AWP6GBL1.....	39
AWP6GBN1.....	39
AWP6GBR1.....	39
AWP6GCA1.....	39
AWP6GGG1.....	39
AWP6GGR1.....	39
AWP6GGS1.....	39
AWP6GHB1.....	39
AWP6GMG1.....	39
AWP6GNK1.....	39
AWP6GPW1.....	39
AWP6GTM1.....	39
AWP6GWH1.....	39
AWP6GWHW1.....	39
<b>D</b>	
DIMBPASS.....	57
DQFF15UBK.....	22
DQFF15UST.....	22
DQFP15BK.....	22

DQFP15ST.....	22
DQFF15UBK.....	22
DQFP15UST.....	22
<b>H</b>	
HCL453PMMTC.....	57
HCL453PMMW.....	57
HDH163PMMTC.....	59
HMKIT.....	57
HMKITBK.....	57
HMKITDB.....	57
HMKITGRY.....	57
HMKITI.....	57
HMKITLA.....	57
HMKITNI.....	57
HMKITW.....	57
HMRKIT.....	57
HMRKITBK.....	57
HMRKITDB.....	57
HMRKITGRY.....	57
HMRKITI.....	57
HMRKITLA.....	57
HMRKITNI.....	57
HMRKITW.....	57
HMRTC.....	57
HMRW.....	57
<b>I</b>	
IWPE-WH.....	61
IWPEUSBAC-WH.....	61
<b>N</b>	
NTL873BKCC6.....	67
NTL873ICC6.....	67
NTL873LACC6.....	67
NTL873NICC6.....	67
NTL873WCC6.....	67
NTL885TRBKCC6.....	67
NTL885TRICC6.....	67
NTL885TRLACC6.....	67
NTL885TRNICC6.....	67
NTL885TRW.....	53, 67
NTL885TRWCC6.....	67
NTLFULLTC.....	67
NTLFULLTCCC6.....	67
NTLFULLW.....	52, 67
NTLFULLWCC6.....	67
NTLHORZTCCC6.....	67
NTLHORZWCC6.....	67
<b>R</b>	
R26USBAC6BK.....	65
R26USBAC6DBCCV4.....	65
R26USBAC6G.....	65
R26USBAC6I.....	65
R26USBAC6LA.....	65

R26USBAC6NICCV4.....	65
R26USBAC6W.....	51, 65
R26USBACBK.....	64
R26USBACDBCCV4.....	64
R26USBACG.....	64
R26USBACI.....	64
R26USBACLA.....	64
R26USBACNICC6.....	64
R26USBACW.....	64
R26USBACC6DBCCV4.....	65
R26USBACC6BK.....	65
R26USBACC6G.....	65
R26USBACC6I.....	65
R26USBACC6LA.....	65
R26USBACC6NICCV4.....	65
R26USBACC6W.....	65
R26USBPD65BK.....	64
R26USBPD65.....	64
R26USBPD65W.....	51, 64
R26USBPD65I.....	64
R26USBPD65LA.....	64
R26USBPD65GRY.....	64
R26USBPD65NICC6.....	64
R26USBPD65GCC6.....	64
R26USBPD65DBCC6.....	64
R26USBPD65CC6.....	64
R26USBPDRED.....	64
R26USBPD65WCC6.....	64
R26USBPD.....	65
R26USBPDBK.....	65
R26USBPDDBCC6.....	65
R26USBPDGCC6.....	65
R26USBPDGRY.....	65
R26USBPDI.....	65
R26USBPDLA.....	65
R26USBPDNICC6.....	65
R26USBPDW.....	50, 65
RCD11.....	59
RCD11BKCC6.....	59
RCD11GRY.....	59
RCD11I.....	59
RCD11LA.....	59
RCD11W.....	59
RCD33BK.....	59
RCD33GRY.....	59
RCD33I.....	59
RCD33LA.....	59
RCD33W.....	59
RCD38GRY.....	59
RCD38TRBK.....	59
RCD38TRI.....	59
RCD38TRLA.....	59
RCD38TRW.....	49, 59
RCD113.....	59
RCD113BK.....	59
RCD113GRY.....	59
RCD113I.....	59

RCD113LA.....	59
RCD113W.....	59
RCDLM.....	59
HDH163PMMW.....	59
RH4FBL3PTC.....	56
RH4FBL3PW.....	56
RH703PTUTC.....	56
RH703PTUW.....	54, 56
RH703PTUWAMCC4.....	56
RHCL453PDBCCV4.....	56
RHCL453PGCCV4.....	56
RHCL453PNICCV4.....	56
RHCL453PTC.....	56
RHCL453PW.....	56
RHCL453PWAMCC4.....	56
RHDH163PBCCCV4.....	59
RHDH163PTC.....	59
RHDH163PW.....	59
RHKIT.....	65
RHKITBK.....	57
RHKITDB.....	57
RHKITGRY.....	57
RHKITI.....	57
RHKITLA.....	57
RHKITNI.....	57
RHKITW.....	57
RHL153.....	56
RHL153P.....	56
RHL153PBK.....	56
RHL153PDB.....	56
RHL153PG.....	56
RHL153PGRY.....	56
RHL153PI.....	56
RHL153PLA.....	56
RHL153PNI.....	56
RHL153PRED.....	56
RHL153PW.....	56
RHL153PW10PK.....	56
RHL743PTC.....	56
RHL743PW.....	56
RHL373PTC.....	56
RHL373PW.....	56
RHLV703PTC.....	56
RHLV703PW.....	56
RRW600UBCCCV4.....	60
RRW600UBK.....	60
RRW600UTC.....	60
RRW600UW.....	60
RRW600VBK.....	60
RRW600VTC.....	60
RRW600VW.....	60
RSWV153.....	60
RSWV203.....	47, 60
RT2BK.....	60
RT2DBCCV4.....	60
RT2GCCV4.....	60
RT2I.....	60
RT2LA.....	60

RT2NICCV4.....	60
RT2W.....	60
RT230BK.....	60
RT230I.....	60
RT230LA.....	60
RT230W.....	60
RWP26.....	72
RWP26BK.....	72
RWP26DBCC6.....	72
RWP26GRY.....	72
RWP26I.....	72
RWP26LA.....	72
RWP26NICC6.....	72
RWP26PW.....	72
RWP26WAMCC6.....	73
RWP262.....	72
RWP262BK.....	72
RWP262DBCC6.....	72
RWP262GRY.....	72
RWP262I.....	72
RWP262LA.....	72
RWP262NICC6.....	72
RWP262W.....	72
RWP262WAMCC6.....	73
RWP263.....	72
RWP263BK.....	72
RWP263DBCC6.....	72
RWP263GRY.....	72
RWP263I.....	72
RWP263LA.....	72
RWP263NICC6.....	72
RWP263W.....	72
RWP263WAMCC6.....	73
RWP264.....	72
RWP264BK.....	72
RWP264DB.....	72
RWP264GRY.....	72
RWP264I.....	72
RWP264LA.....	72
RWP264NI.....	72
RWP264W.....	72
RWP264WAMCC6.....	73
RWP265.....	72
RWP265BK.....	72
RWP265DB.....	72
RWP265GRY.....	72
RWP265I.....	72
RWP265LA.....	72
RWP265NI.....	72
RWP265W.....	72
RWP266.....	72
RWP266BK.....	72
RWP266DB.....	72
RWP266GRY.....	72
RWP266I.....	72
RWP266LA.....	72
RWP266NI.....	72
RWP266W.....	72

**T**

TM8USB4BKCC6.....	64
TM8USB4ICC6.....	64
TM8USB4LACC6.....	64
TM8USB4NICC6.....	64
TM8USB4WCC6.....	51, 64
TM870.....	58
TM870BK.....	58
TM870DBCC10.....	58
TM870GCC10.....	58
TM870GRY.....	58
TM870I.....	58
TM870ISL.....	58
TM870ISL (lighted).....	58
TM870LA.....	58
TM870LASL.....	58
TM870LASL (lighted).....	58
TM870NICC10.....	58
TM870W.....	58
TM870WAMCC4.....	58
TM870WSL.....	47, 58
TM870WSL (lighted).....	58
TM873.....	58
TM873BK.....	58
TM873DBCC10.....	58
TM873GCC10.....	58
TM873GRY.....	58
TM873I.....	58
TM873ISL.....	58
TM873ISL (lighted).....	58
TM873LA.....	58
TM873LASL.....	58
TM873LASL (lighted).....	58
TM873NICC10.....	58
TM873W.....	58
TM873WAMCC4.....	58
TM873WSL.....	58
TM873WSL (lighted).....	58
TM874.....	58
TM874BK.....	58
TM874DBCC6.....	58
TM874GCC6.....	58
TM874I.....	58
TM874ISL.....	58
TM874ISL (lighted).....	58
TM874LA.....	58
TM874LASL.....	58
TM874LASL (lighted).....	58
TM874NICC6.....	58
TM874W.....	58
TM874WSL.....	58
TM874WSL (lighted).....	58
TR20USBPD.....	65
TR20USBPDBK.....	65
TR20USBPDDBCC6.....	65
TR20USBPDGCC6.....	65





TR20USBPDGRY ..... 65  
 TR20USBPDI..... 65  
 TR20USBPDLA..... 65  
 TR20USBPDNICC6..... 65  
 TR20USBPDW ..... 65  
 TR26352R ..... 61  
 TR26352RBK..... 61  
 TR26352RDBCC6 ..... 61  
 TR26352RGCC6 ..... 61  
 TR26352RGRY..... 61  
 TR26352RI..... 61  
 TR26352RLA ..... 61  
 TR26352RNICC6..... 61  
 TR26352RW..... 61

**W**

WNACB40G1..... 27  
 WNACB40M1.....27  
 WNACB40W1..... 15, 27  
 WNAH1G1 ..... 26  
 WNAH1M1..... 26  
 WNAH1W1 ..... 14, 26  
 WNAH2G1 ..... 26  
 WNAH2M1..... 26  
 WNAH2W1 ..... 26  
 WNAH10KITG1 ..... 27  
 WNAH10KITM1 ..... 27  
 WNAH10KITW1..... 27  
 WNAL10G1 ..... 26  
 WNAL10M1..... 26  
 WNAL10W1 ..... 14, 26  
 WNAL23G1..... 27  
 WNAL23M1..... 27  
 WNAL23W1..... 27  
 WNAL33G1..... 25  
 WNAL33M1..... 25  
 WNAL33W1..... 25  
 WNAL43G1 ..... 27  
 WNAL43M1..... 27  
 WNAL43W1 ..... 27  
 WNAL50G1 ..... 26  
 WNAL50M1..... 26  
 WNAL50W1 ..... 14, 26  
 WNAL63G1 ..... 27  
 WNAL63M1..... 27  
 WNAL63W1 ..... 15, 27  
 WNAR153G1 ..... 26  
 WNAR153M1..... 26  
 WNAR153W1 ..... 15, 26  
 WNAR203G1 ..... 26  
 WNAR203M1..... 26  
 WNAR203W1 ..... 26  
 WNP10..... 26, 68  
 WNP20..... 26, 68  
 WNRCB40LA..... 69  
 WNRCB40NI ..... 69  
 WNRCB40WH.....55, 69  
 WNREZK15WH..... 71

WNREZK10WH ..... 71  
 WNREZK50WH ..... 71  
 WNRH1LA ..... 68  
 WNRH1NI..... 68  
 WNRH1WH ..... 54, 68  
 WNRH2LA..... 68  
 WNRH2NI..... 68  
 WNRH2WH..... 68  
 WNRH10KITLA ..... 70  
 WNRH10KITNI..... 70  
 WNRH10KITWH..... 70  
 WNRH15KITWH ..... 70  
 WNRH15KITLA ..... 70  
 WNRH15KITNI..... 70  
 WNRKH10WH..... 70  
 WNRKH53WH..... 70  
 WNRKH532WH ..... 70  
 WNRL10LA..... 68  
 WNRL10NI..... 68  
 WNRL10WH..... 54, 68  
 WNRL23LA..... 69  
 WNRL23NI..... 69  
 WNRL23WH..... 69  
 WNRL33LA..... 69  
 WNRL33NI..... 69  
 WNRL33WH..... 69  
 WNRL43LA..... 69  
 WNRL43NI..... 69  
 WNRL43WH..... 69  
 WNRL50LA..... 68  
 WNRL50NI..... 68  
 WNRL50WH..... 54, 68  
 WNRL63LA..... 69  
 WNRL63NI..... 69  
 WNRL63WH..... 55, 69  
 WNR15LA ..... 68  
 WNR15NI ..... 68  
 WNR15WH ..... 55, 68  
 WNR20LA ..... 68  
 WNR20NI ..... 68  
 WNR20WH ..... 68  
 WRR26USBAC6BK ..... 65  
 WRR26USBAC6I ..... 65  
 WRR26USBAC6LA ..... 65  
 WRR26USBAC6W..... 65

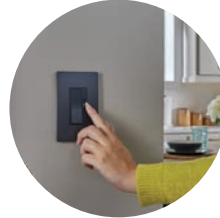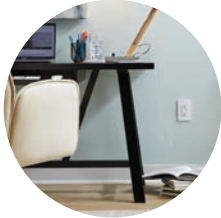

[legrand.us/lightingcontrols](https://legrand.us/lightingcontrols)



[youtube.com/legrand](https://youtube.com/legrand)



[facebook.com/LegrandNA](https://facebook.com/LegrandNA)



[instagram.com/legrandna](https://instagram.com/legrandna)



**Electrical Wiring Systems**

60 Woodlawn Street  
West Hartford, CT  
061101.877.BY.LEGRAND (295.3472)  
[www.legrand.us](http://www.legrand.us)