



PUSH IN CONDUIT TO CONDUIT CLAMP, 1/2" EMT1, 1/2" EMT2, 0.709"–0.866"
OD1, 0.709"–0.866" OD2

CATALOG NUMBER

8P8P



FEATURES

Ideal as spacer between same or different size conduit

No tools required for installation

Top conduit to be used for support only, not a raceway

PRODUCT ATTRIBUTES

Material: Spring Steel

Finish: nVent CADDY Armour

EMT Conduit Size 1: 1/2


EMT Conduit Size 2: 1/2

Outer Diameter 1 (OD1): 0.71" - 0.87"

Outer Diameter 2 (OD2): 0.71" - 0.87"

Ultimate Static Load (F): 25 lb

DIAGRAMS

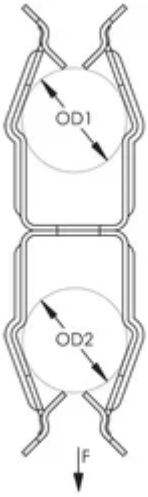

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER



PUSH IN CONDUIT TO CONDUIT CLAMP, 1/2" EMT1, 1/2" EMT2, 0.709"–0.866" OD1, 0.709"–0.866" OD2

CATALOG NUMBER

8P8P



FEATURES

Ideal as spacer between same or different size conduit

No tools required for installation

Top conduit to be used for support only, not a raceway

PRODUCT ATTRIBUTES

Material: Spring Steel

Finish: nVent CADDY Armour

EMT Conduit Size 1: 1/2


EMT Conduit Size 2: 1/2

Outer Diameter 1 (OD1): 0.71" - 0.87"

Outer Diameter 2 (OD2): 0.71" - 0.87"

Ultimate Static Load (F): 25 lb

DIAGRAMS

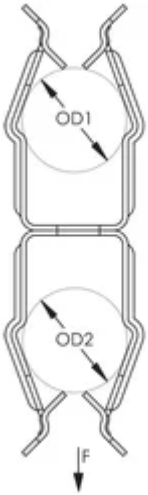

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER