


## Bulk Wire – Multi Conductor Lamp & Lighting Wire Spools

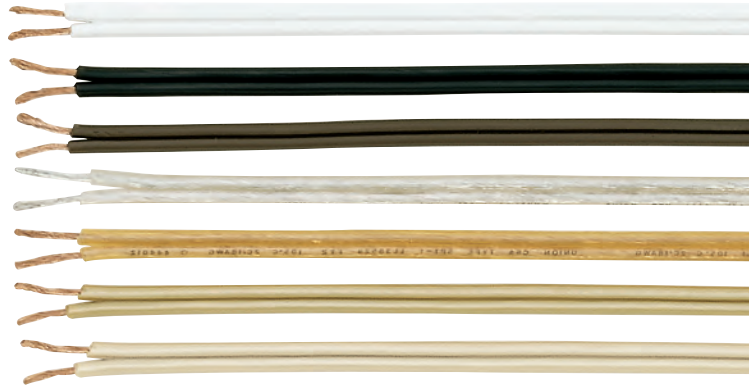

### 18/2 SPT-1 105°C, 250 Ft./Spool

- 93-130 White
- 93-132 Black
- 93-131 Brown
- 93-138 Clear Silver
- 93-139 Clear Gold
- 93-140 Metallic Gold
- 93-241 Ivory



10A-300V-1250W MAX  
Packing: 8 Spools/Master



### 18/2 SPT-1.5 105°C, 250 Ft./Spool

- 93-336 Clear Gold
- 93-337 Clear Silver
- 93-338 Black
- 93-343 Brown



10A-300V-1250W MAX  
Packing: 4 Spools/Master



### 18/2 SPT-2 105°C, 250 Ft./Spool

- 93-127 Black
- 93-168 Clear Silver
- 93-129 Clear Gold
- 93-126 White
- 93-128 Brown
- 93-242 Ivory



10A-300V-1250W MAX  
Packing: 4 Spools/Master




### 16/2 SPT-2 105°C, 250 Ft./Spool

- 93-141 White
- 93-142 Brown
- 93-165 Clear Gold
- 93-166 Black
- 93-167 Clear Silver



13A-300V-1625W MAX  
Packing: 4 Spools/Master

## Bulk Wire – Multi Conductor Lamp & Lighting Wire Spools

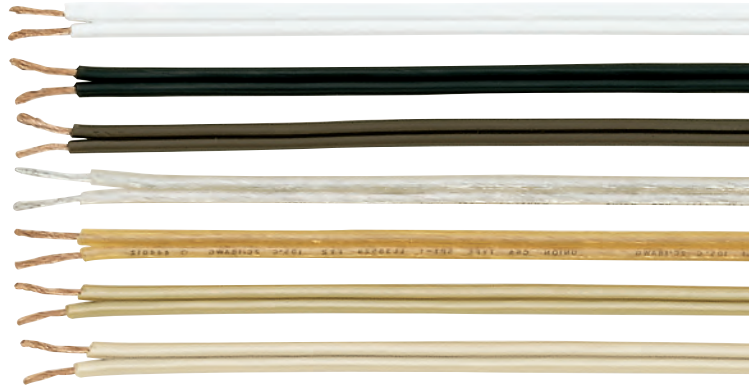

### 18/2 SPT-1 105°C, 250 Ft./Spool

- 93-130 White
- 93-132 Black
- 93-131 Brown
- 93-138 Clear Silver
- 93-139 Clear Gold
- 93-140 Metallic Gold
- 93-241 Ivory



10A-300V-1250W MAX  
Packing: 8 Spools/Master



### 18/2 SPT-1.5 105°C, 250 Ft./Spool

- 93-336 Clear Gold
- 93-337 Clear Silver
- 93-338 Black
- 93-343 Brown



10A-300V-1250W MAX  
Packing: 4 Spools/Master



### 18/2 SPT-2 105°C, 250 Ft./Spool

- 93-127 Black
- 93-168 Clear Silver
- 93-129 Clear Gold
- 93-126 White
- 93-128 Brown
- 93-242 Ivory



10A-300V-1250W MAX  
Packing: 4 Spools/Master



### 16/2 SPT-2 105°C, 250 Ft./Spool

- 93-141 White
- 93-142 Brown
- 93-165 Clear Gold
- 93-166 Black
- 93-167 Clear Silver



13A-300V-1625W MAX  
Packing: 4 Spools/Master