


Right Angle Type

Images

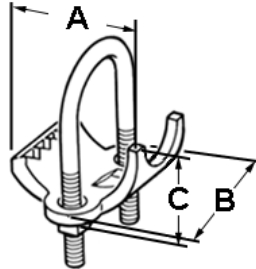

Application

Used to secure Rigid/IMC or EMT conduit perpendicular to beam, channel and angle supports.

Product Information

Material: Malleable Iron Clamp, Steel U-Bolt and Nuts
Finish: Hot Dip Galvanized

Certifications & Codes:

UL File Number: c(UL)us: E161206
UL Standard: 2239
UNSPSC: 31162906

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 3-5/8
Dimension B in Inches: 3-7/8

Catalog ID: 968

UPC Number: 78174700968

Description: 3" Right Angle type conduit clamp for Rigid, IMC and EMT conduit.

Application: Used to secure Rigid/IMC or EMT conduit perpendicular to beam, channel and angle supports.

Trade Size: 3"

Std Pkg Qty: 25

Unit Qty: 5