


## Right Angle Type

### Images

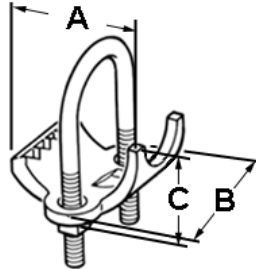

### Application

Used to secure Rigid/IMC or EMT conduit perpendicular to beam, channel and angle supports.

### Product Information

Material: Malleable Iron Clamp, Steel U-Bolt and Nuts  
Finish: Hot Dip Galvanized

### Certifications & Codes:

UL File Number: c(UL)us: E161206  
UL Standard: 2239  
UNSPSC: 31162906

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 4-1/16  
Dimension B in Inches: 4-9/16

**Catalog ID:** 969

**UPC Number:** 78174700969

**Description:** 3-1/2" Right Angle type conduit clamp for Rigid, IMC and EMT conduit.

**Application:** Used to secure Rigid/IMC or EMT conduit perpendicular to beam, channel and angle supports.

**Trade Size:** 3-1/2"

**Std Pkg Qty:** 25

**Unit Qty:** 5