


## Insulating Bushings - Knockout

### Images

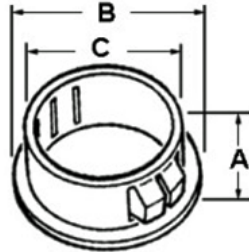

### Application

Converts metallic box rough edged knockout holes to smooth insulated holes for protection of electrical and telecommunications cable. Rated 105 Degrees C.

### Product Information

Material: Plastic  
Finish: Natural

### Certifications & Codes:

CSA File Number: LR24719  
NEMA Standard: FB-1  
UL Standard: UL-514B  
UNSPSC: 39121312

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1

Dimension B in Inches: 1-1/2

Dimension C in Inches: 1-3/8

**Catalog ID:** 9793

**UPC Number:** 781747007933

**Description:** Bushing, Insulating, Plastic Rated 105 Degrees C, 1.375 Inch Hole Dia.

**Application:** Converts metallic box rough edged knockout holes to smooth insulated holes for protection of electrical and telecommunications cable. Rated 105 Degrees C.

**Trade Size:** 1"

**Country of Manufacture:** USA

**Std Pkg Qty:** 500

**Unit Qty:** 50