


Eaton A201103-3

Catalog Number: A201103-3

Eaton Crouse-Hinds series Roughneck E1049 plug contact, Up to 1135A continuous, 777 kcmil, Hexagon crimp or solder, Copper, Female, 1000 Vac/dc

General specifications

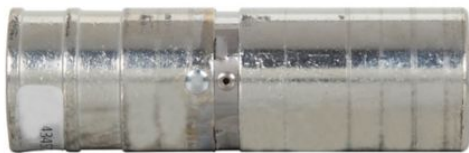

Product Name	Catalog Number
Eaton Crouse-Hinds series Roughneck E1049 plug contact	A201103-3
	UPC
	662275107251
Product Length/Depth	Product Height
6.5 in	22.32 in
Product Width	Product Weight
2.32 in	1.52 lb

Certifications and compliances

Area classification

Ordinary/Non-Hazardous Locations

Standards type

NEC/CEC

NEMA Rating

3

Product specifications

Cable size

777 kcmil

Amperage Rating

Up to 1135A Continuous

Voltage rating

1000 Vac/dc

Gender

Female

Connection type

Hexagon crimp or solder

Contact material

Copper

Resources

Brochures

[Roughneck Single Pole High-amperage Plugs and Connectors brochure](#)

Catalogs

[Roughneck Single Pole High Amperage Plugs and Connectors catalog page](#)

Installation instructions

[IF 1778 - Roughneck E1049 Series Connectors and Receptacles](#)

[IF 1777 - Roughneck E1049 Series Connectors](#)

Specifications and datasheets

[Eaton Specification Sheet - A201103-3](#)