



elite

LED LIGHTING



LIGHTING
ASSOCIATES, INC.

BETTER SERVICE
HIGHER PROFIT MARGINS



RESIDENTIAL
INDUSTRIAL
COMMERCIAL

Over 1000 stocking distributors have increased their profit
by stocking Elite Lighting products.



CATEGORY 1
LED RETROFIT SERIES

CONSULT FACTORY FOR MORE PRICING OPTIONS OR
VOLUME DISCOUNT

LED SLIM RETROFIT SERIES



RL375 - LED RETROFIT MODULE
3" LED FIXTURE WITH HIGHER BRIGHTNESS

550
LUMENS

Example: **RL375-550L-DIMTR-120-30K-90-WH**

Catalog:	CCT:	CRI:	Finish:
RL375 550L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> WH <input type="checkbox"/> BK <input type="checkbox"/> SN




RL575 - LED RETROFIT MODULE
5" LED FIXTURE WITH HIGHER BRIGHTNESS

900
LUMENS

Example: **RL575-900L-DIMTR-120-30K-90-WH**

Catalog:	CCT:	CRI:	Finish:
RL575 900L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> WH <input type="checkbox"/> BK <input type="checkbox"/> SN

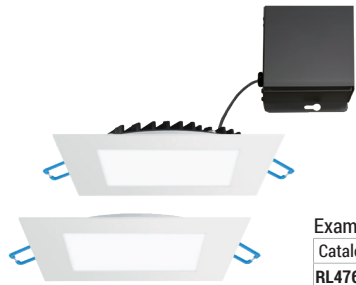

RL476 - LED SQUARE RETROFIT MODULE
4" LED FIXTURE WITH HIGHER BRIGHTNESS

700
LUMENS

Example: **RL476-700L-DIMTR-120-30K-90-WH**

Catalog:	CCT:	CRI:	Finish:
RL476 550L-DIMTR-120 700L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> WH <input type="checkbox"/> BK <input type="checkbox"/> SN

550
LUMENS



RL475 - LED RETROFIT MODULE
4" LED FIXTURE WITH HIGHER BRIGHTNESS

700
LUMENS

Example: **RL475-700L-DIMTR-120-30K-90-WH**

Catalog:	CCT:	CRI:	Finish:
RL475 550L-DIMTR-120 700L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> WH <input type="checkbox"/> BK <input type="checkbox"/> SN

550
LUMENS




RL676 - LED SQUARE RETROFIT MODULE
6" LED FIXTURE WITH HIGHER BRIGHTNESS

900
LUMENS

Example: **RL676-900L-DIMTR-120-30K-90-WH**

Catalog:	CCT:	CRI:	Finish:
RL676 700L-DIMTR-120 900L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> WH <input type="checkbox"/> BK <input type="checkbox"/> SN

700
LUMENS

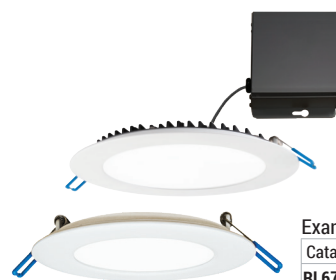

RL675 - LED RETROFIT MODULE
6" LED FIXTURE WITH HIGHER BRIGHTNESS

900
LUMENS

Example: **RL675-900L-DIMTR-120-30K-90-WH**

Catalog:	CCT:	CRI:	Finish:
RL675 700L-DIMTR-120 900L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> WH <input type="checkbox"/> BK <input type="checkbox"/> SN

700
LUMENS



RL876 - LED SQUARE RETROFIT MODULE
8" LED FIXTURE WITH HIGHER BRIGHTNESS

2200
LUMENS

Example: **RL876-2200L-DIMTR-120-30K-90-WH**

Catalog:	CCT:	CRI:	Finish:
RL876 2200L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> WH <input type="checkbox"/> BK <input type="checkbox"/> SN



RL875 - LED RETROFIT MODULE
8" LED FIXTURE WITH HIGHER BRIGHTNESS

2200
LUMENS

Example: **RL875-2200L-DIMTR-120-30K-90-WH**

Catalog:	CCT:	CRI:	Finish:
RL875 2200L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> WH <input type="checkbox"/> BK <input type="checkbox"/> SN



CATEGORY 1 LED RETROFIT SERIES

CONSULT FACTORY FOR MORE PRICING OPTIONS OR
VOLUME DISCOUNT

LED SLIM RETROFIT SERIES



RL373 - LED RETROFIT MODULE
3" LED ADJUSTABLE SLIM RETROFIT

600
LUMENS

Example: **RL373-600L-DIMTR-120-30K-90-WH**

Catalog:	CCT:	CRI:	Finish:
RL373 600L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> WH <input type="checkbox"/> BK <input type="checkbox"/> SN



RL474 - LED RETROFIT MODULE
4" LED ADJUSTABLE SLIM RETROFIT

550
LUMENS

Example: **RL474-550L-DIMTR-120-30K-90-WH**

Catalog:	CCT:	CRI:	Finish:
RL474 550L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> WH <input type="checkbox"/> BK <input type="checkbox"/> SN



RL455 - LED RETROFIT MODULE
4" LED INDIRECT SLIM LIGHTING

500
LUMENS

Example: **RL455-500L-DIMTR-120-30K-90-WH**

Catalog:	CCT:	CRI:	Finish:
RL455 500L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> WH <input type="checkbox"/> BK <input type="checkbox"/> SN

INDIRECT LIGHT



RL655 - LED RETROFIT MODULE
6" LED INDIRECT SLIM LIGHTING

650
LUMENS

Example: **RL655-650L-DIMTR-120-30K-90-WH**

Catalog:	CCT:	CRI:	Finish:
RL655 650L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> WH <input type="checkbox"/> BK <input type="checkbox"/> SN

INDIRECT LIGHT



RL456 - LED SQUARE RETROFIT MODULE
4" LED INDIRECT SLIM LIGHTING

500
LUMENS

Example: **RL456-500L-DIMTR-120-30K-90-WH**

Catalog:	CCT:	CRI:	Finish:
RL456 500L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> WH <input type="checkbox"/> BK <input type="checkbox"/> SN

INDIRECT LIGHT



RL656 - LED SQUARE RETROFIT MODULE
6" LED INDIRECT SLIM LIGHTING

650
LUMENS

Example: **RL656-650L-DIMTR-120-30K-90-WH**

Catalog:	CCT:	CRI:	Finish:
RL656 650L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> WH <input type="checkbox"/> BK <input type="checkbox"/> SN

INDIRECT LIGHT



RL479 - LED BAFFLE RETROFIT MODULE
4" LED FIXTURE WITH HIGHER BRIGHTNESS

700
LUMENS

Example: **RL479-700L-DIMTR-120-30K-90-WH**

Catalog:	CCT:	CRI:	Finish:
RL479 700L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> WH <input type="checkbox"/> BK <input type="checkbox"/> SN

BAFFLE



RL679 - LED BAFFLE RETROFIT MODULE
6" LED FIXTURE WITH HIGHER BRIGHTNESS

700
LUMENS

Example: **RL679-700L-DIMTR-120-30K-90-WH**

Catalog:	CCT:	CRI:	Finish:
RL679 700L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> WH <input type="checkbox"/> BK <input type="checkbox"/> SN

BAFFLE



CATEGORY 1 LED SURFACE MOUNT

CONSULT FACTORY FOR MORE PRICING OPTIONS OR
VOLUME DISCOUNT

RL591 - LED RETROFIT MODULE
5" LED SURFACE MOUNT SLIM FIXTURE



600
LUMENS

Example: **RL591-600L-DIMTR-120-30K-90-WH**

Catalog:	CCT:	CRI:	Finish:
RL591 600L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> WH <input type="checkbox"/> BK <input type="checkbox"/> SN

RL595 - LED RETROFIT MODULE
5" LED SURFACE MOUNT SLIM FIXTURE



600
LUMENS

Example: **RL595-600L-DIMTR-120-30K-90-WH**

Catalog:	CCT:	CRI:	Finish:
RL595 600L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> WH <input type="checkbox"/> BK <input type="checkbox"/> SN

RL791 - LED RETROFIT MODULE
7" LED SURFACE MOUNT SLIM FIXTURE



900
LUMENS

Example: **RL791-900L-DIMTR-120-30K-90-WH**

Catalog:	CCT:	CRI:	Finish:
RL791 900L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> WH <input type="checkbox"/> BK <input type="checkbox"/> SN

RL795 - LED RETROFIT MODULE
7" LED SURFACE MOUNT SLIM FIXTURE



900
LUMENS

Example: **RL795-900L-DIMTR-120-30K-90-WH**

Catalog:	CCT:	CRI:	Finish:
RL795 900L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> WH <input type="checkbox"/> BK <input type="checkbox"/> SN

RL991 - LED RETROFIT MODULE
9" LED SURFACE MOUNT SLIM FIXTURE



1200
LUMENS

Example: **RL991-1200L-DIMTR-120-30K-90-WH**

Catalog:	CCT:	CRI:	Finish:
RL991 1200L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> WH <input type="checkbox"/> BK <input type="checkbox"/> SN

RL995 - LED RETROFIT MODULE
9" LED SURFACE MOUNT SLIM FIXTURE



1200
LUMENS

Example: **RL995-1200L-DIMTR-120-30K-90-WH**

Catalog:	CCT:	CRI:	Finish:
RL995 1200L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> WH <input type="checkbox"/> BK <input type="checkbox"/> SN

RL670 - Universal Recessed and Surface Mount LED Module

FITS 4", 5" AND 6" HOUSINGS AND 4" J-BOX

1000 Available 3 Color Inserts. Check page 5
LUMENS

Example: **RL670-1000L-DIMTR-120-30K-90-W-WH**

Catalog:	CCT:	CRI:	Finish:
RL670-1000L-DIMTR-120 RL670-1000L-MOLT(+\$10)	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> W-WH

RL677 - Universal Recessed and Surface Mount LED Module

FITS 4", 5" AND 6" HOUSINGS AND 4" J-BOX

850
LUMENS

Example: **RL677-850L-DIMTR-120-30K-90-W-WH**

Catalog:	CCT:	CRI:	Finish:
RL677-850L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> W-WH

RL470 - Universal Recessed and Surface Mount LED Module

FITS 4" HOUSINGS AND 4" J-BOX

650 Available 3 Color Inserts. Check page 5
LUMENS

Example: **RL470-650L-DIMTR-120-30K-90-W-WH**

Catalog:	CCT:	CRI:	Finish:
RL470-650L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> WH

RL477 - Universal Recessed and Surface Mount LED Module

FITS 4" HOUSINGS AND 4" J-BOX

600
LUMENS

Example: **RL477-600L-DIMTR-120-30K-90-W-WH**

Catalog:	CCT:	CRI:	Finish:
RL477-600L-DIMTR-120	<input type="checkbox"/> 30K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> W-WH

CATEGORY 1 LED RETROFIT SERIES

CONSULT FACTORY FOR MORE PRICING OPTIONS OR
VOLUME DISCOUNT

Stock the standard white trim


Offer 15 additional trim colors



RL631
Universal LED Retrofit Die-cast Aluminum
Lensed White Baffle
950 LUMENS | **27K, 30K, 35K, 40K, 50K** CCT

AVAILABLE COLOR INSERTS FOR RL631 - 6" RETROFIT

REFLECTORS

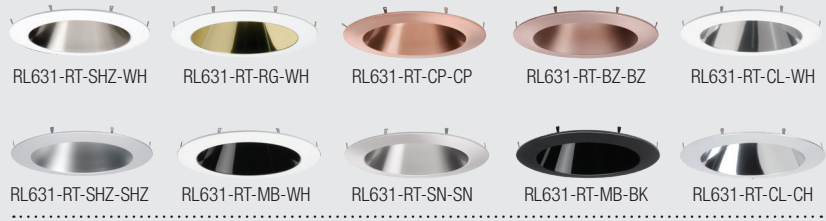

BAFFLES



RL531
Universal LED Retrofit Die-cast Aluminum
Lensed White Baffle
950 LUMENS | **27K, 30K, 35K, 40K, 50K** CCT

AVAILABLE COLOR INSERTS FOR RL531 - 5" RETROFIT

REFLECTORS



BAFFLES



RL431
Universal LED Retrofit Die-cast Aluminum
Lensed White Baffle
650 LUMENS | **27K, 30K, 35K, 40K, 50K** CCT

AVAILABLE COLOR INSERTS FOR RL431 - 4" RETROFIT

REFLECTORS



BAFFLES



RL670 and RL470 Trim Insert colors



CATEGORY 1 LED RETROFIT SERIES

CONSULT FACTORY FOR MORE PRICING OPTIONS OR
VOLUME DISCOUNT

6" LED RETROFIT MODULES



RL629 - Universal LED SMART Dimming Retrofit Die-cast Aluminum Lensed White **Reflector**
FITS IN MOST 6" REGULAR INCANDESCENT HOUSINGS

1000 LUMENS Available 15 Color Inserts. Check page 5.

Example: **RL629-1000L-DIMTR-120-30K-16K-SD-90-W-WH**

Catalog:	CCT:	CRI:	Finish:
RL629-1000L-DIMTR-120	<input type="checkbox"/> 30K-16K	<input type="checkbox"/> 90	<input type="checkbox"/> W-WH



RL635 - Universal LED SMART Dimming Retrofit Die-cast Aluminum Lensed White **Baffle**
FITS IN MOST 6" REGULAR INCANDESCENT HOUSINGS

1000 LUMENS Available 15 Color Inserts. Check page 5.

Example: **RL635-1000L-DIMTR-120-30K-16K-SD-90-W-WH**

Catalog:	CCT:	CRI:	Finish:
RL635-1000L-DIMTR-120	<input type="checkbox"/> 30K-16K	<input type="checkbox"/> 90	<input type="checkbox"/> W-WH



RL631 - Universal LED Retrofit Die-cast Aluminum Lensed White **Baffle**
FITS IN MOST 6" REGULAR INCANDESCENT HOUSINGS

950 LUMENS See page 7 for inserts

Example: **RL631-950L-DIMTR-120-30K-90-W-WH**

Catalog:	CCT:	CRI:	Finish:
RL631-950L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K <input type="checkbox"/> 50K	<input type="checkbox"/> 90	<input type="checkbox"/> W-WH



REL637 - ECONOMY UNIVERSAL 5 INCH , 6 INCH LED RETROFIT BAFFLE LIGHTING MODULE
FITS IN MOST 6" REGULAR INCANDESCENT HOUSINGS

950 LUMENS

Example: **REL637-950L-DIMTR-120-30K-90-W-WH**

Catalog:	CCT:	CRI:	Finish:
REL637-950L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> W-WH



RL628 - Universal LED Retrofit Die-cast Aluminum Lensed White **Reflector**
FITS IN MOST 6" REGULAR INCANDESCENT HOUSINGS

950 LUMENS

Example: **RL628-950L-DIMTR-120-30K-90-W-WH**

Catalog:	CCT:	CRI:	Finish:
RL628-950L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K <input type="checkbox"/> 50K	<input type="checkbox"/> 90	<input type="checkbox"/> W-WH



RL627 - Universal LED Retrofit Die-cast Aluminum Lensed Clear **Reflector**
FITS IN MOST 6" REGULAR INCANDESCENT HOUSINGS

950 LUMENS

Example: **RL627-950L-DIMTR-120-30K-90-CL-WH**

Catalog:	CCT:	CRI:	Finish:
RL627-950L-DIMTR-120	<input type="checkbox"/> 30K	<input type="checkbox"/> 90	<input type="checkbox"/> CL-WH



RL665 - 6" LED ADJUSTABLE RETROFIT 24°, 38°, 60° BEAM ANGLE
FITS IN MOST 6" REGULAR INCANDESCENT HOUSINGS

1100 LUMENS

Example: **RL665-1100L-DIMTR-120-30K-90-NS-W-WH**

Catalog:	CCT:	CRI:	Finish:
RL665-1100L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> NS - 24° / Narrow <input type="checkbox"/> MD - 38° / Medium <input type="checkbox"/> FL - 60° / Flood



RL664 - Universal LED Adjustable Retrofit Module
FITS IN MOST 6" REGULAR INCANDESCENT HOUSINGS

900 LUMENS

Example: **RL664-950L-DIMTR-120-30K-90-W-WH**

Catalog:	CCT:	CRI:	Finish:
RL664-950L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> W-WH



RL685 - Universal LED Retrofit Square Downlighting
FITS IN MOST 6" REGULAR INCANDESCENT HOUSINGS

950 LUMENS

Example: **RL685-950L-DIMTR-120-30K-90-W-WH**

Catalog:	CCT:	CRI:	Finish:
RL685-950L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> W-WH

CATEGORY 1 LED RETROFIT SERIES

CONSULT FACTORY FOR MORE PRICING OPTIONS OR
VOLUME DISCOUNT

LED RETROFIT MODULES 5"



950
LUMENS

RL528 - Universal LED Retrofit Die-cast Aluminum Lensed White Reflector

FITS IN MOST 5" REGULAR INCANDESCENT HOUSINGS

Example: **RL528-950L-DIMTR-120-30K-90-W-WH**

Catalog:	CCT:	CRI:	Finish:
RL528-950L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> W-WH



950
LUMENS

RL531 - Universal LED Retrofit Die-cast Aluminum Lensed White Baffle

FITS IN MOST 5" REGULAR INCANDESCENT HOUSINGS

Example: **RL531-950L-DIMTR-120-30K-90-W-WH**

Catalog:	CCT:	CRI:	Finish:
RL531-950L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 35K	<input type="checkbox"/> 90	<input type="checkbox"/> W-WH



See page 7 for inserts



950
LUMENS

RL527 - Universal LED Retrofit Die-cast Aluminum Lensed Clear Reflector

FITS IN MOST 5" REGULAR INCANDESCENT HOUSINGS

Example: **RL527-950L-DIMTR-120-30K-90-CL-WH**

Catalog:	CCT:	CRI:	Finish:
RL527-950L-DIMTR-120	<input type="checkbox"/> 30K	<input type="checkbox"/> 90	<input type="checkbox"/> CL-WH



LED RETROFIT MODULES WITH JUNCTION BOX



NEW

90
CRI

6"

LED DIMMABLE
100% to 10%

WWW.IUSEELITELED.COM
WEB PAGE

PDF
SPECS.

RL641 COMMERCIAL 6" LED RETROFIT BAFFLE LIGHTING MODULE WITH JUNCTION BOX



Example: **RL641-1150L-DIM10-MVOLT-40K-90-WH**

CATALOG
 RL641-1150L-DIM10-MVOLT

CCT:	CRI:	FINISH:
<input type="checkbox"/> 35K-(3500K) <input type="checkbox"/> 40K-(4000K)	<input type="checkbox"/> 90	<input type="checkbox"/> W-WH

15 WATTS **1150 LUMENS**



NEW

90
CRI

8"

LED DIMMABLE
100% to 10%

WWW.IUSEELITELED.COM
WEB PAGE

PDF
SPECS.

RL841 COMMERCIAL 8" LED RETROFIT BAFFLE LIGHTING MODULE WITH JUNCTION BOX



Example: **RL841-2500L-DIM10-MVOLT-40K-90-WH**

CATALOG
 RL841-2500L-DIM10-MVOLT

CCT:	CRI:	FINISH:
<input type="checkbox"/> 35K-(3500K) <input type="checkbox"/> 40K-(4000K)	<input type="checkbox"/> 90	<input type="checkbox"/> W-WH

25 WATTS **2500 LUMENS**

OPTIONS AND ADDERS:

- DIMTR-120: Fully dimmable down to 10% of initial light output with standard Triac and Low Voltage dimming option.
- DIM10-MVOLT(120/277): 0-10V dimming, must be ordered with 0-10V dimming housing.
- MANY OTHER OPTIONS ON LUMEN PACKAGE AVAILABLE, PLEASE CONSULT ELITE LIGHTING FOR MORE DETAILS.

WWW.IUSEELITELED.COM

TEL: 877-375-5555 • FAX: 877-375-3333

CATEGORY 1 LED RETROFIT SERIES

CONSULT FACTORY FOR MORE PRICING OPTIONS OR
VOLUME DISCOUNT

4" LED RETROFIT MODULES



RL429 - Universal LED SMART Dimming Retrofit Die-cast Aluminum Lensed White **Reflector**
FITS IN MOST 4" REGULAR INCANDESCENT HOUSINGS

750 Available 15 Color Inserts. Check page 5
LUMENS

Example: **RL429-750L-DIMTR-120-30K-16K-SD-90-W-WH**

Catalog:	CCT:	CRI:	Finish:
RL429-750L-DIMTR-120	<input type="checkbox"/> 30K-16K	<input type="checkbox"/> 90	<input type="checkbox"/> W-WH



RL435 - Universal LED SMART Dimming Retrofit Die-cast Aluminum Lensed White **Baffle**
FITS IN MOST 4" REGULAR INCANDESCENT HOUSINGS

750 Available 15 Color Inserts. Check page 5
LUMENS

Example: **RL435-750L-DIMTR-120-30K-16K-SD-90-W-WH**

Catalog:	CCT:	CRI:	Finish:
RL435-750L-DIMTR-120	<input type="checkbox"/> 30K-16K	<input type="checkbox"/> 90	<input type="checkbox"/> W-WH



RL431 - Universal LED Retrofit Die-cast Aluminum Lensed White **Baffle**
FITS IN MOST 4" REGULAR INCANDESCENT HOUSINGS

650 See page 7 for inserts
LUMENS

Example: **RL431-650L-DIMTR-120-30K-90-W-WH**

Catalog:	CCT:	CRI:	Finish:
RL431-650L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 40K <input type="checkbox"/> 50K	<input type="checkbox"/> 90	<input type="checkbox"/> W-WH



REL437 - Economy Universal LED Retrofit Die-cast Aluminum Lensed White **Baffle**
FITS IN MOST 4" REGULAR INCANDESCENT HOUSINGS

700 LUMENS

Example: **REL437-700L-DIMTR-120-30K-90-W-WH**

Catalog:	CCT:	CRI:	Finish:
REL437-700L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> W-WH



RL461 - Round Adjustable LED Retrofit Module
FITS IN MOST 4" REGULAR INCANDESCENT HOUSINGS

650 LUMENS

Example: **RL461-650L-DIMTR-120-30K-90-W-WH**

Catalog:	CCT:	CRI:	Finish:
RL461-650L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> WH <input type="checkbox"/> SN <input type="checkbox"/> BZ <input type="checkbox"/> BK



RL428 - Universal LED Retrofit Die-cast Aluminum Lensed White **Reflector**
FITS IN MOST 4" REGULAR INCANDESCENT HOUSINGS

650 LUMENS

Example: **RL428-650L-DIMTR-120-30K-90-W-WH**

Catalog:	CCT:	CRI:	Finish:
RL428-650L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K <input type="checkbox"/> 50K	<input type="checkbox"/> 90	<input type="checkbox"/> W-WH



RL465 - 4" LED ADJUSTABLE RETROFIT 24°, 38°, 60° BEAM ANGLE
FITS IN MOST 4" REGULAR INCANDESCENT HOUSINGS

650 LUMENS

Example: **RL465-650L-DIMTR-120-30K-90-NS-W-WH**

Catalog:	CCT:	CRI:	Finish:
RL465-650L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> NS - 24° / Narrow <input type="checkbox"/> MD - 38° / Medium <input type="checkbox"/> FL - 60° / Flood



RL481 - Square Adjustable LED Retrofit Module
FITS IN MOST 4" REGULAR INCANDESCENT HOUSINGS

650 LUMENS

Example: **RL481-650L-DIMTR-120-30K-90-W-WH**

Catalog:	CCT:	CRI:	Finish:
RL481-650L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> WH <input type="checkbox"/> SN



RL485 - Universal LED Retrofit Square Downlighting
FITS IN MOST 4" REGULAR INCANDESCENT HOUSINGS

650 LUMENS

Example: **RL485-650L-DIMTR-120-30K-90-W-WH**

Catalog:	CCT:	CRI:	Finish:
RL485-650L-DIMTR-120	<input type="checkbox"/> 27K <input type="checkbox"/> 30K <input type="checkbox"/> 40K	<input type="checkbox"/> 90	<input type="checkbox"/> W-WH



RL403 - Eyeball LED Retrofit Module (12°, 24°, 38° Beam Angle)
FITS IN MOST 4" REGULAR INCANDESCENT HOUSINGS

600 LUMENS

Example: **RL403-600L-DIMTR-120-30K-90-W-WH**


Catalog:	CCT:	CRI:	Finish:
RL403-600L-DIMTR-120	<input type="checkbox"/> 30K	<input type="checkbox"/> 90	<input type="checkbox"/> WH

CATEGORY 2 NEW CONSTRUCTION IC HOUSINGS

LED HOUSING FOR RL SERIES

6"

NEW CONSTRUCTION DEDICATED LED SOCKET HOUSING

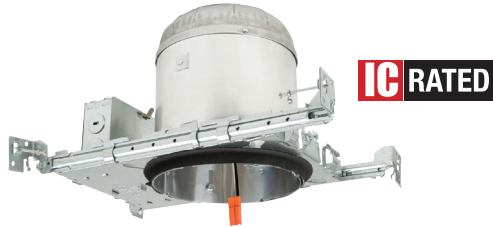

LD6IC-AT-DIMTR-120

6" New Construction IC Housing for Use with Triac and Low Voltage Electronic Dimming RL600 Series LED Module Lighting Components

6"

REMODEL DEDICATED LED SOCKET HOUSING




LD6RIC-AT-DIMTR-120

6" Remodel IC Housing for Use with Triac and Low Voltage Electronic Dimming RL600 Series LED Module Lighting Components

5"

NEW CONSTRUCTION DEDICATED LED SOCKET HOUSING

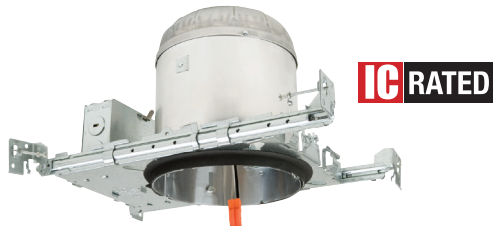

LD5IC-AT-DIMTR-120

5" New Construction IC Housing for Use with Triac and Low Voltage Electronic Dimming RL500 Series LED Module Lighting Components

5"

REMODEL DEDICATED LED SOCKET HOUSING



LD5RIC-AT-DIMTR-120

5" Remodel IC Housing for Use with Triac and Low Voltage Electronic Dimming RL500 Series LED Module Lighting Components

4"

NEW CONSTRUCTION DEDICATED LED SOCKET HOUSING



LD4IC-AT-DIMTR-120

4" New Construction IC Housing for Use with Triac and Low Voltage Electronic Dimming RL400 Series LED Module Lighting Components

4"

REMODEL DEDICATED LED SOCKET HOUSING



LD4RIC-AT-DIMTR-120

4" Remodel IC Housing for Use with Triac and Low Voltage Electronic Dimming RL400 Series LED Module Lighting Components

OPTIONS AND ADDERS:


- DIMTR-120: Fully dimmable down to 10% of initial light output with standard Triac and Low Voltage dimming option.
- DIM10-MVOLT(120/277): 0-10V dimming, must be ordered with 0-10V dimming housing.
- MANY OTHER OPTIONS ON LUMEN PACKAGE AVAILABLE, PLEASE CONSULT ELITE LIGHTING FOR MORE DETAILS.

CATEGORY 2
NEW CONSTRUCTION IC HOUSINGS

6" EZ SERIES INCANDESCENT HOUSINGS WITH LOOSE SOCKET & AF TRIMS



EZ6IC-AT
6" Universal IC Housing w/ Loose Socket and Quick Connectors, Bar Hangers are supplied with 90° Pivoting Mounting Plate and Double Headed Nail
Designed for all AF series trims, eyeballs, gimbals, and adjustables

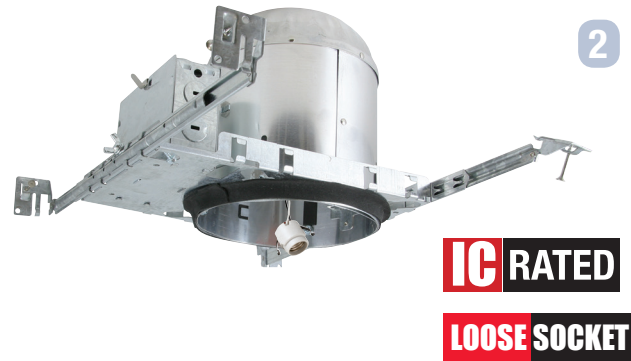

C6IC-AT
6" Economy Universal IC Housing w/ Loose Socket and Quick Connectors and with Adjustable Mounting Bracket
Designed for all AF series trims, eyeballs, gimbals, and adjustables



AF637W-WH
Socket Supporting R30/PAR30 Self Flange Air-Shut Baffle

HOUSING COMPATIBILITY:
1 2 3 4 5 6



AF637P-WH
Socket Supporting R30/PAR30 Self Flange Air-Shut Baffle

HOUSING COMPATIBILITY:
1 2 3 4 5 6



AF640W-WH
Socket Supporting R40/PAR38 Self Flange Premium Air-Shut Baffle

HOUSING COMPATIBILITY:
1 2 3 4



AF640P-WH
Socket Supporting R40/PAR38 Self Flange Premium Air-Shut Baffle

HOUSING COMPATIBILITY:
1 2 3 4



AF632CL-WH
Socket Supporting R30/PAR30 Self Flange Air-Shut Reflector

HOUSING COMPATIBILITY:
1 2 3 4



AF632W-WH
Socket Supporting R30/PAR30 Self Flange Air-Shut White Reflector

HOUSING COMPATIBILITY:
1 2 3 4



AF633W-WH
Socket Supporting R/PAR30 Open Trim

HOUSING COMPATIBILITY:
1 2 3 4



MAXIMUM
40W A19
AF605WH
Socket Supporting Metal Fresnel Shower Trims

HOUSING COMPATIBILITY:
1 2 3 4



MAXIMUM
40W A19
AF601WH
Socket Supporting Metal Albalite Shower Trims

HOUSING COMPATIBILITY:
1 2 3 4

HOUSING COMPATIBILITY GUIDE

1

EZ6IC-AT
(75W PAR30 / 40W A19)

2

C6IC-AT-W
(75W PAR30, R30, 60W A19, 65W BR30)

3

B6IC-AT-W
(75W PAR30, R30, 60W A19, 65W BR30)

4

B6RIC-AT
(75W PAR30, R30, 60W A19, 65W BR30)

5

B26IC-AT-W
(75W PAR30, R30, 60W A19, 65W BR30)

6

B26RIC-AT-W
(75W PAR30, R30, 60W A19, 65W BR30)

CATEGORY 2 NEW CONSTRUCTION IC HOUSINGS

6" INCANDESCENT HOUSINGS WITH SOCKET BRACKET & TRIMS

IC RATED
SOCKET BRACKET

3



LOOSE SOCKET

B61C-AT-W

6" Universal IC Housing with Adjustable Mounting Bracket and Bar Hangers are supplied with 90° Pivoting Mounting Plate and Double Headed Nail

IC RATED

4




B6R1C-AT

6" Universal IC Remodel Housing

IC RATED

5

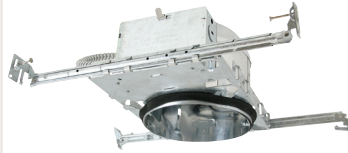

B261C-AT-W

6" Universal Shallow IC Housing

IC RATED

6



B26R1C-AT-W

6" Universal Shallow IC Remodel Housing

B631W-WH

R30/PAR30 Premium Phenolic Baffle with Metal Ring



HOUSING COMPATIBILITY:

1 2 3 4 5 6

B630W-WH

Metal Stepped Baffle R30/PAR30



HOUSING COMPATIBILITY:

2 3 4 5 6

B630P-WH

Metal Stepped Baffle R30/PAR30



HOUSING COMPATIBILITY:

2 3 4 5 6

B603WH

R/PAR 30 Open Trim



HOUSING COMPATIBILITY:

2 3 4 5 6

B607CL-WH

Reflector R/PAR30



HOUSING COMPATIBILITY:

2 3 4 5 6

B608CL-WH

Cone Reflector A-19



HOUSING COMPATIBILITY:

3 4

B611W-WH

PAR30 Baffle Wall Wash



HOUSING COMPATIBILITY:

2 3 4 5 6

B602WH

Eyeball



HOUSING COMPATIBILITY:

1 2 3 4 5 6

B609W-WH

Regressed Eyeball w/ Baffle



HOUSING COMPATIBILITY:

1 2 3 4 5 6

B605WH

Metal Fresnel Shower Trims



HOUSING COMPATIBILITY:

2 3 4 5 6

FOR WET LOCATION

B601WH

Metal Albalite Shower Trims



HOUSING COMPATIBILITY:

2 3 4 5 6

FOR WET LOCATION

6" SLOPE INCANDESCENT HOUSINGS & TRIMS



IC RATED

B361C-AT

6" Slope IC Housing - 2/12 to 6/12 Pitch (9° to 27°)



IC RATED

 
B36R1C-AT

6" Slope IC Remodel Housing - 2/12 to 6/12 Pitch (9° to 27°)



B391W-WH

PAR30/R30 Stepped Baffle



B391P-WH

PAR30/R30 Stepped Baffle

WWW.IUSEELITELED.COM

TEL: 877-375-5555 • FAX: 877-375-3333

11

CATEGORY 2 NEW CONSTRUCTION IC HOUSINGS

5" INCANDESCENT HOUSINGS & TRIMS



IC RATED

B51C-AT-W
5" Universal IC Housing



IC RATED

B5RIC-AT-W
5" Universal IC Remodel Housing



B530W-WH
Stepped Baffle



B530P-WH
Stepped Baffle



B502WH
Eyeball



B501WH
Metal Albalite Lens



B505WH
Metal Fresnel Lens

4" INCANDESCENT HOUSINGS



IC RATED

B41C-AT
4" Miniature IC Housing



B4-AT
4" Miniature Non-IC Housing

 


B4R-AT
4" Miniature Non-IC Remodel Housing

4" INCANDESCENT TRIMS



B401W-WH
Stepped Baffle



B401P-WH
Stepped Baffle



B402CL-WH
Reflector



B403WH
Eyeball (30° Tilt)



B406W-WH
Wall Wash with Baffle



B462CL-WH
Semi-Frosted Shower Trim

4" LOW VOLTAGE HOUSINGS



IC RATED


BL41C-50-M-120-AT
4" Miniature Low Voltage IC Housing with Magnetic Transformer



BL4-75-120
4" Miniature Low Voltage Non-IC Housing with Magnetic Transformer



BL4-50-M-120-AT
4" Miniature Low Voltage Non-IC Housing with Magnetic Transformer

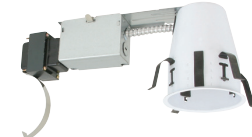

BL4R-50-M-120-AT
4" Miniature Low Voltage Non-IC Remodel Housing with Magnetic Transformer

4" LOW VOLTAGE TRIMS



B1401W-WH
Stepped Baffle (35° Tilt)



B1401P-WH
Stepped Baffle (35° Tilt)



B1402CL-WH
Reflector (35° Tilt)



B1406WH
Surface Adjustable (90° Tilt, 359° Rot.)



B1411WH
Slot Aperture (35° Tilt, 179° Rotation)



B1404W-WH
Eyeball (47° Tilt)



B1414W-WH
Pinhole with Baffle



B1412W-WH
Fully Adjustable (35° Tilt, 359° Rot.)



B1461WH
Adjustable Gimbal (40° Tilt)




B1462CL-WH
Semi-Frosted Shower Trim

CATEGORY 3
LED SURFACE MOUNT SERIES



OMSD1-LED -LED FLUSH MOUNT FIXTURE

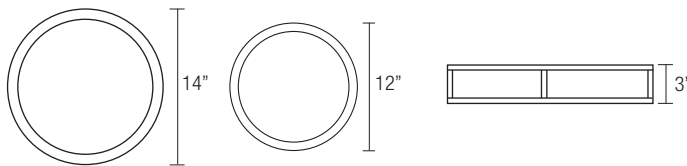


PART NUMBER	LUMES/ VOLTAGE	CCT
OMSD1-LED-12 (12")	1400L-120	30K
OMSD1-LED-14 (14")	1600L-120	35K
OMSD1-LED-18 (18")	1800L-120	50K

WATTAGE: 1400L / 1600L
 CRI: 90+
 FINISH: BN
 GLASS TYPE: OPAL
 HEIGHT: 3"



OMSD2-LED -LED FLUSH MOUNT FIXTURE

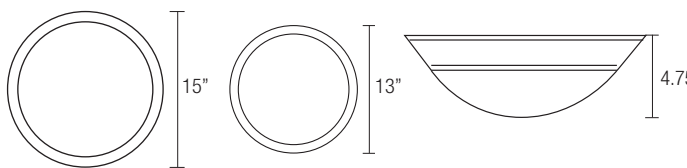


PART NUMBER	LUMES/ VOLTAGE	CCT
OMSD2-LED-13 (13")	1000L-120	30K
OMSD2-LED-15 (15")	1200L-120	40K

WATTAGE: 1000L / 1200L
 CRI: 90+
 FINISH: BN
 GLASS TYPE: OPAL
 HEIGHT: 4.75"



OMS-LED -LED SURFACE MOUNT MUSHROOM FIXTURE

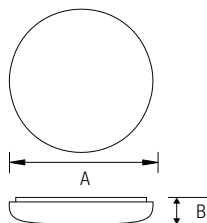

MUSHROOM SERIES
OMS-LED-11-1200L-40K 11" 1200 lumens 40K 120V
OMS-LED-14-2600L-40K 14" 2600 lumens 40K 120V
OMS-LED-19-3500L-40K 19" 3500 lumens 40K 120V

OMS-LED-11
 A. Diameter = 11-1/2"
 B. Height = 3-1/2"
OMS-LED-14
 A. Diameter = 14"
 B. Height = 3-1/2"
OMS-LED-19
 A. Diameter = 19"
 B. Height = 4"



CATEGORY 3 LED UNDERCABINET SERIES

UNDER CABINET LIGHTING

EU SERIES

- T5 Polycarbonate Lens w/ UV Radiation Protection •



PART #	DESCRIPTION
EU-12	12" T5 Undercabinet
EU-21	21" T5 Undercabinet
EU-24	24" T5 Undercabinet
EU-33	33" T5 Undercabinet
EU-42	42" T5 Undercabinet

EZU SERIES

- T8 Polycarbonate Lens w/ UV Radiation Protection •



PART #	DESCRIPTION
EZU-18-T8/T12-E	18" CFL T8/T12 Electronic
EZU-24-T8/T12-E	24" CFL T8/T12 Electronic
EZU-36-T12-E	36" CFL T8/T12 Electronic
EZU-48-T12-E	48" CFL T8/T12 Electronic
EZU-36-T8-E	36" CFL T8/T12 Electronic
EZU-48-T8-E	48" CFL T8/T12 Electronic

PUCK LIGHTS



HU-03-3-WH
White 3 Light Puck
Light Kit



HU-03-3-BK
Black 3 Light Puck
Light Kit



HU-03-3-CH
Chrome 3 Light
Puck Light Kit



HU-03-3-PB
Gold 3 Light Puck
Light Kit

LED PUCK LIGHTS

 


**130
LUMENS**

LED-HU-22
LED Portable Cabinet Light

LED-HU-22WH-30K

COLORS



**390
LUMENS**


LED-HU-22-3
3 LED Portable Cabinet Light

LED-HU-22-3WH-30K

COLORS




LED ROPE LIGHT

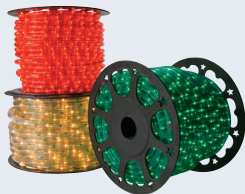

ER-LED-120-150-WW-CL-150
120V LED Warm White Instant Rope Flexilight Clear

ER-LED-120-150-CW-CL-150
120V LED Cool White Instant Rope Flexilight Clear

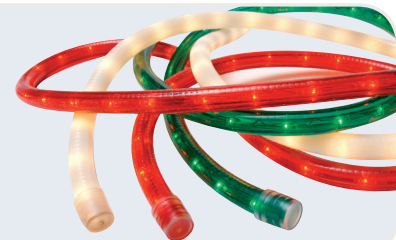

LOW VOLTAGE TRANSFORMERS



ELV-75
75W L. V. Transformer



ELV-105
105W L. V. Transformer



ELV-150
150W L. V. Transformer

CATEGORY 3 LED UNDERCABINET SERIES



ESL-LED SERIES

• LED Slim Link Profile / 120V High Performance •

6"	12"	24"	36"	48"
152L	312L	560L	758L	1125L

Available in 27K, 30K, and 40K CCT.

Delivered up to 1125 lumens per unit

Input Voltage 120

Up to 58 LPW

CRI: 81+


Life rated at 50,000 hours

Dimming compatible

Engineered to eliminate 'dark zones'

Built-in circuitry protects against short circuits

No UV • No IR • No mercury • No lead

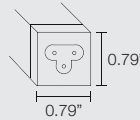

TYPE	LENGTH (WATT, LUMEN)	VOLTAGE	COLOR
ESL-LED	<input type="checkbox"/> 6" (3.1 WATT, 152 LUMEN)	<input type="checkbox"/> 120	<input type="checkbox"/> 27K
	<input type="checkbox"/> 12" (6.1 WATT, 312 LUMEN)		<input type="checkbox"/> 30K
	<input type="checkbox"/> 24" (12 WATT, 560 LUMEN)		<input type="checkbox"/> 40K
	<input type="checkbox"/> 36" (16 WATT, 758 LUMEN)		
	<input type="checkbox"/> 48" (24 WATT, 1125 LUMEN)		



EUL-LED SERIES

• 1-1/2" LED Undercabinet Lighting •



EUL-LED-32-750L-DIMTR-120-30K-WH

32" LED Undercabinet

WH BZ SN

8
WATTS

3000K
CCT

750
LUMENS



EUL-LED-24-550L-DIMTR-120-30K-WH

24" LED Undercabinet

WH BZ SN

6
WATTS

3000K
CCT

550
LUMENS



EUL-LED-16-450L-DIMTR-120-30K-WH

16" LED Undercabinet

WH BZ SN

4
WATTS

3000K
CCT

450
LUMENS



EUL-LED-8-300L-DIMTR-120-30K-WH

8" LED Undercabinet

WH BZ SN

2
WATTS


3000K
CCT

300
LUMENS

EU-LED SERIES

• LED Undercabinet Fixture
Polycarbonate w/ UV Radiation Protection •

9"	12"	18"	24"	34"	42"	46"
300L	450L	600L	900L	1300L	1600L	1800L

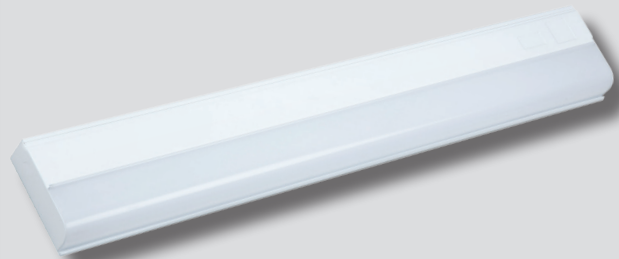

PART NUMBER	DIMMING	CCT	FINISH
<input type="checkbox"/> EU-LED-9-300L - (9", 4 Watts, 300 lumens)	DIMTR-120	<input type="checkbox"/> 3000K	<input type="checkbox"/> WH
<input type="checkbox"/> EU-LED-12-450L (12" - 450 lumens)		<input type="checkbox"/> 3500K	<input type="checkbox"/> BZ
<input type="checkbox"/> EU-LED-18-600L - (18", 7 Watts)		<input type="checkbox"/> 4000K	
<input type="checkbox"/> EU-LED-24-900L (24" - 900 lumens)			
<input type="checkbox"/> EU-LED-34-1300L (34" - 1300 lumens)			
<input type="checkbox"/> EU-LED-42-1600L (42" - 1600 lumens)			
<input type="checkbox"/> EU-LED-46-1800L (46" - 1800 lumens)			

WWW.IUSEELITELED.COM

TEL: 877-375-5555 • FAX: 877-375-3333

15

CATEGORY 3 LED UNDERCABINET SERIES



LED Puck Light

LED-HU-41-LED-240L-30K-90-WH
3W LED ROUND PUCK SERIES

LED-HU-41 is a puck light that can be use for recessed or surface mounted applications.

INPUT VOLT.	THD	INPUT POWER	LUMENS
12	<20%	3W(+/-5%)	240

EXAMPLE: LED-HU-41-LED-240L-30K-90-WH

SERIES	LUMENS	CCT	CRI	FINISH	
LED-HU-41	<input type="checkbox"/> 240L	<input type="checkbox"/> 30K <input type="checkbox"/> 40K	<input type="checkbox"/> 90+	<input type="checkbox"/> WH-White <input type="checkbox"/> BK-Black <input type="checkbox"/> SI-Silver	<input type="checkbox"/> BZ-Bronze <input type="checkbox"/> CH-Chrome <input type="checkbox"/> SN-Satin Nickel



LED Puck Light

LED-HU-45-LED-240L-30K-90-WH
3W LED SQUARE PUCK SERIES

LED-HU-45 is a puck light that can be use for surface mounted applications.

INPUT VOLT.	THD	INPUT POWER	LUMENS
12	<20%	3W(+/-5%)	240

EXAMPLE: LED-HU-45-LED-240L-30K-90-WH

SERIES	LUMENS	CCT	CRI	FINISH	
LED-HU-45	<input type="checkbox"/> 240L	<input type="checkbox"/> 30K <input type="checkbox"/> 40K	<input type="checkbox"/> 90+	<input type="checkbox"/> WH-White <input type="checkbox"/> BK-Black <input type="checkbox"/> SI-Silver	<input type="checkbox"/> BZ-Bronze <input type="checkbox"/> CH-Chrome


ACCESSORIES:



LED-HU-ACC-1-WH (White)
LED-HU-ACC-1-BK (Black)
6-port adapter for led-hu-41 and 45



LED-HU-ACC-2-WW (White)
LED-HU-ACC-2-WB (Black)
24" extension wire to adapter in white, 24" extension wire to driver.

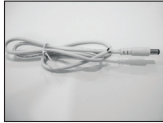

**DIMMABLE COMPACT LED DC
12V ELECTRONIC LOW VOLTAGE DRIVERS**

NOTE: Hard wire only. Power cable sold separately



PART#	Input(120V)	Output(12V)	Depth	Height	Width
LED-HU-ELV-DIMTR-DC-12-25-120	1@25 Watts	12V	2.1"	0.7"	6"
LED-HU-ELV-DIMTR-DC-12-50-120	1@50 Watts	12V	2.5"	1"	7"
LED-HU-ELV-DIMTR-DC-12-60-120	1@60 Watts	12V	2.3"	1.4"	7"

LED-HU SERIES

- Surface/Recessed LED Puck •



LED-HU-30-3W-WH-27K

- Aluminum body
- 3W LED warm white
- 180 lumens
- Surface or Recessed mounted



LED-HU-33-3W-WH-27K

- Aluminum body
- 3W LED warm white
- 180 lumens
- Surface or Recessed mounted
- **Includes: 3 fixtures with quick connectors and mounting hardware. One 9W LED driver with 6' cord.**

LED DRIVERS


The following driver sold separately.

CAT#	Description	Input	Input Current	# of Puck Lights		Wattage	Wattage Per Puck Light	Expected Lumen Output/Fix	Connector's Qty.
				Minimum	Maximum				
LED-HU-30-DR-8W-350	8W/350mA LED Driver	120V	.350mA	1	6	8	1	80LM	6
LED-HU-30-DR-9W-700	9W/700mA LED Driver	120V	.700mA	1	3	9	3	140LM	3
LED-HU-30-DR-12W-700	12W/350mA LED Driver	120V	.350mA	3	3	12	1	80LM	3
LED-HU-30-DR-16W-350	16.8W/350mA LED Driver	120V	.350mA	7	8	16	1	80LM	8
LED-HU-30-DR-24W-700	24W/700mA LED Driver	120V	.700mA	7	7	24	3	140LM	7



2' X 4' NV-LED SERIES

 2' X 4' LED RECESSED VOLUMETRIC LUMINAIRE




2 basket

CATALOG NO.	DIM 10 STANDARD	LUTRON STANDARD	VOLTAGE	CCT
<input type="checkbox"/> 24-NV-LED	<input type="checkbox"/> 4000L-DIM10 <input type="checkbox"/> 5000L-DIM10 <input type="checkbox"/> 6000L-DIM10 <input type="checkbox"/> 8000L-DIM10	<input type="checkbox"/> 4000L-LUTH <input type="checkbox"/> 5000L-LUTH <input type="checkbox"/> 6000L-LUTH <input type="checkbox"/> 8000L-LUTH	<input type="checkbox"/> MVOLT	<input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K
EMERGENCY		<input type="checkbox"/> EMG-LED		

2' X 2' NV-LED SERIES

 2' X 2' LED RECESSED VOLUMETRIC LUMINAIRE




2 basket

CATALOG NO.	DIM 10 STANDARD	LUTRON STANDARD	VOLTAGE	CCT
<input type="checkbox"/> 22-NV-LED	<input type="checkbox"/> 2400L-DIM10 <input type="checkbox"/> 3400L-DIM10 <input type="checkbox"/> 4000L-DIM10	<input type="checkbox"/> 2400L-LUTH <input type="checkbox"/> 3400L-LUTH <input type="checkbox"/> 4000L-LUTH	<input type="checkbox"/> MVOLT	<input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K
EMERGENCY		<input type="checkbox"/> EMG-LED		

2' X 4' OVHP-LED SERIES

 2X4 LED SHALLOW VOLUMETRIC LUMINAIRE




1 basket

CATALOG NO.	DIM 10 STANDARD	LUTRON STANDARD	VOLTAGE	CCT
<input type="checkbox"/> 24-OVHP-LED	<input type="checkbox"/> 4000L-DIM10 <input type="checkbox"/> 5000L-DIM10	<input type="checkbox"/> 4000L-LUTH <input type="checkbox"/> 5000L-LUTH	<input type="checkbox"/> MVOLT	<input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K
EMERGENCY		<input type="checkbox"/> EMG-LED		

2' X 2' OVHP-LED SERIES

 2X2 LED SHALLOW VOLUMETRIC LUMINAIRE



1 basket

CATALOG NO.	DIM 10 STANDARD	LUTRON STANDARD	VOLTAGE	CCT
<input type="checkbox"/> 22-OVHP-LED	<input type="checkbox"/> 4000L-DIM10	<input type="checkbox"/> 4000L-LUTH	<input type="checkbox"/> MVOLT	<input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K
EMERGENCY		<input type="checkbox"/> EMG-LED		

2' X 4' OT-LED SERIES

2X4 LED RECESSED TROFFER LUMINAIRE



CATALOG NO.	DIM 10 STANDARD	LUTRON STANDARD	VOLTAGE	CCT
<input type="checkbox"/> 24-OT-LED	<input type="checkbox"/> 4000L-DIM10 <input type="checkbox"/> 5000L-DIM10 <input type="checkbox"/> 6000L-DIM10 <input type="checkbox"/> 8000L-DIM10	<input type="checkbox"/> 4000L-LUTH <input type="checkbox"/> 5000L-LUTH <input type="checkbox"/> 6000L-LUTH <input type="checkbox"/> 8000L-LUTH	<input type="checkbox"/> MVOLT	<input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K
EMERGENCY		<input type="checkbox"/> EMG-LED		

2' X 2' OT-LED SERIES

2X2 LED RECESSED TROFFER LUMINAIRE



CATALOG NO.	DIM 10 STANDARD	LUTRON STANDARD	VOLTAGE	CCT
<input type="checkbox"/> 22-OT-LED	<input type="checkbox"/> 4000L-DIM10	<input type="checkbox"/> 4000L-LUTH	<input type="checkbox"/> MVOLT	<input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K
EMERGENCY		<input type="checkbox"/> EMG-LED		

CATEGORY 4
LED FLAT PANEL SERIES

2'x4' | 1'x4' | 2'x2' LED FLAT PANEL

2' X 4' FPL1-LED SERIES

2X4 LED FLAT PANEL LUMINAIRE



CATALOG NO.	DIM 10 STANDARD	VOLTAGE	CCT
<input type="checkbox"/> 24-FPL1-LED	<input type="checkbox"/> 3000L - DIM10 <input type="checkbox"/> 4000L - DIM10 <input type="checkbox"/> 5000L - DIM10 <input type="checkbox"/> 6000L - DIM10	<input type="checkbox"/> MVOLT	<input type="checkbox"/> 30K-(3000K) <input type="checkbox"/> 35K-(3500K) <input type="checkbox"/> 40K-(4000K) <input type="checkbox"/> 50K-(5000K)
EMERGENCY			<input type="checkbox"/> EMG-LED

1' X 4' FPL1-LED SERIES

1X4 LED FLAT PANEL LUMINAIRE



CATALOG NO.	DIM 10 STANDARD	VOLTAGE	CCT
<input type="checkbox"/> 14-FPL1-LED	<input type="checkbox"/> 2000L - DIM10 <input type="checkbox"/> 3000L - DIM10 <input type="checkbox"/> 4000L - DIM10 <input type="checkbox"/> 5000L - DIM10	<input type="checkbox"/> MVOLT	<input type="checkbox"/> 30K-(3000K) <input type="checkbox"/> 35K-(3500K) <input type="checkbox"/> 40K-(4000K) <input type="checkbox"/> 50K-(5000K)
EMERGENCY			<input type="checkbox"/> EMG-LED

2' X 2' FPL1-LED SERIES

2X2 LED FLAT PANEL LUMINAIRE



CATALOG NO.	DIM 10 STANDARD	VOLTAGE	CCT
<input type="checkbox"/> 22-FPL1-LED	<input type="checkbox"/> 2000L - DIM10 <input type="checkbox"/> 3000L - DIM10 <input type="checkbox"/> 4000L - DIM10 <input type="checkbox"/> 5000L - DIM10	<input type="checkbox"/> MVOLT	<input type="checkbox"/> 30K-(3000K) <input type="checkbox"/> 35K-(3500K) <input type="checkbox"/> 40K-(4000K) <input type="checkbox"/> 50K-(5000K)
EMERGENCY			<input type="checkbox"/> EMG-LED

FLAT PANEL SURFACE MOUNT KIT

1'X4'



14-FPL1-LED-SMK

2'X4'



24-FPL1-LED-SMK

2'X2'



22-FPL1-LED-SMK

UNIVERSAL RECESSED DRYWALL FLANGE KIT

1'X4'



14FK

2'X4'



24FK

2'X2'



22FK

2'x4' | 2'x2' LED RETROFIT KIT

OVHP-RTK-LED

1% STANDARD DIMMING

2'x4' LED Troffer Retrofit Kit

3000
LUMENS

4000
LUMENS

5000
LUMENS

6000
LUMENS


8000
LUMENS



CATALOG NO.	DIM 10 STANDARD	LUTRON STANDARD	VOLTAGE	CCT
<input type="checkbox"/> 24-OVHP-RTK-LED	<input type="checkbox"/> 4000L-DIM10 <input type="checkbox"/> 5000L-DIM10 <input type="checkbox"/> 6000L-DIM10 <input type="checkbox"/> 8000L-DIM10	<input type="checkbox"/> 4000L-LUTH <input type="checkbox"/> 5000L-LUTH <input type="checkbox"/> 6000L-LUTH <input type="checkbox"/> 8000L-LUTH	<input type="checkbox"/> MVOLT	<input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K <input type="checkbox"/> 50K
	EMERGENCY		<input type="checkbox"/> EMG-LED	


2'x2' LED Troffer Retrofit Kit


3000
LUMENS

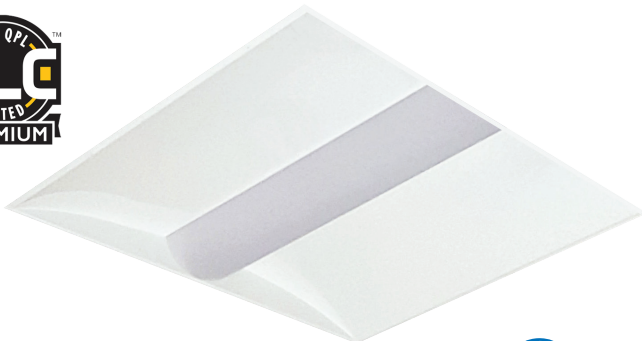

CATALOG NO.	DIM 10 STANDARD	LUTRON STANDARD	VOLTAGE	CCT
<input type="checkbox"/> 22-OVHP-RTK-LED	<input type="checkbox"/> 3000L-DIM10	<input type="checkbox"/> 3000L-LUTH	<input type="checkbox"/> MVOLT	<input type="checkbox"/> 30K <input type="checkbox"/> 35K <input type="checkbox"/> 40K <input type="checkbox"/> 50K
	EMERGENCY		<input type="checkbox"/> EMG-LED	

EASY INSTALLATION

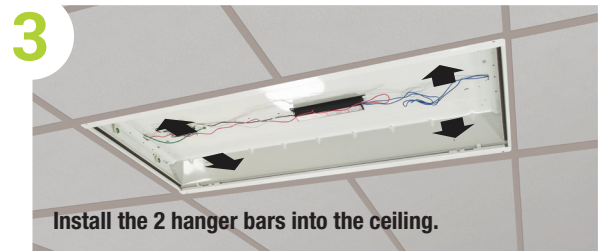

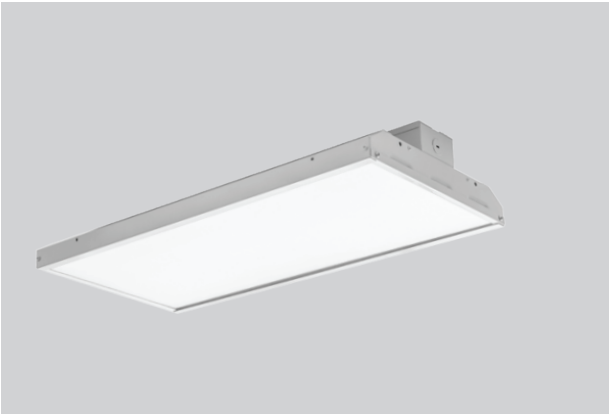

CB2-LED SERIES

LED Cool Beam High Bay (Economy)

CATALOG NO.	LUMENS	DIMMING	EMERGENCY	CCT
<input type="checkbox"/> CB2-LED	<input type="checkbox"/> 13000L <input type="checkbox"/> 26000L	<input type="checkbox"/> DIM10-MVOLT	<input type="checkbox"/> EMG-LED -	<input type="checkbox"/> 40K-(4000K)



OTHER OPTIONS:

- CB2-LED-13000L-WG-WH**
WireGuard for 13000L
- CB2-LED-26000L-WG-WH**
WireGuard for 26000L



CB3-LED SERIES

LED Cool Beam High Bay (Full Body Specification Grade)

CATALOG NO.	LUMENS	DIMMING	EMERGENCY	CCT
<input type="checkbox"/> CB3-LED	<input type="checkbox"/> 18000L <input type="checkbox"/> 22500L	<input type="checkbox"/> DIM10-MVOLT	<input type="checkbox"/> EMG-LED -	<input type="checkbox"/> 40K-(4000K) <input type="checkbox"/> 50K-(5000K)



OTHER OPTIONS:



CB4-LED SERIES

LED Cool Beam High Bay (Full Body Specification Grade)

CATALOG NO.	LUMENS	DIMMING	EMERGENCY	CCT
<input type="checkbox"/> CB4-LED	<input type="checkbox"/> 10000L <input type="checkbox"/> 12000L <input type="checkbox"/> 16000L	<input type="checkbox"/> DIM10-MVOLT	<input type="checkbox"/> EMG-LED -	<input type="checkbox"/> 30K-(3000K) <input type="checkbox"/> 35K-(3500K) <input type="checkbox"/> 40K-(4000K) <input type="checkbox"/> 50K-(5000K)



CB4-LED-CLDF -Clear Lens w/ Door Frame

OTHER OPTIONS:



CB6-LED SERIES

LED Cool Beam High Bay (Full Body Specification Grade)

CATALOG NO.	LUMENS	DIMMING	EMERGENCY	CCT
<input type="checkbox"/> CB6-LED	<input type="checkbox"/> 20000L <input type="checkbox"/> 24000L <input type="checkbox"/> 30000L	<input type="checkbox"/> DIM10-MVOLT	<input type="checkbox"/> EMG-LED -	<input type="checkbox"/> 30K-(3000K) <input type="checkbox"/> 35K-(3500K) <input type="checkbox"/> 40K-(4000K) <input type="checkbox"/> 50K-(5000K)



CB6-LED-CLDF -Clear Lens w/ Door Frame


OTHER OPTIONS:






HD1B-LED Hydro Beam LED IP & Nema Rated High Bay Wide Body

CATALOG NO.	LUMENS	DIMMING	EMERGENCY	CCT
<input type="checkbox"/> HD1B-LED	<input type="checkbox"/> 10000L <input type="checkbox"/> 15000L <input type="checkbox"/> 20000L <input type="checkbox"/> 23000L	<input type="checkbox"/> DIM10-MVOLT	<input type="checkbox"/> EMG-LED -	<input type="checkbox"/> 30K-(3000K) <input type="checkbox"/> 35K-(3500K) <input type="checkbox"/> 40K-(4000K)

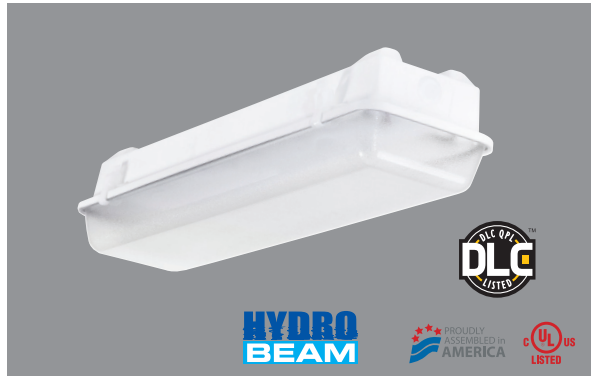

OW1IP-LED LED Vapor Tight Series


CATALOG NO.	LUMENS	DIMMING	EMERGENCY	CCT
<input type="checkbox"/> OW1IP-LED	2' FIXTURE <input type="checkbox"/> 3000L 4' FIXTURE <input type="checkbox"/> 2000L <input type="checkbox"/> 4000L <input type="checkbox"/> 5000L <input type="checkbox"/> 6000L 8' FIXTURE <input type="checkbox"/> 4000L <input type="checkbox"/> 8000L <input type="checkbox"/> 10000L <input type="checkbox"/> 12000L	<input type="checkbox"/> DIM10	<input type="checkbox"/> EMG-LED	<input type="checkbox"/> 30K-(3000K) <input type="checkbox"/> 35K-(3500K) <input type="checkbox"/> 40K-(4000K)

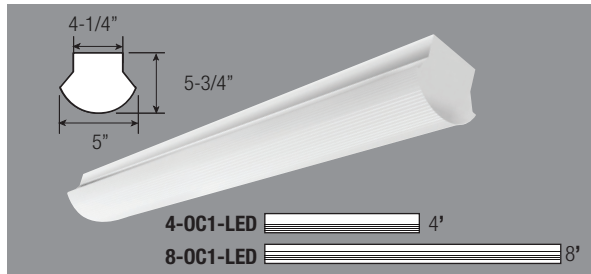

STRIP LIGHTING (SURFACE OR SUSPENDED MOUNT)

OC1-LED LED General Lighting Linear Luminaire

CATALOG NO.	DIM 10 STANDARD	VOLTAGE	CCT	EMERGENCY
<input type="checkbox"/> 4-OC1-LED	<input type="checkbox"/> 4000L	<input type="checkbox"/> MVOLT	<input type="checkbox"/> 40K-(4000K)	<input type="checkbox"/> EMG-LED
<input type="checkbox"/> 8-OC1-LED	<input type="checkbox"/> 8000L			

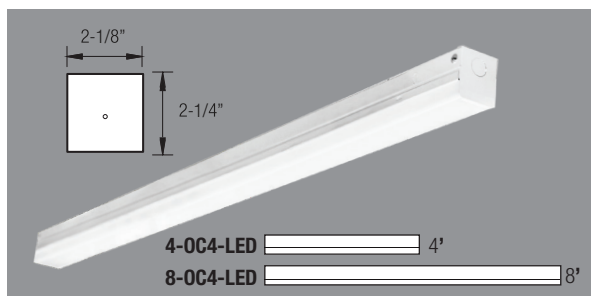

LED GENERAL LIGHTING LINEAR CURVE LUMINAIRE


4-OC4-LED / 8-OC4-LED LED General Lighting Linear Luminaire

CATALOG NO.	DIM 10 STANDARD	VOLTAGE	CCT	EMERGENCY
<input type="checkbox"/> 4-OC4-LED (4 feet)	<input type="checkbox"/> 3000L <input type="checkbox"/> 4000L <input type="checkbox"/> 5000L	<input type="checkbox"/> MVOLT	<input type="checkbox"/> 30K-(3000K) <input type="checkbox"/> 35K-(3500K) <input type="checkbox"/> 40K-(4000K) <input type="checkbox"/> 50K-(5000K)	<input type="checkbox"/> EMG-LED

CATALOG NO.	DIM 10 STANDARD	VOLTAGE	CCT	EMERGENCY
<input type="checkbox"/> 8-OC4-LED (8 feet)	<input type="checkbox"/> 8000L	<input type="checkbox"/> MVOLT	<input type="checkbox"/> 30K-(3000K) <input type="checkbox"/> 35K-(3500K) <input type="checkbox"/> 40K-(4000K) <input type="checkbox"/> 50K-(5000K)	<input type="checkbox"/> EMG-LED




SURFACE ECONOMY MOUNT WRAP AROUND

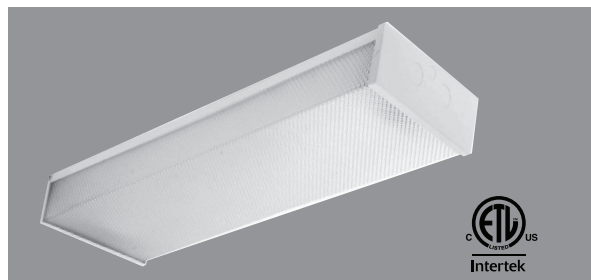

4-OEW-LED-4000L-DIM10-MVOLT-40K-85


INDUSTRIAL LED WRAP AROUND (SURFACE MOUNT)

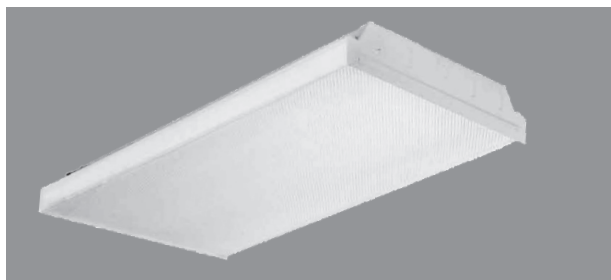

4-OIW-LED-4000L-DIM10-MVOLT-40K-85

COMMERCIAL

4-LAMP HIGH BAY SERIES (T5/T8)

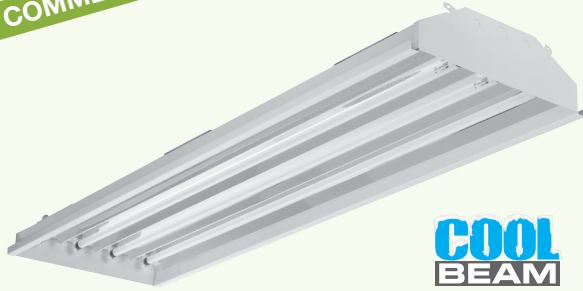

CB4 SERIES

CB-4-54-T5HO

Full Body 4-Lamp 54W T5HO High Bay 120/277 & Advance Cool Running Ballast

CB-4-32-T8

Full Body 4-Lamp 32W T8 High Bay 120/277

CB-4-54-T5HO-GL41K

Full Body 4-Lamp 54W T5HO High Bay 120/277 & Advance Cool Running Ballast & 841 Lamps

CB-4-32-T8-GL41K

Full Body 4-Lamp 32W T8 High Bay 120/277 & 741 Lamps

6-LAMP HIGH BAY SERIES (T5/T8)



CB6 SERIES

CB-6-54-T5HO

Full Body 4-Lamp 54W T5HO High Bay 120/277 & Advance Cool Running Ballast

CB-6-32-T8

Full Body 4-Lamp 32W T8 High Bay 120/277

CB-6-54-T5HO-GL41K

Full Body 4-Lamp 54W T5HO High Bay 120/277 & Advance Cool Running Ballast & 841 Lamps

CB-6-32-T8-GL41K

Full Body 4-Lamp 32W T8 High Bay 120/277 & 741 Lamps

ACCESSORIES FOR HIGH BAY

ACCESSORIES FOR HIGH BAY



CB-4-WG-C2

4-Lamp Cool Beam Wire Guard - Screw Down




CB-6-WG-C2

6-Lamp Cool Beam Wire Guard - Screw Down



CB4-HG

4-Lamp Cool Beam Wire Guard - Hinged w/ Door Frame

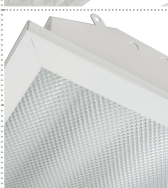

CB6-HG

6-Lamp Cool Beam Wire Guard - Hinged w/ Door Frame



CB-4-CL-C2

4-Lamp Cool Beam Clear Lens & Door



CB-6-CL-C2

6-Lamp Cool Beam Clear Lens & Door



 
CB-4-PL-C2

4-Lamp Cool Beam Prismatic Lens & Door

CB-6-PL-C2

6-Lamp Cool Beam Prismatic Lens & Door

ACCESSORIES FOR HIGH BAY



CB-CHAIN

4 Hooks, 10' Chain



GSS

Set of 10' Gripple Aircraft Cable



PCSB

Straight Blade 120V Plug



PCTL-120

120V 3 - Wire NEMA 5-15 Amp Plug



PCTL-277

277V 3 - Wire NEMA 5-15 Amp Plug



MH

Mounting Hub



MS

Motion Sensor



EPS

Electronic Program Start Ballast for T8/ per Ballast

VAPOR TIGHT SERIES

COMMERCIAL




VAPOR TIGHT SERIES

4-0WVS-2-32-T8-E-MVOLT
2 Lamp 32W T8 4' Vapor Tight


4-0WVS-2-54-T5HO-E-MVOLT
2 Lamp 54W T5HO 4' Vapor Tight

STRIP LIGHTING (WITH REFLECTOR)

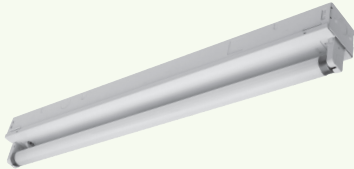

1 LAMP STRIP SERIES

4-0C-1-32T8-E-MVOLT
1 Lamp 4' 32W Open Strip

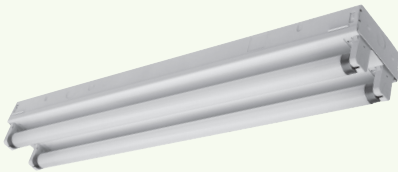


2 LAMP STRIP SERIES

4-0C-2-32T8-E-MVOLT
2 Lamp 4' 32W Open Strip

8-0C-4-32T8-E-MVOLT
4 Lamp 8' 32W Tandem Open Strip

4-0C-WG
4' Wire Guard

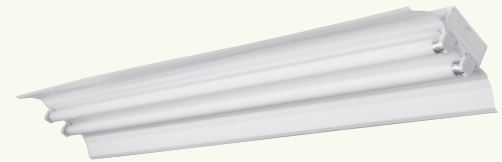

4' & 8' INDUSTRIAL STRIP SERIES

8-0IC-4-32-T8-MVOLT
4 Lamp 32W 8' Strip w/ Reflector

4-0IC-2-32-T8-MVOLT
2 Lamp 32W 4' Strip w/ Reflector

SURFACE MOUNT WRAP AROUND



ECONOMY WRAP AROUND

2-0EW-2-17-T8-120
2' 2 Lamp 7" 17W - 120V

4-0EW-2-32-T8-120
4' 2 Lamp 7" 32W - 120V



INDUSTRIAL WRAP AROUND

4-0IW-2-32-T8-MVOLT
4' 2 Lamp 9" 32W-MVOLT

4-0IW-3-32-T8-MVOLT
4' 3 Lamp 9" 32W-MVOLT

4-0IW-4-32-T8-MVOLT
4' 4 Lamp 9" 32W-MVOLT

SURFACE MOUNT CLOUD



4' CLOUD SERIES

4-0SC-2-32T8-E-MVOLT
2 Lamp 32W 4' Cloud

4-0SC-4-32T8-E-MVOLT
4 Lamp 32W 4' Cloud

MUSHROOM SERIES



MUSHROOM SERIES

OMS-11-2X13W-120
11" 2 Lamp 2x13W

OMS-11-22W-120
11" 1 Lamp 22W

MUSHROOM SERIES

OMS-14-32W-120
14" 1 Lamp 32W

OMS-14-54W-120
14" 1 Lamp 54W

MUSHROOM SERIES

OMS-19-72W-120
19" 1 Lamp 72W

ROUND DRUM SERIES



11" ROUND DRUM SERIES

ORS-11-2X13W-120
11" 2 Lamp 2x13W

ORS-11-22W-120
11" 1 Lamp 22W

14" ROUND DRUM SERIES

ORS-14-32W-120
14" 1 Lamp 32W

ORS-14-54W-120
14" 1 Lamp 54W

19" ROUND DRUM SERIES

ORS-19-72W-120
19" 1 Lamp 72W



ELX-603-R-W
Red LED Exit Sign with Battery Back-Up



ELX-503-R-W
Red LED Exit Sign with AC Only



ELX-703-R-W
Red LED Exit/Emergency Light Combo
w/ Battery Back-up



 
ELX-LED-735-R-W
Red LED Exit/Emergency Light Combo
w/ Battery Back-up



ELM-807-WH
Outdoor Die-Cast Emergency Light
w/ Battery Back-up



ELM-809-WH
MR16 Emergency Light w/ Battery
Back-up



ELM-803-WH
Red LED Exit Sign with Battery Back-Up



ELM-LED-860
Adjustable LED Emergency Light

NOW IN STOCK!



READY TO SHIP!

BALLAST

BALLAST-LAMP COMPATIBILITY CHART

Ballast Part #	Max. Lumen Output	LINEAR FLUORESCENT LAMPS						COMPACT FLUORESCENT LAMPS			
		T5 (W)		T5HO (W)		T8 (W) / T8 (U-Bend) / T9 (Circline)		4-Pin CFL (W)		4-Pin Long CFL (W)	
		1 Lamp	2 Lamp	1 Lamp	2 Lamp	1 Lamp	2 Lamp	1 Lamp	2 Lamp	1 Lamp	2 Lamp
BAL-EMG-T8-500	500	-	-	-	-	17-40	-	13-26	-	18-36	-
BAL-EMG-T8-1400	1400	-	-	-	-	17-110	17-40	13-42	13-39	18-55	18-36
BAL-EMG-T8-3000	3000	-	-	-	-	17-215	17-40	-	13-42	18-55	18-36
BAL-EMG-T5-700	700	8, 14	-	-	-	17-40	-	13-39	-	18-36	-
BAL-EMG-T5-1400	1400	-	8-28	39, 54	-	17-125	17-40	13-42	13-39	18-50	18-36
BAL-EMG-T5-3000	3000	-	8-28	-	39, 54	17-125	17-40	-	13-42	18-55	18-50
BAL-EMG-T5HO-1400	1400	-	8-28	39, 54	-	-	17-40	13-42	13-39	-	18-40
BAL-EMG-T5HO-3000	3000	-	8-28	-	39, 54	17-125	17-40	-	13-42	18-55	18-50

6" COMMERCIAL VERTICAL DOWNLIGHT & TRIMS



BHVR6PL-1X26/32/42-E-MVOLT
6" 26/32/42W Commercial Vertical
Fluorescent Housing



6101CL-WH
6" Vertical Clear
Reflector



6107CL-WH
6" Vertical Clear Wall
Wash Reflector



6104CL-WH
6" Vertical Clear
Reflector with
Prismatic Lens



6105W-WH
6" Vertical White
Baffle with Fresnel
Lens

6" COMMERCIAL HORIZONTAL DOWNLIGHT & TRIMS



BHHR6PL-2X26-E-MVOLT
6" 2X26W Commercial Horizontal
Fluorescent Housing



6501CL-WH
6" Horizontal Clear
Reflector



6507CL-WH
6" Horizontal Clear
Wall Wash Reflector



6504CL-WH
6" Horizontal Clear Reflector
with Prismatic Lens



6505W-WH
6" Horizontal White Baffle
with Fresnel Lens

TRACKLIGHTING

LED TRACK LIGHTING



ET-LED-217
LED Track Fixture

1100
LUMENS

FINISH
AWH -Architecural White
ABK - Architecural Black

Part#: **ET-LED-217-1100L-DIMTR-120-30K-90**



ET-LED-216
LED Track Fixture

800
LUMENS

FINISH
AWH -Architecural White
ABK - Architecural Blac

Part#: **ET-LED-216-800L-DIMTR-120-30K-90**



ET-LED-326
LED Track Fixture

800
LUMENS

FINISH
AWH -Architecural White
ABK - Architecural Black

Part#: **ET-LED-326-800L-DIMTR-120-30K-90**



ET-LED-336
LED Track Fixture

1100
LUMENS

FINISH
AWH -Architecural White
ABK - Architecural Black

Part#: **ET-LED-336-1100L-DIMTR-120-30K-90**



ET-LED-213
LED Track Fixture

1100
LUMENS

FINISH
AWH -Architecural White
ABK - Architecural Black

Part#: **ET-LED-213-1100L-DIMTR-120-30K-90**



ET-LED-302
LED Track Fixture

1100
LUMENS

FINISH
AWH -Architecural White
ABK - Architecural Black

Part#: **ET-LED-302-1100L-DIMTR-120-30K-90**



ET-LED-309
LED Track Fixture

800
LUMENS

FINISH
AWH -Architecural White
ABK - Architecural Blac

Part#: **ET-LED-309-800L-DIMTR-120-30K-90**



ET-LED-212
LED Track Fixture

800
LUMENS

FINISH
AWH -Architecural White
ABK - Architecural Black

Part#: **ET-LED-212-800L-DIMTR-120-30K-90**



ET-LED-322
LED Track Fixture

800
LUMENS

FINISH
AWH -Architecural White
ABK - Architecural Black

Part#: **ET-LED-322-800L-DIMTR-120-30K-90**



ET-LED-310
LED Track Fixture

1100
LUMENS

FINISH
AWH -Architecural White
ABK - Architecural Black

Part#: **ET-LED-310-1100L-DIMTR-120-30K-90**



LOW VOLTAGE TRACK



ET402 - CYLINDER
50W Cylinder Track
Fixture

FINISH
AWH -White
ABK - Black



ET401 - GIMBAL RING
50W Gimbal Ring Track
Fixture

FINISH
AWH -White
ABK - Black



LINE VOLTAGE TRACK CIRCUIT TRACK



ET213 - GIMBAL RING
75W PAR30 Gimbal Ring

FINISH
AWH -White
ABK - Black



ET212 - GIMBAL RING
50W PAR20 Gimbal Ring

FINISH
AWH -White
ABK - Black

1 CIRCUIT TRACK

ET-4-AWH - 4' Track White

ET-8-AWH - 8' Track Black

ET-4-ABK - 4' Track White

ET-8-ABK - 8' Track Black

ACCESSORIES - 1 CIRCUIT TRACK

ET-101-AWH - White Live End Track Connector

ET-101-ABK - Black Live End Track Connector

ET-103-AWH - White Floating Canopy


ET-103-ABK - Black Floating Canopy

ET-107-AWH - White Mini Coupling

ET-107-ABK - Black Mini Coupling

ET-108-AWH - White L Connector w/ Power Entry

ET-108-ABK - Black L Connector w/ Power Entry

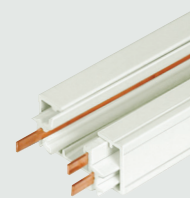



LED TAPE LIGHT SERIES



LB100 SERIES

Features:

- Pre-applied 3M tape allows for fast, hassle free installation
- Field cuttable every 2" or 3 LED's.
- Easy connectors allow for simple plug and play installation.
- UV rays and infrared wavelength are non existent.

Type:

- LB100-15F-65K (Cool White)
- LB100-15F-30K (Warm White)
- LB100-15F-RED
- LB100-15F-AMBER
- LB100-15F-GREEN
- LB100-15F-BLUE

up to
127
*LUMENS
per/foot

16'
Maximum
Continuous run

12V
DC
Voltage

140°
View
Angle

15'
feet



INDOOR TAPE LIGHT



LB102 SERIES

Features:

- Pre-applied 3M tape allows for fast, hassle free installation
- Field cuttable every 2" or 3 LED's.
- Easy connectors allow for simple plug and play installation.
- UV rays and infrared wavelength are non existent.

Type:

- LB102-30F-65K (Cool White)
- LB102-30F-30K (Warm White)

up to
127
*LUMENS
per/foot

32'
Maximum
Continuous run


24V
DC
Voltage

120°
View
Angle

30'
feet



INDOOR TAPE LIGHT

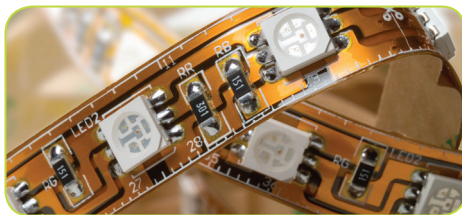

LB103 SERIES

Features:

- Pre-applied 3M tape allows for fast, hassle free installation
- Field cuttable every 2" or 3 LED's.
- Easy connectors allow for simple plug and play installation.
- UV rays and infrared wavelength are non existent.

Type:

- LB103-15F-65K (Cool White)
- LB103-15F-30K (Warm White)

up to
400
*LUMENS
per/foot

16'
Maximum
Continuous run

12V
DC
Voltage

130°
View
Angle

HIGH
LUMEN



INDOOR TAPE LIGHT

HIGH LUMEN



LB106 SERIES

Features:

- Pre-applied 3M tape allows for fast, hassle free installation
- Field cuttable every 2" or 3 LED's.
- Easy connectors allow for simple plug and play installation.
- UV rays and infrared wavelength are non existent.

Type:

- LB106-15F-65K (Cool White)
- LB106-15F-30K (Warm White)
- LB106-15F-RED
- LB106-15F-AMBER
- LB106-15F-GREEN
- LB106-15F-BLUE

up to
127
*LUMENS
per/foot

16'
Maximum
Continuous run

12V
DC
Voltage

140°
View
Angle

15'
feet



INDOOR TAPE LIGHT



LED TAPE LIGHT SERIES



LB101 SERIES

- up to **109** *LUMENS per/foot
- 16'** Maximum Continuous run
- 12V** DC Voltage
- 100°** View Angle

Features:

- Pre-applied 3M tape allows for fast, hassle free installation
- Field cuttable every 2" or 3 LED's.
- Easy connectors allow for simple plug and play installation.
- UV rays and infrared wavelength are non existent.

Type:

- LB101-15F-RGB

Electrical:

- Remote control and adapter required.
- RGB tape light controller has 11 different modes and can be controlled via a remote control device.



INDOOR TAPE LIGHT



LB200 SERIES

- up to **114** *LUMENS per/foot
- 16'** Maximum Continuous run
- 12V** DC Voltage
- 140°** View Angle

Features:

- Pre-applied 3M tape allows for fast, hassle free installation
- Field cuttable every 2" or 3 LED's.
- Easy connectors allow for simple plug and play installation.
- UV rays and infrared wavelength are non existent.

Type:

- LB200-15F-65K (Cool White)
- LB200-15F-30K (Warm White)
- LB200-15F-RED
- LB200-15F-AMBER
- LB200-15F-GREEN
- LB200-15F-BLUE



OUTDOOR TAPE LIGHT



LB201 SERIES

- up to **98** *LUMENS per/foot
- 16'** Maximum Continuous run
- 12V** DC Voltage
- 100°** View Angle

Features:

- Pre-applied 3M tape allows for fast, hassle free installation
- Field cuttable every 2" or 3 LED's.
- Easy connectors allow for simple plug and play installation.
- UV rays and infrared wavelength are non existent.

Type:

- LB201-15F-RGB

Electrical:

- Remote control and adapter required.
- RGB tape light controller has 11 different modes and can be controlled via a remote control device.



OUTDOOR TAPE LIGHT



Driver




- LB100-DR-12V-30W
- LB100-DR-12V-60W

Mini Channel Mounting System

Features

Easy to snap together top and bottom design

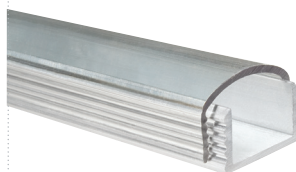


Dimensions

Length: 50"
Height: 1/2"
Width: 3/4"

Finish

- LB100-BC-AL (Aluminium- Base Channel)
- LB100-BC-WH (White- Base Channel)
- LB100-BC-CL (Clear- Base Channel)
- LB100-TC-CL (Clear- Top Cover)
- LB100-TC-CLF (Clear Frosted- Top Cover)
- LB100-TC-WH (White- Top Cover)
- LB100-TC-WF (White Frosted- Top Cover)

LED OUTDOOR LIGHTING

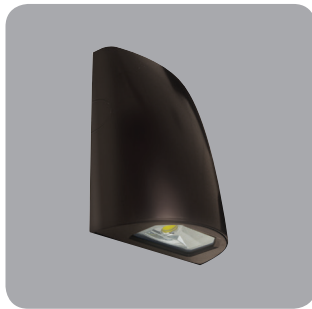

OWP-FC-103-LED-2500L-MVOLT-50K-BZ

LED Small Full Cut-Off Wall Pack

2500 LUMENS | **5000K** CCT



OPTION
EMG-LED - Emergency PHC - Photo cell



OWP-SL-101-LED-2700L-MVOLT-50K-70-BZ

LED SlimLine Wall Pack

2700 LUMENS | **5000K** CCT



OWP-FC-201-LED-6000L-MVOLT-41K-BZ

LED Medium Full Cut-Off Wall Pack

6000 LUMENS | **4000K** CCT



OPTION
EMG-LED - Emergency PHC - Photo cell



OWP-NC-201-LED-4000L-MVOLT-41K-BZ

LED Medium Full Cut-Off Wall Pack

4000 LUMENS | **4000K** CCT



OPTION
EMG-LED - Emergency PHC - Photo cell



OWP-NC-201-LED-6000L-MVOLT-41K-BZ

LED Medium Full Cut-Off Wall Pack

6000 LUMENS | **4000K** CCT



OPTION
EMG-LED - Emergency PHC - Photo cell



OVR-101-LED-6000L-MVOLT-75-40K-BZ

LED CANOPY

6000 LUMENS | **4000K** CCT



OPTION
EMG-LED - Emergency PHC - Photo cell

Motion Activated LED Security Light

OMSSL-LED-101

2-Head Motion Activated LED Security Light

1800 LUMENS



Example: OMSSL-LED-101-1800L-120-30K-180-WH

Catalog:	CCT:	Detection Range	Finish:
OMSSL-LED-101-1800L-120	<input type="checkbox"/> 30K <input type="checkbox"/> 40K <input type="checkbox"/> 50K	<input type="checkbox"/> 150 - 150° angle <input type="checkbox"/> 180 - 180° angle	<input type="checkbox"/> WH <input type="checkbox"/> BZ

OMSSL-LED-102

3-Head Motion Activated LED Security Light

2700 LUMENS



Example: OMSSL-LED-102-2700L-120-30K-180-WH

Catalog:	CCT:	Detection Range	Finish:
OMSSL-LED-102-2700L-120	<input type="checkbox"/> 30K <input type="checkbox"/> 40K <input type="checkbox"/> 50K	<input type="checkbox"/> 150 - 150° angle <input type="checkbox"/> 180 - 180° angle	<input type="checkbox"/> WH <input type="checkbox"/> BZ

LED OUTDOOR LIGHTING



OVT-LED-1500L-MVOLT-40K-GR-WM

LED Vapor Tight for Wet Location

1500 LUMENS | **4000K** CCT



OVT-LED-1500L-MVOLT-40K-GR-CM

LED Vapor Tight for Wet Location

1500 LUMENS | **4000K** CCT



OFL-R-101-LED-1700L-MVOLT-40K-SP*-BZ

LED Small Round Pole and Floodlight

1700 LUMENS | **30K** | **40K** | **50K** CCT



*OPTICS: SP-Spot NFL - Narrow PHC - Photo cell



OFL-R-101-LED-3350L-MVOLT-40K-SP*-BZ

LED Small Round Pole and Floodlight

2500 LUMENS | **30K** | **40K** | **50K** CCT



*OPTICS: SP-Spot NFL - Narrow PHC - Photo cell



OFL-SL-102-LED-1500L-MVOLT-40K-BZ

LED Die-Cast SLIM Floodlight

1500 LUMENS | **4000K** CCT



OWP-SL-102-LED-700L-MVOLT-40K-BZ

LED Die-cast Slimline Wall Pack

700 LUMENS | **4000K** CCT





DISTRIBUTOR LISTS

1	
2	
3	
4	
5	
6	
7	
8	
9	
10	
11	
12	
13	
14	
15	
16	
17	
18	
19	
20	
21	
22	
23	
24	
25	
26	
27	
28	
29	
30	





DISTRIBUTOR LISTS

31	
32	
33	
34	
35	
36	
37	
38	
39	
40	
41	
42	
43	
44	
45	
46	
47	
48	
49	
50	
51	
52	
53	
54	
55	
56	
57	
58	
59	
60	



elite
LED LIGHTING
WWW.IUSEELITE.COM

The products shown in this catalog are covered by USA and international patents. Specifications are subject to change without prior notice. Elite Lighting reserves the right to make any changes in the design, construction and listing approval of the products listed in this catalog which may be required by law or by the rules of any regulatory body or at its discretion. Dimensions and specifications are subject to change without prior notice. Not responsible for any typographical errors. Wattage and specifications may be different for products supplied in CANADA.

Main Office: Los Angeles, CA

- WWW.IUSEELITE.COM
- Tel: 1-323-888-1973 / 1-877-375-5555
- Fax: 1-323-888-1977 / 1-877-375-3333

© Copyright 2018. Elite Lighting. All Rights Reserved / Rev1.0-2018