


## EZ Lock - Connector - Steel

### Images

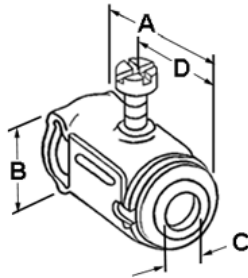

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1.62  
Dimension B in Inches: 1.19  
Dimension C in Inches: .56  
Dimension D in Inches: .75

### Application

Bridgeport Fittings EZ-Lock 3/4 inch steel connector recommended for cables with an O.D. of .56 - .81 or 10/3 to 6/3 Listed for use with steel and aluminum Flexible Metallic Conduit (FMC) in 1/2 inch trade size. Listed for use with Metal Clad (MC) and Armored Cable (AC).

### Product Information

Material: Steel  
Finish: Zinc Coated

### Certifications & Codes:

Federal Specification Number:	A-A-50552
NEMA Standard:	FB-1
UL File Number:	E20534
UL Standard:	UL514B & CSA 22.2
UNSPSC:	39121419

**Catalog ID:** AMC-75

**UPC Number:** 78174720571

**Description:** Bridgeport Fittings AMC-75 3/4 inch EZ Lock AC/MC/FMC connector is designed for ease of use. The AMC-75 installs quickly without the need of a locknut and requires only the tightening of one screw. It accepts a wide range of cables with an outer Diameter of .566 -.81 and is listed for use with steel and aluminum 1/2 inch flexible metallic conduit.

**Application:** Bridgeport Fittings EZ-Lock 3/4 inch steel connector recommended for cables with an O.D. of .56 - .81 or 10/3 to 6/3 Listed for use with steel and aluminum Flexible Metallic Conduit (FMC) in 1/2 inch trade size. Listed for use with Metal Clad (MC) and Armored Cable (AC).

**Trade Size:** 3/4"

**Std Pkg Qty:** 100

**Unit Qty:** 25