


Eaton AN56BN0AC

Catalog Number: AN56BN0AC

Eaton Freedom NEMA motor control starter, Reversing Reset Overload Relay Starter, 2 hp at 115V, 3 hp at 230V, 7-1/2 hp at 208,240V, 10 hp at 480,600V maximum horsepower, 120V/60 Hz or 110V/50 Hz coil voltage, 18A, Three-pole, Size 0

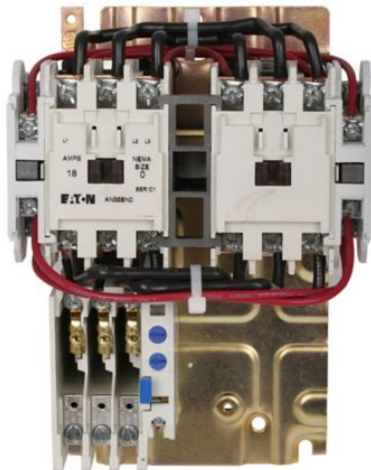

General specifications

Product Name

Eaton Freedom NEMA motor control starter

Catalog Number

AN56BN0AC

UPC

782113972480

Product Length/Depth

4.61 in

Product Height

3.31 in

Product Width

4.38 in

Product Weight

2.6 lb

Warranty

Eaton Selling Policy 25-000, one (1) year UL Listed from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.

Certifications

CSA Certified

Catalog Notes

Heater Packs must be purchased separately

defaultTaxonomyAttributeLabel

HP rating - max

2 hp at 115V, 3 hp at 230V, 7-1/2 hp at 208,240V, 10 hp at 480,600V

Phase

Single-phase, three-phase

Amperage Rating

18A

Size

0

Resources

Catalogs

[Eaton's Volume 10—Enclosed Control](#)

Drawings

[AN56BN0_C AutoCAD 2D Footprint](#)

[AN56BN0_C 2D Drawing Xchange](#)

[AN56BN0_C AutoCAD 2D Footprint \(mm\)](#)

[AN56BN0_C 3D Inventor](#)

[AN56BN0_C 2D PDF](#)

[AN56BN0_C 3D Model Xchange](#)

Specifications and datasheets

[Quick Selector - NEMA Contactors](#)

[Eaton Specification Sheet - AN56BN0AC](#)



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com

© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)