


Kwiksplice™ cable tray,  
24A series cable tray and  
Flextray™ wire basket

B-LINE  
SERIES

## Ready. Set. Ship.

B-Line series KwikSplice™ cable tray,  
24A series cable tray & Flextray™  
stocked in Mississauga for faster delivery!

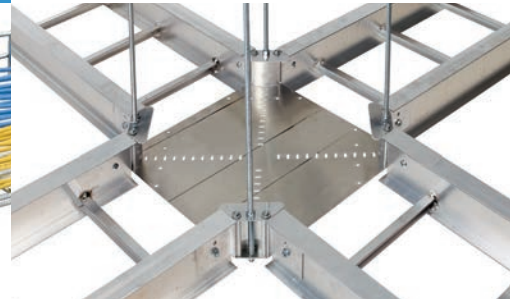

### Now stocked in Mississauga

- KwikSplice™ Aluminum Cable Tray
  - 4 different width options
  - Class C-3m
  - 12" rung spacing and 10' lengths
  - Horizontal & vertical bends
  - Horizontal tees
  - Covers and accessories
- 24 Series Aluminum Cable Tray
  - 4 width options
  - Class D-3m
  - 9" rung spacing and 10' lengths
  - Horizontal & vertical bends
  - Horizontal tees
  - Covers and accessories
- Flextray™ Wire Basket
  - 2" and 4" deep straight sections
  - Splices, supports and popular accessories also available



**EATON**

Powering Business Worldwide

# Flextray™ wire basket cable tray

## B-Line Part # Description

### Straight Sections

<input type="checkbox"/>	FT2X4X10 ELG	2" Deep X 4" Wide X 3M Long Electroplated Zinc Galvanized Finish
<input type="checkbox"/>	FT2X6X10 ELG	2" Deep X 6" Wide X 3M Long Electroplated Zinc Galvanized Finish
<input type="checkbox"/>	FT2X8X10 ELG	2" Deep X 8" Wide X 3M Long Electroplated Zinc Galvanized Finish
<input type="checkbox"/>	FT2X12X10 ELG	2" Deep X 12" Wide X 3M Long Electroplated Zinc Galvanized Finish
<input type="checkbox"/>	FT2X18X10 ELG	2" Deep X 18" Wide X 3M Long Electroplated Zinc Galvanized Finish
<input type="checkbox"/>	FT4X6X10 ELG	4" Deep X 6" Wide X 3M Long Electroplated Zinc Galvanized Finish
<input type="checkbox"/>	FT4X8X10 ELG	4" Deep X 8" Wide X 3M Long Electroplated Zinc Galvanized Finish
<input type="checkbox"/>	FT4X12X10 ELG	4" Deep X 12" Wide X 3M Long Electroplated Zinc Galvanized Finish
<input type="checkbox"/>	FT4X18X10 ELG	4" Deep X 18" Wide X 3M Long Electroplated Zinc Galvanized Finish
<input type="checkbox"/>	FT4X24X10 ELG	4" Deep X 24" Wide X 3M Long Electroplated Zinc Galvanized Finish

### Splicing Accessories

<input type="checkbox"/>	WASHER SPL KIT	Connector Assembly of Staked Washer Stud/Washer & Finned Nut
<input type="checkbox"/>	FTHDWE 1/4	1/4" x 1" Carriage Bolt & Finned Nut
<input type="checkbox"/>	TOP WASHER	1" Square Splice Washer
<input type="checkbox"/>	BTM WASHER	1 3/16" Square Splice Washer
<input type="checkbox"/>	FTSCH	Connecting Hardware
<input type="checkbox"/>	FTSWN	Wing Splice
<input type="checkbox"/>	FTS3SP	Splice Plate
<input type="checkbox"/>	FLEXMATE2	Flexmate Splice Clips
<input type="checkbox"/>	FLEXMATE TOOL	Flexmate Splice Tool
<input type="checkbox"/>	FTSTLC	Tab-Loc Connectors
<input type="checkbox"/>	SPLICE BAR	10 3/16" Long Bar
<input type="checkbox"/>	SUPT WASHER	Hold Down Plate
<input type="checkbox"/>	FTA6HD	Hold Down Plate
<input type="checkbox"/>	FTSHAK	Horizontal Adjustable Kit
<input type="checkbox"/>	90 DEGREE KIT	90 Degree Splice Bar & Hardware


### Accessories

<input type="checkbox"/>	2 IN DIVIDER	2" Divider
<input type="checkbox"/>	4 IN DIVIDER	4" Divider
<input type="checkbox"/>	DROP OUT	Drop out Fitting
<input type="checkbox"/>	FTA2DO	2" Plenum-rated Plastic Cable Drop Out
<input type="checkbox"/>	B719EB	Rubber Cap for Wire Ends
<input type="checkbox"/>	LABEL CLIP	Label Clip
<input type="checkbox"/>	GROUND BOLT	Ground Bolt
<input type="checkbox"/>	GROUND SUPT GL	Ground Wire Support
<input type="checkbox"/>	CLEANSHEAR™	Flextray Cutter
<input type="checkbox"/>	CLEANSHEAR™ BEND	Flextray Cutter/Bender

## B-Line Part # Description

### Hanging Accessories

<input type="checkbox"/>	WB46H	Flip Clip
<input type="checkbox"/>	TRAPEZE SUPT2	Trapeze Support Clip
<input type="checkbox"/>	FTB06CT	6" Center/Trapeze Hanger
<input type="checkbox"/>	FTB08CT	8" Center/Trapeze Hanger
<input type="checkbox"/>	FTB12CT	12" Center/Trapeze Hanger
<input type="checkbox"/>	FTB18CT	18" Center/Trapeze Hanger
<input type="checkbox"/>	FTB24CT	24" Center/Trapeze Hanger
<input type="checkbox"/>	4 L BRKT	4" L Bracket
<input type="checkbox"/>	8 L BRKT	8" L Bracket
<input type="checkbox"/>	12 L BRKT	12" L Bracket
<input type="checkbox"/>	20 L BRKT	20" L Bracket
<input type="checkbox"/>	24 L BRKT	24" L Bracket
<input type="checkbox"/>	FTA9WTK	Wall Termination Kit

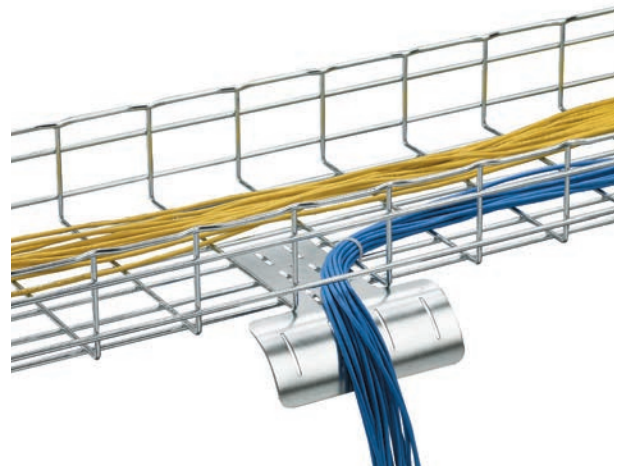

For more information, and to view our larger product offering visit [Eaton.com/flextray](http://Eaton.com/flextray)

B-Line Part #	Competitors Part #		
<b>Straight Sections</b>			
<input type="checkbox"/> KSA4A12-06-120	AH1-4-06-L12-3	LCA43-06-12	CI40LASL3126
<input type="checkbox"/> KSA4A12-12-120	AH1-4-12-L12-3	LCA43-12-12	CI40LASL31212
<input type="checkbox"/> KSA4A12-18-120	AH1-4-18-L12-3	LCA43-18-12	CI40LASL31218
<input type="checkbox"/> KSA4A12-24-120	AH1-4-24-L12-3	LCA43-24-12	CI40LASL31224

<b>Horizontal Bends</b>			
<input type="checkbox"/> KS4A09-06-90HB12	AUF4-06-LHB90-12	LCA43-06-H90, 12R	CI40LAHL90126
<input type="checkbox"/> KS4A09-12-90HB12	AUF4-12-LHB90-12	LCA43-12-H90, 12R	CI40LAHL901212
<input type="checkbox"/> KS4A09-18-90HB12	AUF4-18-LHB90-12	LCA43-18-H90, 12R	CI40LAHL901218
<input type="checkbox"/> KS4A09-24-90HB12	AUF4-24-LHB90-12	LCA43-24-H90, 12R	CI40LAHL901224
<input type="checkbox"/> KS4A09-12-90HB24	AUF4-12-LHB90-24	LCA43-12-H90, 24R	CI40LAHL902412
<input type="checkbox"/> KS4A09-18-90HB24	AUF4-18-LHB90-24	LCA43-18-H90, 24R	CI40LAHL902418
<input type="checkbox"/> KS4A09-24-90HB24	AUF4-24-LHB90-24	LCA43-24-H90, 24R	CI40LAHL902424

<b>Horizontal Tees</b>			
<input type="checkbox"/> KS4A09-06-HT12	AUF4-06-LHT-12	LCA43-06-TEE, 12R	CI40LAHT126
<input type="checkbox"/> KS4A09-12-HT12	AUF4-12-LHT-12	LCA43-12-TEE, 12R	CI40LAHT1212
<input type="checkbox"/> KS4A09-18-HT12	AUF4-18-LHT-12	LCA43-18-TEE, 12R	CI40LAHT1218
<input type="checkbox"/> KS4A09-24-HT12	AUF4-24-LHT-12	LCA43-24-TEE, 12R	CI40LAHT1224
<input type="checkbox"/> KS4A09-12-HT24	AUF4-12-LHT-24	LCA43-12-TEE, 24R	CI40LAHT2412
<input type="checkbox"/> KS4A09-18-HT24	AUF4-18-LHT-24	LCA43-18-TEE, 24R	CI40LAHT2418
<input type="checkbox"/> KS4A09-24-HT24	AUF4-24-LHT-24	LCA43-24-TEE, 24R	CI40LAHT2424

<b>Vertical Inside/Vertical Outside Bends</b>			
<input type="checkbox"/> KS4A09-06-90VI12	AUF4-06-LVI90-12	LCA43-06-VI90, 12R	CI40LAVI90126
<input type="checkbox"/> KS4A09-12-90VI12	AUF4-12-LVI90-12	LCA43-12-VI90, 12R	CI40LAVI901212
<input type="checkbox"/> KS4A09-18-90VI12	AUF4-18-LVI90-12	LCA43-18-VI90, 12R	CI40LAVI901218
<input type="checkbox"/> KS4A09-24-90VI12	AUF4-24-LVI90-12	LCA43-24-VI90, 12R	CI40LAVI901224
<input type="checkbox"/> KS4A09-12-90VI24	AUF4-12-LVI90-24	LCA43-12-VI90, 24R	CI40LAVI902412
<input type="checkbox"/> KS4A09-18-90VI24	AUF4-18-LVI90-24	LCA43-18-VI90, 24R	CI40LAVI902418
<input type="checkbox"/> KS4A09-24-90VI24	AUF4-24-LVI90-24	LCA43-24-VI90, 24R	CI40LAVI902424
<input type="checkbox"/> KS4A09-06-90VO12	AUF4-06-LVO90-12	LCA43-06-VO90, 12R	CI40LAVO90126
<input type="checkbox"/> KS4A09-12-90VO12	AUF4-12-LVO90-12	LCA43-12-VO90, 12R	CI40LAVO901212
<input type="checkbox"/> KS4A09-18-90VO12	AUF4-18-LVO90-12	LCA43-18-VO90, 12R	CI40LAVO901218
<input type="checkbox"/> KS4A09-24-90VO12	AUF4-24-LVO90-12	LCA43-24-VO90, 12R	CI40LAVO901224
<input type="checkbox"/> KS4A09-12-90VO24	AUF4-12-LVO90-24	LCA43-12-VO90, 24R	CI40LAVO902412
<input type="checkbox"/> KS4A09-18-90VO24	AUF4-18-LVO90-24	LCA43-18-VO90, 24R	CI40LAVO902418
<input type="checkbox"/> KS4A09-24-90VO24	AUF4-24-LVO90-24	LCA43-24-VO90, 24R	CI40LAVO902424

B-Line Part #	Description
<b>Splice Plates</b>	
<input type="checkbox"/> KSA4-SSP	4" Splice Plate
<input type="checkbox"/> KSA4-FSP	4" Flexmount Splice Plate
<input type="checkbox"/> KSA4-VSP	4" Vertical Adjustable Splice Plate

<b>Tab and Lock Trapeze Support</b>	
<input type="checkbox"/> KSA-06CT	6" Tab and Lock Trapeze Hanger
<input type="checkbox"/> KSA-12CT	12" Tab and Lock Trapeze Hanger

<b>Accessories</b>	
<input type="checkbox"/> KSA-SDO-12	12" Side Rail Drop Out
<input type="checkbox"/> KSA-OUT06	6" Rung Drop Out
<input type="checkbox"/> KSA-OUT-12	12" Rung Drop Out
<input type="checkbox"/> KSA-OUT-18	18" Rung Drop Out
<input type="checkbox"/> KSA-OUT-24	24" Rung Drop Out
<input type="checkbox"/> 807A-06-120	6" Solid Flange Cover
<input type="checkbox"/> 807A-12-120	12" Solid Flange Cover
<input type="checkbox"/> 807A-18-120	18" Solid Flange Cover
<input type="checkbox"/> 807A-24-120	24" Solid Flange Cover
<input type="checkbox"/> 9A-9012	Standard Indoor Cover Clamp
<input type="checkbox"/> R4A-DSL-120	4" Side Rail Straight Section Barrier Strip
<input type="checkbox"/> R4A-DHB	4" Side Rail Horizontal Bend Barrier Strip
<input type="checkbox"/> 99-30	Bonding Jumper
<input type="checkbox"/> 9A-2130	Grounding Clamp - UL
<input type="checkbox"/> 9ZN-1241	Heavy Duty Hold Down Bracket



For more information, and to view our larger product offering visit [Eaton.com/KwikSplice](https://Eaton.com/KwikSplice)

\* Splice plate included with all straight sections and fittings

# 24A series aluminum cable tray\*

## B-Line Part #

## Description

### Straight Sections

<input type="checkbox"/>	24A09-06-120	4" Side Rail, 9" Rung Spacing, 6" Width, 120" Length, Aluminum Finish
<input type="checkbox"/>	24A09-12-120	4" Side Rail, 9" Rung Spacing, 12" Width, 120" Length, Aluminum Finish
<input type="checkbox"/>	24A09-18-120	4" Side Rail, 9" Rung Spacing, 18" Width, 120" Length, Aluminum Finish
<input type="checkbox"/>	24A09-24-120	4" Side Rail, 9" Rung Spacing, 24" Width, 120" Length, Aluminum Finish

### Horizontal Bends

<input type="checkbox"/>	4A-06-90HB12	4" Side Rail, 6" Width, 90° Horizontal Bend with 12" Bend Radius
<input type="checkbox"/>	4A-12-90HB12	4" Side Rail, 12" Width, 90° Horizontal Bend with 12" Bend Radius
<input type="checkbox"/>	4A-18-90HB12	4" Side Rail, 18" Width, 90° Horizontal Bend with 12" Bend Radius
<input type="checkbox"/>	4A-24-90HB12	4" Side Rail, 24" Width, 90° Horizontal Bend with 12" Bend Radius
<input type="checkbox"/>	4A-06-90HB24	4" Side Rail, 6" Width, 90° Horizontal Bend with 24" Bend Radius
<input type="checkbox"/>	4A-12-90HB24	4" Side Rail, 12" Width, 90° Horizontal Bend with 24" Bend Radius
<input type="checkbox"/>	4A-18-90HB24	4" Side Rail, 18" Width, 90° Horizontal Bend with 24" Bend Radius
<input type="checkbox"/>	4A-24-90HB24	4" Side Rail, 24" Width, 90° Horizontal Bend with 24" Bend Radius

### Horizontal Tees

<input type="checkbox"/>	4A-06-HT12	4" Side Rail, 6" Width, Horizontal Tee with 12" Bend Radius
<input type="checkbox"/>	4A-12-HT12	4" Side Rail, 12" Width, Horizontal Tee with 12" Bend Radius
<input type="checkbox"/>	4A-18-HT12	4" Side Rail, 18" Width, Horizontal Tee with 12" Bend Radius
<input type="checkbox"/>	4A-24-HT12	4" Side Rail, 24" Width, Horizontal Tee with 12" Bend Radius
<input type="checkbox"/>	4A-06-HT24	4" Side Rail, 6" Width, Horizontal Tee with 24" Bend Radius
<input type="checkbox"/>	4A-12-HT24	4" Side Rail, 12" Width, Horizontal Tee with 24" Bend Radius
<input type="checkbox"/>	4A-18-HT24	4" Side Rail, 18" Width, Horizontal Tee with 24" Bend Radius
<input type="checkbox"/>	4A-24-HT24	4" Side Rail, 24" Width, Horizontal Tee with 24" Bend Radius

### Vertical Inside/Vertical Outside Bends

<input type="checkbox"/>	4A-06-90VI12	4" Side Rail, 6" Width, 90° Vertical Inside with 12" Bend Radius
<input type="checkbox"/>	4A-12-90VI12	4" Side Rail, 12" Width, 90° Vertical Inside with 12" Bend Radius
<input type="checkbox"/>	4A-18-90VI12	4" Side Rail, 18" Width, 90° Vertical Inside with 12" Bend Radius
<input type="checkbox"/>	4A-24-90VI12	4" Side Rail, 24" Width, 90° Vertical Inside with 12" Bend Radius
<input type="checkbox"/>	4A-06-90VI24	4" Side Rail, 6" Width, 90° Vertical Inside with 24" Bend Radius
<input type="checkbox"/>	4A-12-90VI24	4" Side Rail, 12" Width, 90° Vertical Inside with 24" Bend Radius
<input type="checkbox"/>	4A-18-90VI24	4" Side Rail, 18" Width, 90° Vertical Inside with 24" Bend Radius
<input type="checkbox"/>	4A-24-90VI24	4" Side Rail, 24" Width, 90° Vertical Inside with 24" Bend Radius
<input type="checkbox"/>	4A-06-90VO12	4" Side Rail, 6" Width, 90° Vertical Outside with 12" Bend Radius
<input type="checkbox"/>	4A-12-90VO12	4" Side Rail, 12" Width, 90° Vertical Outside with 12" Bend Radius
<input type="checkbox"/>	4A-18-90VO12	4" Side Rail, 18" Width, 90° Vertical Outside with 12" Bend Radius
<input type="checkbox"/>	4A-24-90VO12	4" Side Rail, 24" Width, 90° Vertical Outside with 12" Bend Radius
<input type="checkbox"/>	4A-06-90VO24	4" Side Rail, 6" Width, 90° Vertical Outside with 24" Bend Radius
<input type="checkbox"/>	4A-12-90VO24	4" Side Rail, 12" Width, 90° Vertical Outside with 24" Bend Radius
<input type="checkbox"/>	4A-18-90VO24	4" Side Rail, 18" Width, 90° Vertical Outside with 24" Bend Radius
<input type="checkbox"/>	4A-24-90VO24	4" Side Rail, 24" Width, 90° Vertical Outside with 24" Bend Radius

## B-Line Part #

## Description

### Splice Plates

<input type="checkbox"/>	9A-1004	4" Wedge Lock Splice Plates
<input type="checkbox"/>	9A-1014	4" Expansion Splice Plates
<input type="checkbox"/>	9A-1024	4" Vertical Adjustable Splice Plates

### Accessories

<input type="checkbox"/>	73A-120	Straight Section Barrier
<input type="checkbox"/>	73A-90HBFL	Horizontal Bend Barrier Strip
<input type="checkbox"/>	99-30	Bonding Jumper
<input type="checkbox"/>	9A-1104-6	6" Width Ladder Drop-Out
<input type="checkbox"/>	9A-1104-12	12" Width Ladder Drop-Out
<input type="checkbox"/>	9A-1104-18	18" Width Ladder Drop-Out
<input type="checkbox"/>	9A-1104-24	24" Width Ladder Drop-Out
<input type="checkbox"/>	9A-2130	Grounding Clamp
<input type="checkbox"/>	9A-9012	Standard Cover Clamp
<input type="checkbox"/>	9ZN-1241	Heavy Duty Hold Down Bracket

### Straight Section Covers

<input type="checkbox"/>	807A-06-120	6" Width, 120" Length Solid Flanged Cover
<input type="checkbox"/>	807A-12-120	12" Width, 120" Length Solid Flanged Cover
<input type="checkbox"/>	807A-18-120	18" Width, 120" Length Solid Flanged Cover
<input type="checkbox"/>	807A-24-120	24" Width, 120" Length Solid Flanged Cover

\* Splice plate included with all straight sections and fittings



**Eaton**  
1000 Eaton Boulevard  
Cleveland, OH 44122  
United States  
Eaton.com

© 2021 Eaton  
All Rights Reserved  
Printed in USA  
Publication No. SA302003EN  
June 2021 CANSTKCT

B-Line Division  
509 West Monroe Street  
Highland, IL 62249  
United States  
Phone: 800-851-7415

Eaton.com

Eaton is a registered trademark.

All other trademarks are property of their respective owners.

Follow us on social media to get the latest product and support information.

