

B4R

4" Miniature Non-IC Remodel Housing

Catalog Number:

Project Name:

Type:

Note:



LAMP WATTAGE: (1) MAXIMUM 50W R/PAR20/A19



DESIGNED FOR 2" X 6" JOIST CONSTRUCTION

DESCRIPTION

Small aperture thermally protected, specification grade recessed housing. For remodel application non-insulated ceilings or where insulation can be kept 3" from housing. For fast and easy installation in existing plaster or mechanical ceilings from 1/2" to 1-3/8" thick. Four remodel clips are easily retractable for fixture removal if necessary. Junction box is provided with eight 1/2" KOs and four Romex knockouts with strain relief. Accommodates up to 50W PAR20, R20, and A19 lamps.

SPECIFICATION


A. HOUSING - High temperature painted 22 gauge deep drawn single piece housing. Accommodate lamps up to 50W depending on trim used.

B. SOCKET - Medium base screw shell porcelain socket preinstalled on adjustable mounting bracket is designed to allow usage of different lamp types, as well as proper and consistent lamp positioning.

C. INSTALLATION - Four preinstalled spring clips which secure the housing firmly into ceiling to accommodate different ceiling thicknesses from 1/2" to 1-3/8".

D. JUNCTION BOX - UL for feed through wiring with eight 1/2" KOs and four Romex knockouts with strain relief.

E. THERMAL PROTECTION - Standard thermal protection device guards against improper installation, overlampping and misuse of insulation material.

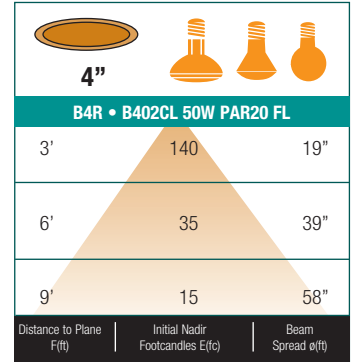

BEAM DIA. MEASURED AT 50% OF NADIR F.C.


FEATURES

- Thermally Protected Non-IC remodel housing.
- Dependable, favorable design and effortless installation.
- Unit slips through 4-1/4" ceiling opening.
- Four preinstalled spring clips which secure the housing firmly into ceiling to accommodate different ceiling thicknesses from 1/2" to 1-3/8".
- Can be installed from below the ceiling.
- 5 1/2" height allows use in 2" x 6" joist construction.
- Preinstalled socket cap provides electrical contact protection against dust, paint and over spray.
- Adjustable socket bracket.

OPTIONS

AIR-SHUT

- Gasket to prevent air flow from heated or air conditioned spaces.
- Meets all national air flow requirements.

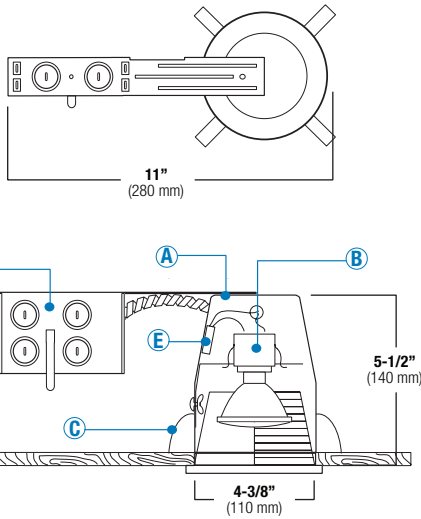

ITEM SELECTOR: (Please check the boxes below for the option desired)

TYPE	AIR-SHUT	OPTION	TRIM TYPE			BAFFLE	REFLECTOR	TRIM/RING	GLASS
B4R	<input type="checkbox"/> AT	<input type="checkbox"/> (W) With quick connects	<input type="checkbox"/> B401 <input type="checkbox"/> B421 <input type="checkbox"/> B402 <input type="checkbox"/> B432 <input type="checkbox"/> B420 <input type="checkbox"/> B496 <input type="checkbox"/> B497 <input type="checkbox"/> B403 <input type="checkbox"/> B461 <input type="checkbox"/> B405 <input type="checkbox"/> B422	<input type="checkbox"/> B406 <input type="checkbox"/> B407 <input type="checkbox"/> B462 <input type="checkbox"/> B452 <input type="checkbox"/> B455 <input type="checkbox"/> B451 <input type="checkbox"/> B454 <input type="checkbox"/> B437 <input type="checkbox"/> B438 <input type="checkbox"/> B439 <input type="checkbox"/> AF401	<input type="checkbox"/> AF402 <input type="checkbox"/> B471 <input type="checkbox"/> B472 <input type="checkbox"/> B473 <input type="checkbox"/> B474 <input type="checkbox"/> B441 <input type="checkbox"/> B443 <input type="checkbox"/> B442 <input type="checkbox"/> B444	<input type="checkbox"/> W <input type="checkbox"/> P <input type="checkbox"/> SN <input type="checkbox"/> CP <input type="checkbox"/> BZ	<input type="checkbox"/> CL <input type="checkbox"/> RG <input type="checkbox"/> W <input type="checkbox"/> MB <input type="checkbox"/> BZ <input type="checkbox"/> CP <input type="checkbox"/> SN <input type="checkbox"/> SHZ	<input type="checkbox"/> WH <input type="checkbox"/> BK <input type="checkbox"/> SN <input type="checkbox"/> CP <input type="checkbox"/> CH <input type="checkbox"/> PB <input type="checkbox"/> BZ	<input type="checkbox"/> Green <input type="checkbox"/> Yellow <input type="checkbox"/> Pink <input type="checkbox"/> Brown <input type="checkbox"/> Navy Blue <input type="checkbox"/> Orange <input type="checkbox"/> Blue <input type="checkbox"/> White <input type="checkbox"/> Red

Specifications:

B4R

AIR-SHUT OPTION TRIM TYPE BAFFLE REFLECTOR TRIM/RING GLASS

BAFFLE	REFLECTOR	TRIM/RING
W White	CL Chrome	WH White
P Black	RG Gold	BK Black
SN Satin Nickel	W White	SN Satin Nickel
CP Copper	MB Black	CP Copper
BZ Bronze	BZ Bronze	CH Chrome
	CP Copper	PB Polish Brass
	SN Satin Nickel	BZ Bronze
	SHZ Satin Haze	

Sample of Catalog Number: B4R-AT-W-B401-W-WH

*For custom baffle, reflector, trim ring, glass color and lens options, please consult factory.



Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions subject to change without notice.

REV: ELITE LIGHTING-SPEC-06-29-2011


4" INCANDESCENT TRIMS

B401CP-CP Phenolic/Metal Stepped Baffle



BAFFLE:
W, P, SN, CP, BZ

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

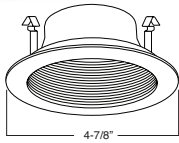

4-7/8"


1 HOUSING COMPATIBILITY GUIDE:

B421SN-SN Stepped Baffle with Socket Bracket



BAFFLE:
W, P, SN, CP, BZ

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

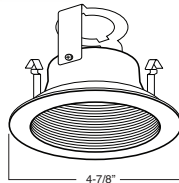

4-7/8"


1 HOUSING COMPATIBILITY GUIDE:

B402CP-WH Reflector



REFLECTOR:
CL, RG, W, MB,
CP, SN, BZ, SHZ

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

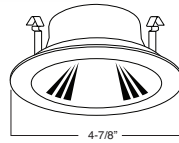

4-7/8"


1 HOUSING COMPATIBILITY GUIDE:

B432RG-WH Reflector with Socket Bracket



REFLECTOR:
CL, RG, W, MB,
CP, SN, BZ, SHZ

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

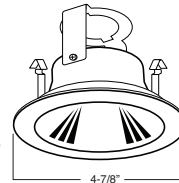

4-7/8"


1 HOUSING COMPATIBILITY GUIDE:

B496P-WH Baffle w/ Adj. Socket Bracket (15° Tilt)



BAFFLE:
W, P, SN, CP, BZ

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

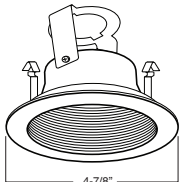

4-7/8"


1 HOUSING COMPATIBILITY GUIDE:

B497CP-WH Reflec. w/ Adj. Socket Bracket (15° Tilt)



REFLECTOR:
CL, RG, W, MB,
CP, SN, BZ

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

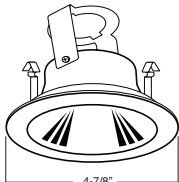


4-7/8"

1 HOUSING COMPATIBILITY GUIDE:

B403WH Eyeball (30° Tilt)



TRIM:
WH, BK, SN, CP, CH,
PB, BZ

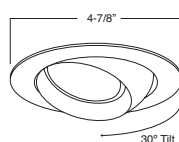


30° Tilt

1 HOUSING COMPATIBILITY GUIDE:

B461PB PAR20 Gimbal Trim (30° Tilt)



TRIM:
WH, BK, SN, CP, CH,
PB, BZ

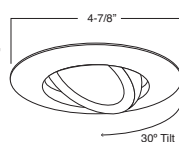


30° Tilt

1 HOUSING COMPATIBILITY GUIDE:

B405WH Slot Aperture



TRIM:
WH, BK, SN, CP, CH,
PB, BZ

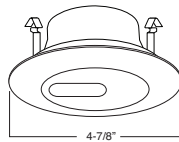


4-7/8"

2 HOUSING COMPATIBILITY GUIDE:

B422WH Pinhole



TRIM:
WH, BK, SN, CP

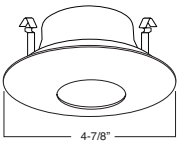

4-7/8"


2 HOUSING COMPATIBILITY GUIDE:

B406P-WH Wall Wash with Baffle



BAFFLE:
W, P, SN, CP, BZ

COVER:
WH, BK

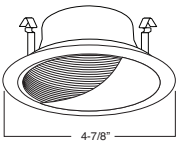

4-7/8"


2 HOUSING COMPATIBILITY GUIDE:

B407CL-WH Wall Wash with Reflector



REFLECTOR:
CL, RG, W, MB,
CP, SN, BZ, SHZ

COVER:
WH, BK

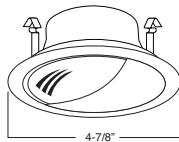

4-7/8"


2 HOUSING COMPATIBILITY GUIDE:

B462CL-WH Semi-Frosted Lens with Reflector



REFLECTOR:
CL, RG, W, MB,
CP, SN, BZ

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

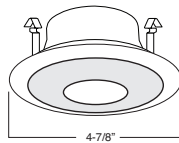


4-7/8"

2 HOUSING COMPATIBILITY GUIDE:

B452CP Albalite Lens



TRIM:
WH, BK, SN, CP, CH,
PB, BZ

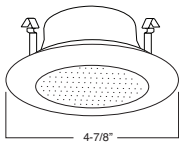


4-7/8"

2 HOUSING COMPATIBILITY GUIDE:

B455PB Fresnel Lens



TRIM:
WH, BK, SN, CP, CH,
PB, BZ

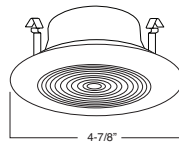


4-7/8"

2 HOUSING COMPATIBILITY GUIDE:

B451PB Drop Opal Lens



TRIM:
WH, BK, SN, CP, CH,
PB, BZ

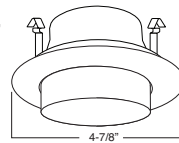

4-7/8"

2 HOUSING COMPATIBILITY GUIDE:

BAFFLE FINISH:
W White
P Black
SN Satin Nickel
CP Copper
BZ Bronze

REFLECTOR FINISH:
CL Chrome
RG Gold
W White
MB Black

BZ Bronze
CP Copper
SN Satin Nickel
SHZ Satin Haze

RING/TRIM FINISH:
WH White
BK Black
SN Satin Nickel
CP Copper

CH Chrome
PB Polish Brass
BZ Bronze

General Lighting

Accent Lighting

Task Lighting

Wall Wash Lighting

Sloped Ceiling Lighting

4 INCH INCANDESCENT TRIMS

4"



Exotic Glass Collection

Elite Lighting now offers a new line of exotic glass trims. The new series of glass trims can elegantly complement any color scheme in any environment. We are certain that with such a wide selection, you will find the perfect colored trim for your project.



B420 - GREEN



B420 - YELLOW



B420 - PINK



B420 - BROWN



B420 - NAVY BLUE



B420 - ORANGE



B420 - BLUE



B420 - WHITE



B420 - RED

B420 - Glass Trim

1 2 3 HOUSING COMPATIBILITY GUIDE:



AVAILABLE EXOTIC GLASS COLORS:
GREEN, YELLOW, PINK, BROWN, NAVY BLUE,
ORANGE, BLUE, WHITE, RED

PATENT #: D570,531



4"

4 INCH INCANDESCENT TRIMS


B454CP-WH Clear Lens with Reflector



FOR WET LOCATION

REFLECTOR:
CL, RG, W, MB,
CP, SN, BZ

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

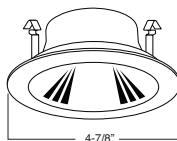

4-7/8"


2 HOUSING COMPATIBILITY GUIDE:

B437WH Smooth Frost Shower Lite



FOR WET LOCATION

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

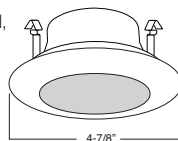

4-7/8"


2 HOUSING COMPATIBILITY GUIDE:

B438WH Designer Point Shower Lite



FOR WET LOCATION

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

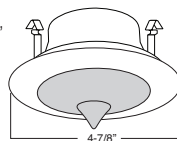

4-7/8"


2 HOUSING COMPATIBILITY GUIDE:

B439WH Smooth Frost Dome Shower Lite



FOR WET LOCATION

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

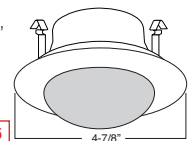

4-7/8"

PATENT #: D509,615

2 HOUSING COMPATIBILITY GUIDE:

BAFFLE FINISH:

- W** White
- P** Black
- SN** Satin Nickel
- CP** Copper
- BZ** Bronze

REFLECTOR FINISH:

- CL** Chrome
- RG** Gold
- W** White
- MB** Black

- BZ** Bronze
- CP** Copper
- SN** Satin Nickel
- SHZ** Satin Haze

RING/TRIM FINISH:

- WH** White
- BK** Black
- SN** Satin Nickel
- CP** Copper
- CH** Chrome
- PB** Polish Brass
- BZ** Bronze

GUIDE	HOUSING COMPATIBILITY	MAX. LAMP WATTAGE
1	B4IC-AT-W, B4-AT-W, B4R-AT-W	50W R/PAR20
2	B4IC-AT-W, B4-AT-W, B4R-AT-W	35W R/PAR20

4" INCANDESCENT TRIMS



AIR SHUT
NEW
CLIP
DESIGN

AF401W-WH
Self Flange Baffle

AIR SHUT

NEW
CLIP
DESIGN



BAFFLE:
W, P, SN, CP, BZ

TRIM:
WH- WHITE SELF
FLANGE

3 HOUSING
COMPATIBILITY
GUIDE:

AF402CP-WH
Self Flange Reflector

AIR SHUT

NEW
CLIP
DESIGN




REFLECTOR:
CL, RG, W, MB, CP

TRIM:
WH- WHITE SELF
FLANGE

3 HOUSING
COMPATIBILITY
GUIDE:

1. Designed to fit most 4" cans
2. Air-Shut baffle/reflector
3. No socket bracket necessary

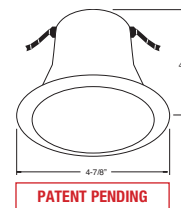

GUIDE	HOUSING COMPATIBILITY	MAX. LAMP WATTAGE
1	B4IC-AT-W, B4-AT-W, B4R-AT-W	50W R/PAR20
2	B4IC-AT-W, B4-AT-W, B4R-AT-W	35W R/PAR20
3	EZ4IC, EZ4, EZ4R	50W R/PAR20

4 INCH INCANDESCENT TRIMS

B471CP-WH
Square Phenolic/Metal Stepped Baffle




BAFFLE:
W, P, SN, CP, BZ

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

PATENT #: D510,151

1 HOUSING
COMPATIBILITY
GUIDE:

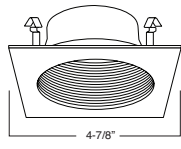

B472SN-WH
Square Baffle w/ Socket Bracket




BAFFLE:
W, P, SN, CP, BZ

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

PATENT #: D510,151

1 HOUSING
COMPATIBILITY
GUIDE:

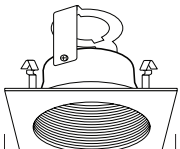

B473CP-WH
Reflector




REFLECTOR:
CL, RG, W, MB,
CP, SN, BZ, SHZ

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

PATENT #: D510,151

1 HOUSING
COMPATIBILITY
GUIDE:

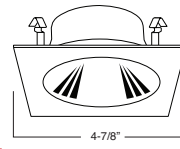

B474CL-WH
Square Reflector w/ Socket Bracket




REFLECTOR:
CL, RG, W, MB,
CP, SN, BZ, SHZ

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

PATENT #: D510,151

1 HOUSING
COMPATIBILITY
GUIDE:

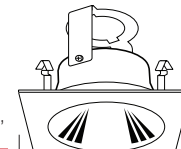


B441WH
Square Eyeball (30° Tilt)



TRIM:
WH, BK, SN, CP, CH,
PB, BZ

PATENT #: D510,151

1 HOUSING
COMPATIBILITY
GUIDE:

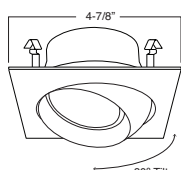


B443WH
Square Slot Aperture



TRIM:
WH, BK, SN, CP, CH,
PB, BZ

PATENT #: D510,151

2 HOUSING
COMPATIBILITY
GUIDE:

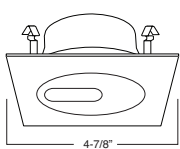


B442WH
PAR20 Gimbal Trim (30° Tilt)



TRIM:
WH, BK, SN, CP, CH,
PB, BZ

PATENT #: D510,151

1 HOUSING
COMPATIBILITY
GUIDE:

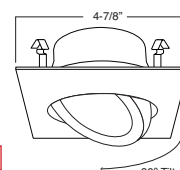

B444CL-WH
Frosted Lens with Reflector




REFLECTOR:
CL, RG, W, MB,
CP, SN

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

PATENT #: D510,151

2 HOUSING
COMPATIBILITY
GUIDE:

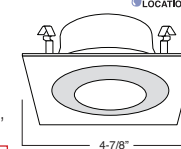

BAFFLE FINISH:
W White
P Black
SN Satin Nickel
CP Copper
BZ Bronze

REFLECTOR FINISH:
CL Chrome
RG Gold
W White
MB Black

BZ Bronze
CP Copper
SN Satin Nickel
SHZ Satin Haze

RING/TRIM FINISH:
WH White
BK Black
SN Satin Nickel
CP Copper

CH Chrome
PB Polish Brass
BZ Bronze

General Lighting
 Wall Wash Lighting

Accent Lighting
 Sloped Ceiling Lighting

Task Lighting

B4R

4" Miniature Non-IC Remodel Housing

LAMP WATTAGE: (1) MAXIMUM 50W R/PAR20/A19

Catalog Number:

Project Name:

Type:

Note:



DESIGNED FOR 2" X 6" JOIST CONSTRUCTION

DESCRIPTION

Small aperture thermally protected, specification grade recessed housing. For remodel application non-insulated ceilings or where insulation can be kept 3" from housing. For fast and easy installation in existing plaster or mechanical ceilings from 1/2" to 1-3/8" thick. Four remodel clips are easily retractable for fixture removal if necessary. Junction box is provided with eight 1/2" KOs and four Romex knockouts with strain relief. Accommodates up to 50W PAR20, R20, and A19 lamps.

SPECIFICATION



A. HOUSING - High temperature painted 22 gauge deep drawn single piece housing. Accommodate lamps up to 50W depending on trim used.

B. SOCKET - Medium base screw shell porcelain socket preinstalled on adjustable mounting bracket is designed to allow usage of different lamp types, as well as proper and consistent lamp positioning.

C. INSTALLATION - Four preinstalled spring clips which secure the housing firmly into ceiling to accommodate different ceiling thicknesses from 1/2" to 1-3/8".

D. JUNCTION BOX - UL for feed through wiring with eight 1/2" KOs and four Romex knockouts with strain relief.

E. THERMAL PROTECTION - Standard thermal protection device guards against improper installation, overlampping and misuse of insulation material.

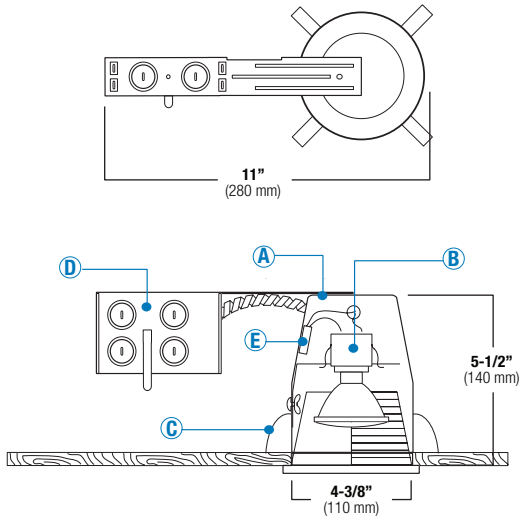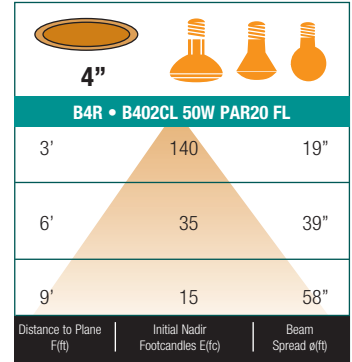

FEATURES

- Thermally Protected Non-IC remodel housing.
- Dependable, favorable design and effortless installation.
- Unit slips through 4-1/4" ceiling opening.
- Four preinstalled spring clips which secure the housing firmly into ceiling to accommodate different ceiling thicknesses from 1/2" to 1-3/8".
- Can be installed from below the ceiling.
- 5 1/2" height allows use in 2" x 6" joist construction.
- Preinstalled socket cap provides electrical contact protection against dust, paint and over spray.
- Adjustable socket bracket.

OPTIONS

AIR-SHUT

- Gasket to prevent air flow from heated or air conditioned spaces.
- Meets all national air flow requirements.



ITEM SELECTOR: (Please check the boxes below for the option desired)

TYPE	AIR-SHUT	OPTION	TRIM TYPE			BAFFLE	REFLECTOR	TRIM/RING	GLASS
B4R	<input type="checkbox"/> AT	<input type="checkbox"/> (W) With quick connects	<input type="checkbox"/> B401 <input type="checkbox"/> B421 <input type="checkbox"/> B402 <input type="checkbox"/> B432 <input type="checkbox"/> B420 <input type="checkbox"/> B496 <input type="checkbox"/> B497 <input type="checkbox"/> B403 <input type="checkbox"/> B461 <input type="checkbox"/> B405 <input type="checkbox"/> B422	<input type="checkbox"/> B406 <input type="checkbox"/> B407 <input type="checkbox"/> B462 <input type="checkbox"/> B452 <input type="checkbox"/> B455 <input type="checkbox"/> B451 <input type="checkbox"/> B454 <input type="checkbox"/> B437 <input type="checkbox"/> B438 <input type="checkbox"/> B439 <input type="checkbox"/> AF401	<input type="checkbox"/> AF402 <input type="checkbox"/> B471 <input type="checkbox"/> B472 <input type="checkbox"/> B473 <input type="checkbox"/> B474 <input type="checkbox"/> B441 <input type="checkbox"/> B443 <input type="checkbox"/> B442 <input type="checkbox"/> B444	<input type="checkbox"/> W <input type="checkbox"/> P <input type="checkbox"/> SN <input type="checkbox"/> CP <input type="checkbox"/> BZ	<input type="checkbox"/> CL <input type="checkbox"/> RG <input type="checkbox"/> W <input type="checkbox"/> MB <input type="checkbox"/> BZ <input type="checkbox"/> CP <input type="checkbox"/> SN <input type="checkbox"/> SHZ	<input type="checkbox"/> WH <input type="checkbox"/> BK <input type="checkbox"/> SN <input type="checkbox"/> CP <input type="checkbox"/> CH <input type="checkbox"/> PB <input type="checkbox"/> BZ	<input type="checkbox"/> Green <input type="checkbox"/> Yellow <input type="checkbox"/> Pink <input type="checkbox"/> Brown <input type="checkbox"/> Navy Blue <input type="checkbox"/> Orange <input type="checkbox"/> Blue <input type="checkbox"/> White <input type="checkbox"/> Red

Specifications:

B4R

AIR-SHUT OPTION TRIM TYPE BAFFLE REFLECTOR TRIM/RING GLASS

BAFFLE	REFLECTOR	TRIM/RING
W White	CL Chrome	WH White
P Black	RG Gold	BK Black
SN Satin Nickel	W White	SN Satin Nickel
CP Copper	MB Black	CP Copper
BZ Bronze	BZ Bronze	CH Chrome
	CP Copper	PB Polish Brass
	SN Satin Nickel	BZ Bronze
	SHZ Satin Haze	

Sample of Catalog Number: B4R-AT-W-B401-W-WH

*For custom baffle, reflector, trim ring, glass color and lens options, please consult factory.



Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions subject to change without notice.

REV: ELITE LIGHTING-SPEC-06-29-2011


4" INCANDESCENT TRIMS

B401CP-CP Phenolic/Metal Stepped Baffle



BAFFLE:
W, P, SN, CP, BZ

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

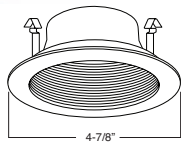


1 HOUSING COMPATIBILITY GUIDE:

B421SN-SN Stepped Baffle with Socket Bracket



BAFFLE:
W, P, SN, CP, BZ

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

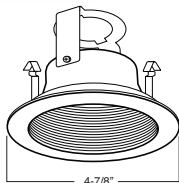


1 HOUSING COMPATIBILITY GUIDE:

B402CP-WH Reflector



REFLECTOR:
CL, RG, W, MB,
CP, SN, BZ, SHZ

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

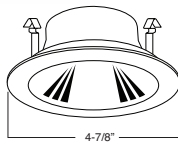


1 HOUSING COMPATIBILITY GUIDE:

B432RG-WH Reflector with Socket Bracket



REFLECTOR:
CL, RG, W, MB,
CP, SN, BZ, SHZ

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

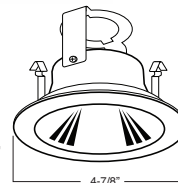


1 HOUSING COMPATIBILITY GUIDE:

B496P-WH Baffle w/ Adj. Socket Bracket (15° Tilt)



BAFFLE:
W, P, SN, CP, BZ

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

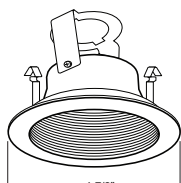


1 HOUSING COMPATIBILITY GUIDE:

B497CP-WH Reflec. w/ Adj. Socket Bracket (15° Tilt)



REFLECTOR:
CL, RG, W, MB,
CP, SN, BZ

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

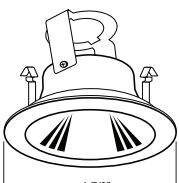


1 HOUSING COMPATIBILITY GUIDE:

B403WH Eyeball (30° Tilt)



TRIM:
WH, BK, SN, CP, CH,
PB, BZ

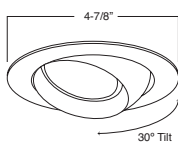


1 HOUSING COMPATIBILITY GUIDE:

B461PB PAR20 Gimbal Trim (30° Tilt)



TRIM:
WH, BK, SN, CP, CH,
PB, BZ

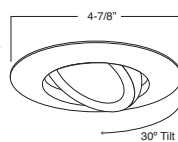


1 HOUSING COMPATIBILITY GUIDE:

B405WH Slot Aperture



TRIM:
WH, BK, SN, CP, CH,
PB, BZ

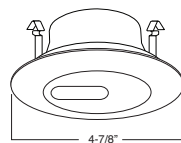


2 HOUSING COMPATIBILITY GUIDE:

B422WH Pinhole



TRIM:
WH, BK, SN, CP

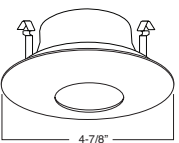


2 HOUSING COMPATIBILITY GUIDE:

B406P-WH Wall Wash with Baffle



BAFFLE:
W, P, SN, CP, BZ

COVER:
WH, BK

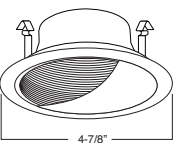


2 HOUSING COMPATIBILITY GUIDE:

B407CL-WH Wall Wash with Reflector



REFLECTOR:
CL, RG, W, MB,
CP, SN, BZ, SHZ

COVER:
WH, BK

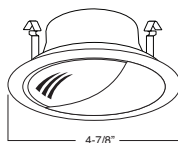


2 HOUSING COMPATIBILITY GUIDE:

B462CL-WH Semi-Frosted Lens with Reflector



REFLECTOR:
CL, RG, W, MB,
CP, SN, BZ

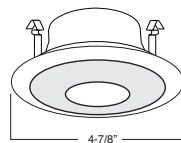


2 HOUSING COMPATIBILITY GUIDE:

B452CP Albalite Lens



TRIM:
WH, BK, SN, CP, CH,
PB, BZ

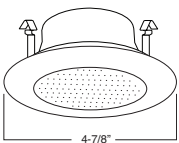


2 HOUSING COMPATIBILITY GUIDE:

B455PB Fresnel Lens



TRIM:
WH, BK, SN, CP, CH,
PB, BZ

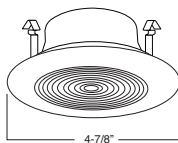


2 HOUSING COMPATIBILITY GUIDE:

B451PB Drop Opal Lens



TRIM:
WH, BK, SN, CP, CH,
PB, BZ

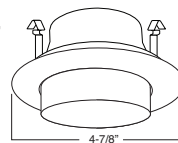

2 HOUSING COMPATIBILITY GUIDE:

BAFFLE FINISH:
W White
P Black
SN Satin Nickel
CP Copper
BZ Bronze

REFLECTOR FINISH:
CL Chrome
RG Gold
W White
MB Black

BZ Bronze
CP Copper
SN Satin Nickel
SHZ Satin Haze

RING/TRIM FINISH:
WH White
BK Black
SN Satin Nickel
CP Copper

CH Chrome
PB Polish Brass
BZ Bronze

General Lighting

Wall Wash Lighting

Accent Lighting

Sloped Ceiling Lighting

Task Lighting

4 INCH INCANDESCENT TRIMS

4"



Exotic Glass Collection

Elite Lighting now offers a new line of exotic glass trims. The new series of glass trims can elegantly complement any color scheme in any environment. We are certain that with such a wide selection, you will find the perfect colored trim for your project.



B420 - GREEN



B420 - YELLOW



B420 - PINK



B420 - BROWN



B420 - NAVY BLUE



B420 - ORANGE



B420 - BLUE



B420 - WHITE



B420 - RED

B420 - Glass Trim

1 2 3 HOUSING COMPATIBILITY GUIDE:



AVAILABLE EXOTIC GLASS COLORS:
GREEN, YELLOW, PINK, BROWN, NAVY BLUE,
ORANGE, BLUE, WHITE, RED

PATENT #: D570,531



4 INCH INCANDESCENT TRIMS

B454CP-WH Clear Lens with Reflector

REFLECTOR:
CL, RG, W, MB,
CP, SN, BZ

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

FOR WET LOCATION

2 HOUSING COMPATIBILITY GUIDE:

B437WH Smooth Frost Shower Lite

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

FOR WET LOCATION

2 HOUSING COMPATIBILITY GUIDE:

B438WH Designer Point Shower Lite

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

FOR WET LOCATION

2 HOUSING COMPATIBILITY GUIDE:

B439WH Smooth Frost Dome Shower Lite

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

FOR WET LOCATION

PATENT #: D509,615

2 HOUSING COMPATIBILITY GUIDE:

BAFFLE FINISH:
W White
P Black
SN Satin Nickel
CP Copper
BZ Bronze

REFLECTOR FINISH:
CL Chrome
RG Gold
W White
MB Black

BZ Bronze
CP Copper
SN Satin Nickel
SHZ Satin Haze

RING/TRIM FINISH:
WH White
BK Black
SN Satin Nickel
CP Copper

CH Chrome
PB Polish Brass
BZ Bronze

GUIDE	HOUSING COMPATIBILITY	MAX. LAMP WATTAGE
1	B4IC-AT-W, B4-AT-W, B4R-AT-W	50W R/PAR20
2	B4IC-AT-W, B4-AT-W, B4R-AT-W	35W R/PAR20

4" INCANDESCENT TRIMS



AIR SHUT
NEW
CLIP
DESIGN

AF401W-WH
Self Flange Baffle

AIR SHUT

NEW
CLIP
DESIGN



BAFFLE:
W, P, SN, CP, BZ

TRIM:
WH- WHITE SELF
FLANGE

3 HOUSING
COMPATIBILITY
GUIDE:

AF402CP-WH
Self Flange Reflector

AIR SHUT

NEW
CLIP
DESIGN




REFLECTOR:
CL, RG, W, MB, CP

TRIM:
WH- WHITE SELF
FLANGE

3 HOUSING
COMPATIBILITY
GUIDE:

1. Designed to fit most 4" cans
2. Air-Shut baffle/reflector
3. No socket bracket necessary

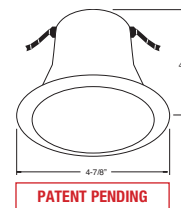

GUIDE	HOUSING COMPATIBILITY	MAX. LAMP WATTAGE
1	B4IC-AT-W, B4-AT-W, B4R-AT-W	50W R/PAR20
2	B4IC-AT-W, B4-AT-W, B4R-AT-W	35W R/PAR20
3	EZ4IC, EZ4, EZ4R	50W R/PAR20

4 INCH INCANDESCENT TRIMS

B471CP-WH
Square Phenolic/Metal Stepped Baffle




BAFFLE:
W, P, SN, CP, BZ

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

PATENT #: D510,151

1 HOUSING
COMPATIBILITY
GUIDE:

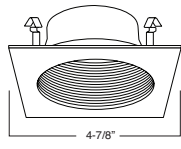

B472SN-WH
Square Baffle w/ Socket Bracket




BAFFLE:
W, P, SN, CP, BZ

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

PATENT #: D510,151

1 HOUSING
COMPATIBILITY
GUIDE:

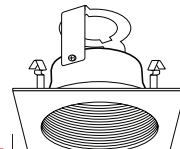

B473CP-WH
Reflector




REFLECTOR:
CL, RG, W, MB,
CP, SN, BZ, SHZ

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

PATENT #: D510,151

1 HOUSING
COMPATIBILITY
GUIDE:

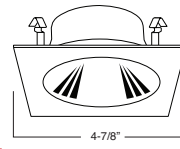

B474CL-WH
Square Reflector w/ Socket Bracket




REFLECTOR:
CL, RG, W, MB,
CP, SN, BZ, SHZ

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

PATENT #: D510,151

1 HOUSING
COMPATIBILITY
GUIDE:

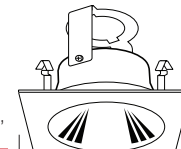


B441WH
Square Eyeball (30° Tilt)



TRIM:
WH, BK, SN, CP, CH,
PB, BZ

PATENT #: D510,151

1 HOUSING
COMPATIBILITY
GUIDE:

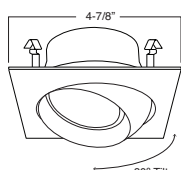


B443WH
Square Slot Aperture



TRIM:
WH, BK, SN, CP, CH,
PB, BZ

PATENT #: D510,151

2 HOUSING
COMPATIBILITY
GUIDE:

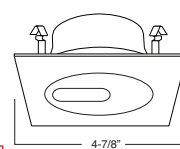


B442WH
PAR20 Gimbal Trim (30° Tilt)



TRIM:
WH, BK, SN, CP, CH,
PB, BZ

PATENT #: D510,151

1 HOUSING
COMPATIBILITY
GUIDE:

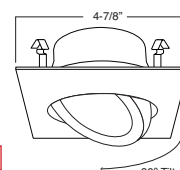

B444CL-WH
Frosted Lens with Reflector




REFLECTOR:
CL, RG, W, MB,
CP, SN

TRIM:
WH, BK, SN, CP, CH,
PB, BZ

PATENT #: D510,151

2 HOUSING
COMPATIBILITY
GUIDE:

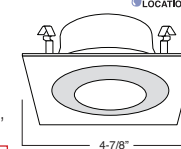

BAFFLE FINISH:
W White
P Black
SN Satin Nickel
CP Copper
BZ Bronze

REFLECTOR FINISH:
CL Chrome
RG Gold
W White
MB Black

BZ Bronze
CP Copper
SN Satin Nickel
SHZ Satin Haze

RING/TRIM FINISH:
WH White
BK Black
SN Satin Nickel
CP Copper

CH Chrome
PB Polish Brass
BZ Bronze

General Lighting
 Wall Wash Lighting

Accent Lighting
 Sloped Ceiling Lighting

Task Lighting