



# B6RIC

## 6" Universal IC Remodel Housing

LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30



DESIGNED FOR 2" X 8" JOIST CONSTRUCTION

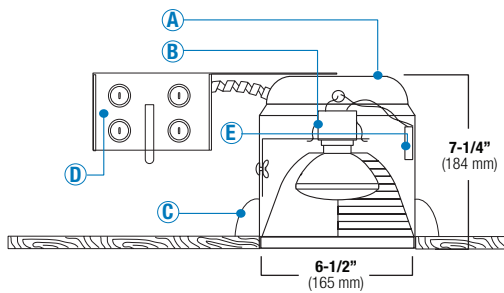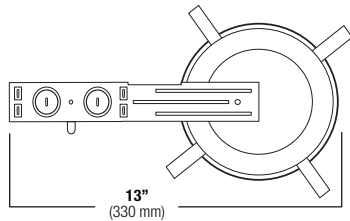

ITEM SELECTOR: (Please check the boxes below for the option desired)

TYPE	AIR-SHUT	OPTION	TRIM TYPE						BAFFLE	REFLECTOR	TRIM/RING	GLASS
B6RIC	<input type="checkbox"/> AT	<input type="checkbox"/> (W) With quick connects	<input type="checkbox"/> B630	<input type="checkbox"/> B609	<input type="checkbox"/> B606L	<input type="checkbox"/> B676	<input type="checkbox"/> B651	<input type="checkbox"/> B688	<input type="checkbox"/> W	<input type="checkbox"/> CL	<input type="checkbox"/> WH	<input type="checkbox"/> Green
			<input type="checkbox"/> B620	<input type="checkbox"/> B619	<input type="checkbox"/> B635	<input type="checkbox"/> B612	<input type="checkbox"/> B611	<input type="checkbox"/> B685	<input type="checkbox"/> P	<input type="checkbox"/> RG	<input type="checkbox"/> BK	<input type="checkbox"/> Yellow
			<input type="checkbox"/> B631	<input type="checkbox"/> B646	<input type="checkbox"/> B636	<input type="checkbox"/> B645	<input type="checkbox"/> B647	<input type="checkbox"/> B696	<input type="checkbox"/> SN	<input type="checkbox"/> W	<input type="checkbox"/> SN	<input type="checkbox"/> Pink
			<input type="checkbox"/> AF637	<input type="checkbox"/> B616	<input type="checkbox"/> B642	<input type="checkbox"/> B648	<input type="checkbox"/> B644	<input type="checkbox"/> B689	<input type="checkbox"/> CP	<input type="checkbox"/> MB	<input type="checkbox"/> CP	<input type="checkbox"/> Brown
			<input type="checkbox"/> AF631	<input type="checkbox"/> B663	<input type="checkbox"/> B641	<input type="checkbox"/> B652	<input type="checkbox"/> B650	<input type="checkbox"/> B680	<input type="checkbox"/> BZ	<input type="checkbox"/> BZ	<input type="checkbox"/> CH	<input type="checkbox"/> Navy Blue
			<input type="checkbox"/> AF639	<input type="checkbox"/> B673	<input type="checkbox"/> B656	<input type="checkbox"/> B603	<input type="checkbox"/> B622			<input type="checkbox"/> CP	<input type="checkbox"/> PB	<input type="checkbox"/> Orange
			<input type="checkbox"/> AF640	<input type="checkbox"/> B683	<input type="checkbox"/> B657	<input type="checkbox"/> B615	<input type="checkbox"/> B625			<input type="checkbox"/> SN	<input type="checkbox"/> BZ	<input type="checkbox"/> Blue
			<input type="checkbox"/> AF632	<input type="checkbox"/> B601	<input type="checkbox"/> B637	<input type="checkbox"/> B633	<input type="checkbox"/> B624			<input type="checkbox"/> SHZ		<input type="checkbox"/> White
			<input type="checkbox"/> B610	<input type="checkbox"/> B601L	<input type="checkbox"/> B643	<input type="checkbox"/> B649	<input type="checkbox"/> B681					<input type="checkbox"/> Red
			<input type="checkbox"/> B607	<input type="checkbox"/> B605	<input type="checkbox"/> B658	<input type="checkbox"/> AF633	<input type="checkbox"/> B687					
			<input type="checkbox"/> B608	<input type="checkbox"/> B605L	<input type="checkbox"/> B659	<input type="checkbox"/> B225	<input type="checkbox"/> B682					
			<input type="checkbox"/> B602	<input type="checkbox"/> B606	<input type="checkbox"/> B675	<input type="checkbox"/> B653	<input type="checkbox"/> B693					

### Specifications:

B6RIC

AIR-SHUT	OPTION	TRIM TYPE	BAFFLE	REFLECTOR	TRIM/RING	GLASS
----------	--------	-----------	--------	-----------	-----------	-------

BAFFLE	REFLECTOR	TRIM/RING
W White	CL Chrome	WH White
P Black	RG Gold	BK Black
SN Satin Nickel	W White	SN Satin Nickel
CP Copper	MB Black	CP Copper
BZ Bronze	BZ Bronze	CH Chrome
	CP Copper	PB Polish Brass
	SN Satin Nickel	BZ Bronze
	SHZ Satin Haze	

Sample of Catalog Number: B6RIC-AT-W-B630-W-WH

\*For custom baffle, reflector, trim ring, glass color and lens options, please consult factory.



Submittal form is available @ [www.iuseelite.com](http://www.iuseelite.com)  
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions subject to change without notice.

REV: ELITE LIGHTING-SPEC-06-29-2011

Catalog Number:

Project Name:

Type:

Note:



### DESCRIPTION

Thermally protected, IC rated specification grade remodel recessed housing. For remodeling installations where housing will be in direct contact with insulation. For fast and easy installation in existing plaster or mechanical ceilings from 1/2" to 1-3/8" thick. Four remodel clips are easily retractable for fixture removal if necessary. Junction box is provided with eight 1/2" KOs and four Romex knockouts with strain relief. Accommodates up to 75W PAR30, BR30, and A19 lamps.

### SPECIFICATION


**A. HOUSING** - Die-formed, all aluminum construction for maximum heat dissipation and rust protection.

**B. SOCKET** - Medium base screw shell porcelain socket preinstalled on adjustable mounting bracket is designed to allow usage of different lamp types, as well as proper and consistent lamp positioning.

**C. INSTALLATION** - Four preinstalled spring clips which secure the housing firmly into ceiling to accommodate different ceiling thicknesses from 1/2" to 1-3/8".

**D. JUNCTION BOX** - UL listed for through-branch circuit wiring, provided with eight 1/2" KOs and four Romex knockouts with strain relief.

**E. THERMAL PROTECTION** - Standard thermal protection device guards against improper installation, overlamping and misuse of insulation material.

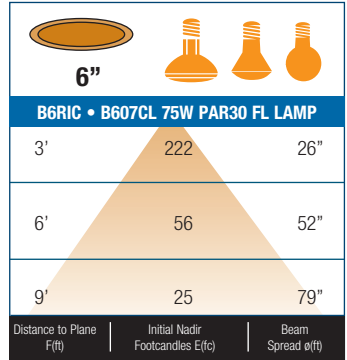

BEAM DIA. MEASURED AT 50% OF NADIR F.C.

### FEATURES

- Thermally Protected remodel IC housing.
- Dependable, favorable design and effortless installation.
- Unit slips through 6-1/2" ceiling opening.
- Four preinstalled spring clips which secure the housing firmly into ceiling to accommodate different ceiling thickness from 1/2" to 1-3/8".
- Can be installed from below the ceiling.
- 7-1/4" height allows use in 2" x 8" joist construction.
- Wire through junction box.
- Adjustable socket bracket.
- Preinstalled socket cap provides electrical contact protection against dust, paint and over spray.

### OPTIONS

#### AIR-SHUT

- Gasket to prevent air flow from heated or air conditioned spaces.
- Meets all national air flow requirements.

# 6" Incandescent Trims

(LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)


Catalog Number:

Project Name:

Type:

Note:



<p><b>B630CP-CP</b> METAL STEPPED BAFFLE R30/PAR30</p>  <p><b>BAFFLE FINISH:</b> W, P, SN, CP, BZ</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p>  <p>7-1/4"</p>	<p><b>B620-ORANGE</b> GLASS TRIM</p>  <p><b>GLASS FINISH:</b> GREEN, YELLOW, PINK, BROWN, NAVY BLUE, ORANGE, WHITE, RED</p>  <p>7-1/4"</p>	<p><b>B631P-WH</b> R30 PREMIUM PHENOLIC BAFFLE / METAL RING</p>  <p><b>BAFFLE FINISH:</b> W, P</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p>  <p>7-1/4"</p>	<p><b>AF637W-WH</b> SELF FLANGE AIR-SHUT BAFFLE</p>  <p><b>AVAILABLE COLOR COMBINATIONS:</b> W-WH, P-WH, P-BK, SN-SN, CP-CP, BZ-BZ</p>  <p>7-1/4"</p>
<p><b>AF631W-WH</b> SELF FLANGE AIR-SHUT BAFFLE</p>  <p><b>AVAILABLE COLOR COMBINATIONS:</b> W-WH, P-WH, P-BK, SN-SN, CP-CP, BZ-BZ</p>  <p>7-1/4"</p>	<p><b>AF639W-WH</b> SELF FLANGE AIR-SHUT BAFFLE</p>  <p><b>AVAILABLE COLOR COMBINATIONS:</b> W-WH</p> <p><b>MATT WHITE FINISH</b></p>  <p>7-1/4"</p>	<p><b>AF640W-WH</b> DEEP SELF FLANGE AIR-SHUT BAFFLE</p>  <p><b>AVAILABLE COLOR COMBINATIONS:</b> W-WH, P-WH, SN-SN, CP-CP, BZ-BZ</p>  <p>7-1/4"</p>	<p><b>AF632RG-WH</b> AIR-SHUT REFLECTOR</p>  <p><b>AVAILABLE COLOR COMBINATIONS:</b> CL-WH, CL-CH, RG-WH, W-WH, MB-WH, CP-CP, SN-SN</p>  <p>7-1/4"</p>
<p><b>B610P-RG-WH</b> CONE REFLECTOR/BAFFLE TRIM</p>  <p><b>BAFFLE FINISH:</b> W, P</p> <p><b>REFLECTOR FINISH:</b> CL, RG</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p>  <p>7-1/4"</p>	<p><b>B607CP-WH</b> REFLECTOR R/PAR30</p>  <p><b>REFLECTOR FINISH:</b> CL, RG, W, MB, CP, SN, BZ, SHZ</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p>  <p>7-1/4"</p>	<p><b>B608CL-WH</b> CONE REFLECTOR A19</p>  <p><b>REFLECTOR FINISH:</b> CL, RG, W, MB, CP, SN, BZ, SHZ</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p>  <p>7-1/4"</p>	<p><b>B602SN</b> EYEBALL</p>  <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p>  <p>8" 30° TILT 359° ROTATION</p>
<p><b>B609W-WH</b> REGRESSED EYEBALL WITH BAFFLE</p>  <p><b>BAFFLE FINISH:</b> W, P, SN, CP, BZ</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> <p><b>EYEBALL FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p>  <p>7-1/4" 30° TILT 359° ROTATION</p>	<p><b>B619RG-PB</b> REGRESSED EYEBALL WITH REFLECTOR</p>  <p><b>REFLECTOR FINISH:</b> CL, RG, W, MB, CP, SN</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> <p><b>EYEBALL FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p>  <p>7-1/4" 30° TILT 359° ROTATION</p>	<p><b>B646P-WH</b> EYEBALL WITH BAFFLE</p>  <p><b>BAFFLE FINISH:</b> W, P</p> <p><b>TRIM/RING FINISH:</b> WH</p>  <p>8" 30° TILT 359° ROTATION</p>	<p><b>B616W-WH</b> PAR20 REGRESSED EYEBALL W/ BAFFLE</p>  <p><b>BAFFLE FINISH:</b> W, P, SN, CP, BZ</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> <p><b>EYEBALL FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p>  <p>7-1/4" 30° TILT 359° ROTATION</p>

# 6" Incandescent Trims

(LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:



<p><b>B663PB</b> PAR30 GIMBAL RING</p>  <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> 	<p><b>B673P-WH</b> PAR30 BAFFLE W/ GIMBAL RING</p>  <p><b>BAFFLE FINISH:</b> W, P, SN, CP, BZ</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> 	<p><b>B683CL-WH</b> PAR30 REFLECTOR W/ GIMBAL RING</p>  <p><b>REFLECTOR FINISH:</b> CL, RG, W, MB, CP, SN</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> 	<p><b>B601CP</b> METAL ALBALITE LENS</p>  <p><b>LENS:</b> ALBALITE</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> 
<p><b>B601L</b> PLASTIC ALBALITE LENS</p>  <p><b>LENS:</b> ALBALITE</p> <p><b>TRIM/RING FINISH:</b> WHITE PLASTIC</p> 	<p><b>B605PB</b> METAL FRESNEL LENS</p>  <p><b>LENS:</b> FRESNEL</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> 	<p><b>B605L</b> PLASTIC FRESNEL LENS</p>  <p><b>LENS:</b> FRESNEL</p> <p><b>TRIM/RING FINISH:</b> WHITE PLASTIC</p> 	<p><b>B606CP</b> METAL DROP OPAL LENS</p>  <p><b>LENS:</b> DROP OPAL</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> 
<p><b>B606L</b> PLASTIC DROP OPAL LENS</p>  <p><b>LENS:</b> DROP OPAL</p> <p><b>TRIM/RING FINISH:</b> WHITE PLASTIC</p> 	<p><b>B635P-WH</b> BAFFLE W/ ALBALITE LENS</p>  <p><b>BAFFLE FINISH:</b> W, P, SN, CP, BZ</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> 	<p><b>B636W-WH</b> BAFFLE W/ FRESNEL LENS</p>  <p><b>BAFFLE FINISH:</b> W, P, SN, CP, BZ</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> 	<p><b>B642CL-WH</b> REFLECTOR W/ FRESNEL LENS</p>  <p><b>REFLECTOR FINISH:</b> CL, RG, W, MB, CP, SN, SHZ</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> 
<p><b>B641RG-WH</b> REFLECTOR W/ ALBALITE LENS</p>  <p><b>REFLECTOR FINISH:</b> CL, RG, W, MB, CP, SN, SHZ</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> 	<p><b>B656W-WH</b> BAFFLE W/ FROSTED DOME SHOWER LENS</p>  <p><b>BAFFLE FINISH:</b> W, P, SN, CP, BZ</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> 	<p><b>B657CL-WH</b> REFLECTOR W/ FROSTED DOME SHOWER LENS</p>  <p><b>REFLECTOR FINISH:</b> CL, RG, W, MB, CP, SN, SHZ</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> 	<p><b>B637W-WH</b> BAFFLE W/ DROP OPAL LENS</p>  <p><b>BAFFLE FINISH:</b> W, P, SN, CP, BZ</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> 

# 6" Incandescent Trims

(LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:




**B643RG-WH**  
REFLECTOR W/ DROP OPAL LENS



**REFLECTOR FINISH:**  
CL, RG, W, MB, CP,  
SN, SHZ

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

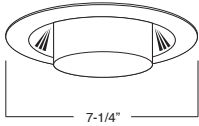


**B658CL-WH**  
REFLECTOR W/ PRISMATIC LENS



**REFLECTOR FINISH:**  
CL, RG, W, MB, CP,  
SN, SHZ

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

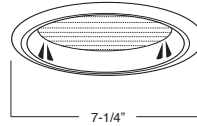


**B659CL-WH**  
REFLECTOR W/ FROSTED LENS



**REFLECTOR FINISH:**  
CL, RG, W, MB, CP,  
SN, SHZ

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

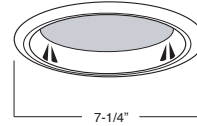


**B675W-WH**  
BAFFLE W/ PRISMATIC LENS



**BAFFLE FINISH:**  
W, P, SN, CP, BZ

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

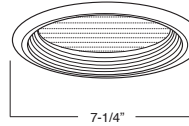


**B676W-WH**  
BAFFLE W/ FROSTED LENS



**BAFFLE FINISH:**  
W, P, SN, CP, BZ

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

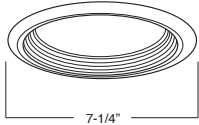


**B612WH**  
SMOOTH FROST DOME SHOWER LENS



**LENS:**  
FROSTED

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

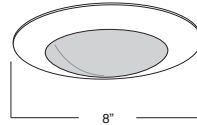


**B645WH**  
DESIGNER POINT SHOWER LENS



**LENS:**  
FROSTED/CLEAR

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

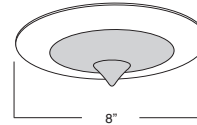


**B648WH**  
DESIGNER CONE SHOWER LENS



**LENS:**  
FROSTED

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

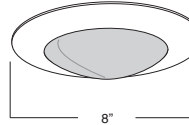


**B652WH**  
SMOOTH FROST SHOWER LENS




**LENS:**  
FROSTED


**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

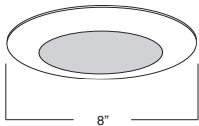

**B603CP**  
R/PAR30 OPEN TRIM

 


**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

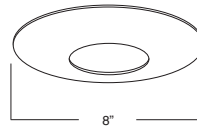

**B615WH**  
DESIGNER PINHOLE




**TRIM/RING FINISH:**  
WH, BK

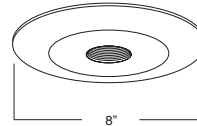

**B633WH**  
R/PAR30 SPLAY TRIM



**TRIM/RING FINISH:**  
WH, BK

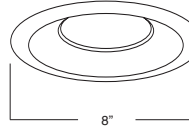


**B649RG-WH**  
PAR20 REFLECTOR




**REFLECTOR FINISH:**  
CL, RG, W, MB,  
CP, SN


**TRIM/RING FINISH:**  
WH, BK

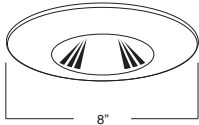

**AF633CH**  
R/PAR30 OPEN TRIM

 

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

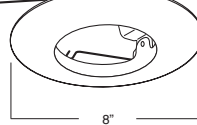


**B225WH**  
OPEN TRIM STEPPED BAFFLE




**BAFFLE FINISH:**  
W, P

**TRIM/RING FINISH:**  
WH

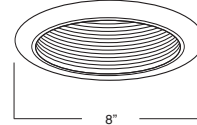


**B653W-WH**  
BAFFLE WITH BAFFLE

 

**BAFFLE FINISH:**  
W, P

**TRIM/RING FINISH:**  
WH, BK, SN, CP,  
CH, PB

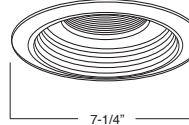

# 6" Incandescent Trims

(LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:



<p><b>B651P-WH</b> PAR20 STEPPED BAFFLE</p>   <p><b>BAFFLE FINISH:</b> W, P, SN, CP, BZ</p> <p><b>TRIM/RING FINISH:</b> WH, BK</p> <p>8"</p>	<p><b>B611W-WH</b> PAR30 BAFFLE WALL WASH</p>   <p><b>AVAILABLE COLOR COMBINATIONS:</b> W-WH, P-WH, SN-SN, CP-CP, BZ-BZ</p> <p><b>COVER FINISH:</b> WH, BK</p> <p>7-1/4"</p>	<p><b>B647P-WH</b> DESIGNER BAFFLE WALL WASH PAR20</p>   <p><b>BAFFLE FINISH:</b> W, P, SN, CP, BZ</p> <p><b>TRIM/RING FINISH:</b> WH</p> <p>8"</p>	<p><b>B644RG-WH</b> DESIGNER REFLECTOR WALL WASH PAR20</p>   <p><b>REFLECTOR FINISH:</b> CL, RG, W, MB, CP, SN</p> <p><b>TRIM/RING FINISH:</b> WH</p> <p>8"</p>
<p><b>B650WH</b> DESIGNER WALL WASH</p>   <p><b>TRIM/RING FINISH:</b> WH</p> <p>8"</p>	<p><b>B622RG-WH</b> R/PAR30 WALL WASH REFLECTOR</p>   <p><b>REFLECTOR FINISH:</b> CL, RG, W, MB, CP, SN, SHZ</p> <p><b>COVER FINISH:</b> WH</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> <p>7-1/4"</p>	<p><b>B625CL-WH</b> A-19 CONE REFLECTOR WALL WASH</p>   <p><b>REFLECTOR FINISH:</b> CL, RG, W, MB, CP, SN, SHZ</p> <p><b>COVER FINISH:</b> WH</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> <p>7-1/4"</p>	<p><b>B624W-CL</b> CONE REFLECTOR BAFFLE WALL WASH</p>   <p><b>BAFFLE FINISH:</b> W, P</p> <p><b>REFLECTOR FINISH:</b> CL, RG</p> <p><b>COVER FINISH:</b> WH</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> <p>7-1/4"</p>
<p><b>B681CP-WH</b> SQUARE BAFFLE TRIM</p>   <p><b>BAFFLE FINISH:</b> W, P, SN, CP, BZ</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP</p> <p>7-1/2"</p>	<p><b>B687CP-WH</b> SQUARE REFLECTOR TRIM</p>   <p><b>REFLECTOR FINISH:</b> CL, RG, W, MB, SN, CP</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP</p> <p>7-1/2"</p>	<p><b>B682WH</b> SQUARE EYEBALL TRIM</p>   <p><b>TRIM/RING FINISH:</b> WH</p> <p>7-1/2"</p>	<p><b>B693WH</b> SQUARE PAR30 GIMBAL TRIM</p>   <p><b>TRIM/RING FINISH:</b> WH</p> <p>7-1/2"</p>
<p><b>B688WH</b> SQUARE ALBALITE SHOWER TRIM</p>   <p><b>LENS:</b> WHITE</p> <p><b>TRIM/RING FINISH:</b> WH</p> <p>7-1/2"</p> <p>FOR WET LOCATION</p>	<p><b>B685WH</b> SQUARE FRESNEL SHOWER TRIM</p>   <p><b>LENS:</b> CLEAR</p> <p><b>TRIM/RING FINISH:</b> WH</p> <p>7-1/2"</p> <p>FOR WET LOCATION</p>	<p><b>B696WH</b> SQUARE DROP OIPAL SHOWER TRIM</p>   <p><b>LENS:</b> WHITE</p> <p><b>TRIM/RING FINISH:</b> WH</p> <p>7-1/2"</p> <p>FOR WET LOCATION</p>	<p><b>B689WH</b> SQUARE DESIGNER CONE SHOWER LENS</p>   <p><b>LENS:</b> FROSTED</p> <p><b>TRIM/RING FINISH:</b> WH</p> <p>7-1/2"</p> <p>FOR WET LOCATION</p>

# 6" Incandescent Trims

( LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:




**B680WH**  
**SQUARE DESIGNER POINT LENS**



**LENS:**  
FROSTED/CLEAR

**TRIM/RING FINISH:**  
WH

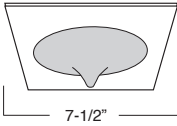

BAFFLE		REFLECTOR		TRIM RING	
<b>W</b>	White	<b>CL</b>	Chrome	<b>WH</b>	White
<b>P</b>	Black	<b>RG</b>	Gold	<b>BK</b>	Black
<b>SN</b>	Satin Nickel	<b>W</b>	White	<b>SN</b>	Satin Nickel
<b>CP</b>	Copper	<b>MB</b>	Black	<b>CP</b>	Copper
<b>BZ</b>	Bronze	<b>CP</b>	Copper	<b>CH</b>	Chrome
		<b>SN</b>	Satin Nickel	<b>PB</b>	Polish Brass
				<b>BZ</b>	Bronze

*\*For custom baffle, reflector, trim ring, glass color and lens options, please consult factory.*



# B6RIC

## 6" Universal IC Remodel Housing

LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30



DESIGNED FOR 2" X 8" JOIST CONSTRUCTION

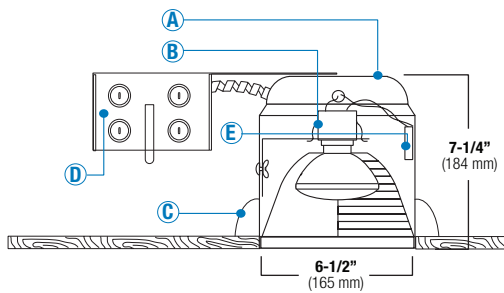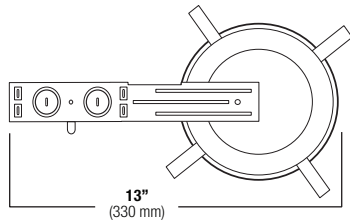

ITEM SELECTOR: (Please check the boxes below for the option desired)

TYPE	AIR-SHUT	OPTION	TRIM TYPE	BAFFLE	REFLECTOR	TRIM/RING	GLASS					
B6RIC	<input type="checkbox"/> AT	<input type="checkbox"/> (W) With quick connects	<input type="checkbox"/> B630	<input type="checkbox"/> B609	<input type="checkbox"/> B606L	<input type="checkbox"/> B676	<input type="checkbox"/> B651	<input type="checkbox"/> B688	<input type="checkbox"/> W	<input type="checkbox"/> CL	<input type="checkbox"/> WH	<input type="checkbox"/> Green
			<input type="checkbox"/> B620	<input type="checkbox"/> B619	<input type="checkbox"/> B635	<input type="checkbox"/> B612	<input type="checkbox"/> B611	<input type="checkbox"/> B685	<input type="checkbox"/> P	<input type="checkbox"/> RG	<input type="checkbox"/> BK	<input type="checkbox"/> Yellow
			<input type="checkbox"/> B631	<input type="checkbox"/> B646	<input type="checkbox"/> B636	<input type="checkbox"/> B645	<input type="checkbox"/> B647	<input type="checkbox"/> B696	<input type="checkbox"/> SN	<input type="checkbox"/> W	<input type="checkbox"/> SN	<input type="checkbox"/> Pink
			<input type="checkbox"/> AF637	<input type="checkbox"/> B616	<input type="checkbox"/> B642	<input type="checkbox"/> B648	<input type="checkbox"/> B644	<input type="checkbox"/> B689	<input type="checkbox"/> CP	<input type="checkbox"/> MB	<input type="checkbox"/> CP	<input type="checkbox"/> Brown
			<input type="checkbox"/> AF631	<input type="checkbox"/> B663	<input type="checkbox"/> B641	<input type="checkbox"/> B652	<input type="checkbox"/> B650	<input type="checkbox"/> B680	<input type="checkbox"/> BZ	<input type="checkbox"/> BZ	<input type="checkbox"/> CH	<input type="checkbox"/> Navy Blue
			<input type="checkbox"/> AF639	<input type="checkbox"/> B673	<input type="checkbox"/> B656	<input type="checkbox"/> B603	<input type="checkbox"/> B622		<input type="checkbox"/> CP	<input type="checkbox"/> CP	<input type="checkbox"/> PB	<input type="checkbox"/> Orange
			<input type="checkbox"/> AF640	<input type="checkbox"/> B683	<input type="checkbox"/> B657	<input type="checkbox"/> B615	<input type="checkbox"/> B625		<input type="checkbox"/> SN	<input type="checkbox"/> SN	<input type="checkbox"/> BZ	<input type="checkbox"/> Blue
			<input type="checkbox"/> AF632	<input type="checkbox"/> B601	<input type="checkbox"/> B637	<input type="checkbox"/> B633	<input type="checkbox"/> B624		<input type="checkbox"/> SHZ			<input type="checkbox"/> White
			<input type="checkbox"/> B610	<input type="checkbox"/> B601L	<input type="checkbox"/> B643	<input type="checkbox"/> B649	<input type="checkbox"/> B681					<input type="checkbox"/> Red
			<input type="checkbox"/> B607	<input type="checkbox"/> B605	<input type="checkbox"/> B658	<input type="checkbox"/> AF633	<input type="checkbox"/> B687					
			<input type="checkbox"/> B608	<input type="checkbox"/> B605L	<input type="checkbox"/> B659	<input type="checkbox"/> B225	<input type="checkbox"/> B682					
			<input type="checkbox"/> B602	<input type="checkbox"/> B606	<input type="checkbox"/> B675	<input type="checkbox"/> B653	<input type="checkbox"/> B693					

### Specifications:

B6RIC    AIR-SHUT    OPTION    TRIM TYPE    BAFFLE    REFLECTOR    TRIM/RING    GLASS

BAFFLE	REFLECTOR	TRIM/RING
W White	CL Chrome	WH White
P Black	RG Gold	BK Black
SN Satin Nickel	W White	SN Satin Nickel
CP Copper	MB Black	CP Copper
BZ Bronze	BZ Bronze	CH Chrome
	CP Copper	PB Polish Brass
	SN Satin Nickel	BZ Bronze
	SHZ Satin Haze	

Sample of Catalog Number: B6RIC-AT-W-B630-W-WH

\*For custom baffle, reflector, trim ring, glass color and lens options, please consult factory.



Submittal form is available @ [www.iuseelite.com](http://www.iuseelite.com)  
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions subject to change without notice.

REV: ELITE LIGHTING-SPEC-06-29-2011

Catalog Number:

Project Name:

Type:

Note:



### DESCRIPTION

Thermally protected, IC rated specification grade remodel recessed housing. For remodeling installations where housing will be in direct contact with insulation. For fast and easy installation in existing plaster or mechanical ceilings from 1/2" to 1-3/8" thick. Four remodel clips are easily retractable for fixture removal if necessary. Junction box is provided with eight 1/2" KO's and four Romex knockouts with strain relief. Accommodates up to 75W PAR30, BR30, and A19 lamps.

### SPECIFICATION


**A. HOUSING** - Die-formed, all aluminum construction for maximum heat dissipation and rust protection.

**B. SOCKET** - Medium base screw shell porcelain socket preinstalled on adjustable mounting bracket is designed to allow usage of different lamp types, as well as proper and consistent lamp positioning.

**C. INSTALLATION** - Four preinstalled spring clips which secure the housing firmly into ceiling to accommodate different ceiling thicknesses from 1/2" to 1-3/8".

**D. JUNCTION BOX** - UL listed for through-branch circuit wiring, provided with eight 1/2" KO's and four Romex knockouts with strain relief.

**E. THERMAL PROTECTION** - Standard thermal protection device guards against improper installation, overlamping and misuse of insulation material.

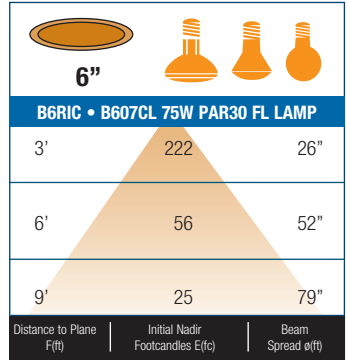

BEAM DIA. MEASURED AT 50% OF NADIR F.C.

### FEATURES

- Thermally Protected remodel IC housing.
- Dependable, favorable design and effortless installation.
- Unit slips through 6-1/2" ceiling opening.
- Four preinstalled spring clips which secure the housing firmly into ceiling to accommodate different ceiling thickness from 1/2" to 1-3/8".
- Can be installed from below the ceiling.
- 7-1/4" height allows use in 2" x 8" joist construction.
- Wire through junction box.
- Adjustable socket bracket.
- Preinstalled socket cap provides electrical contact protection against dust, paint and over spray.

### OPTIONS

#### AIR-SHUT

- Gasket to prevent air flow from heated or air conditioned spaces.
- Meets all national air flow requirements.

# 6" Incandescent Trims

(LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)



Catalog Number:

Project Name:

Type:

Note:

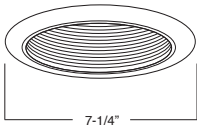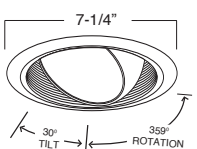

<p><b>B630CP-CP</b> METAL STEPPED BAFFLE R30/PAR30</p>  <p><b>BAFFLE FINISH:</b> W, P, SN, CP, BZ</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p>  <p>7-1/4"</p>	<p><b>B620-ORANGE</b> GLASS TRIM</p>  <p><b>GLASS FINISH:</b> GREEN, YELLOW, PINK, BROWN, NAVY BLUE, ORANGE, WHITE, RED</p>  <p>7-1/4"</p>	<p><b>B631P-WH</b> R30 PREMIUM PHENOLIC BAFFLE / METAL RING</p>  <p><b>BAFFLE FINISH:</b> W, P</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p>  <p>7-1/4"</p>	<p><b>AF637W-WH</b> SELF FLANGE AIR-SHUT BAFFLE</p>  <p><b>AVAILABLE COLOR COMBINATIONS:</b> W-WH, P-WH, P-BK, SN-SN, CP-CP, BZ-BZ</p>  <p>7-1/4"</p>
<p><b>AF631W-WH</b> SELF FLANGE AIR-SHUT BAFFLE</p>  <p><b>AVAILABLE COLOR COMBINATIONS:</b> W-WH, P-WH, P-BK, SN-SN, CP-CP, BZ-BZ</p>  <p>7-1/4"</p>	<p><b>AF639W-WH</b> SELF FLANGE AIR-SHUT BAFFLE</p>  <p><b>AVAILABLE COLOR COMBINATIONS:</b> W-WH</p> <p><b>MATT WHITE FINISH</b></p>  <p>7-1/4"</p>	<p><b>AF640W-WH</b> DEEP SELF FLANGE AIR-SHUT BAFFLE</p>  <p><b>AVAILABLE COLOR COMBINATIONS:</b> W-WH, P-WH, SN-SN, CP-CP, BZ-BZ</p>  <p>7-1/4"</p>	<p><b>AF632RG-WH</b> AIR-SHUT REFLECTOR</p>  <p><b>AVAILABLE COLOR COMBINATIONS:</b> CL-WH, CL-CH, RG-WH, W-WH, MB-WH, CP-CP, SN-SN</p>  <p>7-1/4"</p>
<p><b>B610P-RG-WH</b> CONE REFLECTOR/BAFFLE TRIM</p>  <p><b>BAFFLE FINISH:</b> W, P</p> <p><b>REFLECTOR FINISH:</b> CL, RG</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p>  <p>7-1/4"</p>	<p><b>B607CP-WH</b> REFLECTOR R/PAR30</p>  <p><b>REFLECTOR FINISH:</b> CL, RG, W, MB, CP, SN, BZ, SHZ</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p>  <p>7-1/4"</p>	<p><b>B608CL-WH</b> CONE REFLECTOR A19</p>  <p><b>REFLECTOR FINISH:</b> CL, RG, W, MB, CP, SN, BZ, SHZ</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p>  <p>7-1/4"</p>	<p><b>B602SN</b> EYEBALL</p>  <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p>  <p>8" 30° TILT 359° ROTATION</p>
<p><b>B609W-WH</b> REGRESSED EYEBALL WITH BAFFLE</p>  <p><b>BAFFLE FINISH:</b> W, P, SN, CP, BZ</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> <p><b>EYEBALL FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p>  <p>7-1/4" 30° TILT 359° ROTATION</p>	<p><b>B619RG-PB</b> REGRESSED EYEBALL WITH REFLECTOR</p>  <p><b>REFLECTOR FINISH:</b> CL, RG, W, MB, CP, SN</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> <p><b>EYEBALL FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p>  <p>7-1/4" 30° TILT 359° ROTATION</p>	<p><b>B646P-WH</b> EYEBALL WITH BAFFLE</p>  <p><b>BAFFLE FINISH:</b> W, P</p> <p><b>TRIM/RING FINISH:</b> WH</p>  <p>8" 30° TILT 359° ROTATION</p>	<p><b>B616W-WH</b> PAR20 REGRESSED EYEBALL W/ BAFFLE</p>  <p><b>BAFFLE FINISH:</b> W, P, SN, CP, BZ</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> <p><b>EYEBALL FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p>  <p>7-1/4" 30° TILT 359° ROTATION</p>



# 6" Incandescent Trims

(LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:



<p><b>B663PB</b> PAR30 GIMBAL RING</p>  <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> 	<p><b>B673P-WH</b> PAR30 BAFFLE W/ GIMBAL RING</p>  <p><b>BAFFLE FINISH:</b> W, P, SN, CP, BZ</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> 	<p><b>B683CL-WH</b> PAR30 REFLECTOR W/ GIMBAL RING</p>  <p><b>REFLECTOR FINISH:</b> CL, RG, W, MB, CP, SN</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> 	<p><b>B601CP</b> METAL ALBALITE LENS</p>  <p><b>LENS:</b> ALBALITE</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> 
<p><b>B601L</b> PLASTIC ALBALITE LENS</p>  <p><b>LENS:</b> ALBALITE</p> <p><b>TRIM/RING FINISH:</b> WHITE PLASTIC</p> 	<p><b>B605PB</b> METAL FRESNEL LENS</p>  <p><b>LENS:</b> FRESNEL</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> 	<p><b>B605L</b> PLASTIC FRESNEL LENS</p>  <p><b>LENS:</b> FRESNEL</p> <p><b>TRIM/RING FINISH:</b> WHITE PLASTIC</p> 	<p><b>B606CP</b> METAL DROP OPAL LENS</p>  <p><b>LENS:</b> DROP OPAL</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> 
<p><b>B606L</b> PLASTIC DROP OPAL LENS</p>  <p><b>LENS:</b> DROP OPAL</p> <p><b>TRIM/RING FINISH:</b> WHITE PLASTIC</p> 	<p><b>B635P-WH</b> BAFFLE W/ ALBALITE LENS</p>  <p><b>BAFFLE FINISH:</b> W, P, SN, CP, BZ</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> 	<p><b>B636W-WH</b> BAFFLE W/ FRESNEL LENS</p>  <p><b>BAFFLE FINISH:</b> W, P, SN, CP, BZ</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> 	<p><b>B642CL-WH</b> REFLECTOR W/ FRESNEL LENS</p>  <p><b>REFLECTOR FINISH:</b> CL, RG, W, MB, CP, SN, SHZ</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> 
<p><b>B641RG-WH</b> REFLECTOR W/ ALBALITE LENS</p>  <p><b>REFLECTOR FINISH:</b> CL, RG, W, MB, CP, SN, SHZ</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> 	<p><b>B656W-WH</b> BAFFLE W/ FROSTED DOME SHOWER LENS</p>  <p><b>BAFFLE FINISH:</b> W, P, SN, CP, BZ</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> 	<p><b>B657CL-WH</b> REFLECTOR W/ FROSTED DOME SHOWER LENS</p>  <p><b>REFLECTOR FINISH:</b> CL, RG, W, MB, CP, SN, SHZ</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> 	<p><b>B637W-WH</b> BAFFLE W/ DROP OPAL LENS</p>  <p><b>BAFFLE FINISH:</b> W, P, SN, CP, BZ</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> 

# 6" Incandescent Trims

(LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:




**B643RG-WH**  
REFLECTOR W/ DROP OPAL LENS



**REFLECTOR FINISH:**  
CL, RG, W, MB, CP,  
SN, SHZ

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

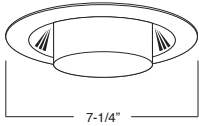


**B658CL-WH**  
REFLECTOR W/ PRISMATIC LENS



**REFLECTOR FINISH:**  
CL, RG, W, MB, CP,  
SN, SHZ

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

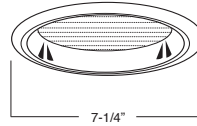


**B659CL-WH**  
REFLECTOR W/ FROSTED LENS



**REFLECTOR FINISH:**  
CL, RG, W, MB, CP,  
SN, SHZ

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

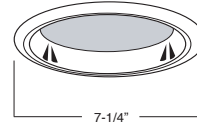


**B675W-WH**  
BAFFLE W/ PRISMATIC LENS



**BAFFLE FINISH:**  
W, P, SN, CP, BZ

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

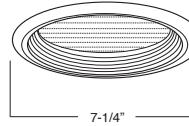


**B676W-WH**  
BAFFLE W/ FROSTED LENS



**BAFFLE FINISH:**  
W, P, SN, CP, BZ

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

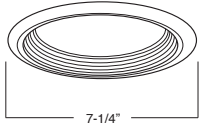


**B612WH**  
SMOOTH FROST DOME SHOWER LENS



**LENS:**  
FROSTED

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

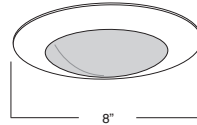


**B645WH**  
DESIGNER POINT SHOWER LENS



**LENS:**  
FROSTED/CLEAR

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

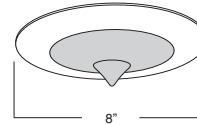


**B648WH**  
DESIGNER CONE SHOWER LENS



**LENS:**  
FROSTED

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

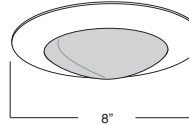


**B652WH**  
SMOOTH FROST SHOWER LENS




**LENS:**  
FROSTED


**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

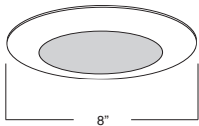

**B603CP**  
R/PAR30 OPEN TRIM

 


**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ

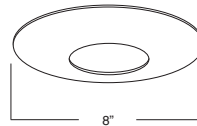

**B615WH**  
DESIGNER PINHOLE




**TRIM/RING FINISH:**  
WH, BK

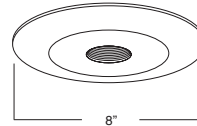

**B633WH**  
R/PAR30 SPLAY TRIM



**TRIM/RING FINISH:**  
WH, BK

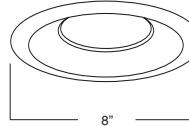


**B649RG-WH**  
PAR20 REFLECTOR




**REFLECTOR FINISH:**  
CL, RG, W, MB,  
CP, SN

**TRIM/RING FINISH:**  
WH, BK

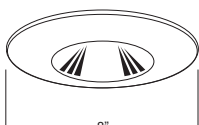

**AF633CH**  
R/PAR30 OPEN TRIM

 

**TRIM/RING FINISH:**  
WH, BK, SN, CP, CH,  
PB, BZ




**B225WH**  
OPEN TRIM STEPPED BAFFLE




**BAFFLE FINISH:**  
W, P

**TRIM/RING FINISH:**  
WH

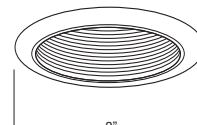


**B653W-WH**  
BAFFLE WITH BAFFLE

 

**BAFFLE FINISH:**  
W, P

**TRIM/RING FINISH:**  
WH, BK, SN, CP,  
CH, PB

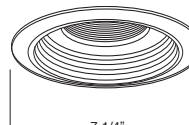

# 6" Incandescent Trims

(LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:



<p><b>B651P-WH</b> PAR20 STEPPED BAFFLE</p>   <p><b>BAFFLE FINISH:</b> W, P, SN, CP, BZ</p> <p><b>TRIM/RING FINISH:</b> WH, BK</p> <p>8"</p>	<p><b>B611W-WH</b> PAR30 BAFFLE WALL WASH</p>   <p><b>AVAILABLE COLOR COMBINATIONS:</b> W-WH, P-WH, SN-SN, CP-CP, BZ-BZ</p> <p><b>COVER FINISH:</b> WH, BK</p> <p>7-1/4"</p>	<p><b>B647P-WH</b> DESIGNER BAFFLE WALL WASH PAR20</p>   <p><b>BAFFLE FINISH:</b> W, P, SN, CP, BZ</p> <p><b>TRIM/RING FINISH:</b> WH</p> <p>8"</p>	<p><b>B644RG-WH</b> DESIGNER REFLECTOR WALL WASH PAR20</p>   <p><b>REFLECTOR FINISH:</b> CL, RG, W, MB, CP, SN</p> <p><b>TRIM/RING FINISH:</b> WH</p> <p>8"</p>
<p><b>B650WH</b> DESIGNER WALL WASH</p>   <p><b>TRIM/RING FINISH:</b> WH</p> <p>8"</p>	<p><b>B622RG-WH</b> R/PAR30 WALL WASH REFLECTOR</p>   <p><b>REFLECTOR FINISH:</b> CL, RG, W, MB, CP, SN, SHZ</p> <p><b>COVER FINISH:</b> WH</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> <p>7-1/4"</p>	<p><b>B625CL-WH</b> A-19 CONE REFLECTOR WALL WASH</p>   <p><b>REFLECTOR FINISH:</b> CL, RG, W, MB, CP, SN, SHZ</p> <p><b>COVER FINISH:</b> WH</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> <p>7-1/4"</p>	<p><b>B624W-CL</b> CONE REFLECTOR BAFFLE WALL WASH</p>   <p><b>BAFFLE FINISH:</b> W, P</p> <p><b>REFLECTOR FINISH:</b> CL, RG</p> <p><b>COVER FINISH:</b> WH</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP, CH, PB, BZ</p> <p>7-1/4"</p>
<p><b>B681CP-WH</b> SQUARE BAFFLE TRIM</p>   <p><b>BAFFLE FINISH:</b> W, P, SN, CP, BZ</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP</p> <p>7-1/2"</p>	<p><b>B687CP-WH</b> SQUARE REFLECTOR TRIM</p>   <p><b>REFLECTOR FINISH:</b> CL, RG, W, MB, SN, CP</p> <p><b>TRIM/RING FINISH:</b> WH, BK, SN, CP</p> <p>7-1/2"</p>	<p><b>B682WH</b> SQUARE EYEBALL TRIM</p>   <p><b>TRIM/RING FINISH:</b> WH</p> <p>7-1/2"</p>	<p><b>B693WH</b> SQUARE PAR30 GIMBAL TRIM</p>   <p><b>TRIM/RING FINISH:</b> WH</p> <p>7-1/2"</p>
<p><b>B688WH</b> SQUARE ALBALITE SHOWER TRIM</p>   <p><b>LENS:</b> WHITE</p> <p><b>TRIM/RING FINISH:</b> WH</p> <p>7-1/2"</p> <p>FOR WET LOCATION</p>	<p><b>B685WH</b> SQUARE FRESNEL SHOWER TRIM</p>   <p><b>LENS:</b> CLEAR</p> <p><b>TRIM/RING FINISH:</b> WH</p> <p>7-1/2"</p> <p>FOR WET LOCATION</p>	<p><b>B696WH</b> SQUARE DROP OIPAL SHOWER TRIM</p>   <p><b>LENS:</b> WHITE</p> <p><b>TRIM/RING FINISH:</b> WH</p> <p>7-1/2"</p> <p>FOR WET LOCATION</p>	<p><b>B689WH</b> SQUARE DESIGNER CONE SHOWER LENS</p>   <p><b>LENS:</b> FROSTED</p> <p><b>TRIM/RING FINISH:</b> WH</p> <p>7-1/2"</p> <p>FOR WET LOCATION</p>

# 6" Incandescent Trims

( LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:




**B680WH**  
**SQUARE DESIGNER POINT LENS**



**LENS:**  
FROSTED/CLEAR

**TRIM/RING FINISH:**  
WH

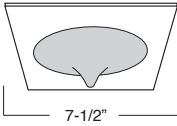

BAFFLE		REFLECTOR		TRIM RING	
<b>W</b>	White	<b>CL</b>	Chrome	<b>WH</b>	White
<b>P</b>	Black	<b>RG</b>	Gold	<b>BK</b>	Black
<b>SN</b>	Satin Nickel	<b>W</b>	White	<b>SN</b>	Satin Nickel
<b>CP</b>	Copper	<b>MB</b>	Black	<b>CP</b>	Copper
<b>BZ</b>	Bronze	<b>CP</b>	Copper	<b>CH</b>	Chrome
		<b>SN</b>	Satin Nickel	<b>PB</b>	Polish Brass
				<b>BZ</b>	Bronze

*\*For custom baffle, reflector, trim ring, glass color and lens options, please consult factory.*