



BC-M CONDUIT TO BEAM CLAMP, 1/2", 3/4" EMT, 1/2", 3/4" RIGID/PIPE,
0.709"–1.181" OD, 0.5" MAX FLANGE

CATALOG NUMBER

BC812M



CERTIFICATIONS




FEATURES

- Easy installation to beam flanges
- Eliminates offset bending conduit
- Conduit clip rotates 360 degrees

PRODUCT ATTRIBUTES

- Material: Spring Steel
- Finish: nVent CADDY Armour
- EMT Conduit Size: 1/2";3/4"
- Rigid Conduit/Pipe Size: 1/2";3/4"
- Outer Diameter (OD): 0.710" - 1.18"
- Flange Thickness (FT): 1/2" Max
- Torque (TQ): 20 ft·lbf
- Static Load (F): 100lb

DIAGRAMS

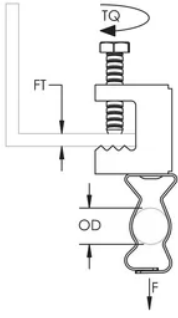

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



nVent.com

Our powerful portfolio of brands:

CADDY ERICO HOFFMAN RAYCHEM SCHROFF

TRACER



BC-M CONDUIT TO BEAM CLAMP, 1/2", 3/4" EMT, 1/2", 3/4" RIGID/PIPE,
0.709"–1.181" OD, 0.5" MAX FLANGE

CATALOG NUMBER

BC812M



CERTIFICATIONS




FEATURES

- Easy installation to beam flanges
- Eliminates offset bending conduit
- Conduit clip rotates 360 degrees

PRODUCT ATTRIBUTES

- Material: Spring Steel
- Finish: nVent CADDY Armour
- EMT Conduit Size: 1/2";3/4"
- Rigid Conduit/Pipe Size: 1/2";3/4"
- Outer Diameter (OD): 0.710" - 1.18"
- Flange Thickness (FT): 1/2" Max
- Torque (TQ): 20 ft·lbf
- Static Load (F): 100lb

DIAGRAMS

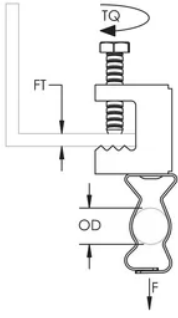

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com **CADDY ERICO HOFFMAN RAYCHEM SCHROFF**
TRACER