

# Class CC, Type M and Class G Fuse Blocks

## BC Series



### Specifications

**Description:** Class CC fuse blocks for use with Class CC fuses ( Bussmann LP-CC, KTK-R, and FNQ-R).

**Dimensions:** See Data Sheet 1105

**Poles:** 1 to 3

### Ratings:

Volts: — 600V  
Amps: — 1/0-30A  
SCCR:— 200kA RMS Sym.

**Agency Information:** CE, UL Listed (Guide IZLT, File E14853), CSA (Class 6225-01, File 47235)

**Flammability Rating:** UL 94V0

**DIN-Rail Adapters:** See page 413 for DRA-1 & DRA-2

### Catalog Numbers

Screw	Terminal Type				Poles
	Screw with Quick Connect*	Pressure Plate	Pressure Plate w/ Quick Connect*	Box Lug	
BC6031S	BC6031SQ	BC6031P	BC6031PQ	BC6031B	1
BC6032S	BC6032SQ	BC6032P	BC6032PQ	BC6032B	2
BC6033S	BC6033SQ	BC6033P	BC6033PQ	BC6033B	3

Data Sheet: 1105

## BCCM Series

**Description:** 3-pole fuse block for use with (2) Class CC fuses and (1) 1/2" x 1 1/2" fuse

### Catalog Numbers


Catalog Numbers	Terminal Type
BCCM6033SQ	Screw with Quick-Connect*
BCCM6033PQ	Pressure Plate w/Quick-Connect*

\*Quick-connect terminal rated for 20A max.

### Recommended Cover Puller

- PF1-WH (White)
- PF1-BK (Black)

## BM Series Type M

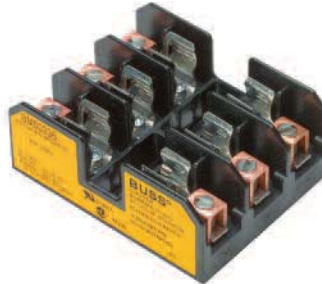

### Specifications

**Description:** Supplementary fuse blocks for use with any 1/2" x 1 1/2" fuses (Bussmann KTK, PVM, FNQ, FNM, BAF, PV, and AGU).

**Dimensions:** See Data Sheet 1104

**Poles:** 1 to 3

**DIN-Rail Adapters:** See page 413 for DRA-1 & DRA-2

### Ratings:

Volts: — 600Vac/dc  
Amps: — 1/0-30A  
SCCR:— 10kA RMS Sym.

**Agency Information:** CE, UL Recognized (Guide IZLT2, File E14853), CSA (Class 6225-01, File 47235).

**Flammability Rating:** UL 94V0.

### Catalog Numbers

Screw with Quick Connect*	Terminal Type			Poles
	Pressure Plate w/ Quick Connect*	Box Lug		
BM6031SQ	BM6031PQ	BM6031B		1
BM6032SQ	BM6032PQ	BM6032B		2
BM6033SQ	BM6033PQ	BM6033B		3

### Recommended Cover Puller

- PF1-WH (White)
- PF1-BK (Black)

Data Sheet: 1104

## BG & G Series



### Specifications

**Description:** Class G fuse blocks for use with Class G fuses (Bussmann SC).

**Dimensions:** See Data Sheet 1106

**Poles:** 1 to 3

### Ratings:

Volts: — 600Vac/dc (0-20A)  
— 480Vac/dc (25-60A)  
Amps: — 1-60A (See Catalog Numbers table)

SCCR: — 100kA RMS Sym.

**Agency Information:** CE, UL Listed 35-60A (Guide IZLT, File E14853), UL Recognized 1-30A, (Guide IZLT2, File E14853), CSA (Class 6225-01, File 47235).

**DIN-Rail Adapters:** See page 413 for DRA-1 & DRA-2.

### Catalog Numbers

Screw with Quick Connect*	Terminal Type				Amps	Poles
	Pressure Plate w/ Quick Connect*	Box Lug	Box Lug w/retaining clip			
BG3011SQ	BG3011PQ	BG3011B	—	—	1	
BG3012SQ	BG3012PQ	BG3012B	—	—	1-15	
BG3013SQ	BG3013PQ	BG3013B	—	—	3	
BG3021SQ	BG3021PQ	BG3021B	—	—	1	
BG3022SQ	BG3022PQ	BG3022B	—	—	20	
BG3023SQ	BG3023PQ	BG3023B	—	—	3	
BG3031S	BG3031P	BG3031B	—	—	1	
BG3032S	BG3032P	BG3032B	—	—	25-30	
BG3033S	BG3033P	BG3033B	—	—	3	
—	—	—	G30060-1CR	—	1	
—	—	—	G30060-2CR	—	35-60	
—	—	G30060-3C	G30060-3CR	—	3	

### Recommended Cover Puller

- PF1-WH (White)
- PF1-BK (Black)

Data Sheet: 1106

# Class CC, Type M and Class G Fuse Blocks

## BC Series



### Specifications

**Description:** Class CC fuse blocks for use with Class CC fuses ( Bussmann LP-CC, KTK-R, and FNQ-R).

**Dimensions:** See Data Sheet 1105

**Poles:** 1 to 3

### Ratings:

Volts: — 600V  
Amps: — 1/0-30A  
SCCR:— 200kA RMS Sym.

**Agency Information:** CE, UL Listed (Guide IZLT, File E14853), CSA (Class 6225-01, File 47235)

**Flammability Rating:** UL 94V0

**DIN-Rail Adapters:** See page 413 for DRA-1 & DRA-2

### Catalog Numbers

Screw	Terminal Type				Poles
	Screw with Quick Connect*	Pressure Plate	Pressure Plate w/ Quick Connect*	Box Lug	
BC6031S	BC6031SQ	BC6031P	BC6031PQ	BC6031B	1
BC6032S	BC6032SQ	BC6032P	BC6032PQ	BC6032B	2
BC6033S	BC6033SQ	BC6033P	BC6033PQ	BC6033B	3

Data Sheet: 1105

## BCCM Series

**Description:** 3-pole fuse block for use with (2) Class CC fuses and (1) 1/2" x 1 1/2" fuse

### Catalog Numbers

Catalog Numbers	Terminal Type
BCCM6033SQ	Screw with Quick-Connect*
BCCM6033PQ	Pressure Plate w/Quick-Connect*

\*Quick-connect terminal rated for 20A max.

### Recommended Cover Puller

- PF1-WH (White)
- PF1-BK (Black)

## BM Series Type M



### Specifications

**Description:** Supplementary fuse blocks for use with any 1/2" x 1 1/2" fuses (Bussmann KTK, PVM, FNQ, FNM, BAF, PV, and AGU).

**Dimensions:** See Data Sheet 1104

**Poles:** 1 to 3

**DIN-Rail Adapters:** See page 413 for DRA-1 & DRA-2

### Ratings:

Volts: — 600Vac/dc  
Amps: — 1/0-30A  
SCCR:— 10kA RMS Sym.

**Agency Information:** CE, UL Recognized (Guide IZLT2, File E14853), CSA (Class 6225-01, File 47235).

**Flammability Rating:** UL 94V0.

### Catalog Numbers

Screw with Quick Connect*	Terminal Type			Poles
	Pressure Plate w/ Quick Connect*	Box Lug	Box Lug	
BM6031SQ	BM6031PQ	BM6031B	—	1
BM6032SQ	BM6032PQ	BM6032B	—	2
BM6033SQ	BM6033PQ	BM6033B	—	3

### Recommended Cover Puller

- PF1-WH (White)
- PF1-BK (Black)

Data Sheet: 1104

## BG & G Series



### Specifications

**Description:** Class G fuse blocks for use with Class G fuses (Bussmann SC).

**Dimensions:** See Data Sheet 1106

**Poles:** 1 to 3

### Ratings:

Volts: — 600Vac/dc (0-20A)  
— 480Vac/dc (25-60A)  
Amps: — 1-60A (See Catalog Numbers table)

SCCR: — 100kA RMS Sym.

**Agency Information:** CE, UL Listed 35-60A (Guide IZLT, File E14853), UL Recognized 1-30A, (Guide IZLT2, File E14853), CSA (Class 6225-01, File 47235).

**DIN-Rail Adapters:** See page 413 for DRA-1 & DRA-2.

### Catalog Numbers

Screw with Quick Connect*	Terminal Type				Amps	Poles
	Pressure Plate w/ Quick Connect*	Box Lug	Box Lug w/retaining clip	Box Lug		
BG3011SQ	BG3011PQ	BG3011B	—	—	1	
BG3012SQ	BG3012PQ	BG3012B	—	—	2	
BG3013SQ	BG3013PQ	BG3013B	—	—	3	
BG3021SQ	BG3021PQ	BG3021B	—	—	1	
BG3022SQ	BG3022PQ	BG3022B	—	—	2	
BG3023SQ	BG3023PQ	BG3023B	—	—	3	
BG3031S	BG3031P	BG3031B	—	—	1	
BG3032S	BG3032P	BG3032B	—	—	2	
BG3033S	BG3033P	BG3033B	—	—	3	
—	—	—	G30060-1CR	—	1	
—	—	—	G30060-2CR	—	2	
—	—	G30060-3C	G30060-3CR	—	3	

### Recommended Cover Puller

- PF1-WH (White)
- PF1-BK (Black)

Data Sheet: 1106