


Eaton BR2030L150

Catalog Number: BR2030L150

Eaton BR style 1-inch loadcenter, main lug, no feed-thru lugs, includes BREQS125 hold-down screw, 150A, single-phase, 30-pole, 30 circuits, 20 spaces, 120/240V, #1-300 kcmil Cu/Al at 60°C or 75°C wire, NEMA 1 enclosure, c2 box size

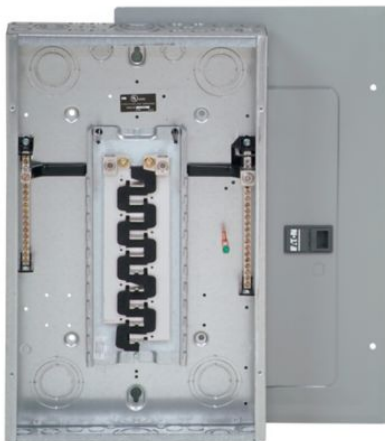

General specifications

Product Name	Catalog Number
Eaton BR main lug loadcenter	BR2030L150
UPC	Product Length/Depth
786676447201	23.1 in
Product Height	Product Width
3.9 in	14.3 in
Product Weight	Warranty
24 lb	10 year
Certifications	Catalog Notes
UL 67 UL 50	Has notch for brhdk125 hold-down kit.

defaultTaxonomyAttributeLabel

Special features

No feed-thru lugs, includes BREQS125 hold-down screw

Type

Main lug

Amperage Rating

150 A

Bus material

Aluminum

Cover

Cover included

Main circuit breaker

BWH

Mounting

Combination

Number of circuits

30

Number of spaces

20

Phase

Single-phase

Used with

Type BR 1-inch breakers

Voltage rating

120/240V

Wire size

#1 AWG-300 kcmil Cu/Al

Box size

C2

Enclosure

NEMA 1

Enclosure material

Metallic

Interrupt rating

25 kAIC

Resources

Brochures

[Loadcenters and Circuit Breakers](#)

[Type BR Arc Fault Circuit Breakers and Loadcenters](#)

Catalogs

[Eaton's Volume 1—Residential and Light Commercial](#)

Drawings

[Dimensional Drawing - BR 1 LOADCENTER, MAIN LUG ONLY, INDOOR NEMA 1, 120/240 VAC, 1 PHASE](#)

Installation instructions

[Cutler-Hammer Type CH and BR Loadcenters - Instructions](#)

Specifications and datasheets

[Eaton Specification Sheet - BR2030L150](#)

Number of wires

3



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)