


Specifications

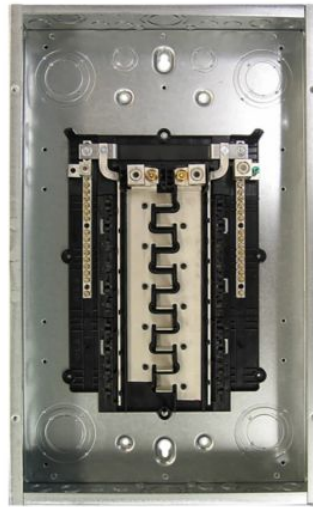

Eaton BRP20L200

Eaton Eaton BR main lug loadcenter, Main lug only, 200 A, X3, Aluminum, NEMA 1, Metallic, 10kAIC, CSR2200, NEMA1, 40 Circuits, Twenty-four pole, 20 Spaces, Two hots, a neutral, and a ground, Single-phase, Type BR 1-inch breakers, 120/240V, #1–300 kcmil

General specifications

PRODUCT NAME	Eaton BR main lug loadcenter
CATALOG NUMBER	BRP20L200
UPC	786689053260
PRODUCT LENGTH/DEPTH	23 in
PRODUCT HEIGHT	3.88 in
PRODUCT WIDTH	14.31 in
PRODUCT WEIGHT	21 lb
WARRANTY	10 year
CERTIFICATIONS	UL 50 UL 67



Powering Business Worldwide

Product specifications

TYPE	MLO
AMPERAGE RATING	200 A
BUS MATERIAL	Aluminum
COVER	Cover included
MAIN CIRCUIT BREAKER	CSR2200
NUMBER OF CIRCUITS	40
NUMBER OF POLES	Single-pole
NUMBER OF SPACES	20
PHASE	Single-phase
USED WITH	Type BR 1-inch breakers
VOLTAGE RATING	120/240V
BOX SIZE	X3
ENCLOSURE	NEMA 1
ENCLOSURE MATERIAL	Metallic
INTERRUPT RATING	10 kAIC
NEMA RATING	NEMA 1
NUMBER OF WIRES	Two hots, neutral and ground

Resources

SPECIFICATIONS AND DATASHEETS	Eaton Specification Sheet - BRP20L200
WARRANTY GUIDES	Eaton type BR circuit breaker limited warranty June 2024

PROJECT NAME:

PROJECT NUMBER:

PREPARED BY:

DATE:



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com


© 2025 Eaton. All Rights Reserved.

Eaton is a registered trademark. Follow us on social media to get the latest product and support information.

All other trademarks are property of their respective owners.



Specifications

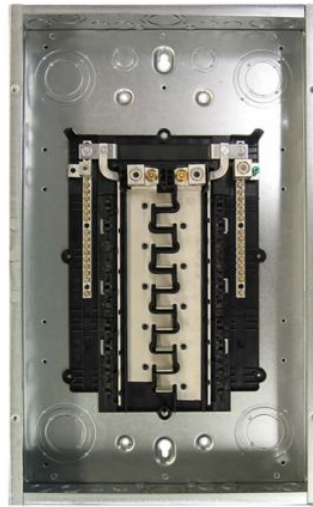

Eaton BRP20L200

Eaton Eaton BR main lug loadcenter, Main lug only, 200 A, X3, Aluminum, NEMA 1, Metallic, 10kAIC, CSR2200, NEMA1, 40 Circuits, Twenty-four pole, 20 Spaces, Two hots, a neutral, and a ground, Single-phase, Type BR 1-inch breakers, 120/240V, #1–300 kcmil

General specifications

PRODUCT NAME	Eaton BR main lug loadcenter
CATALOG NUMBER	BRP20L200
UPC	786689053260
PRODUCT LENGTH/DEPTH	23 in
PRODUCT HEIGHT	3.88 in
PRODUCT WIDTH	14.31 in
PRODUCT WEIGHT	21 lb
WARRANTY	10 year
CERTIFICATIONS	UL 50 UL 67



Powering Business Worldwide

Product specifications

TYPE	MLO
AMPERAGE RATING	200 A
BUS MATERIAL	Aluminum
COVER	Cover included
MAIN CIRCUIT BREAKER	CSR2200
NUMBER OF CIRCUITS	40
NUMBER OF POLES	Single-pole
NUMBER OF SPACES	20
PHASE	Single-phase
USED WITH	Type BR 1-inch breakers
VOLTAGE RATING	120/240V
BOX SIZE	X3
ENCLOSURE	NEMA 1
ENCLOSURE MATERIAL	Metallic
INTERRUPT RATING	10 kAIC
NEMA RATING	NEMA 1
NUMBER OF WIRES	Two hots, neutral and ground

Resources

SPECIFICATIONS AND DATASHEETS	Eaton Specification Sheet - BRP20L200
WARRANTY GUIDES	Eaton type BR circuit breaker limited warranty June 2024

PROJECT NAME:

PROJECT NUMBER:

PREPARED BY:

DATE:



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com

© 2025 Eaton. All Rights Reserved.

Eaton is a registered trademark. Follow us on social media to get the latest product and support information.

All other trademarks are property of their respective owners.

