

SPECIFICATION SHEET

C SERIES COMMERCIAL STYLE SPRINGWOUND AUTO OFF IN-WALL TIMER

APPLICATIONS

- Ventilating fans.
- HVAC.
- Whirlpools.
- Motors and pumps.

FEATURES

VARIABLE TIMING:

Twist knob for time ON setting. Time ON lengths from 15 minutes to 12 hour vary by model.

HOLD FEATURE:

Some models have position for constant ON.

EASY SET:

No adjustments. Just wire and go!

EASY WIRING:

No neutral required. Great for retrofit!

SWITCH TYPE:

SPDT "2 in 1" contacts wire as SPST also, except C460M and C412H are DPST.

COLOR:

Metal-brushed aluminum.

WALL PLATE:

Includes real metal wall plate with screw mounting, to add extra security for commercial applications.

SPECIFICATIONS

INPUT VOLTAGE:

125/250/277VAC, 50/60Hz.

TERMINAL SIZE:

#12AWG.

OPERATING TEMPERATURE:

32 °F to 122 °F (0 °C to 50 °C).



 
*Wallplate included

WIRING DIAGRAMS


USE FOR SPST



USE FOR SPDT



USE FOR DPST

 


ORDERING INFO

CAT. NO.	UPC CODE	HOLD FEATURE
15 MINUTE MAX.		
C515M	15501	No Hold
30 MINUTE MAX.		
C530M	15503	No Hold
60 MINUTE MAX.		
C560M	15505	No Hold
C560MH	15506	With Hold
C460M*	15011	No Hold
2 HOUR MAX.		
C502H	15507	No Hold
6 HOUR MAX.		
C506H	15511	No Hold
12 HOUR MAX.		
C512H	15513	No Hold
C512HH	15514	With Hold
C412H*	15010	No Hold

CONTACT RATINGS

TYPE	VOLTAGE (VAC)	RATING
Resistive	125	20A
	250	10A
	277	10A
Inductive	125	20A
	250	10A
	277	10A
Tungsten	125	7A
Motor	125	1HP
	250	2HP

*DPST switch type.

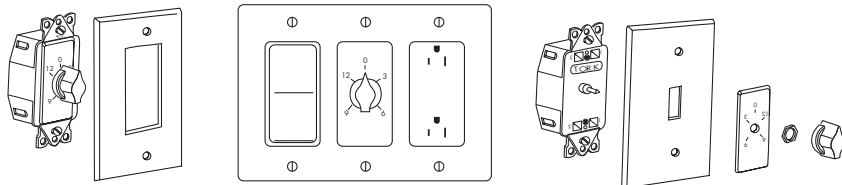

CAUTION: This timer is not to be used in precision timing applications where inaccurate timing could have dangerous consequences (i.e. sun lamp, sauna, etc.).