


# CF 54 CABLOFIL CABLE TRAY


# CABLOFIL®

INNOVATORS IN CABLE MANAGEMENT

8319 State Route 4  
 Mascoutah IL 62258  
 Phone: 800-658-4641  
 618-566-3230  
 Fax: 618-566-3250  
[www.cablofil.com](http://www.cablofil.com)

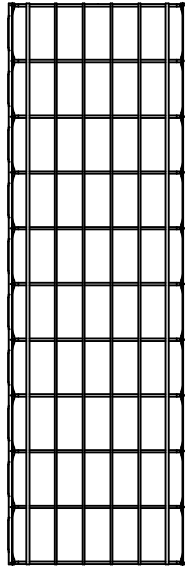


TOP

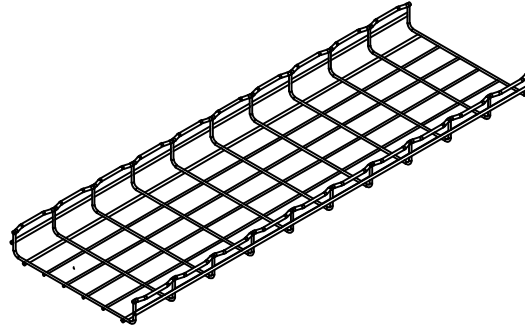



ISOMETRIC



 

FRONT



SIDE

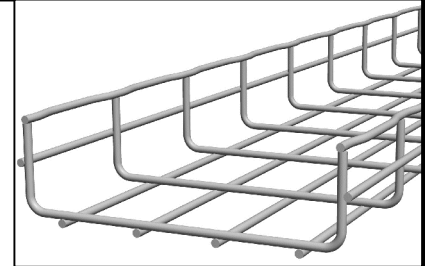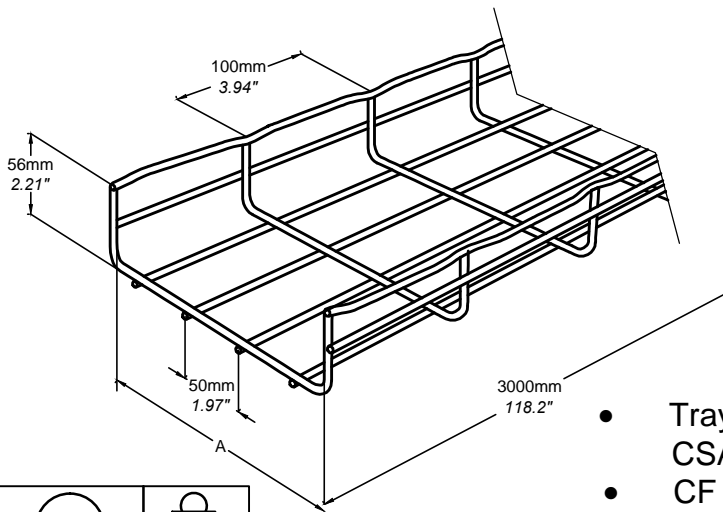

 - Tray designed per NEMA VE-1, CSA C22.2 No. 126
- CF has top wave wire (shown)
- ZF has straight top wire

|  |  |  |
|--|---|---|
|  | in  | mm  |

|                | in    | mm  | lb   |
|----------------|-------|-----|------|
| ZF* & CF54 50  | 1.967 | 50  | 5.3  |
| ZF* & CF54 100 | 3.937 | 100 | 6.5  |
| ZF* & CF54 150 | 5.904 | 150 | 7.8  |
| ZF* & CF54 200 | 7.872 | 200 | 9.0  |
| ZF* & CF54 300 | 11.81 | 300 | 13.4 |
| ZF* & CF54 400 | 15.75 | 400 | 22.8 |
| ZF* & CF54 450 | 17.71 | 450 | 25   |
| ZF* & CF54 500 | 19.68 | 500 | 24.4 |
| ZF* & CF54 550 | 21.65 | 550 | 25.9 |
| ZF* & CF54 600 | 23.62 | 600 | 27.5 |
| ZF54 750*      | 29.53 | 750 | 32.6 |
| ZF54 900*      | 35.43 | 900 | 37.7 |

\* Top Wire Is Straight Type



|    |    |      |
|----|----|------|
| BL | PE | 316L |
| EZ | GC | 304L |


|      | Material                          | Finish                        |
|------|-----------------------------------|-------------------------------|
| EZ   | Carbon Steel ASTM A510 Grade 1008 | Electroplated Zinc, ASTM B633 |
| GC   | Carbon Steel ASTM A510 Grade 1008 | Hot-Dip Galvanized ASTM A123  |
| BL   | Carbon Steel ASTM A510 Grade 1008 | Black Painted ASTM D 3451     |
| PE   | Carbon Steel ASTM A510 Grade 1008 | Custom Painted ASTM D 3451    |
| 304L | AISI TYPE 304L                    | Passivated ASTM A 380         |
| 316L | AISI TYPE 316L                    | Passivated ASTM A 380         |

# CF 54 CABLOFIL CABLE TRAY


# CABLOFIL®

INNOVATORS IN CABLE MANAGEMENT

8319 State Route 4  
 Mascoutah IL 62258  
 Phone: 800-658-4641  
 618-566-3230  
 Fax: 618-566-3250  
[www.cablofil.com](http://www.cablofil.com)

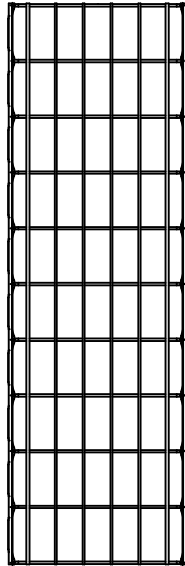


TOP

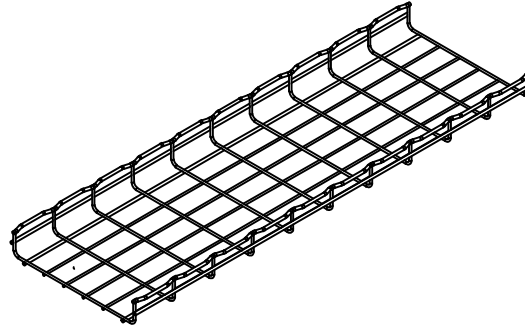



ISOMETRIC



 

FRONT



SIDE

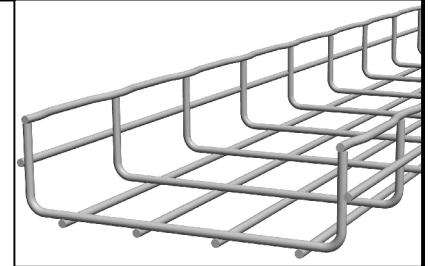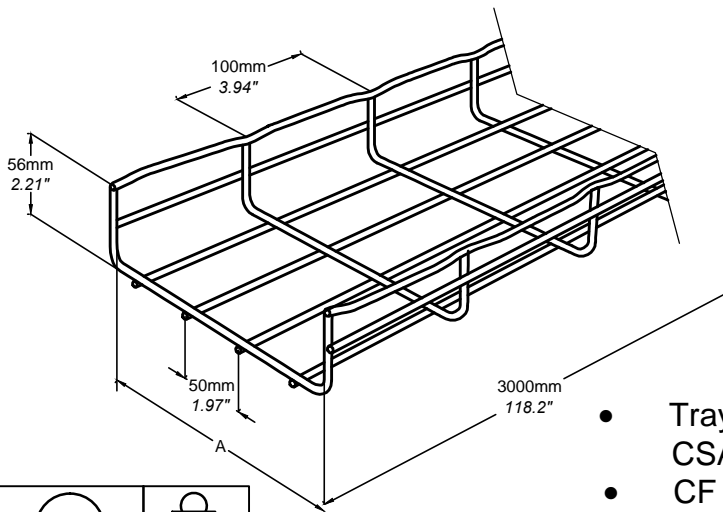

 - Tray designed per NEMA VE-1, CSA C22.2 No. 126
- CF has top wave wire (shown)
- ZF has straight top wire

|  |  |  |    |
|--|---|---|----|
|  | in  | mm  | lb |

|                |       |     |      |
|----------------|-------|-----|------|
| ZF* & CF54 50  | 1.967 | 50  | 5.3  |
| ZF* & CF54 100 | 3.937 | 100 | 6.5  |
| ZF* & CF54 150 | 5.904 | 150 | 7.8  |
| ZF* & CF54 200 | 7.872 | 200 | 9.0  |
| ZF* & CF54 300 | 11.81 | 300 | 13.4 |
| ZF* & CF54 400 | 15.75 | 400 | 22.8 |
| ZF* & CF54 450 | 17.71 | 450 | 25   |
| ZF* & CF54 500 | 19.68 | 500 | 24.4 |
| ZF* & CF54 550 | 21.65 | 550 | 25.9 |
| ZF* & CF54 600 | 23.62 | 600 | 27.5 |
| ZF54 750*      | 29.53 | 750 | 32.6 |
| ZF54 900*      | 35.43 | 900 | 37.7 |

\* Top Wire Is Straight Type



|    |    |      |
|----|----|------|
| BL | PE | 316L |
| EZ | GC | 304L |

|      | Material                          | Finish                        |
|------|-----------------------------------|-------------------------------|
| EZ   | Carbon Steel ASTM A510 Grade 1008 | Electroplated Zinc, ASTM B633 |
| GC   | Carbon Steel ASTM A510 Grade 1008 | Hot-Dip Galvanized ASTM A123  |
| BL   | Carbon Steel ASTM A510 Grade 1008 | Black Painted ASTM D 3451     |
| PE   | Carbon Steel ASTM A510 Grade 1008 | Custom Painted ASTM D 3451    |
| 304L | AISI TYPE 304L                    | Passivated ASTM A 380         |
| 316L | AISI TYPE 316L                    | Passivated ASTM A 380         |